


PN: DA-034-I-Y-A

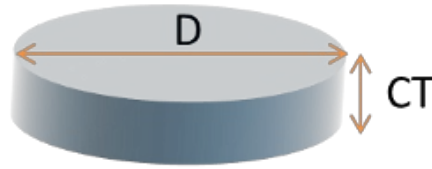

INPUT PARAMETER

Wavelength [nm]:	1064
Minimum Beam Diameter [mm]:	0.27
Beam Mode (SM/MM):	SM or MM

ELEMENT PARAMETER

Element Type:	Window
Material:	Fused Silica
Element Size [mm]:	25.4
Clear Aperture [mm]:	22.9
Thickness [mm]:	3
Coating:	AR/AR coating

OUTPUT PARAMETER

Ring Angle P2P [deg]:	1.35
Axicon Type:	Positive
Transmission efficiency:	Close to 100%
Overall Efficiency:	~ 92%
Zero-Order relative to the incident beam [%]:	<1
Remarks	High Efficiency

Holo/Or can improve the performances of this item. Please send us your requirements