
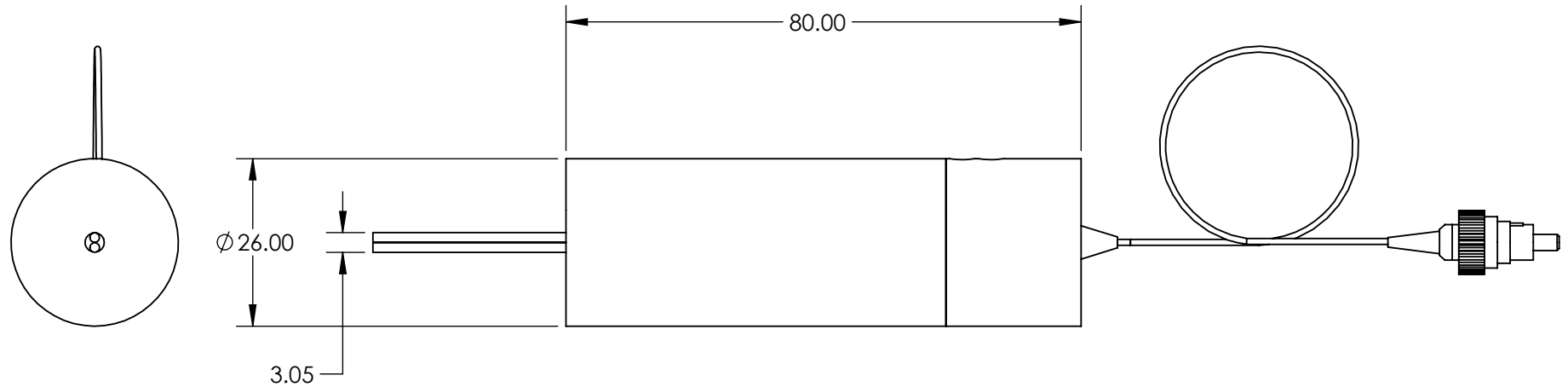


NOTES:


1. LASER CLASS:
IIIb
2. OPERATING TEMPERATURE: 15 to 30 °C
OPERATING VOLTAGE: 5V
3. OUTPUT POWER: 10mW
4. WAVELENGTH RANGE: 658±10 nm

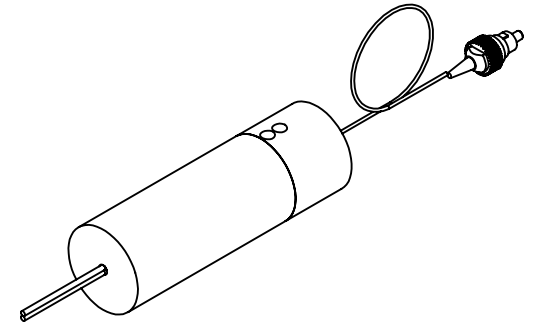

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

EO® Edmund Optics®

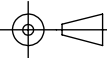THIRD ANGLE PROJECTION 		TITLE	658nm 10mW Pigtailed Laser Diode	
ALL DIMS IN	mm	DWG NO	23778	SHEET 1 OF 1