

[All Products](#) / [Imaging Lenses](#) / [M12 Lenses \(S-Mount Lenses\)](#)
TECHSPEC® Green Series M12 Lenses


- Up to 1/2", S-Mount Lens
- Up to 0.4 MegaPixels, 8.3µm Pixel Size Sensors
- Board Camera Lens Optimized for Close WD and Finite Conjugate
- 6mm to 25mm Focal Lengths

Common Specifications

General

Series:	Green Series	IR Cut Filter:	No
Imaging Lens Type:	Standard Lens		

Physical & Mechanical Properties

Iris Option:	Fixed
---------------------	-------

Optical Properties

Wavelength Range (nm):	400 - 700	Working Distance (mm):	150 - ∞
Coating Specification:	λ/4 MgF ₂ @ 580nm		


Sensor

Pixel Size (µm):	8.30
-------------------------	------

Threading & Mounting

Filter Thread:	N/A
-----------------------	-----

Technical Information

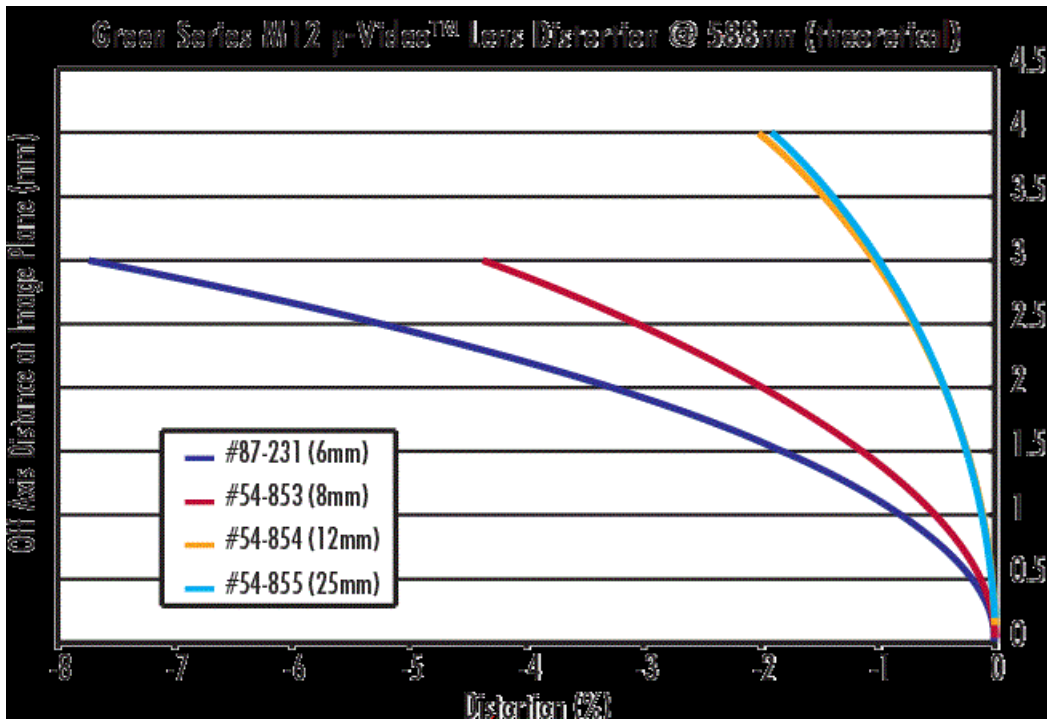

Products

FL (mm)	Aperture (f/#)	Max. Sensor Format	WD (mm)	IR Cut Filter	Stock Number	Price	Buy
6.00	f/1.9	1/3"	150 - ∞	No	#87-231	S\$114.00 Volume Pricing	20+ In Stock
6.00	f/4	1/3"	150 - ∞	No	#69-256	S\$110.00 Volume Pricing	20+ In Stock
6.00	f/5.6	1/3"	150 - ∞	No	#83-934	S\$110.00 Volume Pricing	14 In Stock
6.00	f/8	1/3"	150 - ∞	No	#83-945	S\$110.00 Volume Pricing	20+ In Stock
8.00	f/1.9	1/3"	150 - ∞	No	#54-853	S\$114.00 Volume Pricing	20+ In Stock
12.00	f/2	1/2"	150 - ∞	No	#54-854	S\$114.00 Volume Pricing	20+ In Stock
25.00	f/2.1	1/2"	150 - ∞	No	#54-855	S\$114.00 Volume Pricing	20+ In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com