


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Precision Polished Metal Coatings](#)

TECHSPEC®

Precision Optical Flat Mirrors

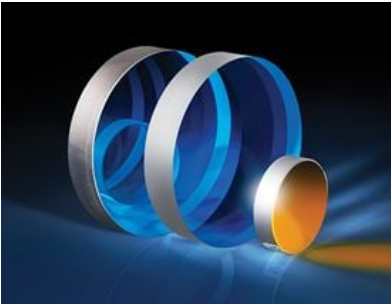

- Fused Silica and ZERODUR® Substrates
- $\lambda/10$ and $\lambda/20$ Surface Flatness
- Variety of Coating Options Offered

Common Specifications

General

Note:

Flatness is specified as Peak to Valley

Physical & Mechanical Properties

Back Surface:

Commercial Polish

Optical Properties

Surface Quality:	60-40	Coating Type:	Metal
------------------	-------	---------------	-------

Technical Information

Products

Surface Flatness (P-V)	Dia. (mm)	Substrate	Coating Specification	Coating	Thickness (mm)	Stock Number	Price	Buy
λ/10	12.70	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-319-522	S\$154.00 Volume Pricing	Contact Us
λ/20	12.70	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-400-522	S\$210.00 Volume Pricing	4 In Stock
λ/10	12.70	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-327-522	S\$168.00 Volume Pricing	1 In Stock
λ/20	12.70	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-404-522	S\$238.00 Volume Pricing	4 In Stock
λ/10	12.70	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-319-533	S\$161.00 Volume Pricing	5 In Stock
λ/20	12.70	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-400-533	S\$217.00 Volume Pricing	20+ In Stock
λ/10	12.70	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-327-533	S\$175.00 Volume Pricing	1 In Stock
λ/20	12.70	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-404-533	S\$245.00 Volume Pricing	2 In Stock
λ/10	12.70	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700-10000nm)	3.20	#43-319-566	S\$175.00 Volume Pricing	20+ In Stock
λ/20	12.70	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700-10000nm)	3.20	#43-400-566	S\$231.00 Volume Pricing	Contact Us

λ/10	12.70	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	3.20	#43-327- 566	S\$189.00 Volume Pricing	Contact Us
λ/20	12.70	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	3.20	#43-404- 566	S\$259.00 Volume Pricing	2 In Stock
λ/10	12.70	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	3.20	#43-319- 577	S\$168.00 Volume Pricing	20+ In Stock
λ/20	12.70	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	3.20	#43-400- 577	S\$224.00 Volume Pricing	Contact Us
λ/10	12.70	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	3.20	#43-327- 577	S\$182.00 Volume Pricing	Contact Us
λ/20	12.70	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	3.20	#43-404- 577	S\$252.00 Volume Pricing	2 In Stock
λ/10	25.40	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	12.70	#01-913- 522	S\$224.00 Volume Pricing	5 In Stock
λ/20	25.40	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	12.70	#43-408- 522	S\$322.00 Volume Pricing	15 In Stock
λ/10	25.40	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	12.70	#32-195- 522	S\$252.00 Volume Pricing	3 In Stock
λ/20	25.40	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	12.70	#43-412- 522	S\$336.00 Volume Pricing	Contact Us
λ/10	25.40	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	12.70	#01-913- 533	S\$231.00 Volume Pricing	3 In Stock

λ/20	25.40	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	12.70	#43-408- 533	S\$329.00 Volume Pricing	20+ In Stock
λ/10	25.40	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	12.70	#32-195- 533	S\$259.00 Volume Pricing	2 In Stock
λ/20	25.40	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	12.70	#43-412- 533	S\$343.00 Volume Pricing	1 In Stock
λ/10	25.40	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	12.70	#01-913- 566	S\$245.00 Volume Pricing	Contact Us
λ/20	25.40	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	12.70	#43-408- 566	S\$343.00 Volume Pricing	1 In Stock
λ/10	25.40	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	12.70	#32-195- 566	S\$273.00 Volume Pricing	6 In Stock
λ/20	25.40	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	12.70	#43-412- 566	S\$357.00 Volume Pricing	6 In Stock
λ/10	25.40	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	12.70	#01-913- 577	S\$238.00 Volume Pricing	4 In Stock
λ/20	25.40	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	12.70	#43-408- 577	S\$336.00 Volume Pricing	Contact Us
λ/10	25.40	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	12.70	#32-195- 577	S\$266.00 Volume Pricing	6 In Stock
λ/20	25.40	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	12.70	#43-412- 577	S\$350.00 Volume Pricing	1 In Stock

$\lambda/10$	50.80	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#01-914-522	S\$371.00 Volume Pricing	5 In Stock
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#43-416-522	S\$483.00 Volume Pricing	4 In Stock
$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#32-199-522	S\$406.00 Volume Pricing	Contact Us
$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#43-420-522	S\$553.00 Volume Pricing	4 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#01-914-533	S\$413.00 Volume Pricing	6 In Stock
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#43-416-533	S\$525.00 Volume Pricing	Contact Us
$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#32-199-533	S\$448.00 Volume Pricing	1 In Stock
$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#43-420-533	S\$595.00 Volume Pricing	6 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#01-914-566	S\$497.00 Volume Pricing	4 In Stock
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#43-416-566	S\$609.00 Volume Pricing	10 In Stock
$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#32-199-566	S\$532.00 Volume Pricing	1 In Stock

$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	12.70	#43-420-566	S\$679.00 Volume Pricing	2 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	12.70	#01-914-577	S\$483.00 Volume Pricing	Contact Us
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	12.70	#43-416-577	S\$595.00 Volume Pricing	3 In Stock
$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	12.70	#32-199-577	S\$518.00 Volume Pricing	2 In Stock
$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	12.70	#43-420-577	S\$665.00 Volume Pricing	9 In Stock
$\lambda/10$	76.20	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	19.10	#01-915-522	S\$819.00 Volume Pricing	2 In Stock
$\lambda/20$	76.20	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	19.10	#47-573-522	S\$924.00 Volume Pricing	8 In Stock
$\lambda/10$	76.20	ZERODUR®	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	19.10	#31-391-522	S\$1,022.00 Volume Pricing	1 In Stock
$\lambda/20$	76.20	ZERODUR®	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	19.10	#48-117-522	S\$1,309.00 Volume Pricing	1 In Stock
$\lambda/10$	76.20	Fused Silica	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450-650nm)	19.10	#01-915-533	S\$903.00 Volume Pricing	2 In Stock
$\lambda/20$	76.20	Fused Silica	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450-650nm)	19.10	#47-573-533	S\$1,008.00 Volume Pricing	Contact Us

λ/10	76.20	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#31-391- 533	S\$1,106.00 Volume Pricing	1 In Stock
λ/20	76.20	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#48-117- 533	S\$1,393.00 Volume Pricing	1 In Stock
λ/10	76.20	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#01-915- 566	S\$945.00 Volume Pricing	3 In Stock
λ/20	76.20	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#47-573- 566	S\$1,050.00 Volume Pricing	Contact Us
λ/10	76.20	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#31-391- 566	S\$1,148.00 Volume Pricing	4 In Stock
λ/20	76.20	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#48-117- 566	S\$1,435.00 Volume Pricing	4 In Stock
λ/10	76.20	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#01-915- 577	S\$931.00 Volume Pricing	1 In Stock
λ/20	76.20	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#47-573- 577	S\$1,036.00 Volume Pricing	10 In Stock
λ/10	76.20	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#31-391- 577	S\$1,134.00 Volume Pricing	1 In Stock
λ/20	76.20	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#48-117- 577	S\$1,421.00 Volume Pricing	7 In Stock
λ/10	101.60	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#01-611- 522	S\$1,400.00 Volume Pricing	Contact Us

λ/20	101.60	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#47-574- 522	S\$1,505.00 Volume Pricing	8 In Stock
λ/10	101.60	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#31-392- 522	S\$1,435.00 Volume Pricing	Contact Us
λ/20	101.60	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#48-118- 522	S\$1,624.00 Volume Pricing	5 In Stock
λ/10	101.60	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#01-611- 533	S\$1,477.00 Volume Pricing	5 In Stock
λ/20	101.60	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#47-574- 533	S\$1,582.00 Volume Pricing	2 In Stock
λ/10	101.60	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#31-392- 533	S\$1,512.00 Volume Pricing	1 In Stock
λ/20	101.60	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#48-118- 533	S\$1,701.00 Volume Pricing	Contact Us
λ/10	101.60	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#01-611- 566	S\$1,533.00 Volume Pricing	4 In Stock
λ/20	101.60	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#47-574- 566	S\$1,638.00 Volume Pricing	3 In Stock
λ/10	101.60	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#31-392- 566	S\$1,568.00 Volume Pricing	3 In Stock
λ/20	101.60	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#48-118- 566	S\$1,757.00 Volume Pricing	3 In Stock

λ/10	101.60	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#01-611- 577	S\$1,512.00 Volume Pricing	3 In Stock
λ/20	101.60	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#47-574- 577	S\$1,617.00 Volume Pricing	4 In Stock
λ/10	101.60	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#31-392- 577	S\$1,547.00 Volume Pricing	2 In Stock
λ/20	101.60	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#48-118- 577	S\$1,736.00 Volume Pricing	7 In Stock
λ/10	127.00	Fused Silica (Corning 7980)	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	25.40	#71-130- 522	S\$2,345.00 Volume Pricing	1 In Stock
λ/10	355.60	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	88.90	#71-247- 522	S\$21,609.00	Contact Us
λ/10	127.00	Fused Silica (Corning 7980)	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	25.40	#71-130- 533	S\$2,471.00 Volume Pricing	1 In Stock
λ/10	127.00	Fused Silica (Corning 7980)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	25.40	#71-130- 566	S\$2,555.00 Volume Pricing	1 In Stock
λ/10	127.00	Fused Silica (Corning 7980)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	25.40	#71-130- 577	S\$2,513.00 Volume Pricing	1 In Stock
λ/20	127.00	Fused Silica (Corning 7980)	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	25.40	#71-131- 522	S\$3,367.00 Volume Pricing	1 In Stock
λ/20	127.00	Fused Silica (Corning 7980)	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	25.40	#71-131- 533	S\$3,493.00 Volume Pricing	1 In Stock

λ/10	355.60	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	88.90	#71-247- 533	S\$21,651.00	Contact Us
λ/20	127.00	Fused Silica (Corning 7980)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	25.40	#71-131- 566	S\$3,577.00 Volume Pricing	1 In Stock
λ/10	355.60	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	88.90	#71-247- 566	S\$22,855.00	Contact Us
λ/20	127.00	Fused Silica (Corning 7980)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	25.40	#71-131- 577	S\$3,535.00 Volume Pricing	Contact Us
λ/10	355.60	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	88.90	#71-247- 577	S\$22,400.00	Contact Us
λ/10	152.40	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	25.40	#01-612- 522	S\$3,052.00 Volume Pricing	2 In Stock
λ/20	152.40	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	25.40	#47-575- 522	S\$4,319.00 Volume Pricing	3 In Stock
λ/10	152.40	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	25.40	#31-393- 522	S\$3,262.00 Volume Pricing	2 In Stock
λ/20	152.40	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	25.40	#48-119- 522	S\$4,844.00 Volume Pricing	2 In Stock
λ/10	152.40	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	25.40	#01-612- 533	S\$3,122.00 Volume Pricing	6 In Stock
λ/20	152.40	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	25.40	#47-575- 533	S\$4,389.00 Volume Pricing	6 In Stock

λ/10	152.40	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	25.40	#31-393- 533	S\$3,332.00 Volume Pricing	Contact Us
λ/20	152.40	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	25.40	#48-119- 533	S\$4,914.00 Volume Pricing	5 In Stock
λ/10	152.40	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	25.40	#01-612- 566	S\$3,304.00 Volume Pricing	5 In Stock
λ/20	152.40	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	25.40	#47-575- 566	S\$4,571.00 Volume Pricing	3 In Stock
λ/10	152.40	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	25.40	#31-393- 566	S\$3,514.00 Volume Pricing	1 In Stock
λ/20	152.40	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	25.40	#48-119- 566	S\$5,096.00 Volume Pricing	Contact Us
λ/10	152.40	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	25.40	#01-612- 577	S\$3,269.00 Volume Pricing	4 In Stock
λ/20	152.40	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	25.40	#47-575- 577	S\$4,536.00 Volume Pricing	3 In Stock
λ/10	152.40	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	25.40	#31-393- 577	S\$3,479.00 Volume Pricing	4 In Stock
λ/20	152.40	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	25.40	#48-119- 577	S\$5,061.00 Volume Pricing	3 In Stock
λ/10	203.20	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	#31-390- 522	S\$6,237.00 Volume Pricing	2 In Stock

λ/20	203.20	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	#49-048- 522	S\$7,665.00 Volume Pricing	Contact Us
λ/10	203.20	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	#31-394- 522	S\$6,601.00 Volume Pricing	1 In Stock
λ/20	203.20	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	#49-049- 522	S\$7,889.00 Volume Pricing	1 In Stock
λ/10	203.20	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#31-390- 533	S\$6,335.00 Volume Pricing	4 In Stock
λ/20	203.20	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#49-048- 533	S\$7,763.00 Volume Pricing	1 In Stock
λ/10	203.20	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#31-394- 533	S\$6,699.00 Volume Pricing	1 In Stock
λ/20	203.20	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#49-049- 533	S\$7,987.00 Volume Pricing	2 In Stock
λ/10	203.20	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#31-390- 566	S\$6,524.00 Volume Pricing	1 In Stock
λ/20	203.20	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#49-048- 566	S\$7,952.00 Volume Pricing	4 In Stock
λ/10	203.20	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#31-394- 566	S\$6,888.00 Volume Pricing	2 In Stock
λ/20	203.20	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#49-049- 566	S\$8,176.00 Volume Pricing	5 In Stock

$\lambda/10$	203.20	Fused Silica	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#31-390-577	S\$6,482.00 Volume Pricing	2 In Stock
$\lambda/20$	203.20	Fused Silica	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#49-048-577	S\$7,910.00 Volume Pricing	2 In Stock
$\lambda/10$	203.20	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#31-394-577	S\$6,846.00 Volume Pricing	1 In Stock
$\lambda/20$	203.20	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#49-049-577	S\$8,134.00 Volume Pricing	Contact Us
$\lambda/10$	254.00	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	#46-715-522	S\$9,471.00 Volume Pricing	2 In Stock
$\lambda/20$	254.00	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	#65-879-522	S\$13,944.00 Volume Pricing	Contact Us
$\lambda/10$	254.00	Fused Silica	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450-650nm)	38.10	#46-715-533	S\$9,618.00 Volume Pricing	3 In Stock
$\lambda/20$	254.00	Fused Silica	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450-650nm)	38.10	#65-879-533	S\$14,091.00 Volume Pricing	Contact Us
$\lambda/10$	254.00	Fused Silica	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	38.10	#46-715-566	S\$9,800.00 Volume Pricing	1 In Stock
$\lambda/20$	254.00	Fused Silica	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	38.10	#65-879-566	S\$14,273.00 Volume Pricing	1 In Stock
$\lambda/10$	254.00	Fused Silica	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#46-715-577	S\$9,765.00 Volume Pricing	3 In Stock

$\lambda/20$	254.00	Fused Silica	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#65-879-577	S\$14,238.00 Volume Pricing	2 In Stock
$\lambda/10$	254.00	ZERODUR®	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	#71-108-522	S\$9,541.00 Volume Pricing	Contact Us
$\lambda/20$	254.00	ZERODUR®	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	#71-110-522	S\$13,825.00 Volume Pricing	Contact Us
$\lambda/10$	254.00	ZERODUR®	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450-650nm)	38.10	#71-108-533	S\$9,688.00 Volume Pricing	Contact Us
$\lambda/20$	254.00	ZERODUR®	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450-650nm)	38.10	#71-110-533	S\$13,972.00 Volume Pricing	Contact Us
$\lambda/10$	254.00	ZERODUR®	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	38.10	#71-108-566	S\$9,870.00 Volume Pricing	Contact Us
$\lambda/20$	254.00	ZERODUR®	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700-10000nm)	38.10	#71-110-566	S\$14,154.00 Volume Pricing	Contact Us
$\lambda/10$	254.00	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#71-108-577	S\$9,835.00 Volume Pricing	Contact Us
$\lambda/20$	254.00	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#71-110-577	S\$14,119.00 Volume Pricing	Contact Us
$\lambda/10$	304.80	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	#69-921-522	S\$12,348.00 Volume Pricing	Contact Us
$\lambda/20$	304.80	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	#65-880-522	S\$18,865.00 Volume Pricing	Contact Us

$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	#71-109- 522	S\$12,397.00 Volume Pricing	Contact Us
$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	#71-111- 522	S\$18,893.00 Volume Pricing	Contact Us
$\lambda/10$	304.80	Fused Silica	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#69-921- 533	S\$12,460.00 Volume Pricing	Contact Us
$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#71-109- 533	S\$12,509.00 Volume Pricing	Contact Us
$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#71-111- 533	S\$19,005.00 Volume Pricing	Contact Us
$\lambda/20$	304.80	Fused Silica	$R_{avg} > 95\% @$ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#65-880- 533	S\$18,977.00 Volume Pricing	1 In Stock
$\lambda/10$	304.80	Fused Silica	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#69-921- 566	S\$12,642.00 Volume Pricing	1 In Stock
$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#71-109- 566	S\$12,691.00 Volume Pricing	Contact Us
$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#71-111- 566	S\$19,187.00 Volume Pricing	Contact Us
$\lambda/20$	304.80	Fused Silica	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#65-880- 566	S\$19,159.00 Volume Pricing	Contact Us
$\lambda/10$	304.80	Fused Silica	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#69-921- 577	S\$12,600.00 Volume Pricing	1 In Stock

$\lambda/20$	304.80	Fused Silica	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#65-880-577	S\$19,117.00 Volume Pricing	Contact Us
$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#71-109-577	S\$12,649.00 Volume Pricing	Contact Us
$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	#71-111-577	S\$19,145.00 Volume Pricing	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com