

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® Uncoated Plano-Convex (PCX) Lenses



- Wavelength Range of 350-2200nm
- Precision Diameter and Centration Tolerances Allow for Easy OEM Integration
- Wide Variety of Diameters, Focal Lengths, and Coatings
- Anti-Reflection PCX Coating Options: [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), [VIS-EXT](#), and [YAG-BBAR](#)

Common Specifications

Physical & Mechanical Properties



Bevel:	Protective as needed
--------	----------------------

Optical Properties

Coating:	Uncoated
----------	----------

Focal Length Tolerance (%):	±1
-----------------------------	----

Technical Information

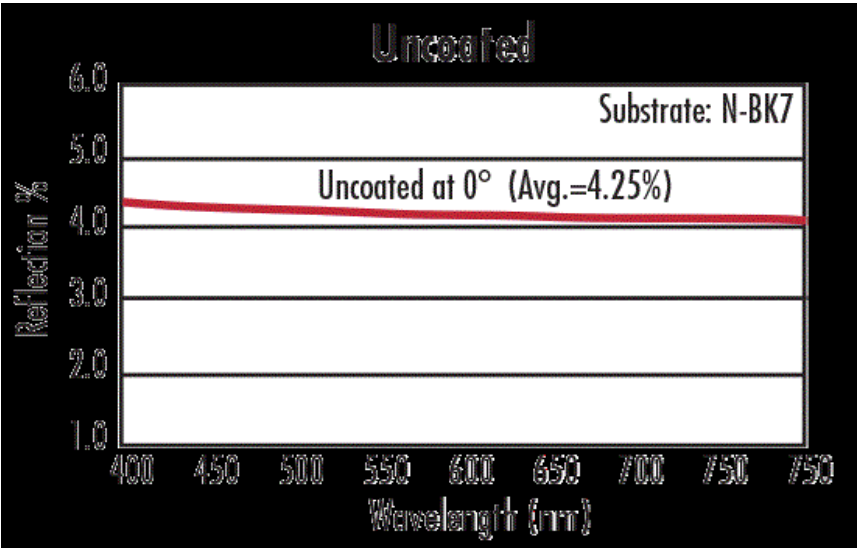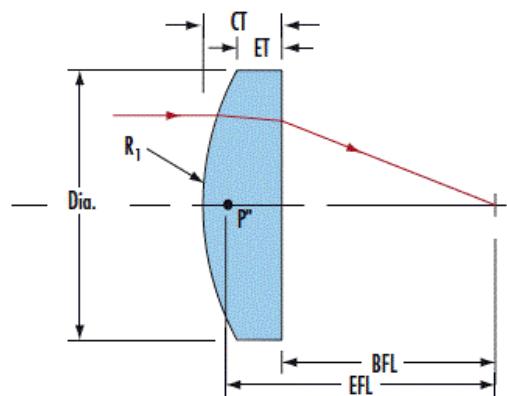

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	Uncoated	N-LASF9	#45-588	S\$103.60 Volume Pricing	Contact Us
1.00	1.00	0.57	Uncoated	N-LASF9	#45-589	S\$103.60 Volume Pricing	20+ In Stock
1.00	1.50	1.07	Uncoated	N-LASF9	#65-252	S\$103.60 Volume Pricing	20+ In Stock
1.00	2.00	1.57	Uncoated	N-LASF9	#65-253	S\$103.60 Volume Pricing	5 In Stock
1.50	1.00	0.57	Uncoated	N-LASF9	#43-394	S\$103.60 Volume Pricing	20+ In Stock
1.50	1.50	1.07	Uncoated	N-LASF9	#43-395	S\$103.60 Volume Pricing	4 In Stock
1.50	2.00	1.57	Uncoated	N-LASF9	#65-254	S\$103.60 Volume Pricing	20+ In Stock
2.00	1.50	1.07	Uncoated	N-LASF9	#43-396	S\$102.20 Volume Pricing	20+ In Stock
2.00	2.00	1.57	Uncoated	N-LASF9	#43-397	S\$102.20 Volume Pricing	Contact Us
2.00	3.00	2.57	Uncoated	N-LASF9	#65-255	S\$102.20 Volume Pricing	20+ In Stock
2.00	4.00	3.57	Uncoated	N-LASF9	#65-256	S\$102.20 Volume Pricing	20+ In Stock
2.50	2.00	1.57	Uncoated	N-LASF9	#43-398	S\$102.20 Volume Pricing	20+ In Stock
2.50	2.50	2.07	Uncoated	N-LASF9	#43-399	S\$102.20 Volume Pricing	20+ In Stock
2.50	3.00	2.57	Uncoated	N-LASF9	#45-590	S\$102.20 Volume Pricing	20+ In Stock
2.50	4.00	3.57	Uncoated	N-LASF9	#48-643	S\$102.20 Volume Pricing	20+ In Stock
2.50	5.00	4.57	Uncoated	N-LASF9	#48-644	S\$102.20 Volume Pricing	6 In Stock
3.00	3.00	1.88	Uncoated	N-SF11	#45-117	S\$82.60 Volume Pricing	20+ In Stock
3.00	4.50	3.50	Uncoated	N-LASF44	#45-141	S\$82.60 Volume Pricing	20+ In Stock

3.00	6.00	4.81	Uncoated	N-BK7	#32-952	S\$74.90 Volume Pricing	20+ In Stock
3.00	7.50	6.51	Uncoated	N-BK7	#48-645	S\$74.90 Volume Pricing	20+ In Stock
3.00	9.00	8.01	Uncoated	N-BK7	#32-954	S\$74.90 Volume Pricing	20+ In Stock
3.00	12.00	11.29	Uncoated	N-BK7	#45-272	S\$74.90 Volume Pricing	20+ In Stock
3.00	15.00	14.22	Uncoated	N-BK7	#45-425	S\$74.90 Volume Pricing	20+ In Stock
4.00	4.00	3.06	Uncoated	N-LASF44	#45-223	S\$74.90 Volume Pricing	20+ In Stock
4.00	6.00	4.51	Uncoated	N-BK7	#45-427	S\$74.90 Volume Pricing	20+ In Stock
4.00	8.00	7.17	Uncoated	N-BAF10	#45-225	S\$68.25 Volume Pricing	20+ In Stock
4.00	10.00	8.92	Uncoated	N-BK7	#45-429	S\$68.25 Volume Pricing	20+ In Stock
4.00	12.00	11.00	Uncoated	N-BK7	#45-431	S\$68.25 Volume Pricing	14 In Stock
4.50	4.50	3.05	Uncoated	N-LASF44	#45-143	S\$74.90 Volume Pricing	20+ In Stock
4.50	9.00	7.41	Uncoated	N-BK7	#45-147	S\$68.25 Volume Pricing	20+ In Stock
5.00	5.00	3.96	Uncoated	N-LASF44	#45-227	S\$56.35 Volume Pricing	20+ In Stock
5.00	7.50	6.43	Uncoated	N-SF11	#48-652	S\$55.65 Volume Pricing	20+ In Stock
5.00	10.00	8.91	Uncoated	N-BK7	#45-229	S\$55.65 Volume Pricing	20+ In Stock
5.00	12.00	10.83	Uncoated	N-BK7	#45-433	S\$55.65 Volume Pricing	20+ In Stock
5.00	15.00	13.94	Uncoated	N-BK7	#45-356	S\$55.65 Volume Pricing	20+ In Stock
5.00	20.00	19.02	Uncoated	N-BK7	#49-873	S\$55.65 Volume Pricing	20+ In Stock
5.00	25.00	23.95	Uncoated	N-BK7	#87-911	S\$55.65 Volume Pricing	20+ In Stock
5.00	30.00	28.95	Uncoated	N-BK7	#87-912	S\$55.65 Volume Pricing	20+ In Stock
6.00	6.00	4.60	Uncoated	N-SF11	#45-077	S\$43.75 Volume Pricing	20+ In Stock

6.00	7.50	6.10	Uncoated	N-SF11	#49-874	S\$42.70 Volume Pricing	20+ In Stock
6.00	9.00	7.95	Uncoated	N-SF5	#32-469	S\$42.70 Volume Pricing	20+ In Stock
6.00	10.00	8.82	Uncoated	N-BK7	#37-775	S\$42.70 Volume Pricing	20+ In Stock
6.00	12.00	10.94	Uncoated	N-BK7	#32-471	S\$41.30 Volume Pricing	20+ In Stock
6.00	15.00	13.68	Uncoated	N-BK7	#45-079	S\$41.30 Volume Pricing	20+ In Stock
6.00	18.00	17.07	Uncoated	N-BK7	#32-473	S\$41.30 Volume Pricing	20+ In Stock
6.00	20.00	19.04	Uncoated	N-BK7	#37-776	S\$41.30 Volume Pricing	20+ In Stock
6.00	21.00	20.06	Uncoated	N-BK7	#45-231	S\$41.30 Volume Pricing	Contact Us
6.00	24.00	23.01	Uncoated	N-BK7	#32-956	S\$41.30 Volume Pricing	20+ In Stock
6.00	25.00	24.04	Uncoated	N-BK7	#37-777	S\$41.30 Volume Pricing	20+ In Stock
6.00	30.00	29.14	Uncoated	N-BK7	#45-119	S\$41.30 Volume Pricing	20+ In Stock
6.00	36.00	34.95	Uncoated	N-BK7	#32-848	S\$41.30 Volume Pricing	20+ In Stock
6.00	48.00	46.95	Uncoated	N-BK7	#45-233	S\$41.30 Volume Pricing	5 In Stock
6.00	60.00	58.95	Uncoated	N-BK7	#67-146	S\$41.30 Volume Pricing	20+ In Stock
6.00	72.00	70.97	Uncoated	N-BK7	#32-850	S\$41.30 Volume Pricing	20+ In Stock
7.00	7.00	5.50	Uncoated	N-SF11	#28-946	S\$43.75 Volume Pricing	20+ In Stock
7.00	10.00	8.10	Uncoated	N-BK7	#28-947	S\$42.70 Volume Pricing	20+ In Stock
7.00	12.00	10.30	Uncoated	N-BK7	#28-948	S\$42.70 Volume Pricing	20+ In Stock
8.00	8.00	6.40	Uncoated	N-SF11	#28-952	S\$43.75 Volume Pricing	20+ In Stock
8.00	10.00	7.60	Uncoated	N-BK7	#28-953	S\$42.70 Volume Pricing	20+ In Stock

8.00	12.00	10.00	Uncoated	N-BK7	#28-954	S\$42.70 Volume Pricing	20+ In Stock
9.00	9.00	7.32	Uncoated	N-SF11	#45-081	S\$44.45 Volume Pricing	20+ In Stock
9.00	10.00	8.49	Uncoated	N-SF11	#37-778	S\$44.45 Volume Pricing	16 In Stock
9.00	12.00	10.60	Uncoated	N-SF11	#49-875	S\$44.45 Volume Pricing	15 In Stock
9.00	13.50	11.94	Uncoated	N-SF5	#32-009	S\$44.45 Volume Pricing	20+ In Stock
9.00	15.00	13.02	Uncoated	N-BK7	#49-876	S\$44.45 Volume Pricing	20+ In Stock
9.00	18.00	16.41	Uncoated	N-BK7	#32-008	S\$42.70 Volume Pricing	20+ In Stock
9.00	20.00	18.55	Uncoated	N-BK7	#37-779	S\$42.70 Volume Pricing	20+ In Stock
9.00	22.00	20.73	Uncoated	N-BK7	#45-235	S\$42.70 Volume Pricing	20+ In Stock
9.00	25.00	23.68	Uncoated	N-BK7	#37-780	S\$42.70 Volume Pricing	14 In Stock
9.00	27.00	25.34	Uncoated	N-BK7	#32-958	S\$42.70 Volume Pricing	20+ In Stock
9.00	36.00	34.48	Uncoated	N-BK7	#45-121	S\$42.70 Volume Pricing	20+ In Stock
9.00	45.00	43.98	Uncoated	N-BK7	#45-358	S\$42.70 Volume Pricing	20+ In Stock
9.00	54.00	52.69	Uncoated	N-BK7	#67-147	S\$42.70 Volume Pricing	20+ In Stock
9.00	72.00	70.68	Uncoated	N-BK7	#67-148	S\$42.70 Volume Pricing	3 In Stock
9.00	90.00	88.68	Uncoated	N-BK7	#67-149	S\$42.70 Volume Pricing	20+ In Stock
10.00	10.00	8.18	Uncoated	N-SF11	#63-471	S\$44.45 Volume Pricing	20+ In Stock
10.00	12.50	10.99	Uncoated	N-SF11	#37-781	S\$44.45 Volume Pricing	20+ In Stock
10.00	15.00	13.32	Uncoated	N-SF11	#63-472	S\$44.45 Volume Pricing	20+ In Stock
10.00	17.50	15.66	Uncoated	N-BK7	#37-782	S\$42.70 Volume Pricing	20+ In Stock
10.00	20.00	18.03	Uncoated	N-BK7	#63-473	S\$42.70 Volume Pricing	20+ In Stock

10.00	25.00	23.02	Uncoated	N-BK7	#63-474	S\$42.70 Volume Pricing	20+ In Stock
10.00	30.00	28.01	Uncoated	N-BK7	#63-475	S\$42.70 Volume Pricing	20+ In Stock
10.00	40.00	38.02	Uncoated	N-BK7	#63-476	S\$42.70 Volume Pricing	20+ In Stock
10.00	50.00	48.02	Uncoated	N-BK7	#63-477	S\$42.70 Volume Pricing	20+ In Stock
10.00	75.00	73.02	Uncoated	N-BK7	#63-478	S\$42.70 Volume Pricing	20+ In Stock
10.00	100.00	98.02	Uncoated	N-BK7	#63-479	S\$42.70 Volume Pricing	3 In Stock
12.00	12.00	9.76	Uncoated	N-SF11	#45-083	S\$47.60 Volume Pricing	Contact Us
12.00	15.00	12.03	Uncoated	N-BK7	#45-302	S\$47.60 Volume Pricing	20+ In Stock
12.00	18.00	16.22	Uncoated	N-SF5	#32-006	S\$47.60 Volume Pricing	20+ In Stock
12.00	20.00	17.69	Uncoated	N-BK7	#49-877	S\$47.60 Volume Pricing	20+ In Stock
12.00	24.00	22.15	Uncoated	N-BK7	#32-011	S\$45.85 Volume Pricing	20+ In Stock
12.00	25.00	23.22	Uncoated	N-BK7	#37-783	S\$45.85 Volume Pricing	20+ In Stock
12.00	30.00	28.02	Uncoated	N-BK7	#45-085	S\$45.85 Volume Pricing	20+ In Stock
12.00	36.00	34.02	Uncoated	N-BK7	#33-352	S\$45.85 Volume Pricing	20+ In Stock
12.00	42.00	40.22	Uncoated	N-BK7	#45-123	S\$45.85 Volume Pricing	20+ In Stock
12.00	48.00	46.36	Uncoated	N-BK7	#32-852	S\$45.85 Volume Pricing	20+ In Stock
12.00	50.00	48.75	Uncoated	N-BK7	#37-784	S\$45.85 Volume Pricing	20+ In Stock
12.00	54.00	52.02	Uncoated	N-BK7	#45-304	S\$45.85 Volume Pricing	20+ In Stock
12.00	60.00	58.37	Uncoated	N-BK7	#32-854	S\$45.85 Volume Pricing	20+ In Stock
12.00	72.00	70.42	Uncoated	N-BK7	#45-125	S\$45.85 Volume Pricing	20+ In Stock

12.00	84.00	82.39	Uncoated	N-BK7	#32-856	S\$45.85 Volume Pricing	20+ In Stock
12.00	100.00	98.35	Uncoated	N-BK7	#45-274	S\$45.85 Volume Pricing	20+ In Stock
12.50	12.50	10.40	Uncoated	N-SF11	#37-785	S\$45.85 Volume Pricing	20+ In Stock
12.50	15.00	13.26	Uncoated	N-SF11	#37-786	S\$45.85 Volume Pricing	8 In Stock
12.50	17.50	15.00	Uncoated	N-BK7	#37-787	S\$45.85 Volume Pricing	20+ In Stock
12.50	20.00	17.69	Uncoated	N-BK7	#37-788	S\$45.85 Volume Pricing	20+ In Stock
12.50	25.00	22.96	Uncoated	N-BK7	#37-789	S\$44.45 Volume Pricing	20+ In Stock
12.50	30.00	28.22	Uncoated	N-BK7	#37-790	S\$44.45 Volume Pricing	20+ In Stock
12.50	35.00	33.42	Uncoated	N-BK7	#37-791	S\$44.45 Volume Pricing	20+ In Stock
12.50	40.00	38.55	Uncoated	N-BK7	#37-792	S\$44.45 Volume Pricing	20+ In Stock
12.50	45.00	43.68	Uncoated	N-BK7	#37-793	S\$44.45 Volume Pricing	11 In Stock
12.50	50.00	48.68	Uncoated	N-BK7	#37-796	S\$44.45 Volume Pricing	20+ In Stock
12.50	75.00	73.88	Uncoated	N-BK7	#37-798	S\$44.45 Volume Pricing	20+ In Stock
12.50	100.00	98.95	Uncoated	N-BK7	#37-800	S\$44.45 Volume Pricing	20+ In Stock
12.70	12.70	10.46	Uncoated	N-SF11	#49-839	S\$45.85 Volume Pricing	20+ In Stock
12.70	15.00	11.53	Uncoated	N-BK7	#49-840	S\$45.85 Volume Pricing	20+ In Stock
12.70	19.10	16.46	Uncoated	N-BK7	#49-841	S\$45.85 Volume Pricing	20+ In Stock
12.70	20.00	17.49	Uncoated	N-BK7	#37-801	S\$45.85 Volume Pricing	4 In Stock
12.70	25.40	23.43	Uncoated	N-BK7	#49-842	S\$44.45 Volume Pricing	20+ In Stock
12.70	30.00	28.22	Uncoated	N-BK7	#37-802	S\$44.45 Volume Pricing	20+ In Stock
12.70	31.80	29.81	Uncoated	N-BK7	#49-843	S\$44.45 Volume Pricing	20+ In Stock

12.70	38.10	36.12	Uncoated	N-BK7	#49-844	S\$44.45 Volume Pricing	12 In Stock
12.70	40.00	38.48	Uncoated	N-BK7	#37-803	S\$44.45 Volume Pricing	20+ In Stock
12.70	44.50	42.69	Uncoated	N-BK7	#49-845	S\$44.45 Volume Pricing	20+ In Stock
12.70	50.80	49.15	Uncoated	N-BK7	#49-846	S\$44.45 Volume Pricing	Contact Us
12.70	100.00	98.88	Uncoated	N-BK7	#37-804	S\$44.45 Volume Pricing	20+ In Stock
15.00	15.00	11.71	Uncoated	N-SF5	#45-093	S\$47.60 Volume Pricing	Contact Us
15.00	18.00	15.61	Uncoated	N-SF5	#49-878	S\$47.60 Volume Pricing	Contact Us
15.00	20.00	17.74	Uncoated	N-SF5	#63-480	S\$47.60 Volume Pricing	20+ In Stock
15.00	22.50	20.50	Uncoated	N-SF5	#32-004	S\$47.60 Volume Pricing	20+ In Stock
15.00	25.00	22.50	Uncoated	N-BK7	#37-806	S\$45.85 Volume Pricing	20+ In Stock
15.00	30.00	27.90	Uncoated	N-BK7	#32-003	S\$45.85 Volume Pricing	20+ In Stock
15.00	40.00	38.02	Uncoated	N-BK7	#45-095	S\$45.85 Volume Pricing	20+ In Stock
15.00	45.00	43.35	Uncoated	N-BK7	#49-879	S\$45.85 Volume Pricing	20+ In Stock
15.00	50.00	48.35	Uncoated	N-BK7	#37-808	S\$45.85 Volume Pricing	20+ In Stock
15.00	60.00	58.65	Uncoated	N-BK7	#45-435	S\$45.85 Volume Pricing	20+ In Stock
15.00	75.00	73.79	Uncoated	N-BK7	#45-360	S\$45.85 Volume Pricing	20+ In Stock
15.00	100.00	98.02	Uncoated	N-BK7	#45-259	S\$45.85 Volume Pricing	20+ In Stock

[#14-374 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

15.00	200.00	197.89	Uncoated	N-BK7		S\$32.55	20+ In Stock
-------	--------	--------	----------	-----------------------	--	----------	--------------

15.00	250.00	248.02	Uncoated	N-BK7	#14-382	S\$45.85 Volume Pricing	20+ In Stock
-------	--------	--------	----------	-----------------------	-------------------------	--	--------------

18.00	18.00	15.20	Uncoated	N-SF11	#48-423	S\$48.30 Volume Pricing	20+ In Stock
-------	-------	-------	----------	------------------------	-------------------------	--	--------------

18.00	22.50	20.26	Uncoated	N-SF11	#49-880	S\$47.60 Volume Pricing	20+ In Stock
-------	-------	-------	----------	------------------------	-------------------------	--	--------------

18.00	27.00	24.73	Uncoated	N-SF5	#32-001	S\$47.60 Volume Pricing	20+ In Stock
-------	-------	-------	----------	-----------------------	-------------------------	--	--------------

18.00	36.00	33.65	Uncoated	N-BK7	#32-000	S\$45.15 Volume Pricing	20+ In Stock
-------	-------	-------	----------	-----------------------	-------------------------	--	--------------

18.00	54.00	52.02	Uncoated	N-BK7	#45-306	S\$45.15 Volume Pricing	20+ In Stock
-------	-------	-------	----------	-----------------------	-------------------------	--	--------------

18.00	72.00	70.05	Uncoated	N-BK7	#32-859	S\$45.15 Volume Pricing	20+ In Stock
-------	-------	-------	----------	-----------------------	-------------------------	--	--------------

18.00	20.00	17.59	Uncoated	N-SF11	#37-810	S\$47.60 Volume Pricing	20+ In Stock
-------	-------	-------	----------	------------------------	-------------------------	--	--------------

18.00	25.00	21.51	Uncoated	N-BK7	#37-811	S\$47.60 Volume Pricing	20+ In Stock
-------	-------	-------	----------	-----------------------	-------------------------	--	--------------

18.00	30.00	27.10	Uncoated	N-BK7	#37-812	S\$45.15 Volume Pricing	20+ In Stock
-------	-------	-------	----------	-----------------------	-------------------------	--	--------------

18.00	50.00	48.09	Uncoated	N-BK7	#37-813	S\$45.15 Volume Pricing	20+ In Stock
-------	-------	-------	----------	-----------------------	-------------------------	--	--------------

20.00	20.00	17.42	Uncoated	N-SF11	#45-237	S\$49.00 Volume Pricing	20+ In Stock
-------	-------	-------	----------	------------------------	-------------------------	--	--------------

20.00	25.00	22.76	Uncoated	N-SF11	#49-881	S\$48.30 Volume Pricing	20+ In Stock
20.00	30.00	27.30	Uncoated	N-BAF10	#45-239	S\$48.30 Volume Pricing	20+ In Stock
20.00	35.00	32.04	Uncoated	N-BK7	#49-882	S\$48.30 Volume Pricing	20+ In Stock
20.00	40.00	36.77	Uncoated	N-BK7	#32-960	S\$45.85 Volume Pricing	20+ In Stock
20.00	50.00	47.87	Uncoated	N-BK7	#45-362	S\$45.85 Volume Pricing	20+ In Stock
20.00	60.00	57.03	Uncoated	N-BK7	#32-962	S\$45.85 Volume Pricing	20+ In Stock
20.00	70.00	68.03	Uncoated	N-BK7	#32-936	S\$45.85 Volume Pricing	20+ In Stock
20.00	80.00	78.45	Uncoated	N-BK7	#45-439	S\$45.85 Volume Pricing	20+ In Stock
20.00	100.00	97.13	Uncoated	N-BK7	#32-475	S\$45.85 Volume Pricing	20+ In Stock
20.00	150.00	148.02	Uncoated	N-BK7	#45-276	S\$45.85 Volume Pricing	20+ In Stock
25.00	25.00	20.22	Uncoated	N-SF5	#45-097	S\$49.00 Volume Pricing	20+ In Stock
25.00	30.00	24.69	Uncoated	N-BK7	#45-364	S\$49.00 Volume Pricing	20+ In Stock
25.00	35.00	30.42	Uncoated	N-BK7	#45-145	S\$49.00 Volume Pricing	20+ In Stock
25.00	40.00	36.31	Uncoated	N-BK7	#45-278	S\$49.00 Volume Pricing	20+ In Stock
25.00	50.00	46.75	Uncoated	N-BK7	#32-477	S\$45.85 Volume Pricing	20+ In Stock
25.00	60.00	56.90	Uncoated	N-BK7	#45-127	S\$45.85 Volume Pricing	20+ In Stock
25.00	75.00	72.00	Uncoated	N-BK7	#32-479	S\$45.85 Volume Pricing	20+ In Stock
25.00	85.00	82.17	Uncoated	N-BK7	#45-366	S\$45.85 Volume Pricing	20+ In Stock
25.00	100.00	97.17	Uncoated	N-BK7	#32-481	S\$45.85 Volume Pricing	20+ In Stock
25.00	125.00	122.70	Uncoated	N-BK7	#32-861	S\$45.85 Volume Pricing	20+ In Stock

25.00	150.00	147.81	Uncoated	N-BK7	#32-863	S\$45.85 Volume Pricing	20+ In Stock
25.00	175.00	172.85	Uncoated	N-BK7	#32-865	S\$45.85 Volume Pricing	20+ In Stock
25.00	200.00	197.89	Uncoated	N-BK7	#33-358	S\$45.85 Volume Pricing	20+ In Stock
25.00	250.00	248.02	Uncoated	N-BK7	#67-150	S\$45.85 Volume Pricing	20+ In Stock
25.00	300.00	298.02	Uncoated	N-BK7	#67-151	S\$45.85 Volume Pricing	20+ In Stock
25.00	400.00	397.89	Uncoated	N-BK7	#33-364	S\$45.85 Volume Pricing	20+ In Stock
25.00	500.00	497.89	Uncoated	N-BK7	#45-280	S\$45.85 Volume Pricing	20+ In Stock
25.00	750.00	747.89	Uncoated	N-BK7	#45-282	S\$45.85 Volume Pricing	20+ In Stock
25.40	25.40	21.48	Uncoated	N-SF11	#49-847	S\$49.00 Volume Pricing	14 In Stock
25.40	38.10	33.48	Uncoated	N-BK7	#49-848	S\$49.00 Volume Pricing	20+ In Stock
25.40	50.80	47.50	Uncoated	N-BK7	#49-849	S\$45.85 Volume Pricing	20+ In Stock
25.40	63.50	60.37	Uncoated	N-BK7	#49-850	S\$45.85 Volume Pricing	20+ In Stock
25.40	76.20	73.56	Uncoated	N-BK7	#49-851	S\$45.85 Volume Pricing	20+ In Stock
25.40	88.90	86.26	Uncoated	N-BK7	#49-852	S\$45.85 Volume Pricing	20+ In Stock
25.40	101.60	98.97	Uncoated	N-BK7	#49-853	S\$45.85 Volume Pricing	20+ In Stock
25.40	35.00	30.46	Uncoated	N-BK7	#37-814	S\$49.00 Volume Pricing	20+ In Stock
25.40	40.00	36.11	Uncoated	N-BK7	#37-815	S\$49.00 Volume Pricing	20+ In Stock
25.40	75.00	72.69	Uncoated	N-BK7	#37-816	S\$45.85 Volume Pricing	20+ In Stock
25.40	100.00	98.02	Uncoated	N-BK7	#37-817	S\$45.85 Volume Pricing	20+ In Stock
25.40	125.00	123.02	Uncoated	N-BK7	#37-818	S\$45.85 Volume Pricing	20+ In Stock
25.40	150.00	148.02	Uncoated	N-BK7	#37-821	S\$45.85 Volume Pricing	20+ In Stock

30.00	30.00	26.13	Uncoated	N-SF11	#48-653	S\$61.25 Volume Pricing	20+ In Stock
30.00	40.00	37.20	Uncoated	N-SF11	#67-152	S\$58.80 Volume Pricing	20+ In Stock
30.00	50.00	46.17	Uncoated	N-SF5	#32-483	S\$58.80 Volume Pricing	20+ In Stock
30.00	60.00	56.03	Uncoated	N-BK7	#45-241	S\$56.35 Volume Pricing	20+ In Stock
30.00	75.00	70.95	Uncoated	N-BK7	#32-485	S\$56.35 Volume Pricing	20+ In Stock
30.00	100.00	96.01	Uncoated	N-BK7	#32-487	S\$56.35 Volume Pricing	20+ In Stock
30.00	120.00	116.04	Uncoated	N-BK7	#45-243	S\$56.35 Volume Pricing	Contact Us
35.00	35.00	30.52	Uncoated	N-SF11	#37-824	S\$63.35 Volume Pricing	20+ In Stock
35.00	50.00	44.40	Uncoated	N-BK7	#37-825	S\$61.25 Volume Pricing	20+ In Stock
35.00	100.00	97.03	Uncoated	N-BK7	#37-828	S\$61.25 Volume Pricing	20+ In Stock
35.00	70.00	66.04	Uncoated	N-BK7	#37-827	S\$61.25 Volume Pricing	20+ In Stock
40.00	40.00	35.13	Uncoated	N-SF11	#48-654	S\$67.20 Volume Pricing	20+ In Stock
40.00	60.00	53.90	Uncoated	N-BK7	#45-149	S\$67.20 Volume Pricing	20+ In Stock
40.00	80.00	74.73	Uncoated	N-BK7	#33-382	S\$65.80 Volume Pricing	20+ In Stock
40.00	100.00	95.39	Uncoated	N-BK7	#33-370	S\$65.80 Volume Pricing	20+ In Stock
40.00	200.00	196.7	Uncoated	N-BK7	#33-376	S\$65.80 Volume Pricing	20+ In Stock
40.00	300.00	296.70	Uncoated	N-BK7	#45-284	S\$65.80 Volume Pricing	20+ In Stock
40.00	400.00	396.70	Uncoated	N-BK7	#45-286	S\$65.80 Volume Pricing	20+ In Stock
50.00	50.00	43.28	Uncoated	N-SF11	#32-970	S\$76.30 Volume Pricing	20+ In Stock
50.00	75.00	67.75	Uncoated	N-BK7	#45-245	S\$73.50 Volume Pricing	20+ In Stock
50.00	100.00	93.41	Uncoated	N-BK7	#32-972	S\$69.30 Volume Pricing	20+ In Stock

50.00	125.00	118.39	Uncoated	N-BK7	#45-247	S\$69.30 Volume Pricing	20+ In Stock
50.00	150.00	144.07	Uncoated	N-BK7	#32-974	S\$69.30 Volume Pricing	20+ In Stock
50.00	175.00	169.05	Uncoated	N-BK7	#45-249	S\$69.30 Volume Pricing	20+ In Stock
50.00	200.00	196.66	Uncoated	N-BK7	#45-151	S\$69.30 Volume Pricing	17 In Stock
50.00	250.00	246.74	Uncoated	N-BK7	#45-153	S\$69.30 Volume Pricing	20+ In Stock
50.00	500.00	496.70	Uncoated	N-BK7	#45-288	S\$69.30 Volume Pricing	20+ In Stock
50.80	50.80	44.08	Uncoated	N-SF11	#29-094	S\$76.30 Volume Pricing	20+ In Stock
50.80	76.20	68.95	Uncoated	N-BK7	#29-095	S\$73.50 Volume Pricing	20+ In Stock
75.00	75.00	53.49	Uncoated	N-BK7	#45-367	S\$124.60 Volume Pricing	20+ In Stock
75.00	100.00	87.57	Uncoated	N-BK7	#71-834	S\$121.10 Volume Pricing	20+ In Stock
75.00	125.00	115.99	Uncoated	N-BK7	#71-835	S\$121.10 Volume Pricing	20+ In Stock
75.00	150.00	142.45	Uncoated	N-BK7	#45-369	S\$121.10 Volume Pricing	20+ In Stock
75.00	175.00	168.68	Uncoated	N-BK7	#71-836	S\$121.10 Volume Pricing	14 In Stock
75.00	200.00	194.24	Uncoated	N-BK7	#45-371	S\$121.10 Volume Pricing	20+ In Stock
75.00	250.00	244.73	Uncoated	N-BK7	#63-482	S\$121.10 Volume Pricing	20+ In Stock
75.00	300.00	294.4	Uncoated	N-BK7	#71-837	S\$121.10 Volume Pricing	Contact Us
75.00	400.00	394.4	Uncoated	N-BK7	#71-838	S\$121.10 Volume Pricing	Contact Us
75.00	500.00	494.73	Uncoated	N-BK7	#63-483	S\$121.10 Volume Pricing	20+ In Stock
75.00	750.00	745.35	Uncoated	N-BK7	#71-839	S\$121.10 Volume Pricing	9 In Stock
100.00	150.00	136.82	Uncoated	N-BK7	#70-952	S\$345.80 Volume Pricing	9 In Stock
100.00	200.00	190.77	Uncoated	N-BK7	#17-899	S\$322.00 Volume Pricing	17 In Stock

100.00	300.00	293.41	Uncoated	N-BK7	#70-953	S\$298.20 Volume Pricing	14 In Stock
100.00	400.00	393.41	Uncoated	N-BK7	#70-954	S\$282.80 Volume Pricing	11 In Stock
125.00	250.00	238.13	Uncoated	N-BK7	#70-955	S\$483.00 Volume Pricing	9 In Stock
150.00	200.00	176.96	Uncoated	N-BK7	#70-956	S\$686.00 Volume Pricing	4 In Stock
150.00	300.00	285.50	Uncoated	N-BK7	#17-915	S\$637.00 Volume Pricing	5 In Stock
200.00	400.00	381.54	Uncoated	N-BK7	#17-931	S\$1,204.00 Volume Pricing	20+ In Stock

Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com