

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Achromatic Lenses](#)

TECHSPEC®

MgF₂ Coated Achromatic Lenses



- Designed for 0° Angle of Incidence
- Less Than 1.75% Reflectance Per Surface @ 400 - 700nm
- [VIS 0°](#) and [VIS-NIR](#) Coated Achromats Also Available

Common Specifications



Physical & Mechanical Properties

Bevel:	Protective as needed
--------	----------------------

Optical Properties

Focal Length Specification Wavelength (nm):	587.6		
Coating:	MgF ₂ (400-700nm)	Power (P-V) @ 632.8nm:	1.5λ
Wavelength Range (nm):	400 - 700		

Technical Information

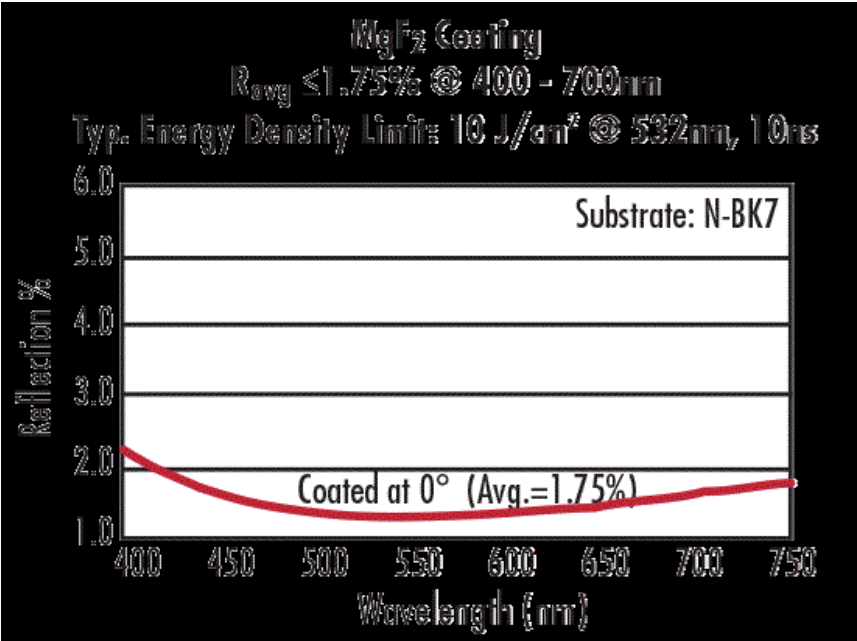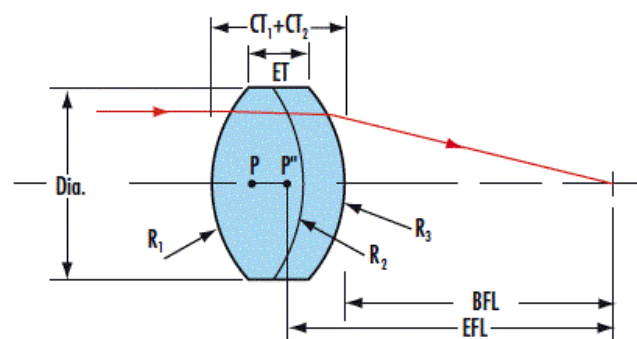

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Substrate	Coating	Stock Number	Price	Buy
1.00	1.50	0.92	N-PSK53A / N-LASF9	MgF ₂ (400-700nm)	#65-564	S\$352.47 Volume Pricing	20+ In Stock
1.00	3.00	2.48	N-PSK53A / N-LASF9	MgF ₂ (400-700nm)	#65-566	S\$352.47 Volume Pricing	20+ In Stock
2.00	3.00	1.89	N-PSK53A / N-LASF9	MgF ₂ (400-700nm)	#65-567	S\$352.47 Volume Pricing	20+ In Stock
2.00	4.00	2.92	N-PSK53A / N-LASF9	MgF ₂ (400-700nm)	#65-568	S\$352.47 Volume Pricing	Contact Us
#83-338 Clearance							
 Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
2.00	9.00	8.00	N-PSK53A / N-LASF9	MgF ₂ (400-700nm)		S\$289.67	2 In Stock
3.00	12.00	10.77	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-262	S\$165.78 Volume Pricing	20+ In Stock
3.00	4.50	2.99	N-LAK22 / N-SF6	MgF ₂ (400-700nm)	#47-721	S\$165.78 Volume Pricing	20+ In Stock

3.00	6.00	4.33	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-089	S\$165.78 Volume Pricing	20+ In Stock
3.00	9.00	7.79	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-090	S\$165.78 Volume Pricing	20+ In Stock
4.00	6.00	3.92	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#63-690	S\$146.36 Volume Pricing	20+ In Stock
4.00	10.00	8.40	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#63-691	S\$146.36 Volume Pricing	20+ In Stock
4.00	12.00	10.70	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#63-692	S\$146.36 Volume Pricing	9 In Stock
4.00	8.00	6.69	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-205	S\$146.36 Volume Pricing	20+ In Stock
5.00	10.00	8.56	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-206	S\$109.78 Volume Pricing	20+ In Stock
5.00	12.50	10.89	N-SSK8 / N-SF56	MgF ₂ (400-700nm)	#49-923	S\$109.78 Volume Pricing	20+ In Stock
5.00	15.00	13.64	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-207	S\$109.78 Volume Pricing	20+ In Stock
5.00	20.00	18.60	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-408	S\$109.78 Volume Pricing	20+ In Stock
5.00	7.50	5.01	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-407	S\$109.78 Volume Pricing	20+ In Stock
6.25	7.50	4.45	N-BAF10 / N-SF57	MgF ₂ (400-700nm)	#49-924	S\$96.33 Volume Pricing	5 In Stock
6.25	10.00	7.83	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-208	S\$96.33 Volume Pricing	20+ In Stock
6.25	12.50	10.36	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#32-299	S\$96.33 Volume Pricing	20+ In Stock

6.25	15.00	12.73	N-SSK8 / N-SF10	MgF ₂ (400-700nm)	#32-301	S\$96.33 Volume Pricing	20+ In Stock
6.25	17.50	15.46	N-SSK8 / N-SF56	MgF ₂ (400-700nm)	#49-925	S\$96.33 Volume Pricing	5 In Stock
6.25	20.00	18.23	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-303	S\$96.33 Volume Pricing	16 In Stock
6.25	25.00	23.45	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-305	S\$96.33 Volume Pricing	20+ In Stock
6.25	30.00	28.43	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-135	S\$96.33 Volume Pricing	Contact Us
6.25	35.00	33.59	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-307	S\$96.33 Volume Pricing	17 In Stock
6.25	40.00	38.46	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-173	S\$96.33 Volume Pricing	20+ In Stock
6.25	50.00	48.61	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-263	S\$96.33 Volume Pricing	20+ In Stock
6.25	60.00	58.46	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-345	S\$96.33 Volume Pricing	Contact Us
9.00	9.00	4.92	N-BASF64 / N-SF66	MgF ₂ (400-700nm)	#65-549	S\$138.90 Volume Pricing	20+ In Stock
9.00	12.00	8.33	N-BAF10 / N-SF57	MgF ₂ (400-700nm)	#45-346	S\$102.31 Volume Pricing	20+ In Stock
9.00	15.00	12.08	N-BAF10 / N-SF6	MgF ₂ (400-700nm)	#49-926	S\$102.31 Volume Pricing	4 In Stock
9.00	18.00	14.91	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-091	S\$102.31 Volume Pricing	20+ In Stock
9.00	22.50	20.21	N-SSK8 / N-SF56	MgF ₂ (400-700nm)	#49-927	S\$102.31 Volume Pricing	20+ In Stock

9.00	27.00	24.22	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-092	S\$102.31 Volume Pricing	20+ In Stock
9.00	36.00	34.17	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-264	S\$102.31 Volume Pricing	20+ In Stock
9.00	40.00	37.54	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-818	S\$102.31 Volume Pricing	20+ In Stock
9.00	45.00	42.97	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-347	S\$102.31 Volume Pricing	20+ In Stock
9.00	60.00	57.59	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-819	S\$102.31 Volume Pricing	1 In Stock
9.00	75.00	72.35	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-820	S\$102.31 Volume Pricing	20+ In Stock
10.00	15.00	10.66	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#63-693	S\$105.29 Volume Pricing	20+ In Stock
10.00	20.00	17.25	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#63-694	S\$105.29 Volume Pricing	14 In Stock
10.00	25.00	22.60	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#63-695	S\$105.29 Volume Pricing	Contact Us
10.00	30.00	27.47	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#63-696	S\$105.29 Volume Pricing	20+ In Stock
10.00	40.00	37.79	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#63-697	S\$105.29 Volume Pricing	20+ In Stock
10.00	50.00	47.45	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#63-698	S\$105.29 Volume Pricing	Contact Us
10.00	100.00	98.16	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#63-699	S\$105.29 Volume Pricing	5 In Stock
12.50	12.50	7.23	N-BASF64 / N-SF66	MgF ₂ (400-700nm)	#65-550	S\$165.78 Volume Pricing	20+ In Stock

12.50	14.00	9.92	N-BAF10 / N-SF5	MgF ₂ (400-700nm)	#45-209	S\$116.49 Volume Pricing	Contact Us
12.50	15.00	10.82	N-LAK22 / N-SF6	MgF ₂ (400-700nm)	#63-700	S\$116.49 Volume Pricing	20+ In Stock
12.50	17.50	13.59	N-BAF10 / N-SF57	MgF ₂ (400-700nm)	#49-928	S\$116.49 Volume Pricing	20+ In Stock
12.50	20.00	16.45	S-BAH11 / N-SF10	MgF ₂ (400-700nm)	#32-309	S\$116.49 Volume Pricing	20+ In Stock
12.50	25.00	21.47	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#32-311	S\$116.49 Volume Pricing	20+ In Stock
12.50	30.00	26.12	N-SSK8 / N-SF10	MgF ₂ (400-700nm)	#32-313	S\$116.49 Volume Pricing	20+ In Stock
12.50	35.00	32.50	N-SK11 / N-SF5	MgF ₂ (400-700nm)	#45-210	S\$116.49 Volume Pricing	Contact Us
12.50	40.00	37.54	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-315	S\$116.49 Volume Pricing	20+ In Stock
12.50	45.00	42.52	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-136	S\$116.49 Volume Pricing	20+ In Stock
12.50	50.00	47.61	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-317	S\$116.49 Volume Pricing	20+ In Stock
12.50	60.00	57.59	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-137	S\$116.49 Volume Pricing	20+ In Stock
12.50	75.00	72.35	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-882	S\$116.49 Volume Pricing	20+ In Stock
12.50	80.00	78.40	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-409	S\$116.49 Volume Pricing	14 In Stock
12.50	90.00	88.47	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-410	S\$116.49 Volume Pricing	20+ In Stock

12.50	100.00	97.92	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-265	S\$116.49 Volume Pricing	20+ In Stock
12.70	15.00	10.56	N-BAF10 / N-SF57	MgF ₂ (400-700nm)	#49-758	S\$116.49 Volume Pricing	20+ In Stock
12.70	19.10	15.38	N-BAF10 / N-SF6	MgF ₂ (400-700nm)	#49-759	S\$116.49 Volume Pricing	20+ In Stock
12.70	25.40	22.45	N-SSK8 / N-SF56	MgF ₂ (400-700nm)	#49-760	S\$116.49 Volume Pricing	20+ In Stock
12.70	31.75	28.83	N-SSK8 / N-SF56	MgF ₂ (400-700nm)	#49-761	S\$116.49 Volume Pricing	20+ In Stock
12.70	38.10	35.57	N-SSK8 / N-SF56	MgF ₂ (400-700nm)	#49-762	S\$116.49 Volume Pricing	20+ In Stock
12.70	44.45	41.98	N-BAK1 / N-SF8	MgF ₂ (400-700nm)	#49-763	S\$116.49 Volume Pricing	20+ In Stock
12.70	50.80	48.86	N-BAK1 / N-SF15	MgF ₂ (400-700nm)	#49-764	S\$116.49 Volume Pricing	Contact Us
12.70	125.00	121.95	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#83-415	S\$116.49 Volume Pricing	20+ In Stock
15.00	15.00	8.57	N-BASF64 / N-SF66	MgF ₂ (400-700nm)	#65-551	S\$182.21 Volume Pricing	20+ In Stock
15.00	20.00	15.34	N-BAF10 / N-SF57	MgF ₂ (400-700nm)	#49-929	S\$140.39 Volume Pricing	13 In Stock
15.00	25.00	20.98	S-BAH11 / N-SF10	MgF ₂ (400-700nm)	#45-174	S\$140.39 Volume Pricing	20+ In Stock
15.00	30.00	25.78	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#32-720	S\$140.39 Volume Pricing	20+ In Stock
15.00	40.00	35.63	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-103	S\$140.39 Volume Pricing	5 In Stock

15.00	50.00	46.17	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-138	S\$140.39 Volume Pricing	20+ In Stock
15.00	60.00	57.48	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#49-930	S\$140.39 Volume Pricing	8 In Stock
15.00	75.00	70.78	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-139	S\$140.39 Volume Pricing	20+ In Stock
18.00	125.00	121.95	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-266	S\$141.88 Volume Pricing	20+ In Stock
18.00	22.50	16.39	N-BAF10 / N-SF57	MgF ₂ (400-700nm)	#49-931	S\$141.88 Volume Pricing	20+ In Stock
18.00	27.00	21.74	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-412	S\$141.88 Volume Pricing	20+ In Stock
18.00	30.00	24.97	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-348	S\$141.88 Volume Pricing	20+ In Stock
18.00	35.00	30.72	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-413	S\$141.88 Volume Pricing	20+ In Stock
18.00	40.00	35.63	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-104	S\$141.88 Volume Pricing	20+ In Stock
18.00	50.00	45.24	N-SSK8 / N-SF10	MgF ₂ (400-700nm)	#32-913	S\$141.88 Volume Pricing	20+ In Stock
18.00	60.00	56.79	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-349	S\$141.88 Volume Pricing	20+ In Stock
18.00	75.00	72.15	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-350	S\$141.88 Volume Pricing	20+ In Stock
18.00	80.00	76.52	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-915	S\$141.88 Volume Pricing	20+ In Stock
20.00	20.00	11.73	N-BASF64 / N-SF66	MgF ₂ (400-700nm)	#65-552	S\$201.62 Volume Pricing	20+ In Stock

20.00	25.00	18.71	N-BAF10 / N-SF6	MgF ₂ (400-700nm)	#49-932	S\$144.87 Volume Pricing	20+ In Stock
20.00	30.00	24.70	S-BAH11 / N-SF10	MgF ₂ (400-700nm)	#45-175	S\$144.87 Volume Pricing	20+ In Stock
20.00	35.00	29.90	S-BAH11 / N-SF10	MgF ₂ (400-700nm)	#45-351	S\$144.87 Volume Pricing	20+ In Stock
20.00	40.00	34.40	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#32-722	S\$144.87 Volume Pricing	20+ In Stock
20.00	50.00	46.93	N-SSK8 / N-SF56	MgF ₂ (400-700nm)	#49-933	S\$144.87 Volume Pricing	20+ In Stock
20.00	60.00	56.51	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-267	S\$144.87 Volume Pricing	20+ In Stock
20.00	80.00	77.26	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#49-934	S\$144.87 Volume Pricing	14 In Stock
25.00	25.00	14.85	N-BASF64 / N-SF66	MgF ₂ (400-700nm)	#65-553	S\$240.45 Volume Pricing	20+ In Stock
25.00	30.00	22.23	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-211	S\$165.78 Volume Pricing	20+ In Stock
25.00	35.00	27.55	S-BAH11 / N-SF10	MgF ₂ (400-700nm)	#32-319	S\$165.78 Volume Pricing	20+ In Stock
25.00	40.00	33.26	S-BAH11 / N-SF10	MgF ₂ (400-700nm)	#32-321	S\$162.79 Volume Pricing	20+ In Stock
25.00	45.00	39.28	N-SK11 / N-SF5	MgF ₂ (400-700nm)	#45-212	S\$162.79 Volume Pricing	20+ In Stock
25.00	50.00	43.53	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#32-323	S\$162.79 Volume Pricing	20+ In Stock
25.00	60.00	52.23	N-SSK8 / N-SF10	MgF ₂ (400-700nm)	#32-724	S\$162.79 Volume Pricing	20+ In Stock

25.00	75.00	70.39	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-325	S\$162.79 Volume Pricing	20+ In Stock
25.00	85.00	81.21	N-SK11 / N-SF5	MgF ₂ (400-700nm)	#45-213	S\$162.79 Volume Pricing	20+ In Stock
25.00	100.00	95.92	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-327	S\$162.79 Volume Pricing	20+ In Stock
25.00	125.00	120.89	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-492	S\$162.79 Volume Pricing	Contact Us
25.00	150.00	146.10	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-494	S\$162.79 Volume Pricing	20+ In Stock
25.00	160.00	157.87	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#67-328	S\$162.79 Volume Pricing	16 In Stock
25.00	175.00	170.84	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-884	S\$162.79 Volume Pricing	20+ In Stock
25.00	200.00	194.14	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-917	S\$162.79 Volume Pricing	20+ In Stock
25.00	225.00	222.69	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-214	S\$162.79 Volume Pricing	20+ In Stock
25.00	250.00	246.63	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-919	S\$162.79 Volume Pricing	20+ In Stock
25.00	275.00	271.60	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-414	S\$162.79 Volume Pricing	20+ In Stock
25.00	300.00	297.73	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-215	S\$162.79 Volume Pricing	20+ In Stock
25.00	400.00	397.84	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-216	S\$162.79 Volume Pricing	20+ In Stock
25.00	500.00	497.57	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-268	S\$162.79 Volume Pricing	20+ In Stock

25.00	750.00	746.47	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#67-329	S\$162.79 Volume Pricing	20+ In Stock
25.40	38.10	30.77	N-BAF10 / N-SF6	MgF ₂ (400-700nm)	#49-765	S\$162.79 Volume Pricing	20+ In Stock
25.40	50.80	44.90	N-SSK8 / N-SF56	MgF ₂ (400-700nm)	#49-766	S\$162.79 Volume Pricing	20+ In Stock
25.40	63.50	57.67	N-SSK8 / N-SF56	MgF ₂ (400-700nm)	#49-767	S\$162.79 Volume Pricing	20+ In Stock
25.40	76.20	71.14	N-SSK8 / N-SF56	MgF ₂ (400-700nm)	#49-768	S\$162.79 Volume Pricing	20+ In Stock
25.40	88.90	83.96	N-BAK1 / N-SF8	MgF ₂ (400-700nm)	#49-769	S\$162.79 Volume Pricing	20+ In Stock
25.40	101.60	97.72	N-BAK1 / N-SF15	MgF ₂ (400-700nm)	#49-770	S\$162.79 Volume Pricing	20+ In Stock
30.00	40.00	31.14	N-BAF10 / N-SF57	MgF ₂ (400-700nm)	#33-917	S\$194.16 Volume Pricing	20+ In Stock
30.00	100.00	94.54	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-500	S\$194.16 Volume Pricing	13 In Stock
30.00	125.00	121.37	N-SK11 / N-SF5	MgF ₂ (400-700nm)	#45-217	S\$194.16 Volume Pricing	20+ In Stock
30.00	150.00	144.63	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-502	S\$194.16 Volume Pricing	20+ In Stock
30.00	200.00	196.57	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-415	S\$194.16 Volume Pricing	20+ In Stock
30.00	300.00	296.85	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-269	S\$194.16 Volume Pricing	20+ In Stock
30.00	50.00	42.57	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#32-496	S\$194.16 Volume Pricing	Contact Us

30.00	60.00	52.50	N-SSK8 / N-SF10	MgF ₂ (400-700nm)	#45-140	S\$194.16 Volume Pricing	20+ In Stock
30.00	75.00	67.44	N-SSK8 / N-SF10	MgF ₂ (400-700nm)	#32-498	S\$194.16 Volume Pricing	20+ In Stock
40.00	50.00	34.46	N-SK11 / N-SF5	MgF ₂ (400-700nm)	#89-681	S\$241.95 Volume Pricing	6 In Stock
40.00	60.00	50.29	N-SK11 / N-SF5	MgF ₂ (400-700nm)	#45-218	S\$241.95 Volume Pricing	20+ In Stock
40.00	80.00	70.75	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-105	S\$241.95 Volume Pricing	20+ In Stock
40.00	100.00	91.24	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#63-701	S\$241.95 Volume Pricing	20+ In Stock
40.00	120.00	111.00	N-SSK8 / N-SF10	MgF ₂ (400-700nm)	#32-921	S\$241.95 Volume Pricing	20+ In Stock
40.00	160.00	154.10	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-923	S\$241.95 Volume Pricing	20+ In Stock
40.00	200.00	194.14	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-925	S\$241.95 Volume Pricing	20+ In Stock
40.00	250.00	244.32	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-935	S\$241.95 Volume Pricing	20+ In Stock
40.00	300.00	293.63	N-BAK4 / N-SF10	MgF ₂ (400-700nm)	#45-178	S\$241.95 Volume Pricing	20+ In Stock
40.00	400.00	394.33	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#32-927	S\$241.95 Volume Pricing	20+ In Stock
40.00	450.00	445.69	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-352	S\$241.95 Volume Pricing	20+ In Stock
40.00	500.00	495.60	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-270	S\$241.95 Volume Pricing	20+ In Stock

40.00	750.00	744.37	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#67-330	S\$241.95 Volume Pricing	20+ In Stock
50.00	75.00	61.17	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#49-291	S\$265.84 Volume Pricing	20+ In Stock
50.00	100.00	89.94	N-BAF10 / N-SF10	MgF ₂ (400-700nm)	#45-353	S\$259.87 Volume Pricing	14 In Stock
50.00	150.00	143.17	N-BAK4 / N-SF10	MgF ₂ (400-700nm)	#32-886	S\$259.87 Volume Pricing	20+ In Stock
50.00	200.00	194.45	N-BAK4 / N-SF10	MgF ₂ (400-700nm)	#45-179	S\$259.87 Volume Pricing	16 In Stock
50.00	250.00	243.41	N-BAK4 / N-SF10	MgF ₂ (400-700nm)	#45-180	S\$259.87 Volume Pricing	20+ In Stock
50.00	300.00	292.91	N-BAK4 / N-SF10	MgF ₂ (400-700nm)	#45-181	S\$259.87 Volume Pricing	20+ In Stock
50.00	350.00	344.32	N-BAK4 / N-SF10	MgF ₂ (400-700nm)	#45-354	S\$259.87 Volume Pricing	20+ In Stock
50.00	500.00	494.50	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-271	S\$259.87 Volume Pricing	20+ In Stock
75.00	100.00	78.32	N-BAF10 / N-SF57	MgF ₂ (400-700nm)	#33-918	S\$454.02 Volume Pricing	20+ In Stock
75.00	150.00	126.46	N-BAK1 / N-SF8	MgF ₂ (400-700nm)	#33-919	S\$454.02 Volume Pricing	20+ In Stock
75.00	200.00	187.69	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-417	S\$454.02 Volume Pricing	20+ In Stock
75.00	300.00	290.62	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-418	S\$454.02 Volume Pricing	20+ In Stock
75.00	400.00	392.10	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#45-419	S\$454.02 Volume Pricing	20+ In Stock

100.00	200.00	162.39	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#22-582	S\$1,590.58 Volume Pricing	Contact Us
100.00	400.00	372.86	N-BK7 / N-SF5	MgF ₂ (400-700nm)	#22-584	S\$1,590.58 Volume Pricing	20+ In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com