


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Float Glass](#)

TECHSPEC® First Surface Mirrors

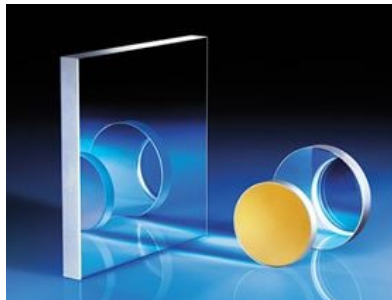


- Wide Variety of Shapes and Sizes Available
- Enhanced Aluminum, Protected Gold, and Protected Silver Coatings for high reflectivity from 450-10000nm
- [Contact Us](#) for Custom Sizes

Common Specifications

Optical Properties

Surface Flatness (P-V):	4 - 6λ	Substrate:	Float Glass
Surface Quality:	60-40	Coating Type:	Metal

Technical Information

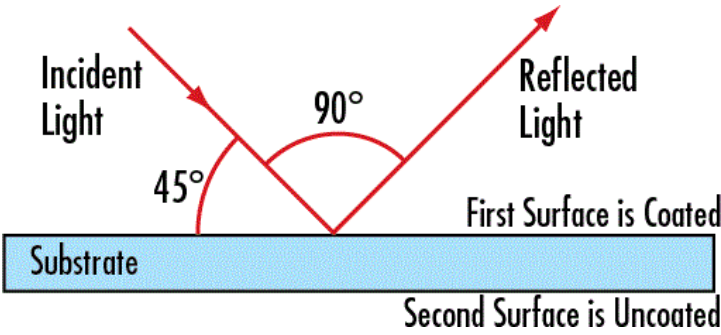

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Coating Specification	Surface Flatness (P-V)	Stock Number	Price	Buy
5.00	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-940	S\$39.90 Volume Pricing	20+ In Stock
-	6.0 x 6.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-866	S\$39.90 Volume Pricing	20+ In Stock
-	6.0 x 8.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-867	S\$39.90 Volume Pricing	20+ In Stock
6.35	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-610	S\$39.90 Volume Pricing	20+ In Stock
10.00	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-941	S\$39.90 Volume Pricing	20+ In Stock
-	10.0 x 10.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-517	S\$39.90 Volume Pricing	20+ In Stock
-	10.0 x 14.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-449	S\$39.90 Volume Pricing	20+ In Stock
12.50	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-942	S\$39.90 Volume Pricing	20+ In Stock
-	12.5 x 12.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-790	S\$39.90 Volume Pricing	20+ In Stock
-	12.5 x 17.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-869	S\$39.90 Volume Pricing	20+ In Stock
12.70	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-483	S\$39.90 Volume Pricing	20+ In Stock

-	12.7 x 12.7	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-484	S\$39.90 Volume Pricing	15 In Stock
15.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-943	S\$39.90 Volume Pricing	20+ In Stock
-	15.0 x 15.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-870	S\$39.90 Volume Pricing	6 In Stock
-	15.0 x 21.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-871	S\$39.90 Volume Pricing	20+ In Stock
18.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-521	S\$39.90 Volume Pricing	20+ In Stock
20.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-944	S\$43.40 Volume Pricing	20+ In Stock
-	20.0 x 20.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-872	S\$43.40 Volume Pricing	20+ In Stock
-	20.0 x 28.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-873	S\$43.40 Volume Pricing	Contact Us
25.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-945	S\$43.40 Volume Pricing	20+ In Stock
-	25.0 x 25.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-792	S\$43.40 Volume Pricing	20+ In Stock
-	25.0 x 35.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-875	S\$43.40 Volume Pricing	20+ In Stock
25.40	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-485	S\$43.40 Volume Pricing	20+ In Stock
-	25.4 x 25.4	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-486	S\$43.40 Volume Pricing	9 In Stock

30.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#46-025	S\$49.70 Volume Pricing	20+ In Stock
35.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#46-027	S\$49.70 Volume Pricing	20+ In Stock
-	35.0 x 35.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-519	S\$49.70 Volume Pricing	20+ In Stock
-	35.0 x 50.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-450	S\$49.70 Volume Pricing	20+ In Stock
38.10	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-487	S\$49.70 Volume Pricing	20+ In Stock
-	38.1 x 38.1	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-488	S\$49.70 Volume Pricing	20+ In Stock
40.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-612	S\$64.05 Volume Pricing	20+ In Stock
50.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-614	S\$64.05 Volume Pricing	20+ In Stock
-	50.0 x 50.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-876	S\$64.05 Volume Pricing	20+ In Stock
-	50.0 x 75.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-451	S\$64.05 Volume Pricing	20+ In Stock
50.80	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-489	S\$64.05 Volume Pricing	5 In Stock
-	50.8 x 50.8	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-490	S\$64.05 Volume Pricing	20+ In Stock
-	60.0 x 85.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#64-410	S\$77.00 Volume Pricing	20+ In Stock

75.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#45-616	S\$77.00 Volume Pricing	Contact Us
-	75.0 x 75.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#48-452	S\$77.00 Volume Pricing	10 In Stock
-	75.0 x 100.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#48-453	S\$77.00 Volume Pricing	20+ In Stock
76.20	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#83-491	S\$77.00 Volume Pricing	10 In Stock
-	76.2 x 76.2	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#83-492	S\$77.00 Volume Pricing	20+ In Stock
100.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#18-920	S\$89.60 Volume Pricing	20+ In Stock
-	100.00 x 100.00	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#18-922	S\$89.60 Volume Pricing	Contact Us
101.60	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#18-924	S\$89.60 Volume Pricing	9 In Stock
-	101.60 x 101.60	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#18-926	S\$89.60 Volume Pricing	20+ In Stock
125.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#18-928	S\$115.50 Volume Pricing	4 In Stock
-	125.00 x 125.00	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#18-930	S\$115.50 Volume Pricing	6 In Stock
127.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#18-932	S\$115.50 Volume Pricing	3 In Stock
-	127.00 x 127.00	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 45^\circ$ 450 - 650nm @ 45°	4 - 6λ	#18-934	S\$115.50 Volume Pricing	20+ In Stock

150.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-349	S\$142.80 Volume Pricing	16 In Stock
-	150.00 x 150.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-350	S\$142.80 Volume Pricing	10 In Stock
200.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-351	S\$190.40 Volume Pricing	11 In Stock
-	200.00 x 200.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-352	S\$190.40 Volume Pricing	9 In Stock
5.00	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-728	S\$60.20 Volume Pricing	Contact Us
-	6.0 x 6.0	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-877	S\$60.20 Volume Pricing	20+ In Stock
-	6.0 x 8.5	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-878	S\$60.20 Volume Pricing	20+ In Stock
6.35	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-611	S\$60.20 Volume Pricing	Contact Us
10.00	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-729	S\$60.20 Volume Pricing	20+ In Stock
-	10.0 x 10.0	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-518	S\$54.25 Volume Pricing	20+ In Stock
-	10.0 x 14.0	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-454	S\$60.20 Volume Pricing	16 In Stock

12.50	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-730	S\$60.20 Volume Pricing	20+ In Stock
-	12.5 x 12.5	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-791	S\$60.20 Volume Pricing	Contact Us
-	12.5 x 17.5	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-880	S\$60.20 Volume Pricing	9 In Stock
12.70	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-493	S\$60.20 Volume Pricing	5 In Stock
-	12.7 x 12.7	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-494	S\$60.20 Volume Pricing	Contact Us
15.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-731	S\$60.20 Volume Pricing	20+ In Stock
-	15.0 x 15.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-881	S\$60.20 Volume Pricing	20+ In Stock
-	15.0 x 21.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-882	S\$60.20 Volume Pricing	20+ In Stock
18.00	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-522	S\$60.20 Volume Pricing	20+ In Stock
20.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-732	S\$71.40 Volume Pricing	20+ In Stock

-	20.0 x 20.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-883	S\$71.40 Volume Pricing	20+ In Stock
-	20.0 x 28.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-884	S\$71.40 Volume Pricing	20+ In Stock
25.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-733	S\$71.40 Volume Pricing	20+ In Stock
-	25.0 x 25.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-793	S\$71.40 Volume Pricing	14 In Stock
-	25.0 x 35.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-886	S\$71.40 Volume Pricing	20+ In Stock
25.40	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-495	S\$71.40 Volume Pricing	20+ In Stock
-	25.4 x 25.4	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-496	S\$71.40 Volume Pricing	2 In Stock
30.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#46-026	S\$112.00 Volume Pricing	11 In Stock
35.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#46-028	S\$112.00 Volume Pricing	17 In Stock
-	35.0 x 35.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-520	S\$112.00 Volume Pricing	14 In Stock

-	35.0 x 50.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-455	S\$112.00 Volume Pricing	20+ In Stock
38.10	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-497	S\$112.00 Volume Pricing	5 In Stock
-	38.1 x 38.1	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-498	S\$112.00 Volume Pricing	17 In Stock
40.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-613	S\$131.60 Volume Pricing	5 In Stock
50.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-615	S\$131.60 Volume Pricing	20+ In Stock
-	50.0 x 50.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-887	S\$131.60 Volume Pricing	20+ In Stock
-	50.0 x 75.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-456	S\$131.60 Volume Pricing	10 In Stock
50.80	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-499	S\$131.60 Volume Pricing	12 In Stock
-	50.8 x 50.8	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-500	S\$131.60 Volume Pricing	2 In Stock
-	60.0 x 85.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#64-411	S\$173.60 Volume Pricing	20+ In Stock

75.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-617	S\$173.60 Volume Pricing	20+ In Stock
-	75.0 x 75.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-457	S\$173.60 Volume Pricing	14 In Stock
-	75.0 x 100.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-458	S\$173.60 Volume Pricing	13 In Stock
76.20	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-501	S\$173.60 Volume Pricing	20+ In Stock
-	76.2 x 76.2	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-502	S\$173.60 Volume Pricing	3 In Stock
100.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#22-431	S\$404.60 Volume Pricing	3 In Stock
-	100.0 x 100.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#22-432	S\$404.60 Volume Pricing	11 In Stock
-	100.00 x 140.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-427	S\$411.60 Volume Pricing	3 In Stock
-	85.00 x 120.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-426	S\$331.80 Volume Pricing	Contact Us

-	50.0 x 75.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-496	S\$77.70 Volume Pricing	14 In Stock
-	50.0 x 50.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-495	S\$77.70 Volume Pricing	20+ In Stock
50.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-494	S\$77.70 Volume Pricing	2 In Stock
-	40.00 x 57.50	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-424	S\$107.80 Volume Pricing	7 In Stock
-	35.0 x 50.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-490	S\$60.20 Volume Pricing	20+ In Stock
-	35.0 x 35.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-489	S\$60.20 Volume Pricing	20+ In Stock
35.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-488	S\$60.20 Volume Pricing	20+ In Stock
-	30.00 x 42.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-423	S\$77.70 Volume Pricing	8 In Stock
30.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-487	S\$60.20 Volume Pricing	20+ In Stock

-	25.0 x 35.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-484	S\$52.85 Volume Pricing	20+ In Stock
-	25.0 x 25.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-483	S\$52.85 Volume Pricing	11 In Stock
25.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-482	S\$52.85 Volume Pricing	Contact Us
-	20.0 x 28.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-481	S\$52.85 Volume Pricing	20+ In Stock
-	20.0 x 20.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-480	S\$52.85 Volume Pricing	20+ In Stock
20.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-479	S\$52.85 Volume Pricing	5 In Stock
-	15.0 x 21.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-477	S\$46.90 Volume Pricing	20+ In Stock
-	15.0 x 15.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-476	S\$46.90 Volume Pricing	20+ In Stock
15.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-475	S\$46.90 Volume Pricing	11 In Stock
-	17.50 x 25.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-422	S\$52.85 Volume Pricing	Contact Us

-	12.5 x 17.5	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-472	S\$46.90 Volume Pricing	20+ In Stock
-	12.5 x 12.5	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-471	S\$46.90 Volume Pricing	6 In Stock
12.50	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-470	S\$46.90 Volume Pricing	20+ In Stock
-	10.0 x 14.0	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-469	S\$46.90 Volume Pricing	20+ In Stock
-	10.0 x 10.0	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-468	S\$46.90 Volume Pricing	8 In Stock
10.00	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-467	S\$46.90 Volume Pricing	20+ In Stock
-	8.00 x 11.50	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-421	S\$46.90 Volume Pricing	12 In Stock
6.35	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-466	S\$46.90 Volume Pricing	11 In Stock
-	6.0 x 8.5	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-465	S\$46.90 Volume Pricing	20+ In Stock
-	6.0 x 6.0	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-464	S\$46.90 Volume Pricing	20+ In Stock

-	5.00 x 7.50	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-420	S\$46.90 Volume Pricing	11 In Stock
-	5.00 x 5.00	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-419	S\$46.90 Volume Pricing	13 In Stock
5.00	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-463	S\$46.90 Volume Pricing	20+ In Stock
12.70	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-040	S\$46.90 Volume Pricing	20+ In Stock
-	12.7 x 12.7	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-041	S\$46.90 Volume Pricing	20+ In Stock
18.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-042	S\$46.90 Volume Pricing	20+ In Stock
25.40	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-043	S\$52.85 Volume Pricing	20+ In Stock
-	25.4 x 25.4	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-044	S\$52.85 Volume Pricing	11 In Stock
38.10	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-045	S\$60.20 Volume Pricing	20+ In Stock

-	38.1 x 38.1	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-046	S\$60.20 Volume Pricing	20+ In Stock
40.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-048	S\$77.70 Volume Pricing	20+ In Stock
50.80	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-049	S\$77.70 Volume Pricing	20+ In Stock
-	50.8 x 50.8	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-050	S\$77.70 Volume Pricing	Contact Us
-	60.0 x 85.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-051	S\$107.80 Volume Pricing	11 In Stock
-	63.50 x 88.90	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-425	S\$126.00 Volume Pricing	5 In Stock
75.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-053	S\$107.80 Volume Pricing	20+ In Stock
-	75.0 x 75.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-054	S\$107.80 Volume Pricing	13 In Stock
-	75.0 x 100.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-055	S\$107.80 Volume Pricing	20+ In Stock
76.20	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-056	S\$107.80 Volume Pricing	10 In Stock

-	76.2 x 76.2	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-057	S\$107.80 Volume Pricing	15 In Stock
100.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#22-443	S\$301.00 Volume Pricing	13 In Stock
-	100.0 x 100.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#22-444	S\$301.00 Volume Pricing	13 In Stock
-	125.0 x 125.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#22-448	S\$411.60 Volume Pricing	8 In Stock
-	150.0 x 150.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#22-452	S\$569.80 Volume Pricing	6 In Stock
-	200.0 x 200.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#22-454	S\$889.00 Volume Pricing	Contact Us
-	5.0 x 5.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-408	S\$39.90 Volume Pricing	8 In Stock
-	5.0 x 7.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-409	S\$39.90 Volume Pricing	9 In Stock
-	8.0 x 11.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-410	S\$39.90 Volume Pricing	20+ In Stock
-	17.5 x 25.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-411	S\$39.90 Volume Pricing	20+ In Stock
-	30.0 x 42.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-412	S\$49.70 Volume Pricing	20+ In Stock

-	40.0 x 57.5	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-413	S\$64.05 Volume Pricing	12 In Stock
-	63.5 x 88.9	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-414	S\$77.00 Volume Pricing	7 In Stock
-	85.0 x 120.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-415	S\$83.30 Volume Pricing	13 In Stock
-	100.0 x 140.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-416	S\$115.50 Volume Pricing	20+ In Stock
-	125.00 x 175.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-413	S\$137.20 Volume Pricing	8 In Stock
225.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-414	S\$212.80 Volume Pricing	8 In Stock
-	225.00 x 225.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-415	S\$212.80 Volume Pricing	9 In Stock
250.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-416	S\$238.00 Volume Pricing	8 In Stock
-	250.00 x 250.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-417	S\$238.00 Volume Pricing	5 In Stock
-	250.00 x 350.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-418	S\$312.20 Volume Pricing	Contact Us
300.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-419	S\$288.40 Volume Pricing	2 In Stock
-	300.00 x 300.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-420	S\$288.40 Volume Pricing	20+ In Stock
-	400.0 x 400.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-417	S\$494.20 Volume Pricing	11 In Stock

-	500.0 x 500.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-418	S\$655.20 Volume Pricing	9 In Stock
---	---------------	------	-------------------------------	---	--------	-------------------------	---	------------



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com