

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

Traditional Coated 193 – 399nm Bandpass Interference Filters



- Available in UV, Visible, and IR Center Wavelengths
- 10 – 80nm Bandwidths Available
- Ideal for Biomedical Applications and Instrumentation Integration
- 193-399nm, [400-699nm](#), and [700-1650nm](#) CWL Options Available

Common Specifications




Physical & Mechanical Properties

Construction:	Mounted in Black Anodized Ring
---------------	--------------------------------

Optical Properties

Angle of Incidence (°):		0	
Coating:		Traditional Coated	
Surface Quality:		80-50	

Technical Information

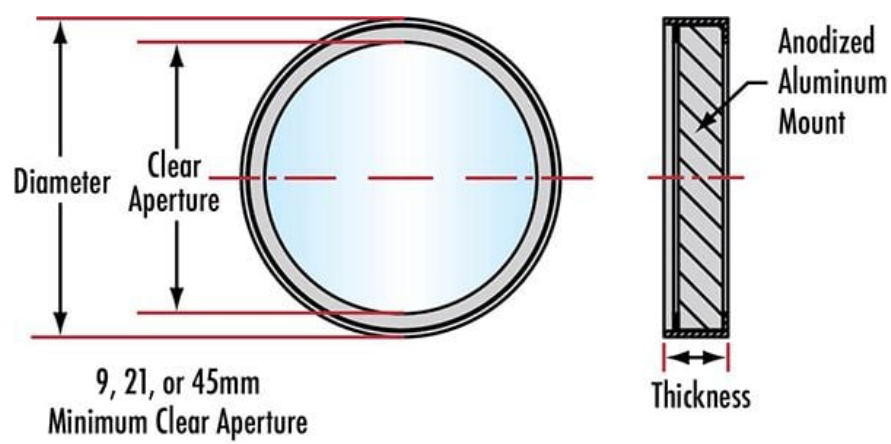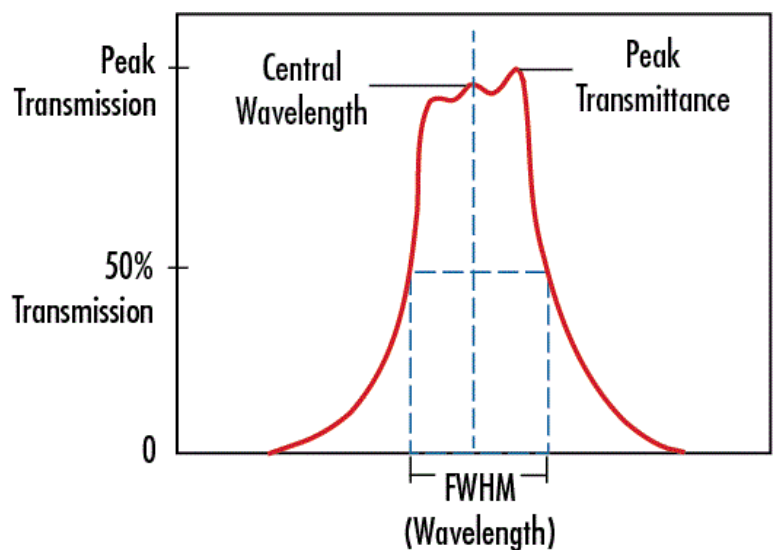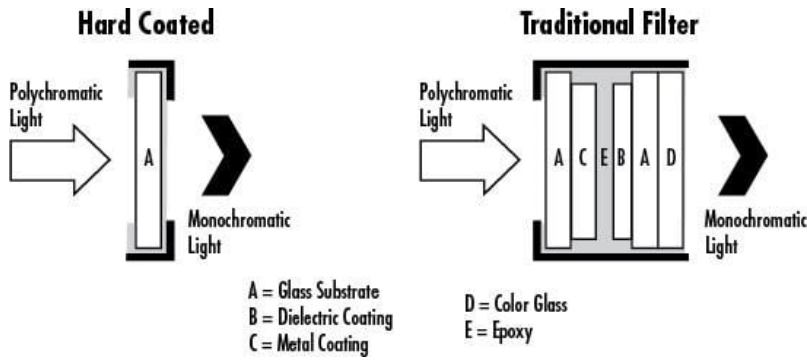

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Minimum Transmission (%)	Blocking Wavelength Range (nm)	Dimensions (mm)	Stock Number	Price	Buy
12.50	193.00	15.00	>12	200 - 10000	-	#67-732	S\$328.57 Volume Pricing	3 In Stock
25.00	193.00	15.00	>12	200 - 10000	-	#67-799	S\$500.32 Volume Pricing	4 In Stock
50.00	193.00	15.00	>12	200 - 10000	-	#67-866	S\$851.30 Volume Pricing	1 In Stock
12.50	200.00	10.00	>12	200 - 10000	-	#67-733	S\$328.57 Volume Pricing	3 In Stock
25.00	200.00	10.00	>12	200 - 10000	-	#67-800	S\$500.32 Volume Pricing	3 In Stock
50.00	200.00	10.00	>12	200 - 10000	-	#67-867	S\$851.30 Volume Pricing	2 In Stock
12.50	214.00	10.00	>12	200 - 10000	-	#67-734	S\$328.57 Volume Pricing	5 In Stock
25.00	214.00	10.00	>12	200 - 10000	-	#67-801	S\$500.32 Volume Pricing	2 In Stock
50.00	214.00	10.00	>12	200 - 10000	-	#67-868	S\$851.30 Volume Pricing	2 In Stock
12.50	220.00	10.00	>12	200 - 10000	-	#67-735	S\$328.57 Volume Pricing	20+ In Stock
25.00	220.00	10.00	12	200 - 10000	-	#67-802	S\$500.32 Volume Pricing	9 In Stock
50.00	220.00	10.00	>12	200 - 10000	-	#67-869	S\$851.30 Volume Pricing	2 In Stock
12.50	228.00	10.00	>15	200 - 10000	-	#67-736	S\$328.57 Volume Pricing	20+ In Stock
25.00	228.00	10.00	>15	200 - 10000	-	#67-803	S\$500.32 Volume Pricing	1 In Stock
50.00	228.00	10.00	>15	200 - 10000	-	#67-870	S\$851.30 Volume Pricing	2 In Stock
12.50	228.00	25.00	>20	200 - 10000	-	#68-336	S\$328.57 Volume Pricing	Contact Us
25.00	228.00	25.00	>20	200 - 10000	-	#68-337	S\$500.32 Volume Pricing	3 In Stock
50.00	228.00	25.00	>20	200 - 10000	-	#68-338	S\$851.30 Volume Pricing	2 In Stock
12.50	232.00	10.00	>15	200 - 10000	-	#67-737	S\$328.57 Volume Pricing	6 In Stock

25.00	232.00	10.00	>15	200 - 10000	-	#67-804	S\$500.32 Volume Pricing	2 In Stock
50.00	232.00	10.00	>15	200 - 10000	-	#67-871	S\$851.30 Volume Pricing	2 In Stock
12.50	239.00	10.00	>15	200 - 10000	-	#67-738	S\$328.57 Volume Pricing	3 In Stock
25.00	239.00	10.00	>15	200 - 10000	-	#67-805	S\$500.32 Volume Pricing	1 In Stock
50.00	239.00	10.00	>15	200 - 10000	-	#67-872	S\$851.30 Volume Pricing	2 In Stock
12.50	248.00	10.00	>12	200 - 10000	-	#67-739	S\$328.57 Volume Pricing	3 In Stock
25.00	248.00	10.00	>12	200 - 10000	-	#67-806	S\$500.32 Volume Pricing	2 In Stock
50.00	248.00	10.00	>12	200 - 10000	-	#67-873	S\$851.30 Volume Pricing	1 In Stock
12.50	250.00	10.00	>12	200 - 10000	-	#67-740	S\$241.95 Volume Pricing	5 In Stock
25.00	250.00	10.00	>12	200 - 10000	-	#67-807	S\$413.70 Volume Pricing	1 In Stock
50.00	250.00	10.00	>12	200 - 10000	-	#67-874	S\$761.69 Volume Pricing	2 In Stock
12.50	254.00	10.00	>12	200 - 10000	-	#67-741	S\$241.95 Volume Pricing	10 In Stock
25.00	254.00	10.00	>12	200 - 10000	-	#67-808	S\$413.70 Volume Pricing	3 In Stock
50.00	254.00	10.00	>12	200 - 10000	-	#67-875	S\$761.69 Volume Pricing	1 In Stock
12.50	254.00	40.00	>20	200 - 10000	-	#67-742	S\$241.95 Volume Pricing	4 In Stock
25.00	254.00	40.00	>20	200 - 10000	-	#67-809	S\$413.70 Volume Pricing	2 In Stock
50.00	254.00	40.00	>20	200 - 10000	-	#67-876	S\$761.69 Volume Pricing	1 In Stock
12.50	260.00	10.00	>12	200 - 10000	-	#67-743	S\$241.95 Volume Pricing	3 In Stock
25.00	260.00	10.00	>12	200 - 10000	-	#67-810	S\$413.70 Volume Pricing	3 In Stock
50.00	260.00	10.00	>12	200 - 10000	-	#67-877	S\$761.69 Volume Pricing	1 In Stock
12.50	265.00	10.00	>12	200 - 10000	-	#67-744	S\$241.95 Volume Pricing	5 In Stock
25.00	265.00	10.00	>12	200 - 10000	-	#67-811	S\$413.70 Volume Pricing	6 In Stock

50.00	265.00	10.00	>12	200 - 10000	-	#67-878	S\$761.69 Volume Pricing	1 In Stock
12.50	270.00	10.00	>12	200 - 10000	-	#67-745	S\$241.95 Volume Pricing	3 In Stock
25.00	270.00	10.00	>12	200 - 10000	-	#67-812	S\$413.70 Volume Pricing	1 In Stock
50.00	270.00	10.00	>12	200 - 10000	-	#67-879	S\$761.69 Volume Pricing	1 In Stock
12.50	280.00	10.00	>12	200 - 10000	-	#67-746	S\$241.95 Volume Pricing	12 In Stock
25.00	280.00	10.00	>12	200 - 10000	-	#67-813	S\$413.70 Volume Pricing	2 In Stock
50.00	280.00	10.00	>12	200 - 10000	-	#67-880	S\$761.69 Volume Pricing	2 In Stock
12.50	289.00	10.00	>15	200 - 10000	-	#67-747	S\$241.95 Volume Pricing	2 In Stock
25.00	289.00	10.00	>15	200 - 10000	-	#67-814	S\$413.70 Volume Pricing	1 In Stock
50.00	289.00	10.00	>15	200 - 10000	-	#67-881	S\$761.69 Volume Pricing	1 In Stock
12.50	297.00	10.00	>15	200 - 10000	-	#67-748	S\$241.95 Volume Pricing	3 In Stock
25.00	297.00	10.00	>15	200 - 10000	-	#67-815	S\$413.70 Volume Pricing	1 In Stock
50.00	297.00	10.00	>15	200 - 10000	-	#67-882	S\$761.69 Volume Pricing	1 In Stock
12.50	300.00	10.00	>15	200 - 10000	-	#67-749	S\$241.95 Volume Pricing	3 In Stock
12.50	300.00	40.00	>20	200 - 10000	-	#67-750	S\$241.95 Volume Pricing	4 In Stock
25.00	300.00	10.00	>15	200 - 10000	-	#67-816	S\$413.70 Volume Pricing	3 In Stock
25.00	300.00	40.00	>20	200 - 10000	-	#67-817	S\$413.70 Volume Pricing	2 In Stock
50.00	300.00	10.00	>15	200 - 10000	-	#67-883	S\$761.69 Volume Pricing	2 In Stock
50.00	300.00	40.00	>20	200 - 10000	-	#67-884	S\$761.69 Volume Pricing	1 In Stock
25.00	320.00	10.00	>25	200 - 10000	-	#67-821	S\$413.70 Volume Pricing	3 In Stock
12.50	307.00	10.00	>15	200 - 10000	-	#67-751	S\$241.95 Volume Pricing	5 In Stock
25.00	307.00	10.00	>15	200 - 10000	-	#67-818	S\$413.70 Volume Pricing	1 In Stock

50.00	307.00	10.00	>15	200 - 10000	-	#67-885	S\$761.69 Volume Pricing	2 In Stock
12.50	310.00	10.00	>15	200 - 10000	-	#67-752	S\$241.95 Volume Pricing	11 In Stock
25.00	310.00	10.00	>15	200 - 10000	-	#67-819	S\$413.70 Volume Pricing	Contact Us
50.00	310.00	10.00	>15	200 - 10000	-	#67-886	S\$761.69 Volume Pricing	2 In Stock
12.50	313.00	10.00	>15	200 - 10000	-	#67-753	S\$241.95 Volume Pricing	2 In Stock
25.00	313.00	10.00	>15	200 - 10000	-	#67-820	S\$413.70 Volume Pricing	1 In Stock
50.00	313.00	10.00	>15	200 - 10000	-	#67-887	S\$761.69 Volume Pricing	2 In Stock
12.50	320.00	10.00	>25	200 - 10000	-	#67-754	S\$241.95 Volume Pricing	1 In Stock
50.00	320.00	10.00	>25	200 - 10000	-	#67-888	S\$761.69 Volume Pricing	1 In Stock
12.50	326.00	10.00	>25	200 - 10000	-	#67-755	S\$241.95 Volume Pricing	4 In Stock
25.00	326.00	10.00	>25	200 - 10000	-	#67-822	S\$413.70 Volume Pricing	3 In Stock
50.00	326.00	10.00	>25	200 - 10000	-	#67-889	S\$761.69 Volume Pricing	Contact Us
12.50	330.00	10.00	>25	200 - 10000	-	#67-756	S\$241.95 Volume Pricing	5 In Stock
25.00	330.00	10.00	>25	200 - 10000	-	#67-823	S\$413.70 Volume Pricing	Contact Us
50.00	330.00	10.00	>25	200 - 10000	-	#67-890	S\$761.69 Volume Pricing	14 In Stock
12.50	350.00	10.00	>25	200 - 10000	-	#67-757	S\$241.95 Volume Pricing	2 In Stock
12.50	350.00	40.00	>25	200 - 10000	-	#67-758	S\$241.95 Volume Pricing	5 In Stock
25.00	350.00	10.00	>25	200 - 10000	-	#67-824	S\$413.70 Volume Pricing	1 In Stock
25.00	350.00	40.00	>25	200 - 10000	-	#67-825	S\$413.70 Volume Pricing	3 In Stock
50.00	350.00	10.00	>25	200 - 10000	-	#67-891	S\$761.69 Volume Pricing	1 In Stock
50.00	350.00	40.00	>25	200 - 10000	-	#67-892	S\$761.69 Volume Pricing	1 In Stock
12.50	355.00	10.00	>25	200 - 10000	-	#67-759	S\$241.95 Volume Pricing	3 In Stock

25.00	355.00	10.00	>25	200 - 10000	-	#67-826	S\$413.70 Volume Pricing	2 In Stock
50.00	355.00	10.00	>25	200 - 10000	-	#67-893	S\$761.69 Volume Pricing	2 In Stock
12.50	360.00	10.00	>25	200 - 10000	-	#67-760	S\$241.95 Volume Pricing	5 In Stock
25.00	360.00	10.00	>25	200 - 10000	-	#67-827	S\$413.70 Volume Pricing	2 In Stock
50.00	360.00	10.00	>25	200 - 10000	-	#67-894	S\$761.69 Volume Pricing	1 In Stock
12.50	370.00	10.00	>25	200 - 10000	-	#67-761	S\$241.95 Volume Pricing	5 In Stock
25.00	370.00	10.00	>25	200 - 10000	-	#67-828	S\$413.70 Volume Pricing	2 In Stock
50.00	370.00	10.00	>25	200 - 10000	-	#67-895	S\$761.69 Volume Pricing	1 In Stock
12.50	380.00	10.00	>25	200 - 10000	-	#67-762	S\$241.95 Volume Pricing	3 In Stock
25.00	380.00	10.00	>25	200 - 10000	-	#67-829	S\$413.70 Volume Pricing	3 In Stock
50.00	380.00	10.00	>25	200 - 10000	-	#67-896	S\$761.69 Volume Pricing	Contact Us
12.50	390.00	10.00	>40	200 - 10000	-	#67-763	S\$241.95 Volume Pricing	11 In Stock
25.00	390.00	10.00	>40	200 - 10000	-	#67-830	S\$413.70 Volume Pricing	2 In Stock
50.00	390.00	10.00	>40	200 - 10000	-	#67-897	S\$761.69 Volume Pricing	1 In Stock
12.50	394.00	10.00	≥30	200 - 1200	-	#65-616	S\$241.95 Volume Pricing	3 In Stock
25.00	394.00	10.00	≥30	200 - 1200	-	#65-676	S\$413.70 Volume Pricing	5 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com