

[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)

TECHSPEC® Sapphire Windows



- Features Extreme Surface Hardness Chemical Resistance
- Transmits Wavelengths Ranging From UV to Mid-Infrared
- Thinner and Stronger than Standard Glass Windows
- Anti-Reflection Coating Options Covering 350 - 5000nm Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	≥90
Edges:	Fine Ground	Knoop Hardness (kg/mm²):	1,900.00
Poisson's Ratio:	0.27	Young's Modulus (GPa):	435



Optical Properties

Abbe Number (v_d):	72.24	Axis Orientation:	Random
Birefringence (n_o-n_e):	0.008 for Visible Light Orthogonal to Optical Axis	Index of Refraction (n_d):	1.77
Substrate:	Sapphire (Al ₂ O ₃)	Surface Quality:	80-50


Material Properties

Coefficient of Thermal Expansion CTE (10⁻⁶/°C):	5.4 (Parallel to C-Axis) 4.3 (Perpendicular to C-Axis)	Density (g/cm³):	3.97
---	---	------------------------------------	------


Technical Information

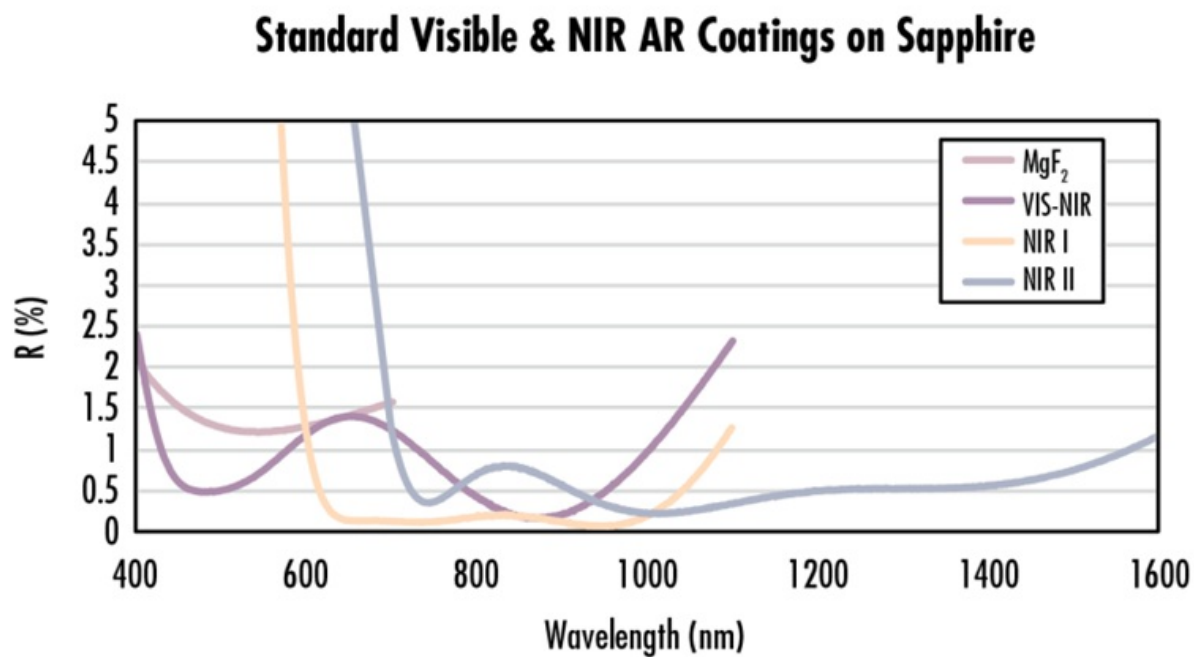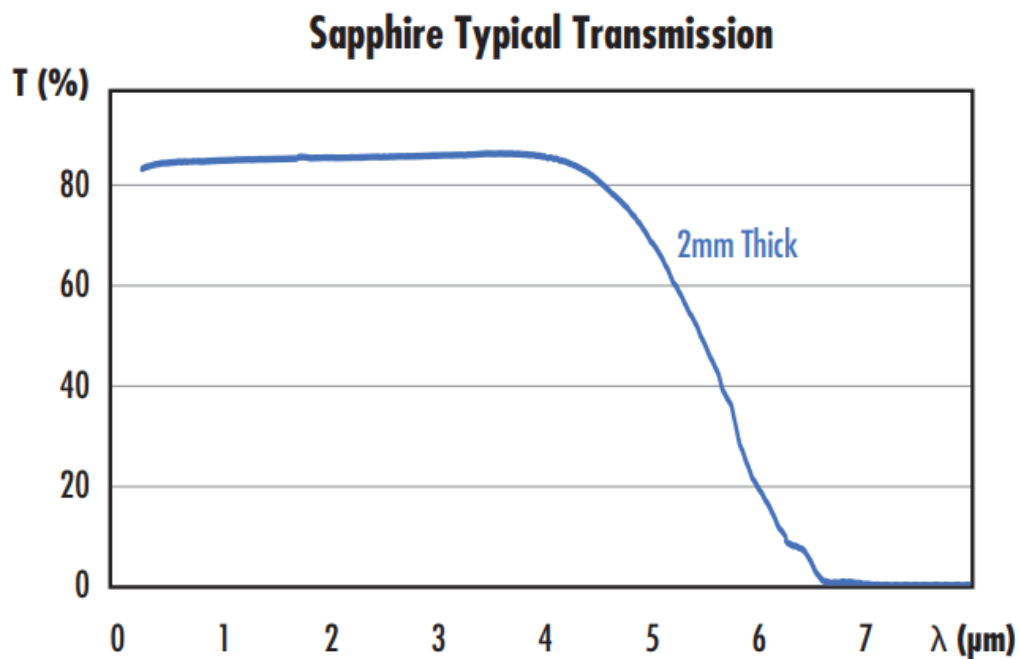

Infrared BBAR Coatings on Sapphire

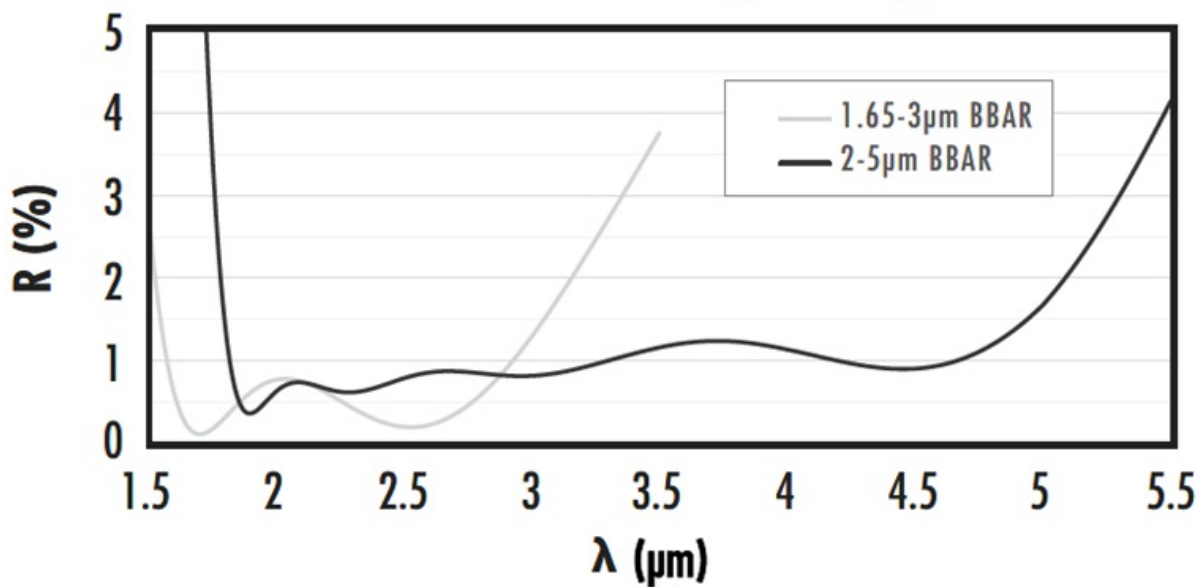

Infrared AR Coated Sapphire Windows 1mm Thickness

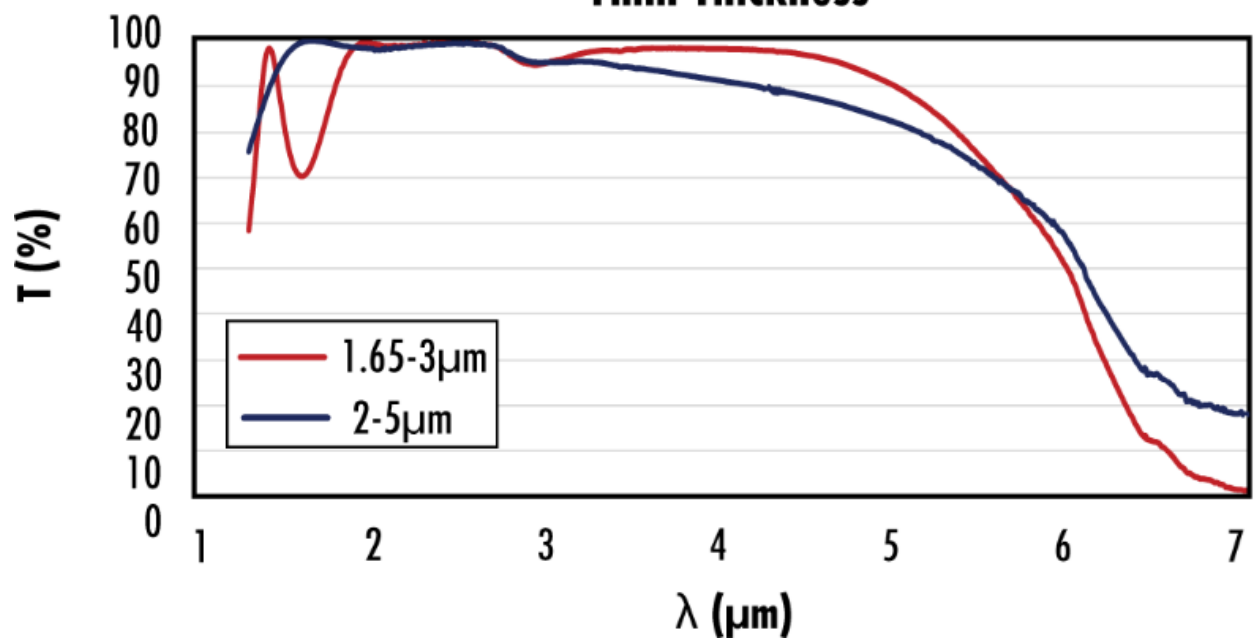

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
1.00	-	0.50	Uncoated	#17-216	S\$35.00 Volume Pricing	20+ In Stock
2.50	-	0.50	Uncoated	#43-627	S\$35.00 Volume Pricing	20+ In Stock
3.20	-	1.00	Uncoated	#17-217	S\$35.00 Volume Pricing	20+ In Stock
5.00	-	0.20	Uncoated	#71-217	S\$48.00 Volume Pricing	20+ In Stock
5.00	-	0.50	Uncoated	#17-218	S\$48.00 Volume Pricing	20+ In Stock
5.00	-	1.00	Uncoated	#43-365	S\$48.00 Volume Pricing	Contact Us
5.00	-	2.00	Uncoated	#25-376	S\$48.00 Volume Pricing	20+ In Stock
5.00	-	3.00	Uncoated	#25-377	S\$48.00 Volume Pricing	20+ In Stock
5.00	-	0.50	MgF ₂ (400-700nm)	#20-623	S\$71.00 Volume Pricing	7 In Stock
5.00	-	1.00	MgF ₂ (400-700nm)	#36-197	S\$71.00 Volume Pricing	8 In Stock
5.00	-	2.00	MgF ₂ (400-700nm)	#25-386	S\$71.00 Volume Pricing	3 In Stock
5.00	-	3.00	MgF ₂ (400-700nm)	#25-387	S\$71.00 Volume Pricing	1 In Stock
5.00	-	0.50	VIS-EXT (350-700nm)	#28-512	S\$79.00 Volume Pricing	7 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#28-513	S\$79.00 Volume Pricing	20+ In Stock

5.00	-	2.00	VIS-EXT (350-700nm)	#28-514	S\$79.00 Volume Pricing	5 In Stock
5.00	-	3.00	VIS-EXT (350-700nm)	#28-515	S\$79.00 Volume Pricing	10 In Stock
5.00	-	0.50	VIS-NIR (400-1000nm)	#20-741	S\$79.00 Volume Pricing	3 In Stock
5.00	-	1.00	VIS-NIR (400-1000nm)	#36-577	S\$79.00 Volume Pricing	4 In Stock
5.00	-	2.00	VIS-NIR (400-1000nm)	#25-396	S\$79.00 Volume Pricing	5 In Stock
5.00	-	3.00	VIS-NIR (400-1000nm)	#25-397	S\$79.00 Volume Pricing	2 In Stock
5.00	-	0.50	NIR I (600-1050nm)	#20-838	S\$79.00 Volume Pricing	3 In Stock
5.00	-	1.00	NIR I (600-1050nm)	#36-477	S\$79.00 Volume Pricing	10 In Stock
5.00	-	2.00	NIR I (600-1050nm)	#25-406	S\$79.00 Volume Pricing	4 In Stock
5.00	-	3.00	NIR I (600-1050nm)	#25-407	S\$79.00 Volume Pricing	2 In Stock
5.00	-	0.50	NIR II (750-1550nm)	#20-904	S\$79.00 Volume Pricing	10 In Stock
5.00	-	1.00	NIR II (750-1550nm)	#36-562	S\$79.00 Volume Pricing	Contact Us
5.00	-	2.00	NIR II (750-1550nm)	#25-416	S\$79.00 Volume Pricing	2 In Stock
5.00	-	3.00	NIR II (750-1550nm)	#25-417	S\$79.00 Volume Pricing	2 In Stock

5.00	-	0.50	BBAR (1650-3000nm)	#20-974	S\$101.00 Volume Pricing	7 In Stock
5.00	-	1.00	BBAR (1650-3000nm)	#15-988	S\$101.00 Volume Pricing	20+ In Stock
5.00	-	2.00	BBAR (1650-3000nm)	#25-426	S\$101.00 Volume Pricing	4 In Stock
5.00	-	3.00	BBAR (1650-3000nm)	#25-427	S\$101.00 Volume Pricing	5 In Stock
5.00	-	0.50	BBAR (2000-5000nm)	#21-011	S\$101.00 Volume Pricing	5 In Stock
5.00	-	1.00	BBAR (2000-5000nm)	#16-000	S\$101.00 Volume Pricing	5 In Stock
5.00	-	2.00	BBAR (2000-5000nm)	#25-436	S\$101.00 Volume Pricing	4 In Stock
5.00	-	3.00	BBAR (2000-5000nm)	#25-437	S\$101.00 Volume Pricing	5 In Stock
6.35	-	0.20	Uncoated	#71-218	S\$48.00 Volume Pricing	20+ In Stock
6.35	-	0.50	Uncoated	#45-567	S\$48.00 Volume Pricing	20+ In Stock
6.35	-	1.00	Uncoated	#17-219	S\$48.00 Volume Pricing	Contact Us
6.35	-	2.00	Uncoated	#17-220	S\$48.00 Volume Pricing	20+ In Stock
6.35	-	0.50	MgF ₂ (400-700nm)	#39-231	S\$71.00 Volume Pricing	20+ In Stock
6.35	-	1.00	MgF ₂ (400-700nm)	#20-627	S\$71.00 Volume Pricing	1 In Stock
6.35	-	2.00	MgF ₂ (400-700nm)	#20-629	S\$71.00 Volume Pricing	2 In Stock

6.35	-	0.50	VIS-EXT (350-700nm)	#28-516	S\$79.00 Volume Pricing	1 In Stock
6.35	-	1.00	VIS-EXT (350-700nm)	#28-517	S\$79.00 Volume Pricing	14 In Stock
6.35	-	2.00	VIS-EXT (350-700nm)	#28-518	S\$79.00 Volume Pricing	5 In Stock
6.35	-	0.50	VIS-NIR (400-1000nm)	#39-246	S\$79.00 Volume Pricing	10 In Stock
6.35	-	1.00	VIS-NIR (400-1000nm)	#20-760	S\$79.00 Volume Pricing	6 In Stock
6.35	-	2.00	VIS-NIR (400-1000nm)	#20-763	S\$79.00 Volume Pricing	4 In Stock
6.35	-	0.50	NIR I (600-1050nm)	#39-252	S\$79.00 Volume Pricing	9 In Stock
6.35	-	1.00	NIR I (600-1050nm)	#20-839	S\$79.00 Volume Pricing	1 In Stock
6.35	-	2.00	NIR I (600-1050nm)	#20-841	S\$79.00 Volume Pricing	12 In Stock
6.35	-	0.50	NIR II (750-1550nm)	#39-262	S\$79.00 Volume Pricing	Contact Us
6.35	-	1.00	NIR II (750-1550nm)	#20-908	S\$79.00 Volume Pricing	Contact Us
6.35	-	2.00	NIR II (750-1550nm)	#20-913	S\$79.00 Volume Pricing	1 In Stock
6.35	-	0.50	BBAR (1650-3000nm)	#15-989	S\$101.00 Volume Pricing	11 In Stock
6.35	-	1.00	BBAR (1650-3000nm)	#20-976	S\$101.00 Volume Pricing	7 In Stock

6.35	-	2.00	BBAR (1650-3000nm)	#20-977	S\$101.00 Volume Pricing	5 In Stock
6.35	-	0.50	BBAR (2000-5000nm)	#16-001	S\$101.00 Volume Pricing	4 In Stock
6.35	-	1.00	BBAR (2000-5000nm)	#21-013	S\$101.00 Volume Pricing	2 In Stock
6.35	-	2.00	BBAR (2000-5000nm)	#21-015	S\$101.00 Volume Pricing	4 In Stock
7.50	-	0.40	Uncoated	#43-628	S\$48.00 Volume Pricing	20+ In Stock
9.50	-	0.50	Uncoated	#43-629	S\$48.00 Volume Pricing	20+ In Stock
10.00	-	0.20	Uncoated	#71-221	S\$66.00 Volume Pricing	20+ In Stock
10.00	-	0.50	Uncoated	#17-221	S\$66.00 Volume Pricing	20+ In Stock
10.00	-	1.00	Uncoated	#43-366	S\$66.00 Volume Pricing	20+ In Stock
10.00	-	2.00	Uncoated	#25-378	S\$66.00 Volume Pricing	20+ In Stock
10.00	-	3.00	Uncoated	#25-379	S\$66.00 Volume Pricing	20+ In Stock
10.00	-	0.50	MgF ₂ (400-700nm)	#20-633	S\$89.00 Volume Pricing	5 In Stock
10.00	-	1.00	MgF ₂ (400-700nm)	#36-201	S\$89.00 Volume Pricing	9 In Stock
10.00	-	2.00	MgF ₂ (400-700nm)	#25-388	S\$89.00 Volume Pricing	4 In Stock
10.00	-	3.00	MgF ₂ (400-700nm)	#25-389	S\$89.00 Volume Pricing	1 In Stock
10.00	-	0.50	VIS-EXT (350-700nm)	#28-519	S\$96.00 Volume Pricing	7 In Stock

10.00	-	1.00	VIS-EXT (350-700nm)	#28-553	S\$96.00 Volume Pricing	1 In Stock
10.00	-	2.00	VIS-EXT (350-700nm)	#28-554	S\$96.00 Volume Pricing	4 In Stock
10.00	-	3.00	VIS-EXT (350-700nm)	#28-555	S\$96.00 Volume Pricing	12 In Stock
10.00	-	0.50	VIS-NIR (400-1000nm)	#20-765	S\$96.00 Volume Pricing	4 In Stock
10.00	-	1.00	VIS-NIR (400-1000nm)	#36-578	S\$96.00 Volume Pricing	11 In Stock
10.00	-	0.50	NIR I (600-1050nm)	#20-848	S\$96.00 Volume Pricing	Contact Us
10.00	-	1.00	NIR I (600-1050nm)	#36-487	S\$96.00 Volume Pricing	6 In Stock
10.00	-	0.50	NIR II (750-1550nm)	#20-914	S\$96.00 Volume Pricing	5 In Stock
10.00	-	1.00	NIR II (750-1550nm)	#36-566	S\$96.00 Volume Pricing	Contact Us
10.00	-	2.00	VIS-NIR (400-1000nm)	#25-398	S\$96.00 Volume Pricing	Contact Us
10.00	-	3.00	VIS-NIR (400-1000nm)	#25-399	S\$96.00 Volume Pricing	11 In Stock
10.00	-	2.00	NIR I (600-1050nm)	#25-408	S\$96.00 Volume Pricing	5 In Stock
10.00	-	3.00	NIR I (600-1050nm)	#25-409	S\$96.00 Volume Pricing	16 In Stock
10.00	-	2.00	NIR II (750-1550nm)	#25-418	S\$96.00 Volume Pricing	20+ In Stock

10.00	-	3.00	NIR II (750-1550nm)	#25-419	S\$96.00 Volume Pricing	3 In Stock
10.00	-	0.50	BBAR (1650-3000nm)	#20-981	S\$118.00 Volume Pricing	3 In Stock
10.00	-	1.00	BBAR (1650-3000nm)	#15-990	S\$118.00 Volume Pricing	Contact Us
10.00	-	2.00	BBAR (1650-3000nm)	#25-428	S\$118.00 Volume Pricing	2 In Stock
10.00	-	3.00	BBAR (1650-3000nm)	#25-429	S\$118.00 Volume Pricing	4 In Stock
10.00	-	0.50	BBAR (2000-5000nm)	#21-016	S\$118.00 Volume Pricing	Contact Us
10.00	-	1.00	BBAR (2000-5000nm)	#16-002	S\$118.00 Volume Pricing	2 In Stock
10.00	-	2.00	BBAR (2000-5000nm)	#25-438	S\$118.00 Volume Pricing	5 In Stock
10.00	-	3.00	BBAR (2000-5000nm)	#25-439	S\$118.00 Volume Pricing	5 In Stock
12.50	-	1.00	VIS-EXT (350-700nm)	#28-556	S\$100.00 Volume Pricing	2 In Stock
12.50	-	1.00	Uncoated	#36-252	S\$69.00 Volume Pricing	20+ In Stock
12.50	-	1.00	MgF ₂ (400-700nm)	#36-202	S\$92.00 Volume Pricing	9 In Stock
12.50	-	1.00	VIS-NIR (400-1000nm)	#36-579	S\$100.00 Volume Pricing	20+ In Stock
12.50	-	1.00	NIR I (600-1050nm)	#36-488	S\$100.00 Volume Pricing	15 In Stock

12.50	-	1.00	NIR II (750-1550nm)	#36-567	S\$100.00 Volume Pricing	9 In Stock
12.50	-	1.00	BBAR (1650-3000nm)	#15-991	S\$121.00 Volume Pricing	Contact Us
12.50	-	1.00	BBAR (2000-5000nm)	#16-003	S\$121.00 Volume Pricing	Contact Us
-	12.50 x 12.50	1.00	Uncoated	#39-228	S\$69.00 Volume Pricing	20+ In Stock
12.70	-	0.20	Uncoated	#71-224	S\$71.00 Volume Pricing	20+ In Stock
12.70	-	0.50	Uncoated	#17-222	S\$71.00 Volume Pricing	20+ In Stock
12.70	-	1.00	Uncoated	#17-223	S\$71.00 Volume Pricing	20+ In Stock
12.70	-	2.00	Uncoated	#17-224	S\$71.00 Volume Pricing	20+ In Stock
12.70	-	3.18	Uncoated	#68-157	S\$71.00 Volume Pricing	20+ In Stock
12.70	-	0.50	MgF ₂ (400-700nm)	#20-634	S\$95.00 Volume Pricing	5 In Stock
12.70	-	1.00	MgF ₂ (400-700nm)	#20-635	S\$95.00 Volume Pricing	1 In Stock
12.70	-	2.00	MgF ₂ (400-700nm)	#20-638	S\$95.00 Volume Pricing	6 In Stock
12.70	-	3.18	MgF ₂ (400-700nm)	#39-232	S\$95.00 Volume Pricing	2 In Stock
12.70	-	1.00	VIS-EXT (350-700nm)	#28-558	S\$102.00 Volume Pricing	11 In Stock
12.70	-	2.00	VIS-EXT (350-700nm)	#28-559	S\$102.00 Volume Pricing	14 In Stock
12.70	-	3.18	VIS-EXT (350-700nm)	#28-560	S\$102.00 Volume Pricing	10 In Stock

12.70	-	0.50	VIS-NIR (400-1000nm)	#20-766	S\$102.00 Volume Pricing	20+ In Stock
12.70	-	1.00	VIS-NIR (400-1000nm)	#20-771	S\$102.00 Volume Pricing	5 In Stock
12.70	-	2.00	VIS-NIR (400-1000nm)	#20-788	S\$102.00 Volume Pricing	5 In Stock
12.70	-	3.18	VIS-NIR (400-1000nm)	#39-247	S\$102.00 Volume Pricing	17 In Stock
12.70	-	0.50	NIR I (600-1050nm)	#20-850	S\$102.00 Volume Pricing	5 In Stock
12.70	-	1.00	NIR I (600-1050nm)	#20-857	S\$102.00 Volume Pricing	15 In Stock
12.70	-	2.00	NIR I (600-1050nm)	#20-859	S\$102.00 Volume Pricing	5 In Stock
12.70	-	3.18	NIR I (600-1050nm)	#39-253	S\$102.00 Volume Pricing	1 In Stock
12.70	-	0.50	NIR II (750-1550nm)	#20-918	S\$102.00 Volume Pricing	6 In Stock
12.70	-	1.00	NIR II (750-1550nm)	#20-926	S\$102.00 Volume Pricing	12 In Stock
12.70	-	2.00	NIR II (750-1550nm)	#20-927	S\$102.00 Volume Pricing	5 In Stock
12.70	-	3.18	NIR II (750-1550nm)	#39-263	S\$102.00 Volume Pricing	10 In Stock
12.70	-	0.50	BBAR (1650-3000nm)	#21-000	S\$123.00 Volume Pricing	5 In Stock
12.70	-	0.50	VIS-EXT (350-700nm)	#28-557	S\$102.00 Volume Pricing	5 In Stock

12.70	-	1.00	BBAR (1650-3000nm)	#21-001	S\$123.00 Volume Pricing	Contact Us
12.70	-	2.00	BBAR (1650-3000nm)	#21-002	S\$123.00 Volume Pricing	5 In Stock
12.70	-	3.18	BBAR (1650-3000nm)	#15-992	S\$123.00 Volume Pricing	1 In Stock
12.70	-	0.50	BBAR (2000-5000nm)	#21-017	S\$123.00 Volume Pricing	10 In Stock
12.70	-	1.00	BBAR (2000-5000nm)	#21-018	S\$123.00 Volume Pricing	14 In Stock
12.70	-	2.00	BBAR (2000-5000nm)	#21-019	S\$123.00 Volume Pricing	13 In Stock
12.70	-	3.18	BBAR (2000-5000nm)	#16-004	S\$123.00 Volume Pricing	20+ In Stock
12.75	-	1.00	Uncoated	#43-631	S\$71.00 Volume Pricing	20+ In Stock
13.00	-	0.50	Uncoated	#43-632	S\$71.00 Volume Pricing	20+ In Stock
15.00	-	0.20	Uncoated	#71-225	S\$91.00 Volume Pricing	10 In Stock
15.00	-	0.50	Uncoated	#17-225	S\$91.00 Volume Pricing	12 In Stock
15.00	-	1.00	Uncoated	#17-226	S\$91.00 Volume Pricing	20+ In Stock
15.00	-	2.00	Uncoated	#43-367	S\$91.00 Volume Pricing	Contact Us
15.00	-	0.50	MgF ₂ (400-700nm)	#20-642	S\$113.00 Volume Pricing	5 In Stock
15.00	-	1.00	MgF ₂ (400-700nm)	#20-647	S\$113.00 Volume Pricing	3 In Stock
15.00	-	2.00	MgF ₂ (400-700nm)	#36-206	S\$113.00 Volume Pricing	6 In Stock

15.00	-	0.50	VIS-EXT (350-700nm)	#28-561	S\$121.00 Volume Pricing	Contact Us
15.00	-	1.00	VIS-EXT (350-700nm)	#28-562	S\$121.00 Volume Pricing	2 In Stock
15.00	-	2.00	VIS-EXT (350-700nm)	#28-563	S\$121.00 Volume Pricing	Contact Us
15.00	-	0.50	VIS-NIR (400-1000nm)	#20-792	S\$121.00 Volume Pricing	9 In Stock
15.00	-	1.00	VIS-NIR (400-1000nm)	#20-793	S\$121.00 Volume Pricing	16 In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#36-580	S\$121.00 Volume Pricing	7 In Stock
15.00	-	0.50	NIR I (600-1050nm)	#20-867	S\$121.00 Volume Pricing	5 In Stock
15.00	-	1.00	NIR I (600-1050nm)	#20-870	S\$121.00 Volume Pricing	9 In Stock
15.00	-	2.00	NIR I (600-1050nm)	#36-492	S\$121.00 Volume Pricing	Contact Us
15.00	-	0.50	NIR II (750-1550nm)	#20-936	S\$121.00 Volume Pricing	4 In Stock
15.00	-	1.00	NIR II (750-1550nm)	#20-939	S\$121.00 Volume Pricing	4 In Stock
15.00	-	2.00	NIR II (750-1550nm)	#36-571	S\$121.00 Volume Pricing	16 In Stock
15.00	-	0.50	BBAR (1650-3000nm)	#21-003	S\$143.00 Volume Pricing	6 In Stock
15.00	-	1.00	BBAR (1650-3000nm)	#21-004	S\$143.00 Volume Pricing	3 In Stock

15.00	-	2.00	BBAR (1650-3000nm)	#15-993	S\$143.00 Volume Pricing	2 In Stock
15.00	-	0.50	BBAR (2000-5000nm)	#21-020	S\$143.00 Volume Pricing	5 In Stock
15.00	-	1.00	BBAR (2000-5000nm)	#21-021	S\$143.00 Volume Pricing	12 In Stock
15.00	-	2.00	BBAR (2000-5000nm)	#16-005	S\$143.00 Volume Pricing	20+ In Stock
17.25	-	1.00	Uncoated	#71-226	S\$91.00 Volume Pricing	6 In Stock
17.25	-	2.00	Uncoated	#43-633	S\$91.00 Volume Pricing	20+ In Stock
20.00	-	0.20	Uncoated	#71-227	S\$112.00 Volume Pricing	20+ In Stock
20.00	-	0.50	Uncoated	#17-227	S\$112.00 Volume Pricing	20+ In Stock
20.00	-	1.00	Uncoated	#17-228	S\$112.00 Volume Pricing	20+ In Stock
20.00	-	2.00	Uncoated	#43-368	S\$112.00 Volume Pricing	Contact Us
20.00	-	3.00	Uncoated	#25-380	S\$112.00 Volume Pricing	20+ In Stock
20.00	-	0.50	MgF ₂ (400-700nm)	#20-660	S\$135.00 Volume Pricing	5 In Stock
20.00	-	1.00	MgF ₂ (400-700nm)	#20-663	S\$135.00 Volume Pricing	9 In Stock
20.00	-	2.00	MgF ₂ (400-700nm)	#36-457	S\$135.00 Volume Pricing	20+ In Stock
20.00	-	3.00	MgF ₂ (400-700nm)	#25-390	S\$135.00 Volume Pricing	1 In Stock
20.00	-	0.50	VIS-EXT (350-700nm)	#28-564	S\$143.00 Volume Pricing	5 In Stock

20.00	-	1.00	VIS-EXT (350-700nm)	#28-565	S\$143.00 Volume Pricing	4 In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#28-566	S\$143.00 Volume Pricing	1 In Stock
20.00	-	3.00	VIS-EXT (350-700nm)	#28-572	S\$143.00 Volume Pricing	6 In Stock
20.00	-	0.50	VIS-NIR (400-1000nm)	#20-797	S\$143.00 Volume Pricing	2 In Stock
20.00	-	1.00	VIS-NIR (400-1000nm)	#20-798	S\$143.00 Volume Pricing	1 In Stock
20.00	-	2.00	VIS-NIR (400-1000nm)	#36-581	S\$143.00 Volume Pricing	Contact Us
20.00	-	3.00	VIS-NIR (400-1000nm)	#25-400	S\$143.00 Volume Pricing	Contact Us
20.00	-	0.50	NIR I (600-1050nm)	#20-873	S\$143.00 Volume Pricing	2 In Stock
20.00	-	1.00	NIR I (600-1050nm)	#20-874	S\$143.00 Volume Pricing	3 In Stock
20.00	-	2.00	NIR I (600-1050nm)	#36-498	S\$143.00 Volume Pricing	17 In Stock
20.00	-	0.50	NIR II (750-1550nm)	#20-941	S\$143.00 Volume Pricing	9 In Stock
20.00	-	1.00	NIR II (750-1550nm)	#20-945	S\$143.00 Volume Pricing	20+ In Stock
20.00	-	2.00	NIR II (750-1550nm)	#36-573	S\$143.00 Volume Pricing	1 In Stock
20.00	-	3.00	NIR I (600-1050nm)	#25-410	S\$143.00 Volume Pricing	5 In Stock

20.00	-	3.00	NIR II (750-1550nm)	#25-420	S\$143.00 Volume Pricing	3 In Stock
20.00	-	0.50	BBAR (1650-3000nm)	#21-005	S\$166.00 Volume Pricing	6 In Stock
20.00	-	1.00	BBAR (1650-3000nm)	#21-006	S\$166.00 Volume Pricing	10 In Stock
20.00	-	2.00	BBAR (1650-3000nm)	#15-994	S\$166.00 Volume Pricing	20+ In Stock
20.00	-	3.00	BBAR (1650-3000nm)	#25-430	S\$166.00 Volume Pricing	2 In Stock
20.00	-	0.50	BBAR (2000-5000nm)	#21-022	S\$166.00 Volume Pricing	5 In Stock
20.00	-	1.00	BBAR (2000-5000nm)	#21-023	S\$166.00 Volume Pricing	20+ In Stock
20.00	-	2.00	BBAR (2000-5000nm)	#16-007	S\$166.00 Volume Pricing	13 In Stock
20.00	-	3.00	BBAR (2000-5000nm)	#25-440	S\$166.00 Volume Pricing	4 In Stock
22.00	-	1.00	Uncoated	#43-634	S\$112.00 Volume Pricing	20+ In Stock
23.00	-	1.50	Uncoated	#23-290	S\$112.00 Volume Pricing	20+ In Stock
23.75	-	1.00	Uncoated	#43-635	S\$112.00 Volume Pricing	20+ In Stock
25.00	-	0.20	Uncoated	#71-229	S\$147.00 Volume Pricing	20+ In Stock
25.00	-	0.50	Uncoated	#17-229	S\$147.00 Volume Pricing	20+ In Stock
25.00	-	1.00	Uncoated	#17-230	S\$147.00 Volume Pricing	20+ In Stock
25.00	-	2.30	Uncoated	#43-369	S\$147.00 Volume Pricing	Contact Us

25.00	-	0.50	MgF ₂ (400-700nm)	#20-676	S\$169.00 Volume Pricing	5 In Stock
25.00	-	1.00	MgF ₂ (400-700nm)	#20-681	S\$169.00 Volume Pricing	3 In Stock
25.00	-	2.30	MgF ₂ (400-700nm)	#36-460	S\$169.00 Volume Pricing	12 In Stock
25.00	-	0.50	VIS-EXT (350-700nm)	#28-688	S\$176.00 Volume Pricing	3 In Stock
25.00	-	1.00	VIS-EXT (350-700nm)	#28-689	S\$176.00 Volume Pricing	11 In Stock
25.00	-	2.30	VIS-EXT (350-700nm)	#28-690	S\$176.00 Volume Pricing	5 In Stock
25.00	-	0.50	VIS-NIR (400-1000nm)	#20-810	S\$176.00 Volume Pricing	3 In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#20-815	S\$176.00 Volume Pricing	20+ In Stock
25.00	-	2.30	VIS-NIR (400-1000nm)	#36-582	S\$176.00 Volume Pricing	4 In Stock
25.00	-	0.50	NIR I (600-1050nm)	#20-880	S\$176.00 Volume Pricing	13 In Stock
25.00	-	1.00	NIR I (600-1050nm)	#20-886	S\$176.00 Volume Pricing	4 In Stock
25.00	-	2.30	NIR I (600-1050nm)	#36-550	S\$176.00 Volume Pricing	3 In Stock
25.00	-	0.50	NIR II (750-1550nm)	#20-951	S\$176.00 Volume Pricing	5 In Stock
25.00	-	1.00	NIR II (750-1550nm)	#20-955	S\$176.00 Volume Pricing	20+ In Stock

25.00	-	2.30	NIR II (750- 1550nm)	#36-576	S\$176.00 Volume Pricing	20+ In Stock
25.00	-	0.50	BBAR (1650- 3000nm)	#21-007	S\$207.00 Volume Pricing	8 In Stock
25.00	-	1.00	BBAR (1650- 3000nm)	#21-008	S\$207.00 Volume Pricing	13 In Stock
25.00	-	2.30	BBAR (1650- 3000nm)	#15-995	S\$207.00 Volume Pricing	9 In Stock
25.00	-	0.50	BBAR (2000- 5000nm)	#21-024	S\$207.00 Volume Pricing	3 In Stock
25.00	-	1.00	BBAR (2000- 5000nm)	#21-060	S\$207.00 Volume Pricing	11 In Stock
25.00	-	2.30	BBAR (2000- 5000nm)	#16-008	S\$207.00 Volume Pricing	16 In Stock
25.40	-	0.20	Uncoated	#71-230	S\$147.00 Volume Pricing	20+ In Stock
25.40	-	0.50	Uncoated	#17-231	S\$147.00 Volume Pricing	20+ In Stock
25.40	-	1.00	Uncoated	#17-232	S\$147.00 Volume Pricing	20+ In Stock
25.40	-	2.25	Uncoated	#43-636	S\$147.00 Volume Pricing	20+ In Stock
25.40	-	5.00	Uncoated	#25-381	S\$147.00 Volume Pricing	3 In Stock
25.40	-	0.50	MgF ₂ (400- 700nm)	#20-689	S\$169.00 Volume Pricing	1 In Stock
25.40	-	1.00	MgF ₂ (400- 700nm)	#20-690	S\$169.00 Volume Pricing	2 In Stock
25.40	-	2.30	MgF ₂ (400- 700nm)	#39-233	S\$169.00 Volume Pricing	6 In Stock
25.40	-	5.00	MgF ₂ (400- 700nm)	#25-391	S\$169.00 Volume Pricing	4 In Stock

25.40	-	0.50	VIS-EXT (350-700nm)	#28-691	S\$176.00 Volume Pricing	1 In Stock
25.40	-	1.00	VIS-EXT (350-700nm)	#28-692	S\$176.00 Volume Pricing	3 In Stock
25.40	-	2.30	VIS-EXT (350-700nm)	#28-693	S\$176.00 Volume Pricing	5 In Stock
25.40	-	5.00	VIS-EXT (350-700nm)	#28-694	S\$176.00 Volume Pricing	8 In Stock
25.40	-	0.50	VIS-NIR (400-1000nm)	#20-834	S\$176.00 Volume Pricing	5 In Stock
25.40	-	1.00	VIS-NIR (400-1000nm)	#20-836	S\$176.00 Volume Pricing	5 In Stock
25.40	-	2.30	VIS-NIR (400-1000nm)	#39-248	S\$176.00 Volume Pricing	Contact Us
25.40	-	5.00	VIS-NIR (400-1000nm)	#25-401	S\$176.00 Volume Pricing	3 In Stock
25.40	-	0.50	NIR I (600-1050nm)	#20-901	S\$176.00 Volume Pricing	7 In Stock
25.40	-	1.00	NIR I (600-1050nm)	#20-903	S\$176.00 Volume Pricing	5 In Stock
25.40	-	2.30	NIR I (600-1050nm)	#39-254	S\$176.00 Volume Pricing	9 In Stock
25.40	-	5.00	NIR I (600-1050nm)	#25-411	S\$176.00 Volume Pricing	5 In Stock
25.40	-	0.50	NIR II (750-1550nm)	#20-963	S\$176.00 Volume Pricing	5 In Stock
25.40	-	1.00	NIR II (750-1550nm)	#20-971	S\$176.00 Volume Pricing	11 In Stock

25.40	-	2.30	NIR II (750-1550nm)	#39-264	S\$176.00 Volume Pricing	10 In Stock
25.40	-	5.00	NIR II (750-1550nm)	#25-421	S\$176.00 Volume Pricing	5 In Stock
25.40	-	0.50	BBAR (1650-3000nm)	#21-009	S\$207.00 Volume Pricing	6 In Stock
25.40	-	1.00	BBAR (1650-3000nm)	#21-010	S\$207.00 Volume Pricing	13 In Stock
25.40	-	2.30	BBAR (1650-3000nm)	#15-996	S\$207.00 Volume Pricing	Contact Us
25.40	-	5.00	BBAR (1650-3000nm)	#25-431	S\$207.00 Volume Pricing	Contact Us
25.40	-	0.50	BBAR (2000-5000nm)	#21-061	S\$207.00 Volume Pricing	9 In Stock
25.40	-	1.00	BBAR (2000-5000nm)	#21-062	S\$207.00 Volume Pricing	10 In Stock
25.40	-	2.30	BBAR (2000-5000nm)	#16-009	S\$207.00 Volume Pricing	Contact Us
25.40	-	5.00	BBAR (2000-5000nm)	#25-441	S\$207.00 Volume Pricing	Contact Us
-	25.40 x 25.40	1.00	Uncoated	#39-230	S\$172.00 Volume Pricing	20+ In Stock
28.00	-	1.50	Uncoated	#23-291	S\$193.00 Volume Pricing	14 In Stock
30.00	-	0.50	Uncoated	#71-231	S\$186.00 Volume Pricing	14 In Stock
30.00	-	1.00	Uncoated	#48-919	S\$193.00 Volume Pricing	20+ In Stock
30.00	-	2.00	Uncoated	#25-382	S\$193.00 Volume Pricing	20+ In Stock
30.00	-	1.00	MgF ₂ (400-700nm)	#39-234	S\$225.00 Volume Pricing	5 In Stock

30.00	-	2.00	MgF ₂ (400-700nm)	#25-392	S\$225.00 Volume Pricing	Contact Us
30.00	-	1.00	VIS-EXT (350-700nm)	#28-695	S\$256.00 Volume Pricing	Contact Us
30.00	-	2.00	VIS-EXT (350-700nm)	#28-696	S\$256.00 Volume Pricing	8 In Stock
30.00	-	1.00	VIS-NIR (400-1000nm)	#37-702	S\$256.00 Volume Pricing	9 In Stock
30.00	-	2.00	VIS-NIR (400-1000nm)	#25-402	S\$256.00 Volume Pricing	5 In Stock
30.00	-	1.00	NIR I (600-1050nm)	#39-256	S\$256.00 Volume Pricing	10 In Stock
30.00	-	2.00	NIR I (600-1050nm)	#25-412	S\$256.00 Volume Pricing	1 In Stock
30.00	-	1.00	NIR II (750-1550nm)	#39-265	S\$256.00 Volume Pricing	20+ In Stock
30.00	-	2.00	NIR II (750-1550nm)	#25-422	S\$256.00 Volume Pricing	2 In Stock
30.00	-	1.00	BBAR (1650-3000nm)	#15-997	S\$278.00 Volume Pricing	13 In Stock
30.00	-	2.00	BBAR (1650-3000nm)	#25-432	S\$278.00 Volume Pricing	5 In Stock
30.00	-	1.00	BBAR (2000-5000nm)	#16-010	S\$278.00 Volume Pricing	20+ In Stock
30.00	-	2.00	BBAR (2000-5000nm)	#25-442	S\$278.00 Volume Pricing	2 In Stock
31.60	-	1.50	Uncoated	#23-292	S\$193.00 Volume Pricing	20+ In Stock
31.75	-	1.00	Uncoated	#43-637	S\$193.00 Volume Pricing	Contact Us

31.75	-	1.00	MgF ₂ (400-700nm)	#39-236	S\$225.00 Volume Pricing	20+ In Stock
31.75	-	1.00	VIS-EXT (350-700nm)	#28-697	S\$256.00 Volume Pricing	5 In Stock
31.75	-	1.00	VIS-NIR (400-1000nm)	#39-249	S\$256.00 Volume Pricing	4 In Stock
31.75	-	1.00	NIR I (600-1050nm)	#39-257	S\$256.00 Volume Pricing	20+ In Stock
31.75	-	1.00	NIR II (750-1550nm)	#39-266	S\$256.00 Volume Pricing	5 In Stock
35.00	-	1.00	Uncoated	#48-920	S\$307.00 Volume Pricing	20+ In Stock
35.00	-	2.20	Uncoated	#23-293	S\$307.00 Volume Pricing	20+ In Stock
35.00	-	1.00	MgF ₂ (400-700nm)	#39-238	S\$338.00 Volume Pricing	5 In Stock
35.00	-	1.00	VIS-EXT (350-700nm)	#28-698	S\$370.00 Volume Pricing	Contact Us
35.00	-	1.00	VIS-NIR (400-1000nm)	#39-250	S\$370.00 Volume Pricing	20+ In Stock
35.00	-	1.00	NIR I (600-1050nm)	#39-258	S\$370.00 Volume Pricing	8 In Stock
35.00	-	1.00	NIR II (750-1550nm)	#39-267	S\$368.00 Volume Pricing	3 In Stock
38.00	-	1.50	Uncoated	#23-294	S\$351.00 Volume Pricing	20+ In Stock
38.10	-	1.00	Uncoated	#45-568	S\$351.00 Volume Pricing	20+ In Stock
38.10	-	1.00	MgF ₂ (400-700nm)	#39-242	S\$391.00 Volume Pricing	Contact Us

38.10	-	1.00	VIS-EXT (350-700nm)	#28-699	S\$415.00 Volume Pricing	4 In Stock
38.10	-	1.00	VIS-NIR (400-1000nm)	#39-251	S\$415.00 Volume Pricing	13 In Stock
38.10	-	1.00	NIR I (600-1050nm)	#39-259	S\$415.00 Volume Pricing	3 In Stock
38.10	-	1.00	NIR II (750-1550nm)	#39-268	S\$415.00 Volume Pricing	5 In Stock
40.00	-	1.00	Uncoated	#25-383	S\$387.00 Volume Pricing	20+ In Stock
40.00	-	2.00	Uncoated	#48-921	S\$387.00 Volume Pricing	20+ In Stock
40.00	-	1.00	MgF ₂ (400-700nm)	#25-393	S\$426.00 Volume Pricing	3 In Stock
40.00	-	2.00	MgF ₂ (400-700nm)	#39-243	S\$426.00 Volume Pricing	4 In Stock
40.00	-	2.00	VIS-EXT (350-700nm)	#28-703	S\$457.00 Volume Pricing	16 In Stock
40.00	-	1.00	VIS-EXT (350-700nm)	#28-702	S\$457.00 Volume Pricing	3 In Stock
40.00	-	1.00	VIS-NIR (400-1000nm)	#25-403	S\$457.00 Volume Pricing	16 In Stock
40.00	-	2.00	VIS-NIR (400-1000nm)	#37-703	S\$457.00 Volume Pricing	12 In Stock
40.00	-	1.00	NIR I (600-1050nm)	#25-413	S\$457.00 Volume Pricing	5 In Stock
40.00	-	2.00	NIR I (600-1050nm)	#39-260	S\$457.00 Volume Pricing	20+ In Stock
40.00	-	1.00	NIR II (750-1550nm)	#25-423	S\$457.00 Volume Pricing	4 In Stock

40.00	-	2.00	NIR II (750-1550nm)	#39-269	S\$455.00 Volume Pricing	5 In Stock
40.00	-	1.00	BBAR (1650-3000nm)	#25-433	S\$478.00 Volume Pricing	4 In Stock
40.00	-	2.00	BBAR (1650-3000nm)	#15-998	S\$478.00 Volume Pricing	3 In Stock
40.00	-	1.00	BBAR (2000-5000nm)	#25-443	S\$478.00 Volume Pricing	5 In Stock
40.00	-	2.00	BBAR (2000-5000nm)	#16-011	S\$478.00 Volume Pricing	9 In Stock
40.20	-	1.50	Uncoated	#23-295	S\$387.00 Volume Pricing	20+ In Stock
43.20	-	1.50	Uncoated	#23-296	S\$435.00 Volume Pricing	Contact Us
50.00	-	1.00	Uncoated	#25-384	S\$576.00 Volume Pricing	14 In Stock
50.00	-	1.00	MgF ₂ (400-700nm)	#25-394	S\$628.00 Volume Pricing	1 In Stock
50.00	-	1.00	VIS-EXT (350-700nm)	#28-704	S\$643.00 Volume Pricing	5 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#25-404	S\$643.00 Volume Pricing	1 In Stock
50.00	-	1.00	NIR I (600-1050nm)	#25-414	S\$643.00 Volume Pricing	3 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#25-424	S\$643.00 Volume Pricing	2 In Stock
50.00	-	1.00	BBAR (1650-3000nm)	#25-434	S\$681.00 Volume Pricing	4 In Stock
50.00	-	1.00	BBAR (2000-5000nm)	#25-444	S\$681.00 Volume Pricing	1 In Stock

50.80	-	0.50	Uncoated	#71-233	S\$576.00 Volume Pricing	8 In Stock
50.80	-	1.00	Uncoated	#25-385	S\$576.00 Volume Pricing	20+ In Stock
50.80	-	3.18	Uncoated	#45-817	S\$576.00 Volume Pricing	20+ In Stock
50.80	-	1.00	MgF ₂ (400-700nm)	#25-395	S\$628.00 Volume Pricing	1 In Stock
50.80	-	3.18	MgF ₂ (400-700nm)	#39-245	S\$628.00 Volume Pricing	6 In Stock
50.80	-	3.18	VIS-EXT (350-700nm)	#28-706	S\$643.00 Volume Pricing	9 In Stock
50.80	-	1.00	VIS-EXT (350-700nm)	#28-705	S\$643.00 Volume Pricing	20+ In Stock
50.80	-	1.00	VIS-NIR (400-1000nm)	#25-405	S\$643.00 Volume Pricing	8 In Stock
50.80	-	3.18	VIS-NIR (400-1000nm)	#37-704	S\$643.00 Volume Pricing	8 In Stock
50.80	-	1.00	NIR I (600-1050nm)	#25-415	S\$643.00 Volume Pricing	4 In Stock
50.80	-	3.18	NIR I (600-1050nm)	#39-261	S\$643.00 Volume Pricing	11 In Stock
50.80	-	1.00	NIR II (750-1550nm)	#25-425	S\$643.00 Volume Pricing	4 In Stock
50.80	-	3.18	NIR II (750-1550nm)	#39-270	S\$643.00 Volume Pricing	8 In Stock
50.80	-	1.00	BBAR (1650-3000nm)	#25-435	S\$681.00 Volume Pricing	5 In Stock
50.80	-	3.18	BBAR (1650-3000nm)	#15-999	S\$687.00 Volume Pricing	7 In Stock

50.80	-	1.00	BBAR (2000-5000nm)	#25-445	S\$681.00 Volume Pricing	3 In Stock
50.80	-	3.18	BBAR (2000-5000nm)	#16-013	S\$681.00 Volume Pricing	Contact Us
55.00	-	2.00	Uncoated	#23-297	S\$668.00 Volume Pricing	20+ In Stock
59.20	-	1.50	Uncoated	#23-298	S\$744.00 Volume Pricing	20+ In Stock
63.50	-	2.00	Uncoated	#48-922	S\$788.00 Volume Pricing	20+ In Stock
75.00	-	1.00	Uncoated	#71-234	S\$1,216.00 Volume Pricing	5 In Stock
75.00	-	2.00	Uncoated	#47-542	S\$1,223.00 Volume Pricing	14 In Stock
75.00	-	2.00	MgF ₂ (400-700nm)	#18-947	S\$1,311.00 Volume Pricing	4 In Stock
75.00	-	2.00	VIS-EXT (350-700nm)	#28-707	S\$1,342.00 Volume Pricing	2 In Stock
75.00	-	2.00	VIS-NIR (400-1000nm)	#18-948	S\$1,349.00 Volume Pricing	20+ In Stock
75.00	-	2.00	NIR I (600-1050nm)	#18-949	S\$1,349.00 Volume Pricing	2 In Stock
75.00	-	2.00	NIR II (750-1550nm)	#18-950	S\$1,349.00 Volume Pricing	9 In Stock
75.00	-	2.00	BBAR (1650-3000nm)	#18-951	S\$1,386.00 Volume Pricing	4 In Stock
75.00	-	2.00	BBAR (2000-5000nm)	#18-952	S\$1,386.00 Volume Pricing	Contact Us
100.00	-	2.00	Uncoated	#17-233	S\$1,727.00 Volume Pricing	9 In Stock
100.00	-	2.00	VIS-NIR (400-1000nm)	#24-172	S\$2,067.00 Volume Pricing	3 In Stock

125.00	-	2.00	Uncoated	#19-507	S\$2,136.00 Volume Pricing	5 In Stock
125.00	-	2.00	VIS-NIR (400-1000nm)	#24-173	S\$2,628.00 Volume Pricing	8 In Stock
150.00	-	3.00	Uncoated	#19-508	S\$2,804.00 Volume Pricing	7 In Stock
150.00	-	3.00	VIS-NIR (400-1000nm)	#24-174	S\$3,402.00 Volume Pricing	1 In Stock

[#75-137 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	5 x 5	1.00	Uncoated		S\$52.85 Volume Pricing	1 In Stock
---	-------	------	----------	--	--	------------

[#75-141 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

- 10 x 10 1.00 Uncoated

S\$83.30
[Volume Pricing](#)

11 In Stock

[#75-142 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

- 20 x 20 2.00 Uncoated

S\$142.80
[Volume Pricing](#)

1 In Stock

[#75-143 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25 x 25	2.30	Uncoated		S\$186.20 Volume Pricing	15 In Stock
---	---------	------	----------	--	---	-------------

[#75-144 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	50 x 50	3.18	Uncoated		S\$735.00 Volume Pricing	Contact Us
---	---------	------	----------	--	---	------------

[#75-146 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-

75 x 75

2.00

Uncoated

S\$1,547.00
[Volume Pricing](#)

14 In Stock

[#75-147 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-

12.5 x 17.5

1.00

Uncoated

S\$114.80
[Volume Pricing](#)

15 In Stock

[#75-148 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

- 25 x 35 2.00 Uncoated

S\$246.40
[Volume Pricing](#)

4 In Stock

[#75-149 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

- 35 x 50 2.00 Uncoated

S\$492.80
[Volume Pricing](#)

Contact Us

[#75-151 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	5 x 5	1.00	VIS-NIR (400-1000nm)	S\$100.10 Volume Pricing	9 In Stock
---	-------	------	-------------------------	---	------------

[#75-157 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	10 x 10	1.00	VIS-NIR (400-1000nm)	S\$113.40 Volume Pricing	7 In Stock
---	---------	------	-------------------------	---	------------

[#75-160 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	20 x 20	2.00	VIS-NIR (400-1000nm)	S\$172.20 Volume Pricing	8 In Stock
---	---------	------	-------------------------	---	------------

[#75-164 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25 x 25	2.30	VIS-NIR (400-1000nm)	S\$186.20 Volume Pricing	6 In Stock
---	---------	------	-------------------------	---	------------

[#75-166 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	50 x 50	3.18	VIS-NIR (400-1000nm)	S\$826.00 Volume Pricing	9 In Stock
---	---------	------	-------------------------	---	------------

[#75-167 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	75 x 75	2.00	VIS-NIR (400-1000nm)	S\$1,722.00 Volume Pricing	5 In Stock
---	---------	------	-------------------------	---	------------

[#75-168 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	12.5 x 17.5	1.00	VIS-NIR (400-1000nm)	S\$154.00 Volume Pricing	9 In Stock
---	-------------	------	-------------------------	---	------------

[#75-169 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25 x 35	2.00	VIS-NIR (400-1000nm)	S\$326.20 Volume Pricing	9 In Stock
---	---------	------	-------------------------	---	------------

[#75-170 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	35 x 50	2.00	VIS-NIR (400- 1000nm)	S\$582.40 Volume Pricing	9 In Stock
---	---------	------	-----------------------------	---	------------

[#75-171 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	5 x 5	1.00	NIR I (600- 1050nm)	S\$100.10 Volume Pricing	9 In Stock
---	-------	------	---------------------------	---	------------

[#75-172 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	10 x 10	1.00	NIR I (600-1050nm)	S\$113.40 Volume Pricing	9 In Stock
---	---------	------	-----------------------	---	------------

[#75-175 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	20 x 20	2.00	NIR I (600-1050nm)	S\$172.20 Volume Pricing	9 In Stock
---	---------	------	-----------------------	---	------------

[#75-177 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25 x 25	2.30	NIR I (600-1050nm)	S\$186.20 Volume Pricing	8 In Stock
---	---------	------	-----------------------	---	------------

[#75-181 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	50 x 50	3.18	NIR I (600-1050nm)	S\$826.00 Volume Pricing	9 In Stock
---	---------	------	-----------------------	---	------------

[#75-183 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	75 x 75	2.00	NIR I (600-1050nm)		S\$1,722.00 Volume Pricing	5 In Stock
---	---------	------	-----------------------	--	---	------------

[#75-184 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	12.5 x 17.5	1.00	NIR I (600-1050nm)		S\$154.00 Volume Pricing	9 In Stock
---	-------------	------	-----------------------	--	---	------------

[#75-185 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

- 25 x 35 2.00 NIR I (600-1050nm)

S\$326.20
[Volume Pricing](#)

9 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#) [#75-188 New](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

- 35 x 50 2.00 NIR I (600-1050nm)

S\$582.40
[Volume Pricing](#)

9 In Stock