


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Visible Windows](#)

High Efficiency Anti-Reflection (HEAR) Coated Windows

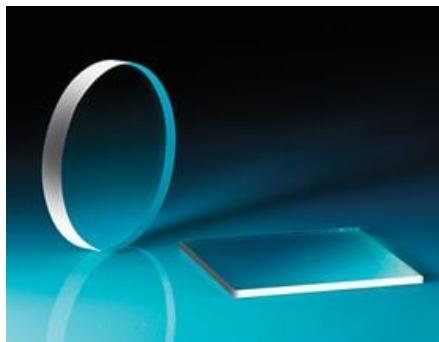


- High Transmission
- Eliminate Back Reflections and Reduce Glare
- Available in a Wide Range of Sizes

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	≥ 90
Optical Properties			
Angle of Incidence (°):	0	Coating:	BBAR (425-700nm)
Coating Specification:	$R_{avg} \leq 0.5\% @ 425 - 700\text{nm}$	Substrate:	Float Glass
Surface Quality:	80-50	Wavelength Range (nm):	425 - 700

Technical Information

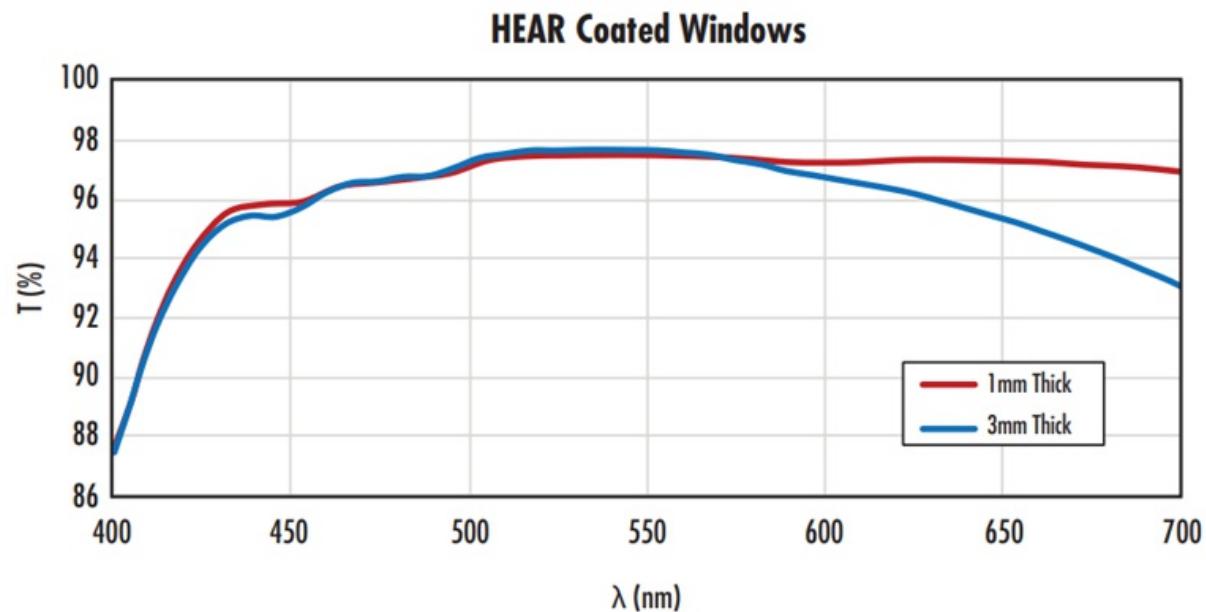

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
<u>#71-564 New</u>						
5.00	-	1.00	BBAR (425- 700nm)	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$32.20 <u>Volume Pricing</u>	20+ In Stock
<u>#71-565 New</u>						
5.00	-	3.00	BBAR (425- 700nm)	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$32.20 <u>Volume Pricing</u>	20+ In Stock

[#71-566 New](#)

10.00	-	1.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$34.30 <u>Volume Pricing</u>	20+ In Stock

[#71-567 New](#)

10.00	-	3.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$34.30 <u>Volume Pricing</u>	20+ In Stock

12.50	-	1.00	BBAR (425- 700nm)	<u>#21-324</u>	S\$35.70 <u>Volume Pricing</u>	20+ In Stock
12.70	-	1.00	BBAR (425- 700nm)	<u>#39-279</u>	S\$36.40 <u>Volume Pricing</u>	20+ In Stock

12.70	-	2.00	BBAR (425- 700nm)	#71-590	S\$35.70 Volume Pricing	20+ In Stock
12.70	-	3.00	BBAR (425- 700nm)	#39-283	S\$36.40 Volume Pricing	20+ In Stock

[#71-582 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	12.70 x 12.70	1.00	BBAR (425- 700nm)		S\$36.40 Volume Pricing	20+ In Stock
---	---------------	------	-------------------------	--	--------------------------------------------	--------------

[#71-583 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	12.70 x 12.70	3.00	BBAR (425- 700nm)		S\$36.05 Volume Pricing	20+ In Stock
---	---------------	------	-------------------------	--	--------------------------------------------	--------------

[#71-568 New](#)

15.00	-	1.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	S\$36.40 <u>Volume Pricing</u>	20+ In Stock
-------	---	------	-------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------	---------------------------------------------------	--------------

[#71-569 New](#)

15.00	-	3.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	S\$36.40 <u>Volume Pricing</u>	16 In Stock
-------	---	------	-------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------	---------------------------------------------------	-------------

[#71-570 New](#)

20.00	-	1.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	S\$36.40 <u>Volume Pricing</u>	20+ In Stock
-------	---	------	-------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------	---------------------------------------------------	--------------

[#71-571 New](#)

20.00	-	3.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	S\$36.40 <u>Volume Pricing</u>	20+ In Stock
-------	---	------	-------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------	---------------------------------------------------	--------------

25.00	-	1.00	BBAR (425- 700nm)	<u>#21-325</u>	S\$38.50 <u>Volume Pricing</u>	20+ In Stock
-------	---	------	-------------------------	--------------------------------	---------------------------------------------------	--------------

25.40	-	1.00	BBAR (425- 700nm)	<u>#48-924</u>	S\$38.50 <u>Volume Pricing</u>	20+ In Stock
-------	---	------	-------------------------	--------------------------------	---------------------------------------------------	--------------

-	25.40 x 25.40	1.00	BBAR (425- 700nm)	<u>#48-923</u>	S\$38.50 <u>Volume Pricing</u>	20+ In Stock
---	---------------	------	-------------------------	--------------------------------	---------------------------------------------------	--------------

25.40	-	2.00	BBAR (425- 700nm)	#71-591	S\$38.50 Volume Pricing	14 In Stock
25.40	-	3.00	BBAR (425- 700nm)	#46-098	S\$38.50 Volume Pricing	Contact Us
-	25.40 x 25.40	3.00	BBAR (425- 700nm)	#46-097	S\$38.50 Volume Pricing	20+ In Stock

[#71-584 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	25.40 x 50.80	1.00	BBAR (425- 700nm)	S\$39.90 Volume Pricing	11 In Stock
---	---------------	------	-------------------------	--------------------------------------------	-------------

[#71-585 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	25.40 x 50.80	3.00	BBAR (425- 700nm)	S\$39.90 Volume Pricing	20+ In Stock
---	---------------	------	-------------------------	--------------------------------------------	--------------

[#71-572 New](#)

30.00	-	1.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	S\$39.20 <u>Volume Pricing</u>	3 In Stock
-------	---	------	-------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------	---------------------------------------------------	------------

[#71-573 New](#)

30.00	-	3.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	S\$39.20 <u>Volume Pricing</u>	20+ In Stock
-------	---	------	-------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------	---------------------------------------------------	--------------

[#71-574 New](#)

35.00	-	1.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$38.50 <u>Volume Pricing</u>	20+ In Stock

[#71-575 New](#)

35.00	-	3.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$37.80 <u>Volume Pricing</u>	20+ In Stock

38.10	-	1.00	BBAR (425- 700nm)	<u>#39-280</u>	S\$38.50 <u>Volume Pricing</u>	20+ In Stock
38.10	-	2.00	BBAR (425- 700nm)	<u>#71-592</u>	S\$38.50 <u>Volume Pricing</u>	20+ In Stock

38.10	-	3.00	BBAR (425- 700nm)	#39-284	S\$38.50 Volume Pricing	20+ In Stock
-------	---	------	-------------------------	-------------------------	--------------------------------------------	--------------

[#71-576 New](#)



New

40.00	-	1.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$39.20 Volume Pricing	20+ In Stock
-------	---	------	-------------------------	----------------------------------------------------------------------------------------------------------------------------------------------------	--------------------------------------------	--------------

[#71-577 New](#)



New

40.00	-	3.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$39.20 Volume Pricing	20+ In Stock
-------	---	------	-------------------------	----------------------------------------------------------------------------------------------------------------------------------------------------	--------------------------------------------	--------------

50.00	-	3.00	BBAR (425- 700nm)	#21-326	S\$39.90 Volume Pricing	13 In Stock
-------	---	------	-------------------------	-------------------------	--------------------------------------------	-------------

50.80	-	1.00	BBAR (425- 700nm)	#48-926	S\$39.90 Volume Pricing	20+ In Stock
-------	---	------	-------------------------	-------------------------	--------------------------------------------	--------------

-	50.80 x 50.80	1.00	BBAR (425- 700nm)	#48-925	S\$39.90 Volume Pricing	20+ In Stock
50.80	-	2.00	BBAR (425- 700nm)	#71-593	S\$39.90 Volume Pricing	Contact Us
-	50.80 x 50.80	2.00	BBAR (425- 700nm)	#71-594	S\$38.50 Volume Pricing	16 In Stock
50.80	-	3.00	BBAR (425- 700nm)	#46-100	S\$39.90 Volume Pricing	20+ In Stock
-	50.80 x 50.80	3.00	BBAR (425- 700nm)	#46-099	S\$39.90 Volume Pricing	16 In Stock

[#71-586 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

S\$49.00
[Volume Pricing](#)

20+ In Stock

-	50.80 x 76.20	1.00	BBAR (425- 700nm)
---	---------------	------	-------------------------

[#71-587 New](#)



New

				Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$49.00 <u>Volume Pricing</u>	20+ In Stock
-	50.80 x 76.20	3.00	BBAR (425- 700nm)			

63.50	-	1.00	BBAR (425- 700nm)	<u>#39-281</u>	S\$42.70 <u>Volume Pricing</u>	20+ In Stock
63.50	-	3.00	BBAR (425- 700nm)	<u>#39-285</u>	S\$42.70 <u>Volume Pricing</u>	20+ In Stock
75.00	-	3.00	BBAR (425- 700nm)	<u>#21-328</u>	S\$49.00 <u>Volume Pricing</u>	4 In Stock
76.20	-	1.00	BBAR (425- 700nm)	<u>#48-928</u>	S\$49.00 <u>Volume Pricing</u>	16 In Stock
-	76.20 x 76.20	1.00	BBAR (425- 700nm)	<u>#48-927</u>	S\$49.00 <u>Volume Pricing</u>	20+ In Stock
76.20	-	2.00	BBAR (425- 700nm)	<u>#71-595</u>	S\$49.00 <u>Volume Pricing</u>	20+ In Stock
-	76.20 x 76.20	2.00	BBAR (425- 700nm)	<u>#71-596</u>	S\$49.00 <u>Volume Pricing</u>	20+ In Stock
76.20	-	3.00	BBAR (425- 700nm)	<u>#46-102</u>	S\$49.00 <u>Volume Pricing</u>	20+ In Stock

-	76.20 x 76.20	3.00	BBAR (425- 700nm)	#46-101	S\$49.00 Volume Pricing	4 In Stock
88.90	-	1.00	BBAR (425- 700nm)	#39-282	S\$56.70 Volume Pricing	20+ In Stock
88.90	-	3.00	BBAR (425- 700nm)	#39-286	S\$56.70 Volume Pricing	20+ In Stock
101.60	-	1.00	BBAR (425- 700nm)	#48-930	S\$64.40 Volume Pricing	20+ In Stock
-	101.60 x 101.60	1.00	BBAR (425- 700nm)	#48-929	S\$64.40 Volume Pricing	20+ In Stock
101.60	-	2.00	BBAR (425- 700nm)	#71-597	S\$64.40 Volume Pricing	13 In Stock
-	101.60 x 101.60	2.00	BBAR (425- 700nm)	#71-598	S\$64.40 Volume Pricing	10 In Stock
101.60	-	3.00	BBAR (425- 700nm)	#46-104	S\$64.40 Volume Pricing	20+ In Stock
-	101.60 x 101.60	3.00	BBAR (425- 700nm)	#46-103	S\$64.40 Volume Pricing	Contact Us
-	101.60 x 127.00	3.00	BBAR (425- 700nm)	#21-329	S\$69.30 Volume Pricing	20+ In Stock
127.00	-	1.00	BBAR (425- 700nm)	#63-216	S\$82.60 Volume Pricing	20+ In Stock
-	127.00 x 177.80	1.00	BBAR (425- 700nm)	#63-217	S\$82.60 Volume Pricing	20+ In Stock
127.00	-	2.00	BBAR (425- 700nm)	#71-599	S\$82.60 Volume Pricing	20+ In Stock
-	127.00 x 177.80	2.00	BBAR (425- 700nm)	#71-600	S\$82.60 Volume Pricing	3 In Stock

127.00	-	3.00	BBAR (425- 700nm)	#48-858	S\$82.60 Volume Pricing	20+ In Stock
-	127.00 x 177.80	3.00	BBAR (425- 700nm)	#43-973	S\$82.60 Volume Pricing	20+ In Stock

[#71-578 New](#)



New

152.00	-	1.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$87.50 Volume Pricing	20+ In Stock
--------	---	------	-------------------------	----------------------------------------------------------------------------------------------------------------------------------------------------	--------------------------------------------	--------------

[#71-579 New](#)



New

152.00	-	3.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$87.50 Volume Pricing	9 In Stock
--------	---	------	-------------------------	----------------------------------------------------------------------------------------------------------------------------------------------------	--------------------------------------------	------------

[#71-580 New](#)

177.00	-	1.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	S\$91.00 <u>Volume Pricing</u>	20+ In Stock
--------	---	------	-------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------	---------------------------------------------------	--------------

[#71-581 New](#)

177.00	-	3.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	S\$91.00 <u>Volume Pricing</u>	20+ In Stock
--------	---	------	-------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------	---------------------------------------------------	--------------

203.20	-	1.00	BBAR (425- 700nm)	<u>#63-218</u>	S\$100.80 <u>Volume Pricing</u>	5 In Stock
-	203.20 x 203.20	3.00	BBAR (425- 700nm)	<u>#21-330</u>	S\$100.80 <u>Volume Pricing</u>	12 In Stock

-	203.20 x 254.00	1.00	BBAR (425-700nm)	#63-219	S\$100.80 Volume Pricing	20+ In Stock
203.20	-	3.00	BBAR (425-700nm)	#48-859	S\$100.80 Volume Pricing	20+ In Stock
-	203.20 x 254.00	3.00	BBAR (425-700nm)	#43-974	S\$100.80 Volume Pricing	20+ In Stock
254.00	-	1.00	BBAR (425-700nm)	#63-220	S\$147.00 Volume Pricing	11 In Stock
-	254.00 x 254.00	3.00	BBAR (425-700nm)	#21-331	S\$147.00 Volume Pricing	6 In Stock
-	254.00 x 304.80	1.00	BBAR (425-700nm)	#63-221	S\$147.00 Volume Pricing	14 In Stock
254.00	-	3.00	BBAR (425-700nm)	#48-860	S\$147.00 Volume Pricing	20+ In Stock
-	254.00 x 304.80	3.00	BBAR (425-700nm)	#43-975	S\$147.00 Volume Pricing	20+ In Stock
-	304.80 x 304.80	3.00	BBAR (425-700nm)	#21-332	S\$176.40 Volume Pricing	8 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com