

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Double-Convex \(DCX\) Lenses](#)

TECHSPEC® UV Fused Silica Double-Convex (DCX) Lenses



- Ideal for Imaging Applications
- Minimize Aberrations Including Spherical and Coma
- Precision Fused Silica Substrate

Common Specifications

Physical & Mechanical Properties


Bevel: Protective as needed

Optical Properties


Substrate: [Fused Silica](#) (Corning 7980)

Surface Quality:	40-20	Power (P-V) @ 632.8nm:	1.5λ
Irregularity (P-V) @ 632.8nm:	λ/4	Focal Length Specification Wavelength (nm):	587.6
Focal Length Tolerance (%):	±1		


Technical Information

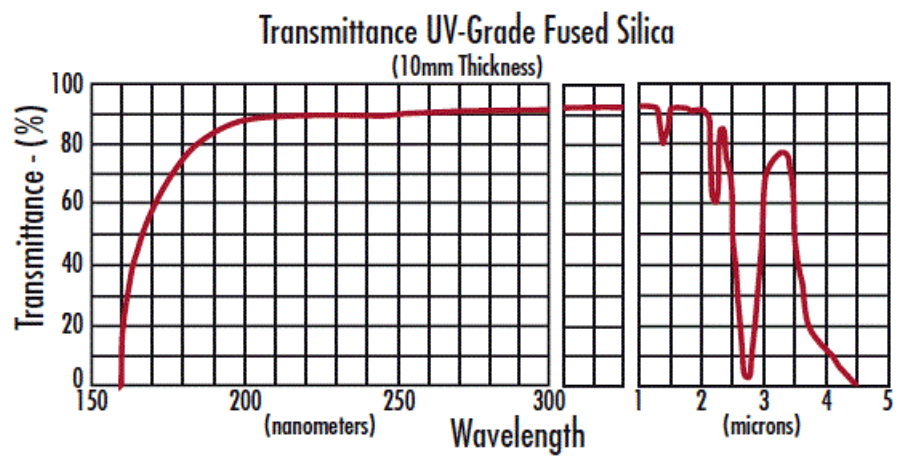


UV FS Transmission Curve

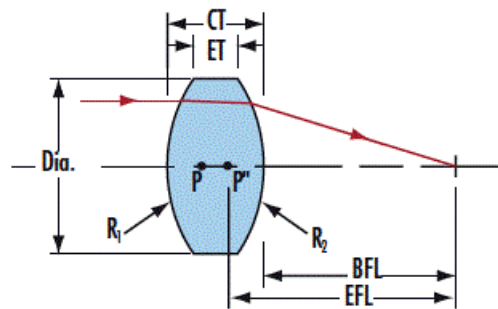

Standard Visible Anti-Reflection Coatings

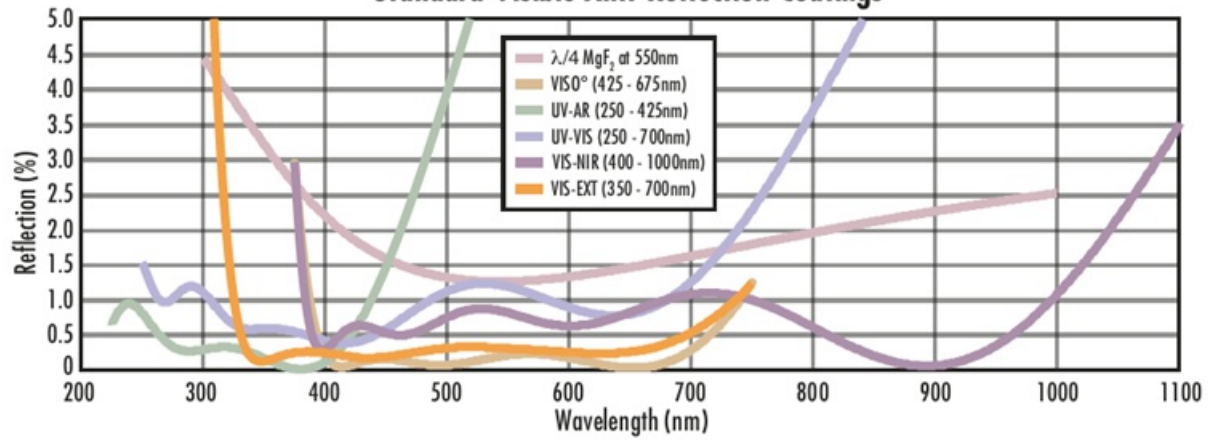

Standard Near Infrared Anti-Reflection Coatings

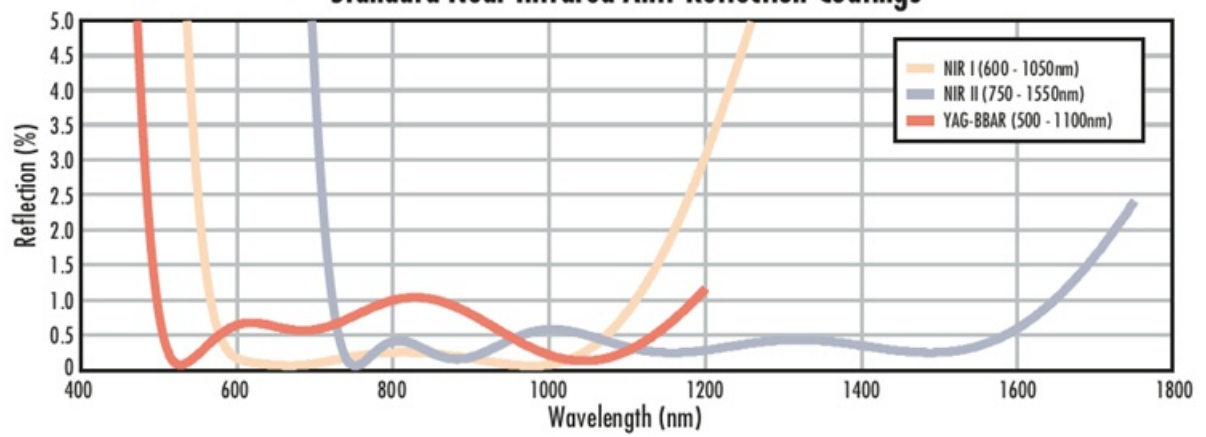

Products

Dia. (mm)	BFL (mm)	EFL (mm)	Coating	Substrate	Stock Number	Price	Buy
6.00	4.38	6.00	Uncoated	Fused Silica	#49-238	S\$174.74 Volume Pricing	20+ In Stock
6.00	4.38	6.00	UV-AR (250-425nm)	Fused Silica	#49-246	S\$206.10 Volume Pricing	20+ In Stock
6.00	4.38	6.00	UV-VIS (250-700nm)	Fused Silica	#49-254	S\$206.10 Volume Pricing	16 In Stock
6.00	4.38	6.00	VIS-EXT (350-700nm)	Fused Silica	#22-196	S\$206.10 Volume Pricing	8 In Stock
6.00	4.38	6.00	VIS 0° (425-675nm)	Fused Silica	#49-262	S\$203.12 Volume Pricing	Contact Us
6.00	4.38	6.00	VIS-NIR (400-1000nm)	Fused Silica	#63-817	S\$206.10 Volume Pricing	13 In Stock
6.00	4.38	6.00	NIR I (600-1050nm)	Fused Silica	#22-156	S\$203.12 Volume Pricing	7 In Stock
6.00	4.38	6.00	NIR II (750-1550nm)	Fused Silica	#22-176	S\$203.12 Volume Pricing	2 In Stock
6.00	8.02	9.00	Uncoated	Fused Silica	#49-239	S\$174.74 Volume Pricing	6 In Stock
6.00	8.02	9.00	UV-AR (250-425nm)	Fused Silica	#49-247	S\$206.10 Volume Pricing	7 In Stock
6.00	8.02	9.00	UV-VIS (250-700nm)	Fused Silica	#49-255	S\$206.10 Volume Pricing	20+ In Stock
6.00	8.02	9.00	VIS 0° (425-675nm)	Fused Silica	#49-263	S\$203.12 Volume Pricing	20+ In Stock
6.00	8.02	9.00	VIS-NIR (400-1000nm)	Fused Silica	#63-818	S\$206.10 Volume Pricing	12 In Stock
6.00	11.23	12.00	Uncoated	Fused Silica	#49-240	S\$174.74 Volume Pricing	20+ In Stock

6.00	11.23	12.00	UV-AR (250-425nm)	Fused Silica	#49-248	S\$206.10 Volume Pricing	1 In Stock
6.00	11.23	12.00	UV-VIS (250-700nm)	Fused Silica	#49-256	S\$206.10 Volume Pricing	5 In Stock
6.00	11.23	12.00	VIS-EXT (350-700nm)	Fused Silica	#22-195	S\$206.10 Volume Pricing	3 In Stock
6.00	11.23	12.00	VIS 0° (425-675nm)	Fused Silica	#49-264	S\$203.12 Volume Pricing	12 In Stock
6.00	11.23	12.00	VIS-NIR (400-1000nm)	Fused Silica	#63-819	S\$206.10 Volume Pricing	20+ In Stock
6.00	11.23	12.00	NIR I (600-1050nm)	Fused Silica	#22-155	S\$203.12 Volume Pricing	5 In Stock
6.00	11.23	12.00	NIR II (750-1550nm)	Fused Silica	#22-175	S\$203.12 Volume Pricing	2 In Stock
6.00	17.30	18.00	Uncoated	Fused Silica	#49-983	S\$167.27 Volume Pricing	20+ In Stock
6.00	17.30	18.00	UV-AR (250-425nm)	Fused Silica	#49-987	S\$198.64 Volume Pricing	5 In Stock
6.00	17.30	18.00	UV-VIS (250-700nm)	Fused Silica	#49-991	S\$198.64 Volume Pricing	8 In Stock
6.00	17.30	18.00	VIS 0° (425-675nm)	Fused Silica	#49-995	S\$195.65 Volume Pricing	5 In Stock
6.00	17.30	18.00	VIS-NIR (400-1000nm)	Fused Silica	#63-820	S\$198.64 Volume Pricing	16 In Stock
6.00	23.31	24.00	Uncoated	Fused Silica	#49-984	S\$167.27 Volume Pricing	20+ In Stock
6.00	23.31	24.00	UV-AR (250-425nm)	Fused Silica	#49-988	S\$198.64 Volume Pricing	4 In Stock
6.00	23.31	24.00	UV-VIS (250-700nm)	Fused Silica	#49-992	S\$198.64 Volume Pricing	Contact Us
6.00	23.31	24.00	VIS 0° (425-675nm)	Fused Silica	#49-996	S\$195.65 Volume Pricing	13 In Stock

6.00	23.31	24.00	VIS-NIR (400-1000nm)	Fused Silica	#63-821	S\$198.64 Volume Pricing	20+ In Stock
9.00	7.12	9.00	Uncoated	Fused Silica	#49-241	S\$179.22 Volume Pricing	20+ In Stock
9.00	7.12	9.00	UV-AR (250-425nm)	Fused Silica	#49-249	S\$210.58 Volume Pricing	20+ In Stock
9.00	7.12	9.00	UV-VIS (250-700nm)	Fused Silica	#49-257	S\$210.58 Volume Pricing	13 In Stock
9.00	7.12	9.00	VIS-EXT (350-700nm)	Fused Silica	#22-200	S\$210.58 Volume Pricing	4 In Stock
9.00	7.12	9.00	VIS 0° (425-675nm)	Fused Silica	#49-265	S\$207.60 Volume Pricing	5 In Stock
9.00	7.12	9.00	VIS-NIR (400-1000nm)	Fused Silica	#63-822	S\$210.58 Volume Pricing	7 In Stock
9.00	7.12	9.00	NIR I (600-1050nm)	Fused Silica	#22-160	S\$207.60 Volume Pricing	2 In Stock
9.00	7.12	9.00	NIR II (750-1550nm)	Fused Silica	#22-180	S\$207.60 Volume Pricing	4 In Stock
9.00	12.32	13.50	Uncoated	Fused Silica	#49-242	S\$179.22 Volume Pricing	20+ In Stock
9.00	12.32	13.50	UV-AR (250-425nm)	Fused Silica	#49-250	S\$210.58 Volume Pricing	4 In Stock
9.00	12.32	13.50	UV-VIS (250-700nm)	Fused Silica	#49-258	S\$210.58 Volume Pricing	1 In Stock
9.00	12.32	13.50	VIS-EXT (350-700nm)	Fused Silica	#22-197	S\$210.58 Volume Pricing	1 In Stock
9.00	12.32	13.50	VIS 0° (425-675nm)	Fused Silica	#49-266	S\$207.60 Volume Pricing	5 In Stock
9.00	12.32	13.50	VIS-NIR (400-1000nm)	Fused Silica	#63-823	S\$210.58 Volume Pricing	20+ In Stock
9.00	12.32	13.50	NIR I (600-1050nm)	Fused Silica	#22-157	S\$207.60 Volume Pricing	4 In Stock

9.00	12.32	13.50	NIR II (750-1550nm)	Fused Silica	#22-177	S\$207.60 Volume Pricing	5 In Stock
9.00	17.09	18.00	Uncoated	Fused Silica	#49-243	S\$179.22 Volume Pricing	20+ In Stock
9.00	17.09	18.00	UV-AR (250-425nm)	Fused Silica	#49-251	S\$210.58 Volume Pricing	20+ In Stock
9.00	17.09	18.00	UV-VIS (250-700nm)	Fused Silica	#49-259	S\$210.58 Volume Pricing	Contact Us
9.00	17.09	18.00	VIS-EXT (350-700nm)	Fused Silica	#22-198	S\$210.58 Volume Pricing	4 In Stock
9.00	17.09	18.00	VIS 0° (425-675nm)	Fused Silica	#49-267	S\$207.60 Volume Pricing	Contact Us
9.00	17.09	18.00	VIS-NIR (400-1000nm)	Fused Silica	#63-824	S\$210.58 Volume Pricing	Contact Us
9.00	17.09	18.00	NIR I (600-1050nm)	Fused Silica	#22-158	S\$207.60 Volume Pricing	5 In Stock
9.00	17.09	18.00	NIR II (750-1550nm)	Fused Silica	#22-178	S\$207.60 Volume Pricing	4 In Stock
9.00	26.13	27.00	Uncoated	Fused Silica	#49-985	S\$171.75 Volume Pricing	20+ In Stock
9.00	26.13	27.00	UV-AR (250-425nm)	Fused Silica	#49-989	S\$203.12 Volume Pricing	3 In Stock
9.00	26.13	27.00	UV-VIS (250-700nm)	Fused Silica	#49-993	S\$203.12 Volume Pricing	14 In Stock
9.00	26.13	27.00	VIS-EXT (350-700nm)	Fused Silica	#22-199	S\$203.12 Volume Pricing	5 In Stock
9.00	26.13	27.00	VIS 0° (425-675nm)	Fused Silica	#49-997	S\$198.64 Volume Pricing	7 In Stock
9.00	26.13	27.00	VIS-NIR (400-1000nm)	Fused Silica	#63-825	S\$203.12 Volume Pricing	20+ In Stock
9.00	26.13	27.00	NIR I (600-1050nm)	Fused Silica	#22-159	S\$198.64 Volume Pricing	5 In Stock

9.00	26.13	27.00	NIR II (750-1550nm)	Fused Silica	#22-179	S\$198.64 Volume Pricing	5 In Stock
9.00	35.31	36.00	Uncoated	Fused Silica	#49-986	S\$171.75 Volume Pricing	20+ In Stock
9.00	35.31	36.00	UV-AR (250-425nm)	Fused Silica	#49-990	S\$203.12 Volume Pricing	1 In Stock
9.00	35.31	36.00	UV-VIS (250-700nm)	Fused Silica	#49-994	S\$203.12 Volume Pricing	20+ In Stock
9.00	35.31	36.00	VIS 0° (425-675nm)	Fused Silica	#49-998	S\$198.64 Volume Pricing	8 In Stock
9.00	35.31	36.00	VIS-NIR (400-1000nm)	Fused Silica	#63-826	S\$203.12 Volume Pricing	20+ In Stock
12.00	9.25	12.00	Uncoated	Fused Silica	#48-034	S\$179.22 Volume Pricing	20+ In Stock
12.00	9.25	12.00	UV-AR (250-425nm)	Fused Silica	#48-040	S\$215.06 Volume Pricing	14 In Stock
12.00	9.25	12.00	UV-VIS (250-700nm)	Fused Silica	#48-834	S\$215.06 Volume Pricing	7 In Stock
12.00	9.25	12.00	VIS-EXT (350-700nm)	Fused Silica	#22-203	S\$215.06 Volume Pricing	2 In Stock
12.00	9.25	12.00	VIS 0° (425-675nm)	Fused Silica	#48-974	S\$210.58 Volume Pricing	9 In Stock
12.00	9.25	12.00	VIS-NIR (400-1000nm)	Fused Silica	#63-827	S\$215.06 Volume Pricing	20+ In Stock
12.00	9.25	12.00	NIR I (600-1050nm)	Fused Silica	#22-163	S\$210.58 Volume Pricing	3 In Stock
12.00	9.25	12.00	NIR II (750-1550nm)	Fused Silica	#22-183	S\$210.58 Volume Pricing	7 In Stock
12.00	13.37	15.00	Uncoated	Fused Silica	#49-244	S\$179.22 Volume Pricing	20+ In Stock
12.00	13.37	15.00	UV-AR (250-425nm)	Fused Silica	#49-252	S\$215.06 Volume Pricing	5 In Stock

12.00	13.37	15.00	UV-VIS (250-700nm)	Fused Silica	#49-260	S\$215.06 Volume Pricing	13 In Stock
12.00	13.37	15.00	VIS-EXT (350-700nm)	Fused Silica	#22-204	S\$215.06 Volume Pricing	14 In Stock
12.00	13.37	15.00	VIS 0° (425-675nm)	Fused Silica	#49-268	S\$210.58 Volume Pricing	2 In Stock
12.00	13.37	15.00	VIS-NIR (400-1000nm)	Fused Silica	#63-828	S\$215.06 Volume Pricing	20+ In Stock
12.00	13.37	15.00	NIR I (600-1050nm)	Fused Silica	#22-164	S\$210.58 Volume Pricing	3 In Stock
12.00	13.37	15.00	NIR II (750-1550nm)	Fused Silica	#22-184	S\$210.58 Volume Pricing	4 In Stock
12.00	18.44	20.00	Uncoated	Fused Silica	#48-035	S\$179.22 Volume Pricing	13 In Stock
12.00	18.44	20.00	UV-AR (250-425nm)	Fused Silica	#48-041	S\$215.06 Volume Pricing	Contact Us
12.00	18.44	20.00	UV-VIS (250-700nm)	Fused Silica	#48-835	S\$215.06 Volume Pricing	Contact Us
12.00	18.44	20.00	VIS-EXT (350-700nm)	Fused Silica	#22-205	S\$215.06 Volume Pricing	5 In Stock
12.00	18.44	20.00	VIS 0° (425-675nm)	Fused Silica	#48-975	S\$210.58 Volume Pricing	15 In Stock
12.00	18.44	20.00	VIS-NIR (400-1000nm)	Fused Silica	#63-829	S\$215.06 Volume Pricing	20+ In Stock
12.00	18.44	20.00	NIR I (600-1050nm)	Fused Silica	#22-165	S\$210.58 Volume Pricing	5 In Stock
12.00	18.44	20.00	NIR II (750-1550nm)	Fused Silica	#22-185	S\$210.58 Volume Pricing	5 In Stock
12.00	22.92	24.00	Uncoated	Fused Silica	#49-245	S\$179.22 Volume Pricing	20+ In Stock
12.00	22.92	24.00	UV-AR (250-425nm)	Fused Silica	#49-253	S\$215.06 Volume Pricing	2 In Stock

12.00	22.92	24.00	UV-VIS (250-700nm)	Fused Silica	#49-261	S\$215.06 Volume Pricing	Contact Us
12.00	22.92	24.00	VIS-EXT (350-700nm)	Fused Silica	#22-206	S\$215.06 Volume Pricing	5 In Stock
12.00	22.92	24.00	VIS 0° (425-675nm)	Fused Silica	#49-269	S\$210.58 Volume Pricing	5 In Stock
12.00	22.92	24.00	VIS-NIR (400-1000nm)	Fused Silica	#63-830	S\$215.06 Volume Pricing	20+ In Stock
12.00	22.92	24.00	NIR I (600-1050nm)	Fused Silica	#22-166	S\$210.58 Volume Pricing	4 In Stock
12.00	22.92	24.00	NIR II (750-1550nm)	Fused Silica	#22-186	S\$210.58 Volume Pricing	5 In Stock
12.00	28.77	30.00	Uncoated	Fused Silica	#48-036	S\$170.26 Volume Pricing	20+ In Stock
12.00	28.77	30.00	UV-AR (250-425nm)	Fused Silica	#48-042	S\$206.10 Volume Pricing	4 In Stock
12.00	28.77	30.00	UV-VIS (250-700nm)	Fused Silica	#48-836	S\$206.10 Volume Pricing	6 In Stock
12.00	28.77	30.00	VIS-EXT (350-700nm)	Fused Silica	#22-201	S\$206.10 Volume Pricing	4 In Stock
12.00	28.77	30.00	VIS 0° (425-675nm)	Fused Silica	#48-976	S\$201.62 Volume Pricing	8 In Stock
12.00	28.77	30.00	VIS-NIR (400-1000nm)	Fused Silica	#63-831	S\$206.10 Volume Pricing	12 In Stock
12.00	28.77	30.00	NIR I (600-1050nm)	Fused Silica	#22-161	S\$201.62 Volume Pricing	4 In Stock
12.00	28.77	30.00	NIR II (750-1550nm)	Fused Silica	#22-181	S\$201.62 Volume Pricing	5 In Stock
12.00	33.85	35.00	Uncoated	Fused Silica	#48-037	S\$170.26 Volume Pricing	20+ In Stock
12.00	33.85	35.00	UV-AR (250-425nm)	Fused Silica	#48-043	S\$206.10 Volume Pricing	Contact Us

12.00	33.85	35.00	UV-VIS (250-700nm)	Fused Silica	#48-837	S\$206.10 Volume Pricing	Contact Us
12.00	33.85	35.00	VIS-EXT (350-700nm)	Fused Silica	#22-202	S\$206.10 Volume Pricing	1 In Stock
12.00	33.85	35.00	VIS 0° (425-675nm)	Fused Silica	#48-977	S\$201.62 Volume Pricing	9 In Stock
12.00	33.85	35.00	VIS-NIR (400-1000nm)	Fused Silica	#63-832	S\$206.10 Volume Pricing	14 In Stock
12.00	33.85	35.00	NIR I (600-1050nm)	Fused Silica	#22-162	S\$201.62 Volume Pricing	3 In Stock
12.00	33.85	35.00	NIR II (750-1550nm)	Fused Silica	#22-182	S\$201.62 Volume Pricing	4 In Stock
12.00	43.96	45.00	Uncoated	Fused Silica	#48-038	S\$170.26 Volume Pricing	20+ In Stock
12.00	43.96	45.00	UV-AR (250-425nm)	Fused Silica	#48-044	S\$206.10 Volume Pricing	1 In Stock
12.00	43.96	45.00	UV-VIS (250-700nm)	Fused Silica	#48-838	S\$206.10 Volume Pricing	Contact Us
12.00	43.96	45.00	VIS 0° (425-675nm)	Fused Silica	#48-978	S\$201.62 Volume Pricing	Contact Us
12.00	43.96	45.00	VIS-NIR (400-1000nm)	Fused Silica	#63-833	S\$206.10 Volume Pricing	20+ In Stock
12.00	74.11	75.00	Uncoated	Fused Silica	#48-039	S\$170.26 Volume Pricing	7 In Stock
12.00	74.11	75.00	UV-VIS (250-700nm)	Fused Silica	#48-839	S\$206.10 Volume Pricing	12 In Stock
12.00	74.11	75.00	UV-AR (250-425nm)	Fused Silica	#48-045	S\$206.10 Volume Pricing	4 In Stock
12.00	74.11	75.00	VIS-EXT (350-700nm)	Fused Silica	#22-207	S\$206.10 Volume Pricing	2 In Stock
12.00	74.11	75.00	VIS 0° (425-675nm)	Fused Silica	#48-979	S\$201.62 Volume Pricing	15 In Stock

12.00	74.11	75.00	VIS-NIR (400-1000nm)	Fused Silica	#63-834	S\$206.10 Volume Pricing	16 In Stock
12.00	74.11	75.00	NIR I (600-1050nm)	Fused Silica	#22-167	S\$201.62 Volume Pricing	5 In Stock
12.00	74.11	75.00	NIR II (750-1550nm)	Fused Silica	#22-187	S\$201.62 Volume Pricing	4 In Stock
18.00	17.18	20.00	Uncoated	Fused Silica	#08-083	S\$191.17 Volume Pricing	20+ In Stock
18.00	17.18	20.00	UV-AR (250-425nm)	Fused Silica	#46-290	S\$225.52 Volume Pricing	20+ In Stock
18.00	17.18	20.00	UV-VIS (250-700nm)	Fused Silica	#48-840	S\$225.52 Volume Pricing	1 In Stock
18.00	17.18	20.00	VIS-EXT (350-700nm)	Fused Silica	#22-208	S\$225.52 Volume Pricing	4 In Stock
18.00	17.18	20.00	VIS 0° (425-675nm)	Fused Silica	#48-980	S\$222.53 Volume Pricing	14 In Stock
18.00	17.18	20.00	VIS-NIR (400-1000nm)	Fused Silica	#63-835	S\$225.52 Volume Pricing	7 In Stock
18.00	17.18	20.00	NIR I (600-1050nm)	Fused Silica	#22-168	S\$222.53 Volume Pricing	3 In Stock
18.00	17.18	20.00	NIR II (750-1550nm)	Fused Silica	#22-188	S\$222.53 Volume Pricing	5 In Stock
18.00	38.50	40.00	Uncoated	Fused Silica	#08-084	S\$191.17 Volume Pricing	10 In Stock
18.00	38.50	40.00	UV-AR (250-425nm)	Fused Silica	#46-291	S\$225.52 Volume Pricing	3 In Stock
18.00	38.50	40.00	UV-VIS (250-700nm)	Fused Silica	#48-841	S\$225.52 Volume Pricing	Contact Us
18.00	38.50	40.00	VIS-EXT (350-700nm)	Fused Silica	#22-209	S\$225.52 Volume Pricing	5 In Stock
18.00	38.50	40.00	VIS 0° (425-675nm)	Fused Silica	#48-981	S\$222.53 Volume Pricing	8 In Stock

18.00	38.50	40.00	VIS-NIR (400-1000nm)	Fused Silica	#63-836	S\$225.52 Volume Pricing	1 In Stock
18.00	38.50	40.00	NIR I (600-1050nm)	Fused Silica	#22-169	S\$222.53 Volume Pricing	5 In Stock
18.00	38.50	40.00	NIR II (750-1550nm)	Fused Silica	#22-189	S\$222.53 Volume Pricing	5 In Stock
25.00	20.93	25.00	Uncoated	Fused Silica	#48-293	S\$201.62 Volume Pricing	20+ In Stock
25.00	20.93	25.00	UV-AR (250-425nm)	Fused Silica	#48-304	S\$235.97 Volume Pricing	20+ In Stock
25.00	20.93	25.00	UV-VIS (250-700nm)	Fused Silica	#48-842	S\$235.97 Volume Pricing	20+ In Stock
25.00	20.93	25.00	VIS-EXT (350-700nm)	Fused Silica	#22-212	S\$235.97 Volume Pricing	3 In Stock
25.00	20.93	25.00	VIS 0° (425-675nm)	Fused Silica	#48-982	S\$232.99 Volume Pricing	12 In Stock
25.00	20.93	25.00	VIS-NIR (400-1000nm)	Fused Silica	#63-837	S\$235.97 Volume Pricing	8 In Stock
25.00	20.93	25.00	NIR I (600-1050nm)	Fused Silica	#22-172	S\$232.99 Volume Pricing	9 In Stock
25.00	20.93	25.00	NIR II (750-1550nm)	Fused Silica	#22-192	S\$232.99 Volume Pricing	14 In Stock
25.00	48.02	50.00	Uncoated	Fused Silica	#48-294	S\$201.62 Volume Pricing	20+ In Stock
25.00	48.02	50.00	UV-AR (250-425nm)	Fused Silica	#48-305	S\$235.97 Volume Pricing	20+ In Stock
25.00	48.02	50.00	UV-VIS (250-700nm)	Fused Silica	#48-843	S\$235.97 Volume Pricing	7 In Stock
25.00	48.02	50.00	VIS-EXT (350-700nm)	Fused Silica	#22-213	S\$235.97 Volume Pricing	5 In Stock
25.00	48.02	50.00	VIS 0° (425-675nm)	Fused Silica	#48-983	S\$232.99 Volume Pricing	16 In Stock

25.00	48.02	50.00	VIS-NIR (400-1000nm)	Fused Silica	#63-838	S\$235.97 Volume Pricing	7 In Stock
25.00	48.02	50.00	NIR I (600-1050nm)	Fused Silica	#22-173	S\$232.99 Volume Pricing	5 In Stock
25.00	48.02	50.00	NIR II (750-1550nm)	Fused Silica	#22-193	S\$232.99 Volume Pricing	Contact Us
25.00	58.08	60.00	Uncoated	Fused Silica	#48-295	S\$194.16 Volume Pricing	8 In Stock
25.00	58.08	60.00	UV-AR (250-425nm)	Fused Silica	#48-306	S\$228.51 Volume Pricing	14 In Stock
25.00	58.08	60.00	UV-VIS (250-700nm)	Fused Silica	#48-844	S\$228.51 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS-EXT (350-700nm)	Fused Silica	#22-214	S\$228.51 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS 0° (425-675nm)	Fused Silica	#48-984	S\$225.52 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS-NIR (400-1000nm)	Fused Silica	#63-839	S\$228.51 Volume Pricing	12 In Stock
25.00	58.08	60.00	NIR I (600-1050nm)	Fused Silica	#22-174	S\$225.52 Volume Pricing	4 In Stock
25.00	58.08	60.00	NIR II (750-1550nm)	Fused Silica	#22-194	S\$225.52 Volume Pricing	4 In Stock
25.00	73.91	75.60	Uncoated	Fused Silica	#48-296	S\$194.16 Volume Pricing	20+ In Stock
25.00	73.91	75.60	UV-AR (250-425nm)	Fused Silica	#48-307	S\$228.51 Volume Pricing	6 In Stock
25.00	73.91	75.60	UV-VIS (250-700nm)	Fused Silica	#48-845	S\$228.51 Volume Pricing	2 In Stock
25.00	73.91	75.60	VIS-EXT (350-700nm)	Fused Silica	#22-210	S\$228.51 Volume Pricing	3 In Stock
25.00	73.91	75.60	VIS 0° (425-675nm)	Fused Silica	#48-985	S\$225.52 Volume Pricing	11 In Stock

25.00	73.91	75.60	VIS-NIR (400-1000nm)	Fused Silica	#63-840	S\$228.51 Volume Pricing	8 In Stock
25.00	73.91	75.60	NIR I (600-1050nm)	Fused Silica	#22-170	S\$225.52 Volume Pricing	5 In Stock
25.00	73.91	75.60	NIR II (750-1550nm)	Fused Silica	#22-190	S\$225.52 Volume Pricing	1 In Stock
25.00	98.70	100.00	Uncoated	Fused Silica	#48-297	S\$194.16 Volume Pricing	15 In Stock
25.00	98.70	100.00	UV-AR (250-425nm)	Fused Silica	#48-308	S\$228.51 Volume Pricing	13 In Stock
25.00	98.70	100.00	UV-VIS (250-700nm)	Fused Silica	#48-846	S\$228.51 Volume Pricing	11 In Stock
25.00	98.70	100.00	VIS-EXT (350-700nm)	Fused Silica	#22-211	S\$228.51 Volume Pricing	8 In Stock
25.00	98.70	100.00	VIS 0° (425-675nm)	Fused Silica	#48-986	S\$225.52 Volume Pricing	7 In Stock
25.00	98.70	100.00	VIS-NIR (400-1000nm)	Fused Silica	#63-841	S\$228.51 Volume Pricing	2 In Stock
25.00	98.70	100.00	NIR I (600-1050nm)	Fused Silica	#22-171	S\$225.52 Volume Pricing	4 In Stock
25.00	98.70	100.00	NIR II (750-1550nm)	Fused Silica	#22-191	S\$225.52 Volume Pricing	3 In Stock
25.00	123.82	125.00	Uncoated	Fused Silica	#48-298	S\$185.19 Volume Pricing	20+ In Stock
25.00	123.82	125.00	UV-AR (250-425nm)	Fused Silica	#48-309	S\$221.04 Volume Pricing	2 In Stock
25.00	123.82	125.00	UV-VIS (250-700nm)	Fused Silica	#48-847	S\$221.04 Volume Pricing	10 In Stock
25.00	123.82	125.00	VIS 0° (425-675nm)	Fused Silica	#48-987	S\$216.56 Volume Pricing	14 In Stock
25.00	123.82	125.00	VIS-NIR (400-1000nm)	Fused Silica	#63-842	S\$221.04 Volume Pricing	5 In Stock

25.00	148.37	150.00	Uncoated	Fused Silica	#48-299	S\$185.19 Volume Pricing	20+ In Stock
25.00	148.37	150.00	UV-AR (250-425nm)	Fused Silica	#48-310	S\$221.04 Volume Pricing	16 In Stock
25.00	148.37	150.00	UV-VIS (250-700nm)	Fused Silica	#48-848	S\$221.04 Volume Pricing	2 In Stock
25.00	148.37	150.00	VIS 0° (425-675nm)	Fused Silica	#48-988	S\$216.56 Volume Pricing	7 In Stock
25.00	148.37	150.00	VIS-NIR (400-1000nm)	Fused Silica	#63-843	S\$221.04 Volume Pricing	4 In Stock
25.00	198.84	200.00	Uncoated	Fused Silica	#48-300	S\$185.19 Volume Pricing	5 In Stock
25.00	198.84	200.00	UV-AR (250-425nm)	Fused Silica	#48-311	S\$221.04 Volume Pricing	20+ In Stock
25.00	198.84	200.00	UV-VIS (250-700nm)	Fused Silica	#48-849	S\$221.04 Volume Pricing	Contact Us
25.00	198.84	200.00	VIS 0° (425-675nm)	Fused Silica	#48-989	S\$216.56 Volume Pricing	20+ In Stock
25.00	198.84	200.00	VIS-NIR (400-1000nm)	Fused Silica	#63-844	S\$221.04 Volume Pricing	1 In Stock
25.00	248.90	250.00	Uncoated	Fused Silica	#48-301	S\$185.19 Volume Pricing	20+ In Stock
25.00	248.90	250.00	UV-AR (250-425nm)	Fused Silica	#48-312	S\$221.04 Volume Pricing	6 In Stock
25.00	248.90	250.00	UV-VIS (250-700nm)	Fused Silica	#48-850	S\$221.04 Volume Pricing	Contact Us
25.00	248.90	250.00	VIS 0° (425-675nm)	Fused Silica	#48-990	S\$216.56 Volume Pricing	5 In Stock
25.00	248.90	250.00	VIS-NIR (400-1000nm)	Fused Silica	#63-845	S\$221.04 Volume Pricing	5 In Stock
25.00	298.94	300.00	Uncoated	Fused Silica	#48-302	S\$185.19 Volume Pricing	20+ In Stock

25.00	298.94	300.00	UV-AR (250-425nm)	Fused Silica	#48-313	S\$221.04 Volume Pricing	14 In Stock
25.00	298.94	300.00	UV-VIS (250-700nm)	Fused Silica	#48-851	S\$221.04 Volume Pricing	6 In Stock
25.00	298.94	300.00	VIS 0° (425-675nm)	Fused Silica	#48-991	S\$216.56 Volume Pricing	20+ In Stock
25.00	298.94	300.00	VIS-NIR (400-1000nm)	Fused Silica	#63-846	S\$221.04 Volume Pricing	4 In Stock
25.00	498.85	500.00	Uncoated	Fused Silica	#48-303	S\$185.19 Volume Pricing	11 In Stock
25.00	498.85	500.00	UV-AR (250-425nm)	Fused Silica	#48-314	S\$221.04 Volume Pricing	20+ In Stock
25.00	498.85	500.00	UV-VIS (250-700nm)	Fused Silica	#48-852	S\$221.04 Volume Pricing	7 In Stock
25.00	498.85	500.00	VIS 0° (425-675nm)	Fused Silica	#48-992	S\$216.56 Volume Pricing	6 In Stock
25.00	498.85	500.00	VIS-NIR (400-1000nm)	Fused Silica	#63-847	S\$221.04 Volume Pricing	3 In Stock
30.00	25.12	30.00	Uncoated	Fused Silica	#22-413	S\$231.49 Volume Pricing	5 In Stock
30.00	25.12	30.00	UV-AR (250-425nm)	Fused Silica	#26-600	S\$276.30 Volume Pricing	2 In Stock
30.00	25.12	30.00	UV-VIS (250-700nm)	Fused Silica	#26-606	S\$268.83 Volume Pricing	1 In Stock
30.00	25.12	30.00	VIS 0° (425-675nm)	Fused Silica	#26-612	S\$276.30 Volume Pricing	2 In Stock
30.00	25.12	30.00	VIS-NIR (400-1000nm)	Fused Silica	#26-618	S\$276.30 Volume Pricing	1 In Stock
40.00	33.49	40.00	Uncoated	Fused Silica	#22-420	S\$258.38 Volume Pricing	Contact Us

40.00	33.49	40.00	UV-AR (250-425nm)	Fused Silica	#26-601	S\$307.66 Volume Pricing	1 In Stock
40.00	33.49	40.00	UV-VIS (250-700nm)	Fused Silica	#26-607	S\$300.19 Volume Pricing	2 In Stock
40.00	33.49	40.00	VIS 0° (425-675nm)	Fused Silica	#26-613	S\$307.66 Volume Pricing	5 In Stock
40.00	33.49	40.00	VIS-NIR (400-1000nm)	Fused Silica	#26-619	S\$307.66 Volume Pricing	4 In Stock
50.00	41.87	50.00	Uncoated	Fused Silica	#22-426	S\$434.61 Volume Pricing	20+ In Stock
50.00	41.87	50.00	UV-AR (250-425nm)	Fused Silica	#26-602	S\$479.41 Volume Pricing	13 In Stock
50.00	41.87	50.00	UV-VIS (250-700nm)	Fused Silica	#26-608	S\$471.95 Volume Pricing	Contact Us
50.00	41.87	50.00	VIS 0° (425-675nm)	Fused Silica	#26-614	S\$479.41 Volume Pricing	5 In Stock
50.00	41.87	50.00	VIS-NIR (400-1000nm)	Fused Silica	#26-620	S\$479.41 Volume Pricing	1 In Stock
50.00	97.13	100.00	Uncoated	Fused Silica	#22-427	S\$434.61 Volume Pricing	Contact Us
50.00	97.13	100.00	UV-AR (250-425nm)	Fused Silica	#26-603	S\$479.41 Volume Pricing	Contact Us
50.00	97.13	100.00	UV-VIS (250-700nm)	Fused Silica	#26-609	S\$471.95 Volume Pricing	4 In Stock
50.00	97.13	100.00	VIS 0° (425-675nm)	Fused Silica	#26-615	S\$479.41 Volume Pricing	3 In Stock
50.00	97.13	100.00	VIS-NIR (400-1000nm)	Fused Silica	#26-621	S\$479.41 Volume Pricing	Contact Us
50.00	148.00	150.00	Uncoated	Fused Silica	#22-428	S\$434.61 Volume Pricing	10 In Stock

50.00	148.00	150.00	UV-AR (250-425nm)	Fused Silica	#26-604	S\$479.41 Volume Pricing	3 In Stock
50.00	148.00	150.00	UV-VIS (250-700nm)	Fused Silica	#26-610	S\$471.95 Volume Pricing	4 In Stock
50.00	148.00	150.00	VIS 0° (425-675nm)	Fused Silica	#26-616	S\$479.41 Volume Pricing	5 In Stock
50.00	148.00	150.00	VIS-NIR (400-1000nm)	Fused Silica	#26-622	S\$479.41 Volume Pricing	4 In Stock
50.00	198.39	200.00	Uncoated	Fused Silica	#22-429	S\$434.61 Volume Pricing	3 In Stock
50.00	198.39	200.00	UV-AR (250-425nm)	Fused Silica	#26-605	S\$479.41 Volume Pricing	2 In Stock
50.00	198.39	200.00	UV-VIS (250-700nm)	Fused Silica	#26-611	S\$471.95 Volume Pricing	1 In Stock
50.00	198.39	200.00	VIS 0° (425-675nm)	Fused Silica	#26-617	S\$479.41 Volume Pricing	5 In Stock
50.00	198.39	200.00	VIS-NIR (400-1000nm)	Fused Silica	#26-623	S\$479.41 Volume Pricing	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com