


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)

TECHSPEC® 1λ UV Fused Silica Windows

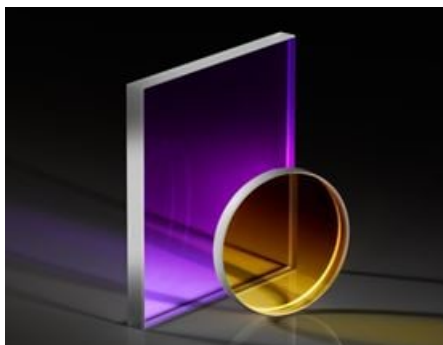

- Available Uncoated or with Broadband Anti-Reflection Coatings
- Ideal for Cost Sensitive Broadband Applications
- Circular and Square Sizes from 5mm to 100mm
- [λ/4](#) or [λ/10](#) UV Fused Silica Windows Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	90
Edges:	Fine Ground	Knoop Hardness (kg/mm²):	522.00
Parallelism (arcmin):	<5	Poisson's Ratio:	0.16
Young's Modulus (GPa):	73		


Optical Properties

Abbe Number (v_d):	67.8		
Index of Refraction (n_d):	1.458	Surface Quality:	60-40



Material Properties

Coefficient of Thermal Expansion CTE (10⁻⁶/°C):	0.52 (+5 to +35°C) 0.57 (0 to +200°C) 0.48 (-100 to +200°C)	Density (g/cm³):	2.20
---	---	------------------------------------	------


Technical Information

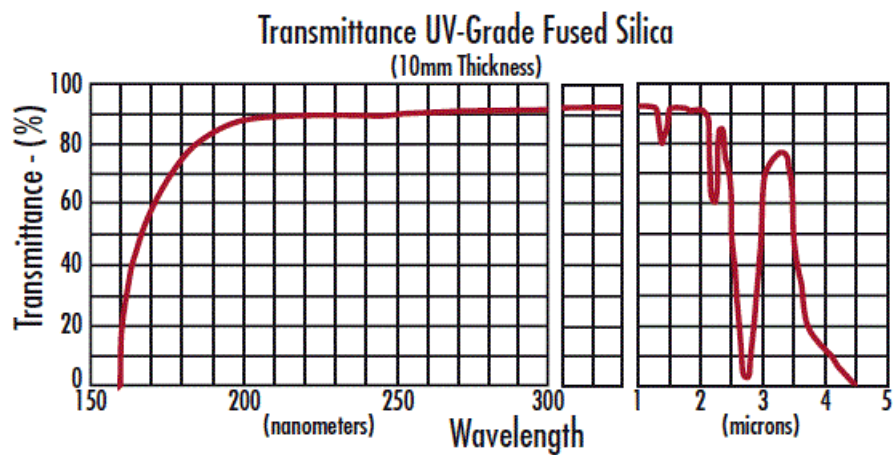


UV FS Transmission Curve

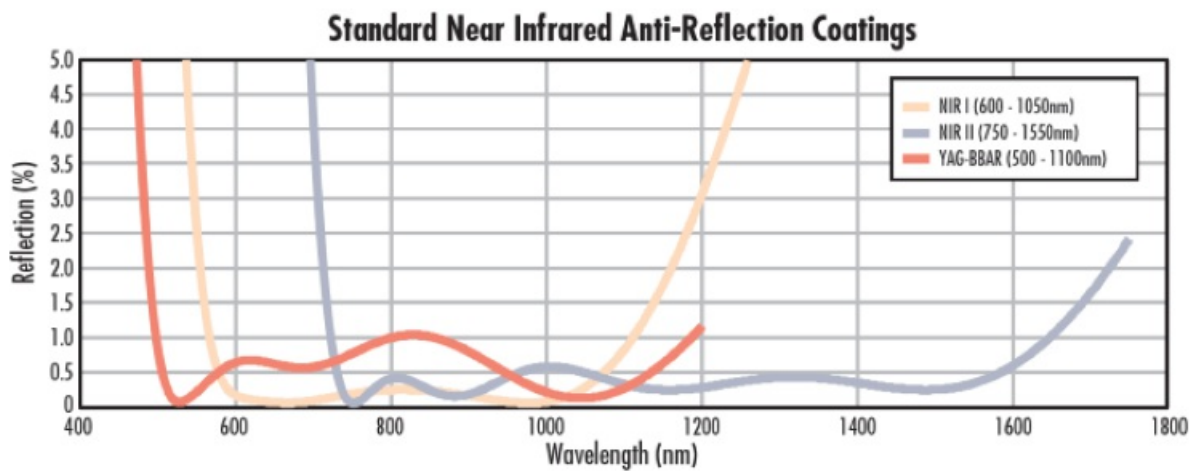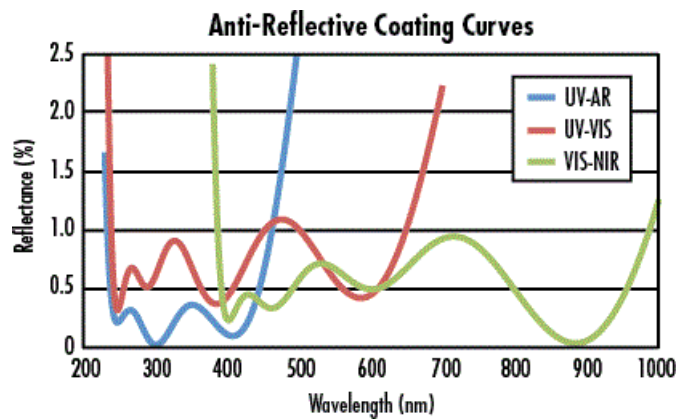

Standard Visible Anti-Reflection Coatings

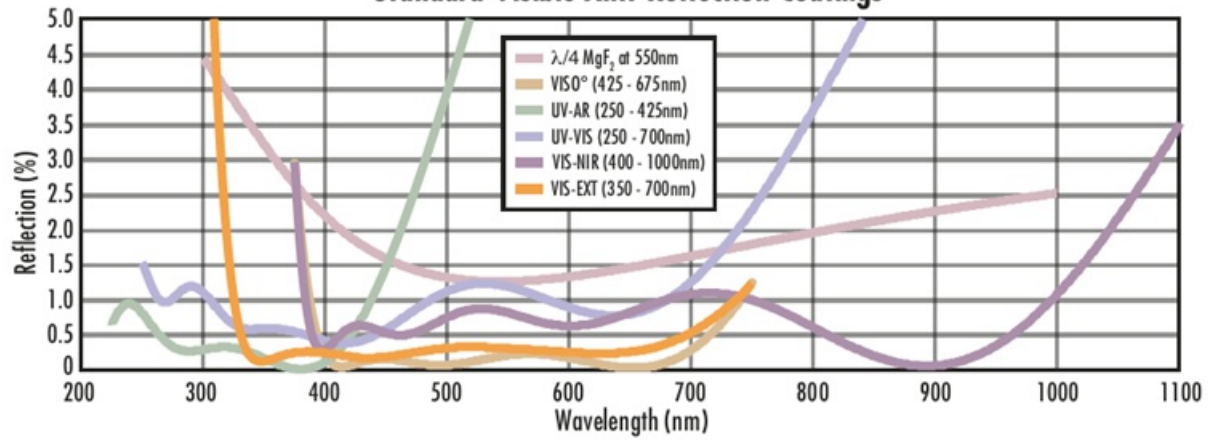

Standard Near Infrared Anti-Reflection Coatings

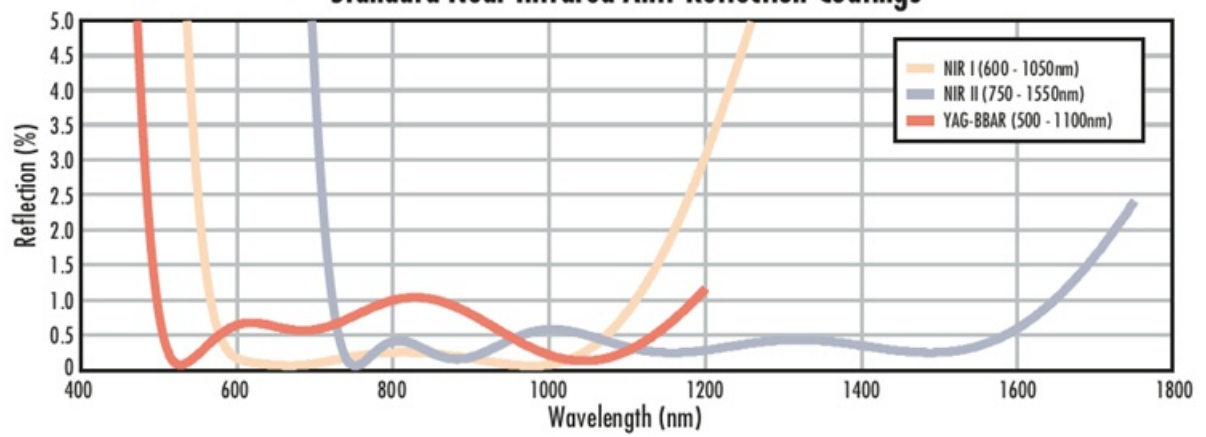

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
5.00	-	1.00	Uncoated	#45-463	S\$105.00 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-AR (250-425nm)	#45-807	S\$147.00 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-VIS (250-700nm)	#84-469	S\$147.00 Volume Pricing	5 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#25-184	S\$152.60 Volume Pricing	4 In Stock
5.00	-	1.00	MgF ₂ (400-700nm)	#11-917	S\$126.70 Volume Pricing	5 In Stock
5.00	-	1.00	VIS 0° (425-675nm)	#36-990	S\$144.20 Volume Pricing	20+ In Stock
5.00	-	1.00	VIS-NIR (400-1000nm)	#49-637	S\$152.60 Volume Pricing	9 In Stock
5.00	-	1.00	YAG-BBAR (500-1100nm)	#25-213	S\$152.60 Volume Pricing	8 In Stock
5.00	-	1.00	NIR I (600-1050nm)	#36-989	S\$144.20 Volume Pricing	20+ In Stock
5.00	-	1.00	NIR II (750-1550nm)	#39-293	S\$144.20 Volume Pricing	5 In Stock
10.00	-	1.00	Uncoated	#45-308	S\$105.00 Volume Pricing	20+ In Stock
10.00	-	1.00	UV-AR (250-425nm)	#45-808	S\$147.00 Volume Pricing	6 In Stock
10.00	-	1.00	UV-VIS (250-700nm)	#84-470	S\$147.00 Volume Pricing	Contact Us
10.00	-	1.00	VIS-EXT (350-700nm)	#25-185	S\$152.60 Volume Pricing	3 In Stock
10.00	-	1.00	MgF ₂ (400-700nm)	#11-918	S\$126.70 Volume Pricing	8 In Stock
10.00	-	1.00	VIS 0° (425-675nm)	#36-968	S\$144.20 Volume Pricing	20+ In Stock

10.00	-	1.00	VIS-NIR (400-1000nm)	#49-638	S\$152.60 Volume Pricing	20+ In Stock
10.00	-	1.00	YAG-BBAR (500-1100nm)	#25-214	S\$152.60 Volume Pricing	11 In Stock
10.00	-	1.00	NIR I (600-1050nm)	#36-967	S\$144.20 Volume Pricing	3 In Stock
10.00	-	1.00	NIR II (750-1550nm)	#39-294	S\$144.20 Volume Pricing	20+ In Stock
12.50	-	1.00	Uncoated	#22-692	S\$105.00 Volume Pricing	20+ In Stock
12.50	-	1.00	UV-AR (250-425nm)	#23-302	S\$147.00 Volume Pricing	3 In Stock
12.50	-	1.00	UV-VIS (250-700nm)	#23-303	S\$147.00 Volume Pricing	2 In Stock
12.50	-	1.00	VIS-EXT (350-700nm)	#25-186	S\$152.60 Volume Pricing	3 In Stock
12.50	-	1.00	MgF ₂ (400-700nm)	#23-301	S\$126.70 Volume Pricing	4 In Stock
12.50	-	1.00	VIS 0° (425-675nm)	#23-304	S\$144.20 Volume Pricing	9 In Stock
12.50	-	1.00	VIS-NIR (400-1000nm)	#23-305	S\$152.60 Volume Pricing	6 In Stock
12.50	-	1.00	YAG-BBAR (500-1100nm)	#25-215	S\$152.60 Volume Pricing	2 In Stock
12.50	-	1.00	NIR I (600-1050nm)	#23-306	S\$144.20 Volume Pricing	7 In Stock
12.50	-	1.00	NIR II (750-1550nm)	#23-307	S\$144.20 Volume Pricing	5 In Stock
12.50	-	2.00	Uncoated	#45-309	S\$105.00 Volume Pricing	20+ In Stock
12.50	-	2.00	UV-AR (250-425nm)	#45-809	S\$147.00 Volume Pricing	20+ In Stock

12.50	-	2.00	UV-VIS (250-700nm)	#84-471	S\$147.00 Volume Pricing	Contact Us
12.50	-	2.00	VIS-EXT (350-700nm)	#25-187	S\$152.60 Volume Pricing	5 In Stock
12.50	-	2.00	MgF ₂ (400-700nm)	#11-919	S\$126.70 Volume Pricing	5 In Stock
12.50	-	2.00	VIS 0° (425-675nm)	#36-970	S\$144.20 Volume Pricing	1 In Stock
12.50	-	2.00	VIS-NIR (400-1000nm)	#49-639	S\$152.60 Volume Pricing	10 In Stock
12.50	-	2.00	YAG-BBAR (500-1100nm)	#25-216	S\$152.60 Volume Pricing	4 In Stock
12.50	-	2.00	NIR I (600-1050nm)	#36-969	S\$144.20 Volume Pricing	9 In Stock
12.50	-	2.00	NIR II (750-1550nm)	#39-295	S\$144.20 Volume Pricing	Contact Us
-	12.50 x 12.50	2.00	Uncoated	#48-200	S\$109.20 Volume Pricing	20+ In Stock
-	12.50 x 12.50	2.00	UV-AR (250-425nm)	#48-202	S\$152.60 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	UV-VIS (250-700nm)	#84-472	S\$152.60 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	VIS-EXT (350-700nm)	#25-188	S\$156.80 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	MgF ₂ (400-700nm)	#11-920	S\$130.20 Volume Pricing	6 In Stock
-	12.50 x 12.50	2.00	VIS 0° (425-675nm)	#36-972	S\$147.00 Volume Pricing	Contact Us
-	12.50 x 12.50	2.00	VIS-NIR (400-1000nm)	#49-640	S\$156.80 Volume Pricing	4 In Stock
-	12.50 x 12.50	2.00	YAG-BBAR (500-1100nm)	#25-217	S\$156.80 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	NIR I (600-1050nm)	#36-971	S\$147.00 Volume Pricing	9 In Stock

-	12.50 x 12.50	2.00	NIR II (750-1550nm)	#39-296	S\$144.20 Volume Pricing	1 In Stock
-	12.50 x 17.50	2.00	Uncoated	#71-192	S\$111.30 Volume Pricing	20+ In Stock
12.70	-	2.00	Uncoated	#15-307	S\$105.00 Volume Pricing	4 In Stock
12.70	-	2.00	UV-AR (250-425nm)	#25-252	S\$147.00 Volume Pricing	4 In Stock
12.70	-	2.00	UV-VIS (250-700nm)	#25-263	S\$147.00 Volume Pricing	2 In Stock
12.70	-	2.00	VIS-EXT (350-700nm)	#25-189	S\$152.60 Volume Pricing	3 In Stock
12.70	-	2.00	MgF ₂ (400-700nm)	#25-318	S\$126.70 Volume Pricing	4 In Stock
12.70	-	2.00	VIS 0° (425-675nm)	#25-274	S\$144.20 Volume Pricing	3 In Stock
12.70	-	2.00	VIS-NIR (400-1000nm)	#25-307	S\$152.60 Volume Pricing	2 In Stock
12.70	-	2.00	YAG-BBAR (500-1100nm)	#25-218	S\$152.60 Volume Pricing	5 In Stock
12.70	-	2.00	NIR I (600-1050nm)	#25-285	S\$144.20 Volume Pricing	3 In Stock
12.70	-	2.00	NIR II (750-1550nm)	#25-296	S\$144.20 Volume Pricing	4 In Stock
15.00	-	1.00	Uncoated	#22-693	S\$109.20 Volume Pricing	20+ In Stock
15.00	-	1.00	UV-AR (250-425nm)	#23-309	S\$152.60 Volume Pricing	1 In Stock
15.00	-	1.00	UV-VIS (250-700nm)	#23-310	S\$152.60 Volume Pricing	5 In Stock
15.00	-	1.00	VIS-EXT (350-700nm)	#25-190	S\$156.80 Volume Pricing	5 In Stock
15.00	-	1.00	MgF ₂ (400-700nm)	#23-308	S\$130.20 Volume Pricing	3 In Stock
15.00	-	1.00	VIS 0° (425-675nm)	#23-311	S\$147.00 Volume Pricing	4 In Stock

15.00	-	1.00	VIS-NIR (400-1000nm)	#23-312	S\$156.80 Volume Pricing	2 In Stock
15.00	-	1.00	YAG-BBAR (500-1100nm)	#25-219	S\$156.80 Volume Pricing	3 In Stock
15.00	-	1.00	NIR I (600-1050nm)	#23-313	S\$147.00 Volume Pricing	1 In Stock
15.00	-	1.00	NIR II (750-1550nm)	#23-314	S\$147.00 Volume Pricing	2 In Stock
15.00	-	2.00	Uncoated	#45-310	S\$109.20 Volume Pricing	20+ In Stock
15.00	-	2.00	UV-AR (250-425nm)	#45-810	S\$152.60 Volume Pricing	20+ In Stock
15.00	-	2.00	UV-VIS (250-700nm)	#84-473	S\$152.60 Volume Pricing	5 In Stock
15.00	-	2.00	VIS-EXT (350-700nm)	#25-191	S\$156.80 Volume Pricing	6 In Stock
15.00	-	2.00	MgF ₂ (400-700nm)	#11-921	S\$130.20 Volume Pricing	2 In Stock
15.00	-	2.00	VIS 0° (425-675nm)	#36-974	S\$147.00 Volume Pricing	17 In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#49-641	S\$156.80 Volume Pricing	Contact Us
15.00	-	2.00	YAG-BBAR (500-1100nm)	#25-220	S\$156.80 Volume Pricing	2 In Stock
15.00	-	2.00	NIR I (600-1050nm)	#36-973	S\$147.00 Volume Pricing	5 In Stock
15.00	-	2.00	NIR II (750-1550nm)	#39-297	S\$147.00 Volume Pricing	5 In Stock
20.00	-	1.00	Uncoated	#22-694	S\$113.40 Volume Pricing	20+ In Stock
20.00	-	1.00	UV-AR (250-425nm)	#23-316	S\$156.80 Volume Pricing	5 In Stock
20.00	-	1.00	UV-VIS (250-700nm)	#23-317	S\$156.80 Volume Pricing	3 In Stock

20.00	-	1.00	VIS-EXT (350-700nm)	#25-192	S\$161.00 Volume Pricing	5 In Stock
20.00	-	1.00	MgF ₂ (400- 700nm)	#23-315	S\$135.10 Volume Pricing	1 In Stock
20.00	-	1.00	VIS 0° (425- 675nm)	#23-318	S\$152.60 Volume Pricing	2 In Stock
20.00	-	1.00	VIS-NIR (400- 1000nm)	#23-319	S\$161.00 Volume Pricing	Contact Us
20.00	-	1.00	YAG-BBAR (500- 1100nm)	#25-221	S\$161.00 Volume Pricing	4 In Stock
20.00	-	1.00	NIR I (600- 1050nm)	#23-320	S\$152.60 Volume Pricing	4 In Stock
20.00	-	1.00	NIR II (750- 1550nm)	#23-321	S\$152.60 Volume Pricing	Contact Us
20.00	-	2.00	Uncoated	#45-464	S\$113.40 Volume Pricing	20+ In Stock
20.00	-	2.00	UV-AR (250- 425nm)	#45-811	S\$156.80 Volume Pricing	5 In Stock
20.00	-	2.00	UV-VIS (250- 700nm)	#84-474	S\$156.80 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#25-193	S\$161.00 Volume Pricing	5 In Stock
20.00	-	2.00	MgF ₂ (400- 700nm)	#11-922	S\$135.10 Volume Pricing	4 In Stock
20.00	-	2.00	VIS 0° (425- 675nm)	#36-976	S\$152.60 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS-NIR (400- 1000nm)	#49-642	S\$161.00 Volume Pricing	20+ In Stock
20.00	-	2.00	YAG-BBAR (500- 1100nm)	#25-222	S\$161.00 Volume Pricing	8 In Stock
20.00	-	2.00	NIR I (600- 1050nm)	#36-975	S\$152.60 Volume Pricing	10 In Stock
20.00	-	2.00	NIR II (750- 1550nm)	#39-298	S\$152.60 Volume Pricing	3 In Stock

25.00	-	1.00	Uncoated	#19-837	S\$120.40 Volume Pricing	8 In Stock
25.00	-	1.00	UV-AR (250-425nm)	#19-846	S\$163.80 Volume Pricing	7 In Stock
25.00	-	1.00	UV-VIS (250-700nm)	#19-847	S\$163.80 Volume Pricing	1 In Stock
25.00	-	2.00	VIS-EXT (350-700nm)	#25-195	S\$168.00 Volume Pricing	1 In Stock
25.00	-	1.00	MgF ₂ (400-700nm)	#19-845	S\$141.40 Volume Pricing	14 In Stock
25.00	-	1.00	VIS 0° (425-675nm)	#19-848	S\$159.60 Volume Pricing	5 In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#19-849	S\$168.00 Volume Pricing	15 In Stock
25.00	-	2.00	YAG-BBAR (500-1100nm)	#25-224	S\$168.00 Volume Pricing	1 In Stock
25.00	-	1.00	NIR I (600-1050nm)	#19-850	S\$159.60 Volume Pricing	4 In Stock
25.00	-	1.00	NIR II (750-1550nm)	#19-851	S\$159.60 Volume Pricing	6 In Stock
25.00	-	2.00	Uncoated	#45-311	S\$120.40 Volume Pricing	20+ In Stock
25.00	-	2.00	UV-AR (250-425nm)	#45-812	S\$163.80 Volume Pricing	20+ In Stock
25.00	-	2.00	UV-VIS (250-700nm)	#84-475	S\$163.80 Volume Pricing	20+ In Stock
25.00	-	1.00	VIS-EXT (350-700nm)	#25-194	S\$168.00 Volume Pricing	8 In Stock
25.00	-	2.00	MgF ₂ (400-700nm)	#11-923	S\$141.40 Volume Pricing	10 In Stock
25.00	-	2.00	VIS 0° (425-675nm)	#36-978	S\$159.60 Volume Pricing	8 In Stock
25.00	-	2.00	VIS-NIR (400-1000nm)	#49-643	S\$168.00 Volume Pricing	20+ In Stock

25.00	-	1.00	YAG-BBAR (500-1100nm)	#25-223	S\$168.00 Volume Pricing	2 In Stock
25.00	-	2.00	NIR I (600-1050nm)	#36-977	S\$159.60 Volume Pricing	5 In Stock
25.00	-	2.00	NIR II (750-1550nm)	#39-299	S\$159.60 Volume Pricing	9 In Stock
25.00	-	3.00	Uncoated	#19-838	S\$120.40 Volume Pricing	20+ In Stock
25.00	-	3.00	UV-AR (250-425nm)	#19-853	S\$163.80 Volume Pricing	5 In Stock
25.00	-	3.00	UV-VIS (250-700nm)	#19-854	S\$163.80 Volume Pricing	9 In Stock
25.00	-	3.00	VIS-EXT (350-700nm)	#25-196	S\$168.00 Volume Pricing	9 In Stock
25.00	-	3.00	MgF ₂ (400-700nm)	#19-852	S\$141.40 Volume Pricing	5 In Stock
25.00	-	3.00	VIS 0° (425-675nm)	#19-855	S\$159.60 Volume Pricing	1 In Stock
25.00	-	3.00	VIS-NIR (400-1000nm)	#19-856	S\$168.00 Volume Pricing	8 In Stock
25.00	-	3.00	YAG-BBAR (500-1100nm)	#25-225	S\$168.00 Volume Pricing	4 In Stock
25.00	-	3.00	NIR I (600-1050nm)	#19-857	S\$159.60 Volume Pricing	3 In Stock
25.00	-	3.00	NIR II (750-1550nm)	#19-858	S\$159.60 Volume Pricing	14 In Stock
25.00	-	4.00	Uncoated	#19-839	S\$120.40 Volume Pricing	16 In Stock
25.00	-	4.00	UV-AR (250-425nm)	#19-860	S\$163.80 Volume Pricing	3 In Stock
25.00	-	4.00	UV-VIS (250-700nm)	#19-861	S\$163.80 Volume Pricing	3 In Stock
25.00	-	4.00	VIS-EXT (350-700nm)	#25-197	S\$168.00 Volume Pricing	2 In Stock
25.00	-	4.00	MgF ₂ (400-700nm)	#19-859	S\$141.40 Volume Pricing	4 In Stock

25.00	-	4.00	VIS 0° (425-675nm)	#19-862	S\$159.60 Volume Pricing	8 In Stock
25.00	-	4.00	VIS-NIR (400-1000nm)	#19-863	S\$168.00 Volume Pricing	8 In Stock
25.00	-	4.00	YAG-BBAR (500-1100nm)	#25-226	S\$168.00 Volume Pricing	7 In Stock
25.00	-	4.00	NIR I (600-1050nm)	#19-864	S\$159.60 Volume Pricing	5 In Stock
25.00	-	4.00	NIR II (750-1550nm)	#19-865	S\$159.60 Volume Pricing	10 In Stock
25.00	-	5.00	Uncoated	#19-840	S\$120.40 Volume Pricing	Contact Us
25.00	-	5.00	UV-AR (250-425nm)	#19-867	S\$163.80 Volume Pricing	4 In Stock
25.00	-	5.00	UV-VIS (250-700nm)	#19-868	S\$163.80 Volume Pricing	4 In Stock
25.00	-	5.00	VIS-EXT (350-700nm)	#25-198	S\$168.00 Volume Pricing	5 In Stock
25.00	-	5.00	MgF ₂ (400-700nm)	#19-866	S\$141.40 Volume Pricing	5 In Stock
25.00	-	5.00	VIS 0° (425-675nm)	#19-869	S\$159.60 Volume Pricing	4 In Stock
25.00	-	5.00	VIS-NIR (400-1000nm)	#19-870	S\$168.00 Volume Pricing	5 In Stock
25.00	-	5.00	YAG-BBAR (500-1100nm)	#25-227	S\$168.00 Volume Pricing	5 In Stock
25.00	-	5.00	NIR I (600-1050nm)	#19-871	S\$159.60 Volume Pricing	3 In Stock
25.00	-	5.00	NIR II (750-1550nm)	#19-872	S\$159.60 Volume Pricing	6 In Stock
-	25.00 x 25.00	2.00	Uncoated	#48-201	S\$124.60 Volume Pricing	9 In Stock
-	25.00 x 25.00	2.00	UV-AR (250-425nm)	#48-203	S\$168.00 Volume Pricing	9 In Stock

-	25.00 x 25.00	2.00	UV-VIS (250-700nm)	#84-476	S\$168.00 Volume Pricing	5 In Stock
-	25.00 x 25.00	2.00	VIS-EXT (350-700nm)	#25-199	S\$173.60 Volume Pricing	9 In Stock
-	25.00 x 25.00	2.00	MgF ₂ (400-700nm)	#11-924	S\$145.60 Volume Pricing	14 In Stock
-	25.00 x 25.00	2.00	VIS 0° (425-675nm)	#36-980	S\$163.80 Volume Pricing	5 In Stock
-	25.00 x 25.00	2.00	VIS-NIR (400-1000nm)	#49-644	S\$173.60 Volume Pricing	15 In Stock
-	25.00 x 25.00	2.00	YAG-BBAR (500-1100nm)	#25-228	S\$173.60 Volume Pricing	6 In Stock
-	25.00 x 25.00	2.00	NIR I (600-1050nm)	#36-979	S\$163.80 Volume Pricing	2 In Stock
-	25.00 x 25.00	2.00	NIR II (750-1550nm)	#39-300	S\$163.80 Volume Pricing	8 In Stock
-	25.00 x 35.00	3.00	Uncoated	#71-193	S\$132.30 Volume Pricing	Contact Us
25.40	-	1.00	Uncoated	#25-244	S\$120.40 Volume Pricing	20+ In Stock
25.40	-	1.00	UV-AR (250-425nm)	#25-253	S\$163.80 Volume Pricing	8 In Stock
25.40	-	1.00	UV-VIS (250-700nm)	#25-264	S\$163.80 Volume Pricing	4 In Stock
25.40	-	1.00	VIS-EXT (350-700nm)	#25-329	S\$168.00 Volume Pricing	3 In Stock
25.40	-	1.00	MgF ₂ (400-700nm)	#25-319	S\$141.40 Volume Pricing	5 In Stock
25.40	-	1.00	VIS 0° (425-675nm)	#25-275	S\$159.60 Volume Pricing	6 In Stock
25.40	-	1.00	VIS-NIR (400-1000nm)	#25-308	S\$168.00 Volume Pricing	5 In Stock
25.40	-	1.00	YAG-BBAR (500-1100nm)	#25-337	S\$168.00 Volume Pricing	2 In Stock

25.40	-	1.00	NIR I (600-1050nm)	#25-286	S\$159.60 Volume Pricing	1 In Stock
25.40	-	1.00	NIR II (750-1550nm)	#25-297	S\$159.60 Volume Pricing	2 In Stock
25.40	-	2.00	Uncoated	#15-308	S\$120.40 Volume Pricing	5 In Stock
25.40	-	2.00	UV-AR (250-425nm)	#25-254	S\$163.80 Volume Pricing	1 In Stock
25.40	-	2.00	UV-VIS (250-700nm)	#25-265	S\$163.80 Volume Pricing	3 In Stock
25.40	-	2.00	VIS-EXT (350-700nm)	#25-200	S\$168.00 Volume Pricing	5 In Stock
25.40	-	2.00	MgF ₂ (400-700nm)	#25-320	S\$141.40 Volume Pricing	1 In Stock
25.40	-	2.00	VIS 0° (425-675nm)	#25-276	S\$159.60 Volume Pricing	4 In Stock
25.40	-	2.00	VIS-NIR (400-1000nm)	#25-309	S\$168.00 Volume Pricing	1 In Stock
25.40	-	2.00	YAG-BBAR (500-1100nm)	#25-229	S\$168.00 Volume Pricing	4 In Stock
25.40	-	2.00	NIR I (600-1050nm)	#25-287	S\$159.60 Volume Pricing	4 In Stock
25.40	-	2.00	NIR II (750-1550nm)	#25-298	S\$159.60 Volume Pricing	2 In Stock
25.40	-	3.00	Uncoated	#25-245	S\$120.40 Volume Pricing	20+ In Stock
25.40	-	3.00	UV-AR (250-425nm)	#25-255	S\$163.80 Volume Pricing	5 In Stock
25.40	-	3.00	UV-VIS (250-700nm)	#25-266	S\$163.80 Volume Pricing	2 In Stock
25.40	-	3.00	VIS-EXT (350-700nm)	#25-330	S\$168.00 Volume Pricing	1 In Stock
25.40	-	3.00	MgF ₂ (400-700nm)	#25-321	S\$141.40 Volume Pricing	3 In Stock
25.40	-	3.00	VIS 0° (425-675nm)	#25-277	S\$159.60 Volume Pricing	5 In Stock

25.40	-	3.00	VIS-NIR (400-1000nm)	#25-310	S\$168.00 Volume Pricing	2 In Stock
25.40	-	3.00	YAG-BBAR (500-1100nm)	#25-338	S\$168.00 Volume Pricing	5 In Stock
25.40	-	3.00	NIR I (600-1050nm)	#25-288	S\$162.40 Volume Pricing	3 In Stock
25.40	-	3.00	NIR II (750-1550nm)	#25-299	S\$159.60 Volume Pricing	1 In Stock
25.40	-	4.00	Uncoated	#25-246	S\$120.40 Volume Pricing	20+ In Stock
25.40	-	4.00	UV-AR (250-425nm)	#25-256	S\$163.80 Volume Pricing	4 In Stock
25.40	-	4.00	UV-VIS (250-700nm)	#25-267	S\$163.80 Volume Pricing	5 In Stock
25.40	-	4.00	VIS-EXT (350-700nm)	#25-331	S\$168.00 Volume Pricing	5 In Stock
25.40	-	4.00	MgF ₂ (400-700nm)	#25-322	S\$141.40 Volume Pricing	5 In Stock
25.40	-	4.00	VIS 0° (425-675nm)	#25-278	S\$159.60 Volume Pricing	5 In Stock
25.40	-	4.00	VIS-NIR (400-1000nm)	#25-311	S\$168.00 Volume Pricing	14 In Stock
25.40	-	4.00	YAG-BBAR (500-1100nm)	#25-339	S\$168.00 Volume Pricing	5 In Stock
25.40	-	4.00	NIR I (600-1050nm)	#25-289	S\$159.60 Volume Pricing	4 In Stock
25.40	-	4.00	NIR II (750-1550nm)	#25-300	S\$159.60 Volume Pricing	1 In Stock
25.40	-	5.00	Uncoated	#25-247	S\$120.40 Volume Pricing	20+ In Stock
25.40	-	5.00	UV-AR (250-425nm)	#25-257	S\$163.80 Volume Pricing	5 In Stock
25.40	-	5.00	UV-VIS (250-700nm)	#25-268	S\$163.80 Volume Pricing	5 In Stock

25.40	-	5.00	VIS-EXT (350-700nm)	#25-332	S\$168.00 Volume Pricing	3 In Stock
25.40	-	5.00	MgF ₂ (400- 700nm)	#25-323	S\$141.40 Volume Pricing	5 In Stock
25.40	-	5.00	VIS 0° (425- 675nm)	#25-279	S\$159.60 Volume Pricing	2 In Stock
25.40	-	5.00	VIS-NIR (400- 1000nm)	#25-312	S\$168.00 Volume Pricing	3 In Stock
25.40	-	5.00	YAG-BBAR (500- 1100nm)	#25-340	S\$168.00 Volume Pricing	4 In Stock
25.40	-	5.00	NIR I (600- 1050nm)	#25-290	S\$162.40 Volume Pricing	4 In Stock
25.40	-	5.00	NIR II (750- 1550nm)	#25-301	S\$159.60 Volume Pricing	3 In Stock
30.00	-	1.00	Uncoated	#22-695	S\$141.40 Volume Pricing	Contact Us
30.00	-	1.00	UV-AR (250- 425nm)	#23-323	S\$194.60 Volume Pricing	3 In Stock
30.00	-	1.00	UV-VIS (250- 700nm)	#23-324	S\$194.60 Volume Pricing	3 In Stock
30.00	-	1.00	VIS-EXT (350-700nm)	#25-201	S\$197.40 Volume Pricing	2 In Stock
30.00	-	1.00	MgF ₂ (400- 700nm)	#23-322	S\$173.60 Volume Pricing	4 In Stock
30.00	-	1.00	VIS 0° (425- 675nm)	#23-325	S\$189.00 Volume Pricing	2 In Stock
30.00	-	1.00	VIS-NIR (400- 1000nm)	#23-326	S\$197.40 Volume Pricing	Contact Us
30.00	-	1.00	YAG-BBAR (500- 1100nm)	#25-230	S\$197.40 Volume Pricing	2 In Stock
30.00	-	1.00	NIR I (600- 1050nm)	#23-327	S\$189.00 Volume Pricing	1 In Stock
30.00	-	1.00	NIR II (750- 1550nm)	#23-328	S\$189.00 Volume Pricing	5 In Stock

30.00	-	3.00	Uncoated	#45-569	S\$141.40 Volume Pricing	20+ In Stock
30.00	-	3.00	UV-AR (250-425nm)	#45-813	S\$194.60 Volume Pricing	5 In Stock
30.00	-	3.00	UV-VIS (250-700nm)	#84-477	S\$194.60 Volume Pricing	12 In Stock
30.00	-	3.00	VIS-EXT (350-700nm)	#25-202	S\$197.40 Volume Pricing	1 In Stock
30.00	-	3.00	MgF ₂ (400-700nm)	#11-925	S\$173.60 Volume Pricing	9 In Stock
30.00	-	3.00	VIS 0° (425-675nm)	#36-982	S\$189.00 Volume Pricing	7 In Stock
30.00	-	3.00	VIS-NIR (400-1000nm)	#49-645	S\$197.40 Volume Pricing	7 In Stock
30.00	-	3.00	YAG-BBAR (500-1100nm)	#25-231	S\$197.40 Volume Pricing	3 In Stock
30.00	-	3.00	NIR I (600-1050nm)	#36-981	S\$189.00 Volume Pricing	Contact Us
30.00	-	3.00	NIR II (750-1550nm)	#39-301	S\$189.00 Volume Pricing	4 In Stock
-	35.00 x 50.00	4.00	Uncoated	#71-194	S\$161.00 Volume Pricing	20+ In Stock
40.00	-	1.00	Uncoated	#22-696	S\$151.20 Volume Pricing	20+ In Stock
40.00	-	1.00	UV-AR (250-425nm)	#23-330	S\$203.00 Volume Pricing	2 In Stock
40.00	-	1.00	UV-VIS (250-700nm)	#23-331	S\$203.00 Volume Pricing	2 In Stock
40.00	-	1.00	VIS-EXT (350-700nm)	#25-203	S\$207.20 Volume Pricing	2 In Stock
40.00	-	1.00	MgF ₂ (400-700nm)	#23-329	S\$180.60 Volume Pricing	4 In Stock
40.00	-	1.00	VIS 0° (425-675nm)	#23-332	S\$197.40 Volume Pricing	2 In Stock
40.00	-	1.00	VIS-NIR (400-1000nm)	#23-333	S\$207.20 Volume Pricing	3 In Stock

40.00	-	1.00	YAG-BBAR (500-1100nm)	#25-232	S\$207.20 Volume Pricing	Contact Us
40.00	-	1.00	NIR I (600-1050nm)	#23-334	S\$197.40 Volume Pricing	7 In Stock
40.00	-	1.00	NIR II (750-1550nm)	#23-335	S\$197.40 Volume Pricing	2 In Stock
40.00	-	4.00	Uncoated	#45-570	S\$151.20 Volume Pricing	20+ In Stock
40.00	-	4.00	UV-AR (250-425nm)	#45-814	S\$203.00 Volume Pricing	20+ In Stock
40.00	-	4.00	UV-VIS (250-700nm)	#84-478	S\$203.00 Volume Pricing	3 In Stock
40.00	-	4.00	VIS-EXT (350-700nm)	#25-204	S\$207.20 Volume Pricing	2 In Stock
40.00	-	4.00	MgF ₂ (400-700nm)	#11-926	S\$180.60 Volume Pricing	1 In Stock
40.00	-	4.00	VIS 0° (425-675nm)	#36-984	S\$197.40 Volume Pricing	12 In Stock
40.00	-	4.00	VIS-NIR (400-1000nm)	#49-646	S\$207.20 Volume Pricing	7 In Stock
40.00	-	4.00	YAG-BBAR (500-1100nm)	#25-233	S\$207.20 Volume Pricing	4 In Stock
40.00	-	4.00	NIR I (600-1050nm)	#36-983	S\$197.40 Volume Pricing	3 In Stock
40.00	-	4.00	NIR II (750-1550nm)	#39-302	S\$197.40 Volume Pricing	10 In Stock
50.00	-	1.00	Uncoated	#19-841	S\$184.80 Volume Pricing	20+ In Stock
50.00	-	1.00	UV-AR (250-425nm)	#19-874	S\$245.00 Volume Pricing	4 In Stock
50.00	-	1.00	UV-VIS (250-700nm)	#19-875	S\$245.00 Volume Pricing	2 In Stock
50.00	-	1.00	VIS-EXT (350-700nm)	#25-205	S\$249.20 Volume Pricing	5 In Stock
50.00	-	1.00	MgF ₂ (400-700nm)	#19-873	S\$215.60 Volume Pricing	1 In Stock

50.00	-	1.00	VIS 0° (425-675nm)	#19-876	S\$240.80 Volume Pricing	2 In Stock
50.00	-	5.00	NIR II (750-1550nm)	#19-900	S\$240.80 Volume Pricing	1 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#19-877	S\$249.20 Volume Pricing	1 In Stock
50.00	-	1.00	YAG-BBAR (500-1100nm)	#25-234	S\$249.20 Volume Pricing	3 In Stock
50.00	-	5.00	NIR I (600-1050nm)	#19-899	S\$240.80 Volume Pricing	1 In Stock
50.00	-	2.00	Uncoated	#19-842	S\$184.80 Volume Pricing	20+ In Stock
50.00	-	2.00	UV-AR (250-425nm)	#19-881	S\$245.00 Volume Pricing	3 In Stock
50.00	-	2.00	UV-VIS (250-700nm)	#19-882	S\$245.00 Volume Pricing	12 In Stock
50.00	-	2.00	VIS-EXT (350-700nm)	#25-206	S\$249.20 Volume Pricing	6 In Stock
50.00	-	2.00	MgF ₂ (400-700nm)	#19-880	S\$215.60 Volume Pricing	5 In Stock
50.00	-	2.00	VIS 0° (425-675nm)	#19-883	S\$240.80 Volume Pricing	3 In Stock
50.00	-	2.00	VIS-NIR (400-1000nm)	#19-884	S\$249.20 Volume Pricing	5 In Stock
50.00	-	2.00	YAG-BBAR (500-1100nm)	#25-235	S\$249.20 Volume Pricing	1 In Stock
50.00	-	1.00	NIR I (600-1050nm)	#19-878	S\$240.80 Volume Pricing	5 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#19-879	S\$240.80 Volume Pricing	4 In Stock
50.00	-	3.00	Uncoated	#19-843	S\$184.80 Volume Pricing	20+ In Stock
50.00	-	3.00	UV-AR (250-425nm)	#19-888	S\$245.00 Volume Pricing	2 In Stock

50.00	-	3.00	UV-VIS (250-700nm)	#19-889	S\$245.00 Volume Pricing	3 In Stock
50.00	-	3.00	VIS-EXT (350-700nm)	#25-207	S\$249.20 Volume Pricing	8 In Stock
50.00	-	3.00	MgF ₂ (400-700nm)	#19-887	S\$215.60 Volume Pricing	1 In Stock
50.00	-	3.00	VIS 0° (425-675nm)	#19-890	S\$240.80 Volume Pricing	1 In Stock
50.00	-	3.00	VIS-NIR (400-1000nm)	#19-891	S\$249.20 Volume Pricing	4 In Stock
50.00	-	3.00	YAG-BBAR (500-1100nm)	#25-236	S\$249.20 Volume Pricing	1 In Stock
50.00	-	2.00	NIR I (600-1050nm)	#19-885	S\$240.80 Volume Pricing	2 In Stock
50.00	-	2.00	NIR II (750-1550nm)	#19-886	S\$240.80 Volume Pricing	1 In Stock
50.00	-	4.00	Uncoated	#47-230	S\$184.80 Volume Pricing	20+ In Stock
50.00	-	4.00	UV-AR (250-425nm)	#49-635	S\$245.00 Volume Pricing	Contact Us
50.00	-	4.00	UV-VIS (250-700nm)	#84-479	S\$245.00 Volume Pricing	8 In Stock
50.00	-	4.00	VIS-EXT (350-700nm)	#25-208	S\$249.20 Volume Pricing	3 In Stock
50.00	-	4.00	MgF ₂ (400-700nm)	#11-927	S\$215.60 Volume Pricing	7 In Stock
50.00	-	4.00	VIS 0° (425-675nm)	#36-986	S\$240.80 Volume Pricing	4 In Stock
50.00	-	4.00	VIS-NIR (400-1000nm)	#49-647	S\$249.20 Volume Pricing	9 In Stock
50.00	-	4.00	YAG-BBAR (500-1100nm)	#25-237	S\$249.20 Volume Pricing	4 In Stock
50.00	-	3.00	NIR I (600-1050nm)	#19-892	S\$246.40 Volume Pricing	1 In Stock

50.00	-	3.00	NIR II (750-1550nm)	#19-893	S\$240.80 Volume Pricing	5 In Stock
50.00	-	5.00	Uncoated	#19-844	S\$184.80 Volume Pricing	20+ In Stock
50.00	-	5.00	UV-AR (250-425nm)	#19-895	S\$245.00 Volume Pricing	2 In Stock
50.00	-	5.00	UV-VIS (250-700nm)	#19-896	S\$245.00 Volume Pricing	3 In Stock
50.00	-	5.00	VIS-EXT (350-700nm)	#25-209	S\$249.20 Volume Pricing	3 In Stock
50.00	-	5.00	MgF ₂ (400-700nm)	#19-894	S\$215.60 Volume Pricing	5 In Stock
50.00	-	5.00	VIS 0° (425-675nm)	#19-897	S\$240.80 Volume Pricing	1 In Stock
50.00	-	5.00	VIS-NIR (400-1000nm)	#19-898	S\$249.20 Volume Pricing	5 In Stock
50.00	-	5.00	YAG-BBAR (500-1100nm)	#25-238	S\$249.20 Volume Pricing	2 In Stock
50.00	-	4.00	NIR I (600-1050nm)	#36-985	S\$240.80 Volume Pricing	5 In Stock
50.00	-	4.00	NIR II (750-1550nm)	#39-303	S\$240.80 Volume Pricing	5 In Stock
-	50.00 x 50.00	4.00	Uncoated	#47-231	S\$189.00 Volume Pricing	20+ In Stock
-	50.00 x 50.00	4.00	UV-AR (250-425nm)	#49-636	S\$249.20 Volume Pricing	7 In Stock
-	50.00 x 50.00	4.00	UV-VIS (250-700nm)	#84-480	S\$249.20 Volume Pricing	5 In Stock
-	50.00 x 50.00	4.00	VIS-EXT (350-700nm)	#25-210	S\$254.80 Volume Pricing	1 In Stock
-	50.00 x 50.00	4.00	MgF ₂ (400-700nm)	#11-928	S\$219.80 Volume Pricing	5 In Stock
-	50.00 x 50.00	4.00	VIS 0° (425-675nm)	#36-988	S\$245.00 Volume Pricing	5 In Stock
-	50.00 x 50.00	4.00	VIS-NIR (400-1000nm)	#49-648	S\$254.80 Volume Pricing	5 In Stock

-	50.00 x 50.00	4.00	YAG-BBAR (500-1100nm)	#25-239	S\$254.80 Volume Pricing	2 In Stock
-	50.00 x 50.00	4.00	NIR I (600-1050nm)	#36-987	S\$245.00 Volume Pricing	1 In Stock
-	50.00 x 50.00	4.00	NIR II (750-1550nm)	#39-304	S\$245.00 Volume Pricing	2 In Stock
50.80	-	1.00	Uncoated	#25-248	S\$184.80 Volume Pricing	20+ In Stock
50.80	-	1.00	UV-AR (250-425nm)	#25-258	S\$245.00 Volume Pricing	4 In Stock
50.80	-	1.00	UV-VIS (250-700nm)	#25-269	S\$245.00 Volume Pricing	1 In Stock
50.80	-	1.00	VIS-EXT (350-700nm)	#25-333	S\$249.20 Volume Pricing	4 In Stock
50.80	-	1.00	MgF ₂ (400-700nm)	#25-324	S\$215.60 Volume Pricing	1 In Stock
50.80	-	1.00	VIS 0° (425-675nm)	#25-280	S\$240.80 Volume Pricing	5 In Stock
50.80	-	1.00	VIS-NIR (400-1000nm)	#25-313	S\$249.20 Volume Pricing	3 In Stock
50.80	-	1.00	YAG-BBAR (500-1100nm)	#25-341	S\$249.20 Volume Pricing	6 In Stock
50.80	-	1.00	NIR I (600-1050nm)	#25-291	S\$240.80 Volume Pricing	5 In Stock
50.80	-	1.00	NIR II (750-1550nm)	#25-302	S\$240.80 Volume Pricing	2 In Stock
50.80	-	2.00	Uncoated	#25-249	S\$184.80 Volume Pricing	9 In Stock
50.80	-	2.00	UV-AR (250-425nm)	#25-259	S\$245.00 Volume Pricing	1 In Stock
50.80	-	2.00	UV-VIS (250-700nm)	#25-270	S\$245.00 Volume Pricing	4 In Stock
50.80	-	2.00	VIS-EXT (350-700nm)	#25-334	S\$249.20 Volume Pricing	1 In Stock
50.80	-	2.00	MgF ₂ (400-700nm)	#25-325	S\$215.60 Volume Pricing	5 In Stock

50.80	-	2.00	VIS 0° (425-675nm)	#25-281	S\$240.80 Volume Pricing	5 In Stock
50.80	-	2.00	VIS-NIR (400-1000nm)	#25-314	S\$249.20 Volume Pricing	1 In Stock
50.80	-	2.00	YAG-BBAR (500-1100nm)	#25-342	S\$249.20 Volume Pricing	2 In Stock
50.80	-	2.00	NIR I (600-1050nm)	#25-292	S\$240.80 Volume Pricing	1 In Stock
50.80	-	2.00	NIR II (750-1550nm)	#25-303	S\$240.80 Volume Pricing	3 In Stock
50.80	-	3.00	Uncoated	#25-250	S\$184.80 Volume Pricing	20+ In Stock
50.80	-	3.00	UV-AR (250-425nm)	#25-260	S\$245.00 Volume Pricing	2 In Stock
50.80	-	3.00	UV-VIS (250-700nm)	#25-271	S\$245.00 Volume Pricing	2 In Stock
50.80	-	3.00	VIS-EXT (350-700nm)	#25-335	S\$249.20 Volume Pricing	Contact Us
50.80	-	3.00	MgF ₂ (400-700nm)	#25-326	S\$215.60 Volume Pricing	5 In Stock
50.80	-	3.00	VIS 0° (425-675nm)	#25-282	S\$240.80 Volume Pricing	5 In Stock
50.80	-	3.00	VIS-NIR (400-1000nm)	#25-315	S\$249.20 Volume Pricing	3 In Stock
50.80	-	3.00	YAG-BBAR (500-1100nm)	#25-343	S\$249.20 Volume Pricing	9 In Stock
50.80	-	3.00	NIR I (600-1050nm)	#25-293	S\$246.40 Volume Pricing	4 In Stock
50.80	-	3.00	NIR II (750-1550nm)	#25-304	S\$240.80 Volume Pricing	1 In Stock
50.80	-	4.00	Uncoated	#15-309	S\$184.80 Volume Pricing	Contact Us
50.80	-	4.00	UV-AR (250-425nm)	#25-261	S\$245.00 Volume Pricing	5 In Stock

50.80	-	4.00	UV-VIS (250-700nm)	#25-272	S\$245.00 Volume Pricing	6 In Stock
50.80	-	4.00	VIS-EXT (350-700nm)	#25-211	S\$249.20 Volume Pricing	5 In Stock
50.80	-	4.00	MgF ₂ (400-700nm)	#25-327	S\$215.60 Volume Pricing	5 In Stock
50.80	-	4.00	VIS 0° (425-675nm)	#25-283	S\$240.80 Volume Pricing	5 In Stock
50.80	-	4.00	VIS-NIR (400-1000nm)	#25-316	S\$249.20 Volume Pricing	3 In Stock
50.80	-	4.00	YAG-BBAR (500-1100nm)	#25-240	S\$249.20 Volume Pricing	5 In Stock
50.80	-	4.00	NIR I (600-1050nm)	#25-294	S\$240.80 Volume Pricing	4 In Stock
50.80	-	4.00	NIR II (750-1550nm)	#25-305	S\$240.80 Volume Pricing	5 In Stock
50.80	-	5.00	Uncoated	#25-251	S\$184.80 Volume Pricing	7 In Stock
50.80	-	5.00	UV-AR (250-425nm)	#25-262	S\$245.00 Volume Pricing	4 In Stock
50.80	-	5.00	UV-VIS (250-700nm)	#25-273	S\$245.00 Volume Pricing	3 In Stock
50.80	-	5.00	VIS-EXT (350-700nm)	#25-336	S\$249.20 Volume Pricing	6 In Stock
50.80	-	5.00	MgF ₂ (400-700nm)	#25-328	S\$215.60 Volume Pricing	5 In Stock
50.80	-	5.00	VIS 0° (425-675nm)	#25-284	S\$240.80 Volume Pricing	5 In Stock
50.80	-	5.00	VIS-NIR (400-1000nm)	#25-317	S\$249.20 Volume Pricing	5 In Stock
50.80	-	5.00	YAG-BBAR (500-1100nm)	#25-344	S\$249.20 Volume Pricing	5 In Stock
50.80	-	5.00	NIR I (600-1050nm)	#25-295	S\$240.80 Volume Pricing	5 In Stock

50.80	-	5.00	NIR II (750-1550nm)	#25-306	S\$240.80 Volume Pricing	5 In Stock
75.00	-	5.00	Uncoated	#39-291	S\$270.20 Volume Pricing	10 In Stock
-	75.00 x 75.00	5.00	Uncoated	#70-700	S\$299.60 Volume Pricing	7 In Stock
75.00	-	5.00	VIS-EXT (350-700nm)	#25-212	S\$392.00 Volume Pricing	1 In Stock
75.00	-	5.00	MgF ₂ (400-700nm)	#11-929	S\$331.80 Volume Pricing	Contact Us
75.00	-	5.00	YAG-BBAR (500-1100nm)	#25-241	S\$399.00 Volume Pricing	2 In Stock
-	100.00 x 100.00	5.00	Uncoated	#70-701	S\$642.60 Volume Pricing	6 In Stock
100.00	-	8.00	Uncoated	#39-292	S\$523.60 Volume Pricing	10 In Stock
100.00	-	8.00	UV-AR (250-425nm)	#23-614	S\$889.00 Volume Pricing	1 In Stock
100.00	-	8.00	UV-VIS (250-700nm)	#22-052	S\$889.00 Volume Pricing	Contact Us
100.00	-	8.00	MgF ₂ (400-700nm)	#11-930	S\$606.20 Volume Pricing	5 In Stock
100.00	-	8.00	VIS 0° (425-675nm)	#22-053	S\$875.00 Volume Pricing	2 In Stock
100.00	-	8.00	VIS-NIR (400-1000nm)	#22-054	S\$889.00 Volume Pricing	5 In Stock
100.00	-	8.00	VIS-EXT (350-700nm)	#29-630	S\$889.00 Volume Pricing	1 In Stock
100.00	-	8.00	NIR II (750-1550nm)	#29-629	S\$875.00 Volume Pricing	1 In Stock
100.00	-	8.00	NIR I (600-1050nm)	#29-628	S\$875.00 Volume Pricing	5 In Stock
100.00	-	8.00	YAG-BBAR (500-1100nm)	#29-631	S\$889.00 Volume Pricing	4 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com