

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Float Glass](#)

4-6λ First Surface Mirrors



- Wide Variety of Shapes and Sizes Available
- >85% Reflection of Visible Light
- [Contact Us](#) for Custom Sizes

Common Specifications

Physical & Mechanical Properties


Bevel: Protective as needed

Optical Properties

Surface Flatness (P-V): 4 - 6λ

Substrate:	Float Glass	Surface Quality:	80-50
Coating Specification:	R _{avg} >85% @ 400 - 700nm	Coating:	Protected Aluminum (400-700nm)
Coating Type:	Metal	Angle of Incidence (°):	45.00
Wavelength Range (nm):	400 - 700		

Technical Information

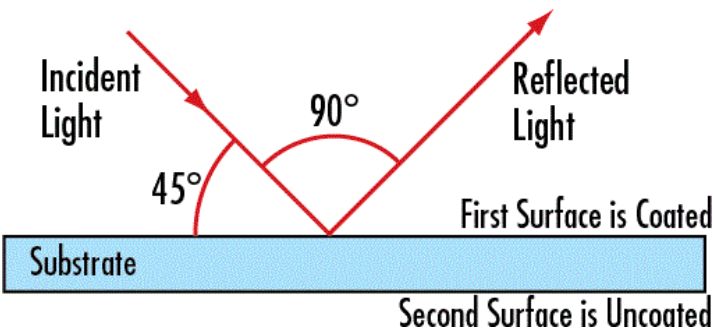

Products

Dia. (mm)	Surface Flatness (P-V)	Dimensions (mm)	Coating Specification	Coating	AOI (°)	Stock Number	Price	Buy
-	4 - 6λ	3.0 x 3.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-001	S\$10.45 Volume Pricing	20+ In Stock
5.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#27-400	S\$19.04 Volume Pricing	20+ In Stock
6.30	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-354	S\$21.65 Volume Pricing	20+ In Stock
9.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-647	S\$23.90 Volume Pricing	20+ In Stock
-	4 - 6λ	9.0 x 9.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-004	S\$23.90 Volume Pricing	20+ In Stock
-	4 - 6λ	9.5 x 11.2	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-418	S\$23.90 Volume Pricing	20+ In Stock
12.50	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#27-402	S\$23.90 Volume Pricing	15 In Stock
12.70	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-243	S\$23.90 Volume Pricing	20+ In Stock
-	4 - 6λ	12.7 x 12.7	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-244	S\$23.90 Volume Pricing	20+ In Stock
-	4 - 6λ	12.7 x 18.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#83-535	S\$25.39 Volume Pricing	20+ In Stock
15.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-006	S\$26.88 Volume Pricing	20+ In Stock

16.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-648	S\$26.88 Volume Pricing	15 In Stock
-	4 - 6λ	17.0 x 23.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-417	S\$26.88 Volume Pricing	20+ In Stock
19.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-649	S\$26.88 Volume Pricing	20+ In Stock
-	4 - 6λ	19.0 x 19.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-650	S\$26.88 Volume Pricing	20+ In Stock
-	4 - 6λ	21.0 x 26.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-286	S\$29.87 Volume Pricing	20+ In Stock
-	4 - 6λ	22.0 x 22.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-368	S\$29.87 Volume Pricing	20+ In Stock
-	4 - 6λ	22.0 x 29.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-419	S\$29.87 Volume Pricing	20+ In Stock
25.40	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-245	S\$29.87 Volume Pricing	20+ In Stock
-	4 - 6λ	25.4 x 25.4	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-246	S\$29.87 Volume Pricing	20+ In Stock
-	4 - 6λ	25.4 x 35.4	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#83-536	S\$32.49 Volume Pricing	20+ In Stock
26.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-009	S\$30.99 Volume Pricing	20+ In Stock
-	4 - 6λ	30.0 x 40.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#30-429	S\$38.83 Volume Pricing	20+ In Stock
-	4 - 6λ	31.0 x 77.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-366	S\$38.83 Volume Pricing	20+ In Stock

32.00	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-651	S\$38.83 Volume Pricing	20+ In Stock
-	4 - 6λ	35.0 x 109.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-359	S\$38.83 Volume Pricing	20+ In Stock
-	4 - 6λ	38.0 x 38.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-652	S\$38.83 Volume Pricing	Contact Us
-	4 - 6λ	38.0 x 38.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-422	S\$38.83 Volume Pricing	20+ In Stock
-	4 - 6λ	38.0 x 51.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#31-425	S\$38.83 Volume Pricing	20+ In Stock
-	4 - 6λ	38.0 x 150.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-442	S\$42.94 Volume Pricing	20+ In Stock
38.10	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-247	S\$38.83 Volume Pricing	8 In Stock
-	4 - 6λ	38.1 x 38.1	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-248	S\$38.83 Volume Pricing	20+ In Stock
-	4 - 6λ	38.1 x 53.9	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#83-537	S\$38.83 Volume Pricing	6 In Stock
-	4 - 6λ	50.0 x 125.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-365	S\$51.52 Volume Pricing	20+ In Stock
50.80	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-249	S\$51.52 Volume Pricing	20+ In Stock
-	4 - 6λ	50.8 x 50.8	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-250	S\$51.52 Volume Pricing	Contact Us
-	4 - 6λ	50.8 x 71.8	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#83-538	S\$51.52 Volume Pricing	20+ In Stock

-	4 - 6λ	51.0 x 76.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-040	S\$51.52 Volume Pricing	20+ In Stock
-	4 - 6λ	60.0 x 270.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-279	S\$171.75 Volume Pricing	2 In Stock
-	4 - 6λ	73.0 x 116.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-371	S\$60.49 Volume Pricing	9 In Stock
-	4 - 6λ	76.0 x 102.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-041	S\$60.49 Volume Pricing	15 In Stock
76.20	4 - 6λ	-	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#69-251	S\$60.49 Volume Pricing	20+ In Stock
#69-252 Clearance								
Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.								
-	4 - 6λ	76.2 x 76.2	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00		S\$60.49 Volume Pricing	20+ In Stock
-	4 - 6λ	76.2 x 107.8	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#83-539	S\$60.49 Volume Pricing	20+ In Stock
-	4 - 6λ	81.0 x 100.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#41-621	S\$60.49 Volume Pricing	20+ In Stock
-	4 - 6λ	85.0 x 101.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-362	S\$60.49 Volume Pricing	20+ In Stock

-	4 - 6λ	102.0 x 127.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-042	S\$112.01 Volume Pricing	10 In Stock
-	4 - 6λ	127.0 x 178.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#41-320	S\$112.01 Volume Pricing	20+ In Stock
-	4 - 6λ	127.0 x 178.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-043	S\$112.01 Volume Pricing	20+ In Stock
-	4 - 6λ	169.0 x 194.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#41-405	S\$112.01 Volume Pricing	8 In Stock
-	4 - 6λ	200.0 x 235.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-358	S\$237.47 Volume Pricing	20+ In Stock
-	4 - 6λ	204.0 x 254.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#41-321	S\$237.47 Volume Pricing	9 In Stock
-	4 - 6λ	204.0 x 254.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#40-067	S\$237.47 Volume Pricing	11 In Stock
-	4 - 6λ	254.0 x 254.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-653	S\$237.47 Volume Pricing	20+ In Stock
-	4 - 6λ	254.0 x 313.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-654	S\$246.43 Volume Pricing	8 In Stock
-	4 - 6λ	254.0 x 313.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#32-248	S\$246.43 Volume Pricing	20+ In Stock
-	4 - 6λ	254.0 x 356.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#85-036	S\$358.44 Volume Pricing	20+ In Stock
-	4 - 6λ	356.0 x 356.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-655	S\$358.44 Volume Pricing	5 In Stock
-	4 - 6λ	406.0 x 406.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#46-656	S\$401.75 Volume Pricing	11 In Stock

-	4 - 6λ	406.0 x 406.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#85-206	S\$440.58 Volume Pricing	9 In Stock
-	4 - 6λ	408.0 x 609.0	R _{avg} >85% @ 400 - 700nm	Protected Aluminum (400- 700nm)	45.00	#85-207	S\$634.74 Volume Pricing	20+ In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com