

[All Products](#) / [Optics](#) / [Beamsplitters](#) / [Plate Beamsplitters](#)
TECHSPEC® C-Mounted Plate Beamsplitters


- Pre-Mounted 90 Degree Interface
- Four C-Threaded Mounting Holes
- Several Beamsplitting Options Available
- Additional C-Mounted [Beamsplitters](#), [Filters](#), and [Mirrors](#) Available

Common Specifications

Physical & Mechanical Properties

Construction:	Plate	Extension Length (mm):	38.0
Housing:	Black Anodized Aluminum	Housing Dimension:	38 x 38 x 50


Optical Properties

Reflection/Transmission Tolerance (%):	±5
---	----

Threading & Mounting

Mount:	C-Mount Enclosure
Thread Type:	C-Mount (1" x 32 TPI)

Technical Information

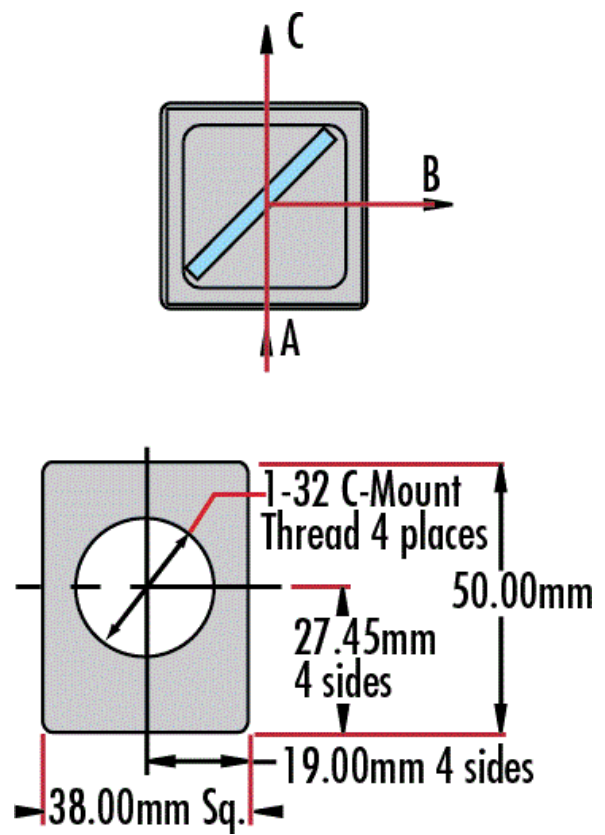

Products

Substrate	Reflection/Transmission Ratio (R/T)	Wavelength Range (nm)	Stock Number	Price	Buy
Float Glass	50/50	400 - 700	#54-824	S\$467.60 Volume Pricing	4 In Stock
N-BK7	30/70	400 - 700	#49-684	S\$467.60 Volume Pricing	2 In Stock
N-BK7	50/50	400 - 700	#49-685	S\$467.60 Volume Pricing	14 In Stock
N-BK7	70/30	400 - 700	#49-686	S\$467.60 Volume Pricing	4 In Stock
N-BK7	30/70	700 - 1100	#49-687	S\$467.60 Volume Pricing	Contact Us
N-BK7	50/50	700 - 1100	#49-688	S\$467.60 Volume Pricing	3 In Stock
N-BK7	70/30	700 - 1100	#49-689	S\$467.60 Volume Pricing	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com