

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Float Glass](#)
TECHSPEC® C-Mounted First Surface Mirror


- Ideal for Precision Alignment
- 35 x 35mm Mirror Dimensions
- 50mm H x 38mm W x 38mm D Housing Dimensions
- [Mirror](#) and [Housing](#) Available Separately

Common Specifications

General

Type of Optics:	First Surface Mirror
-----------------	----------------------

Physical & Mechanical Properties

Dimensions (mm):	38 x 38 x 50
------------------	--------------

Dimensional Tolerance (mm):	±0.25
-----------------------------	-------

Edges:	Ground
--------	--------

Extension Length (mm):	38.0
------------------------	------

Optical Properties

Surface Flatness (P-V):	4 - 6λ
-------------------------	--------

Substrate:	Float Glass
------------	-------------


Surface Quality:	60-40
------------------	-------

Coating Type:	Metal
---------------	-------

Threading & Mounting

Thread Type:	C-Mount (1" x 32 TPI)
--------------	-----------------------

Technical Information

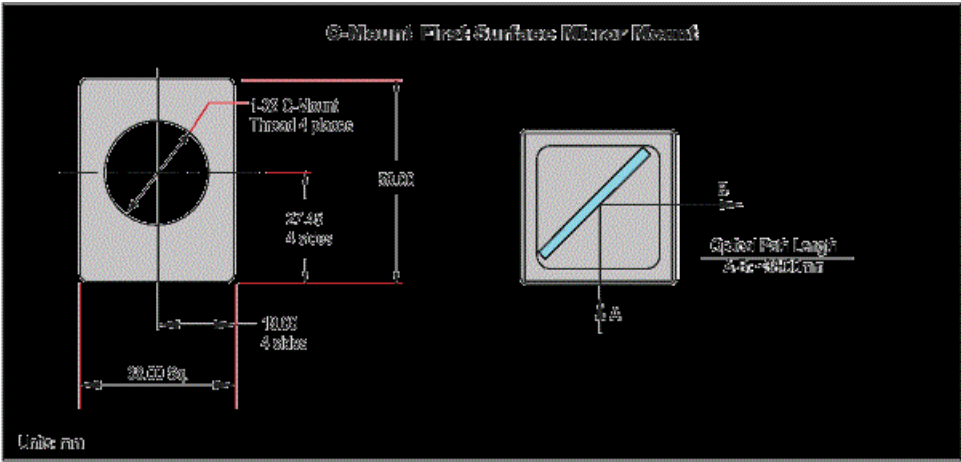

Products

Surface Flatness (P-V)	Dimensions (mm)	Coating Specification	Coating	Stock Number	Price	Buy
4 - 6λ	38 x 38 x 50	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	#54-825	S\$469.00 Volume Pricing	5 In Stock
4 - 6λ	38 x 38 x 50	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700-10000nm)	#36-153	S\$470.40 Volume Pricing	1 In Stock
4 - 6λ	38 x 38 x 50	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450-10000nm)	#36-154	S\$470.40 Volume Pricing	4 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com