

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Ball and Condenser Lenses](#)

TECHSPEC® N-BK7 Half-Ball Lenses



- Fiber Coupling Half-Spheres
- Collimating Lenses

Common Specifications

Physical & Mechanical Properties

Center Thickness
Tolerance (mm): ± 0.05

Diameter Tolerance
(μm): ± 2.5


Optical Properties

Substrate: [N-BK7](#)

Coating: Uncoated

Wavelength Range
(nm): 350 - 2200

Technical Information

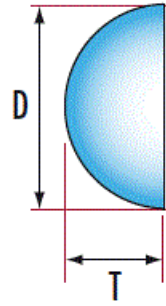

Products

Dia. (mm)	Substrate	Type	Coating	Stock Number	Price	Buy
0.50	N-BK7	Half-Ball Lens	Uncoated	#49-567	S\$80.50 Volume Pricing	17 In Stock
1.00	N-BK7	Half-Ball Lens	Uncoated	#49-568	S\$80.50 Volume Pricing	11 In Stock
2.00	N-BK7	Half-Ball Lens	Uncoated	#45-933	S\$75.60 Volume Pricing	20+ In Stock
3.00	N-BK7	Half-Ball Lens	Uncoated	#47-269	S\$75.60 Volume Pricing	20+ In Stock
4.00	N-BK7	Half-Ball Lens	Uncoated	#45-934	S\$75.60 Volume Pricing	20+ In Stock
5.00	N-BK7	Half-Ball Lens	Uncoated	#47-270	S\$78.40 Volume Pricing	20+ In Stock
6.00	N-BK7	Half-Ball Lens	Uncoated	#45-935	S\$80.50 Volume Pricing	20+ In Stock
8.00	N-BK7	Half-Ball Lens	Uncoated	#45-936	S\$88.20 Volume Pricing	20+ In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com