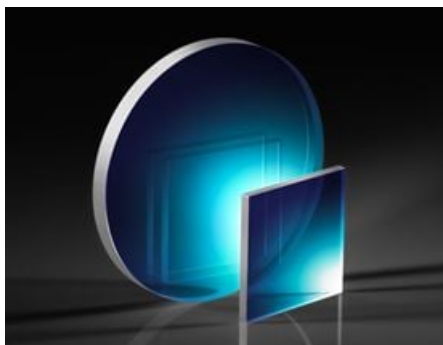


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)
TECHSPEC® $\lambda/10$ UV Fused Silica Windows


- UV, Visible, and NIR Anti-Reflection Coated Versions Available
- $\lambda/10$ Transmitted Wavefront Distortion
- Circular and Square Sizes from 2mm to 150mm
- [1 \$\lambda\$](#) or [\$\lambda/4\$](#) UV Fused Silica Windows Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Edges:	Fine Ground
Knoop Hardness (kg/mm²):	522.00	Poisson's Ratio:	0.16
Young's Modulus (GPa):	73		



Optical Properties

Abbe Number (v_d):	67.8
Index of Refraction (n_d):	1.458

Material Properties

Density (g/cm³):	2.20
------------------------------------	------

Technical Information

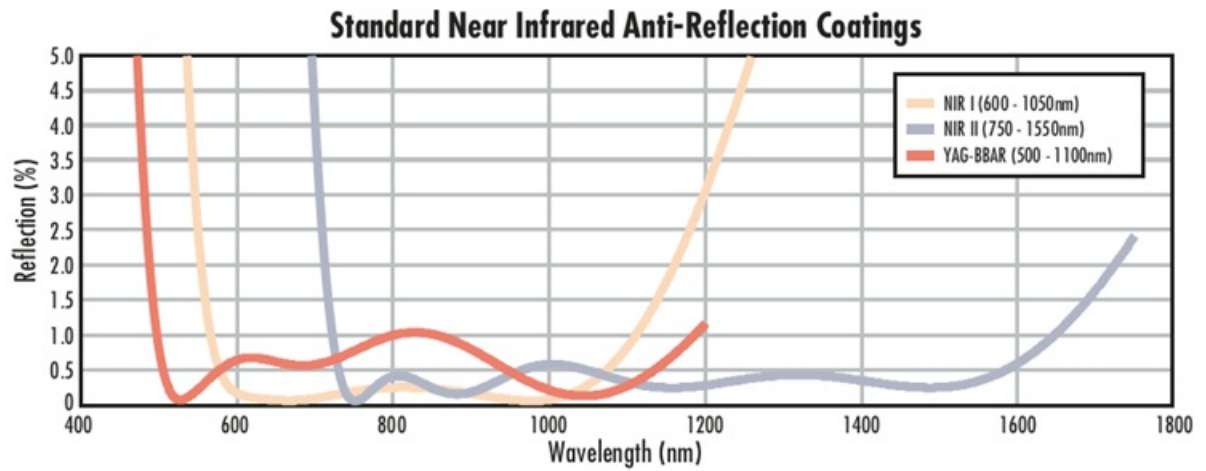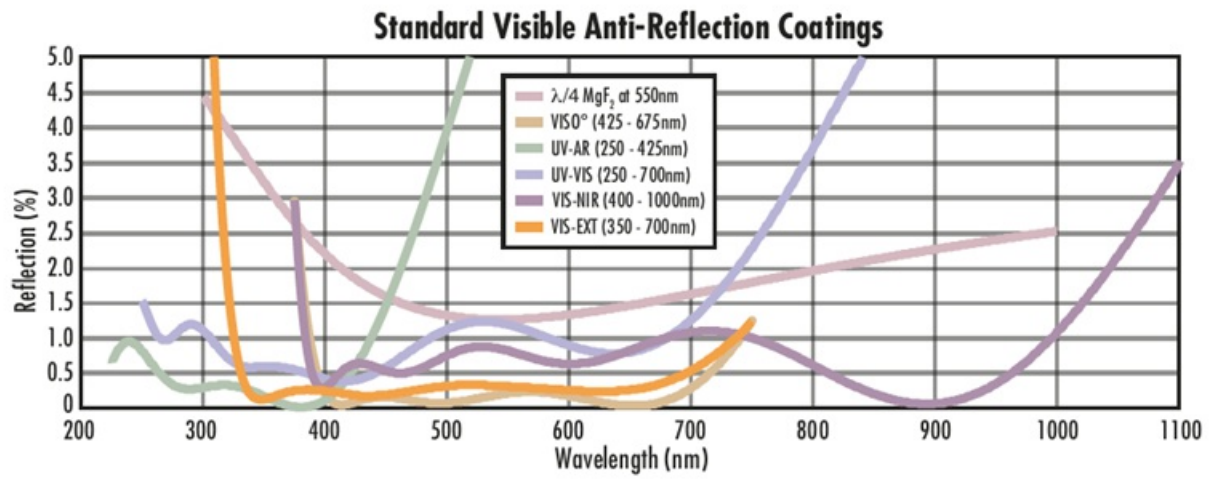

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
2.00	-	1.00	Uncoated	#27-669	S\$147.00 Volume Pricing	5 In Stock
2.50	-	1.00	Uncoated	#27-670	S\$147.00 Volume Pricing	20+ In Stock
3.00	-	1.00	Uncoated	#27-671	S\$155.40 Volume Pricing	20+ In Stock
4.00	-	1.00	Uncoated	#27-672	S\$165.20 Volume Pricing	17 In Stock
5.00	-	1.00	Uncoated	#47-833	S\$184.80 Volume Pricing	20+ In Stock
10.00	-	1.25	Uncoated	#47-192	S\$184.80 Volume Pricing	20+ In Stock
12.50	-	1.50	Uncoated	#47-193	S\$189.00 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	Uncoated	#23-136	S\$179.20 Volume Pricing	20+ In Stock
12.50	-	2.00	Uncoated	#63-107	S\$189.00 Volume Pricing	20+ In Stock
12.70	-	1.50	Uncoated	#15-402	S\$179.20 Volume Pricing	Contact Us
15.00	-	2.00	Uncoated	#47-194	S\$197.40 Volume Pricing	20+ In Stock
20.00	-	2.00	Uncoated	#63-204	S\$210.00 Volume Pricing	20+ In Stock
25.00	-	1.00	Uncoated	#11-876	S\$224.00 Volume Pricing	Contact Us
25.00	-	2.00	Uncoated	#11-877	S\$224.00 Volume Pricing	20+ In Stock
25.00	-	3.00	Uncoated	#47-195	S\$224.00 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	Uncoated	#23-137	S\$224.00 Volume Pricing	20+ In Stock
25.00	-	5.00	Uncoated	#11-878	S\$224.00 Volume Pricing	20+ In Stock

25.40	-	3.00	Uncoated	#15-403	S\$224.00 Volume Pricing	1 In Stock
30.00	-	4.00	Uncoated	#47-834	S\$284.20 Volume Pricing	20+ In Stock
40.00	-	4.00	Uncoated	#47-835	S\$323.40 Volume Pricing	20+ In Stock
50.00	-	1.00	Uncoated	#34-599	S\$392.00 Volume Pricing	20+ In Stock
50.00	-	2.00	Uncoated	#34-600	S\$392.00 Volume Pricing	Contact Us
50.00	-	3.00	Uncoated	#34-601	S\$392.00 Volume Pricing	20+ In Stock
50.00	-	5.00	Uncoated	#47-836	S\$392.00 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	Uncoated	#23-138	S\$392.00 Volume Pricing	Contact Us
50.00	-	6.00	Uncoated	#34-602	S\$392.00 Volume Pricing	5 In Stock
50.80	-	5.00	Uncoated	#15-404	S\$392.00 Volume Pricing	15 In Stock
75.00	-	3.00	Uncoated	#36-935	S\$653.80 Volume Pricing	20+ In Stock
75.00	-	5.00	Uncoated	#36-936	S\$653.80 Volume Pricing	20+ In Stock
100.00	-	5.00	Uncoated	#17-561	S\$833.00 Volume Pricing	20+ In Stock
125.00	-	6.00	Uncoated	#17-562	S\$1,050.00 Volume Pricing	20+ In Stock
150.00	-	8.00	Uncoated	#17-563	S\$1,463.00 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-AR (250-425nm)	#65-870	S\$240.80 Volume Pricing	11 In Stock
10.00	-	1.25	UV-AR (250-425nm)	#65-871	S\$232.40 Volume Pricing	6 In Stock
12.50	-	1.50	UV-AR (250-425nm)	#65-872	S\$236.60 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	UV-AR (250-425nm)	#24-296	S\$236.60 Volume Pricing	2 In Stock

12.50	-	2.00	UV-AR (250-425nm)	#68-487	S\$236.60 Volume Pricing	17 In Stock
12.70	-	1.50	UV-AR (250-425nm)	#15-405	S\$236.60 Volume Pricing	Contact Us
15.00	-	2.00	UV-AR (250-425nm)	#65-873	S\$245.00 Volume Pricing	20+ In Stock
20.00	-	2.00	UV-AR (250-425nm)	#65-874	S\$257.60 Volume Pricing	20+ In Stock
25.00	-	1.00	UV-AR (250-425nm)	#11-879	S\$270.20 Volume Pricing	1 In Stock
25.00	-	2.00	UV-AR (250-425nm)	#11-880	S\$270.20 Volume Pricing	5 In Stock
25.00	-	3.00	UV-AR (250-425nm)	#65-875	S\$270.20 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	UV-AR (250-425nm)	#24-304	S\$270.20 Volume Pricing	8 In Stock
25.00	-	5.00	UV-AR (250-425nm)	#11-881	S\$270.20 Volume Pricing	6 In Stock
25.40	-	3.00	UV-AR (250-425nm)	#15-406	S\$270.20 Volume Pricing	8 In Stock
30.00	-	4.00	UV-AR (250-425nm)	#65-876	S\$338.80 Volume Pricing	8 In Stock
40.00	-	4.00	UV-AR (250-425nm)	#65-877	S\$378.00 Volume Pricing	Contact Us
50.00	-	1.00	UV-AR (250-425nm)	#36-938	S\$446.60 Volume Pricing	3 In Stock
50.00	-	2.00	UV-AR (250-425nm)	#36-943	S\$446.60 Volume Pricing	Contact Us
50.00	-	3.00	UV-AR (250-425nm)	#36-948	S\$446.60 Volume Pricing	5 In Stock
50.00	-	5.00	UV-AR (250-425nm)	#65-878	S\$446.60 Volume Pricing	9 In Stock
-	50.00 x 50.00	5.00	UV-AR (250-425nm)	#24-312	S\$446.60 Volume Pricing	1 In Stock
50.00	-	6.00	UV-AR (250-425nm)	#36-953	S\$446.60 Volume Pricing	5 In Stock
50.80	-	5.00	UV-AR (250-425nm)	#15-407	S\$446.60 Volume Pricing	1 In Stock

75.00	-	3.00	UV-AR (250-425nm)	#36-958	S\$763.00 Volume Pricing	3 In Stock
75.00	-	5.00	UV-AR (250-425nm)	#36-963	S\$763.00 Volume Pricing	4 In Stock
5.00	-	1.00	UV-VIS (250-700nm)	#48-062	S\$240.80 Volume Pricing	15 In Stock
10.00	-	1.25	UV-VIS (250-700nm)	#48-063	S\$232.40 Volume Pricing	20+ In Stock
12.50	-	1.50	UV-VIS (250-700nm)	#48-064	S\$236.60 Volume Pricing	14 In Stock
-	12.50 x 12.50	1.50	UV-VIS (250-700nm)	#24-297	S\$236.60 Volume Pricing	1 In Stock
12.50	-	2.00	UV-VIS (250-700nm)	#68-488	S\$236.60 Volume Pricing	Contact Us
12.70	-	1.50	UV-VIS (250-700nm)	#15-408	S\$236.60 Volume Pricing	1 In Stock
15.00	-	2.00	UV-VIS (250-700nm)	#48-065	S\$245.00 Volume Pricing	3 In Stock
20.00	-	2.00	UV-VIS (250-700nm)	#63-206	S\$257.60 Volume Pricing	12 In Stock
25.00	-	1.00	UV-VIS (250-700nm)	#11-882	S\$270.20 Volume Pricing	7 In Stock
25.00	-	2.00	UV-VIS (250-700nm)	#11-883	S\$270.20 Volume Pricing	15 In Stock
25.00	-	3.00	UV-VIS (250-700nm)	#48-066	S\$270.20 Volume Pricing	5 In Stock
-	25.00 x 25.00	3.00	UV-VIS (250-700nm)	#24-305	S\$270.20 Volume Pricing	4 In Stock
25.00	-	5.00	UV-VIS (250-700nm)	#11-884	S\$270.20 Volume Pricing	11 In Stock
25.40	-	3.00	UV-VIS (250-700nm)	#15-409	S\$270.20 Volume Pricing	5 In Stock
30.00	-	4.00	UV-VIS (250-700nm)	#48-067	S\$338.80 Volume Pricing	10 In Stock
40.00	-	4.00	UV-VIS (250-700nm)	#48-068	S\$378.00 Volume Pricing	2 In Stock
50.00	-	1.00	UV-VIS (250-700nm)	#36-939	S\$446.60 Volume Pricing	Contact Us

50.00	-	2.00	UV-VIS (250-700nm)	#36-944	S\$446.60 Volume Pricing	Contact Us
50.00	-	3.00	UV-VIS (250-700nm)	#36-949	S\$446.60 Volume Pricing	7 In Stock
50.00	-	5.00	UV-VIS (250-700nm)	#48-069	S\$446.60 Volume Pricing	5 In Stock
-	50.00 x 50.00	5.00	UV-VIS (250-700nm)	#24-313	S\$446.60 Volume Pricing	6 In Stock
50.00	-	6.00	UV-VIS (250-700nm)	#36-954	S\$446.60 Volume Pricing	1 In Stock
50.80	-	5.00	UV-VIS (250-700nm)	#15-410	S\$446.60 Volume Pricing	3 In Stock
75.00	-	3.00	UV-VIS (250-700nm)	#36-959	S\$763.00 Volume Pricing	20+ In Stock
75.00	-	5.00	UV-VIS (250-700nm)	#36-964	S\$763.00 Volume Pricing	Contact Us
100.00	-	5.00	UV-VIS (250-700nm)	#22-064	S\$1,288.00 Volume Pricing	8 In Stock
125.00	-	6.00	UV-VIS (250-700nm)	#22-065	S\$1,659.00 Volume Pricing	5 In Stock
150.00	-	8.00	UV-VIS (250-700nm)	#22-066	S\$2,198.00 Volume Pricing	2 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#13-330	S\$245.00 Volume Pricing	5 In Stock
10.00	-	1.25	VIS-EXT (350-700nm)	#13-331	S\$236.60 Volume Pricing	7 In Stock
-	12.50 x 12.50	1.50	VIS-EXT (350-700nm)	#24-301	S\$240.80 Volume Pricing	4 In Stock
12.50	-	1.50	VIS-EXT (350-700nm)	#13-332	S\$240.80 Volume Pricing	7 In Stock
12.50	-	2.00	VIS-EXT (350-700nm)	#13-333	S\$240.80 Volume Pricing	5 In Stock
12.70	-	1.50	VIS-EXT (350-700nm)	#15-781	S\$240.80 Volume Pricing	11 In Stock
15.00	-	2.00	VIS-EXT (350-700nm)	#13-334	S\$249.20 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#13-335	S\$263.20 Volume Pricing	9 In Stock

25.00	-	1.00	VIS-EXT (350-700nm)	#13-336	S\$275.80 Volume Pricing	Contact Us
25.00	-	2.00	VIS-EXT (350-700nm)	#13-337	S\$275.80 Volume Pricing	12 In Stock
-	25.00 x 25.00	3.00	VIS-EXT (350-700nm)	#24-309	S\$275.80 Volume Pricing	1 In Stock
25.00	-	3.00	VIS-EXT (350-700nm)	#13-338	S\$275.80 Volume Pricing	5 In Stock
25.00	-	5.00	VIS-EXT (350-700nm)	#13-339	S\$275.80 Volume Pricing	8 In Stock
25.40	-	3.00	VIS-EXT (350-700nm)	#15-782	S\$275.80 Volume Pricing	4 In Stock
30.00	-	4.00	VIS-EXT (350-700nm)	#16-461	S\$344.40 Volume Pricing	2 In Stock
40.00	-	4.00	VIS-EXT (350-700nm)	#13-341	S\$383.60 Volume Pricing	Contact Us
50.00	-	1.00	VIS-EXT (350-700nm)	#13-342	S\$452.20 Volume Pricing	3 In Stock
50.00	-	2.00	VIS-EXT (350-700nm)	#13-343	S\$452.20 Volume Pricing	Contact Us
50.00	-	3.00	VIS-EXT (350-700nm)	#13-344	S\$452.20 Volume Pricing	2 In Stock
50.00	-	5.00	VIS-EXT (350-700nm)	#13-345	S\$452.20 Volume Pricing	5 In Stock
-	50.00 x 50.00	5.00	VIS-EXT (350-700nm)	#24-317	S\$452.20 Volume Pricing	7 In Stock
50.00	-	6.00	VIS-EXT (350-700nm)	#13-346	S\$452.20 Volume Pricing	5 In Stock
50.80	-	5.00	VIS-EXT (350-700nm)	#15-783	S\$452.20 Volume Pricing	Contact Us
75.00	-	3.00	VIS-EXT (350-700nm)	#15-799	S\$777.00 Volume Pricing	2 In Stock
75.00	-	5.00	VIS-EXT (350-700nm)	#15-800	S\$777.00 Volume Pricing	1 In Stock
5.00	-	1.00	VIS-NIR (400-1000nm)	#84-449	S\$245.00 Volume Pricing	4 In Stock

10.00	-	1.25	VIS-NIR (400-1000nm)	#84-450	S\$236.60 Volume Pricing	9 In Stock
12.50	-	1.50	VIS-NIR (400-1000nm)	#84-451	S\$240.80 Volume Pricing	11 In Stock
-	12.50 x 12.50	1.50	VIS-NIR (400-1000nm)	#24-302	S\$240.80 Volume Pricing	1 In Stock
12.50	-	2.00	VIS-NIR (400-1000nm)	#84-452	S\$240.80 Volume Pricing	1 In Stock
12.70	-	1.50	VIS-NIR (400-1000nm)	#15-414	S\$240.80 Volume Pricing	1 In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#84-453	S\$249.20 Volume Pricing	1 In Stock
20.00	-	2.00	VIS-NIR (400-1000nm)	#84-454	S\$263.20 Volume Pricing	20+ In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#11-888	S\$275.80 Volume Pricing	20+ In Stock
25.00	-	2.00	VIS-NIR (400-1000nm)	#11-889	S\$275.80 Volume Pricing	9 In Stock
-	25.00 x 25.00	3.00	VIS-NIR (400-1000nm)	#24-310	S\$275.80 Volume Pricing	5 In Stock
25.00	-	3.00	VIS-NIR (400-1000nm)	#84-455	S\$275.80 Volume Pricing	20+ In Stock
25.00	-	5.00	VIS-NIR (400-1000nm)	#11-890	S\$275.80 Volume Pricing	2 In Stock
25.40	-	3.00	VIS-NIR (400-1000nm)	#15-415	S\$275.80 Volume Pricing	6 In Stock
30.00	-	4.00	VIS-NIR (400-1000nm)	#84-456	S\$344.40 Volume Pricing	5 In Stock

40.00	-	4.00	VIS-NIR (400-1000nm)	#84-457	S\$383.60 Volume Pricing	11 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#36-941	S\$452.20 Volume Pricing	8 In Stock
50.00	-	2.00	VIS-NIR (400-1000nm)	#36-946	S\$452.20 Volume Pricing	7 In Stock
50.00	-	3.00	VIS-NIR (400-1000nm)	#36-951	S\$452.20 Volume Pricing	5 In Stock
50.00	-	5.00	VIS-NIR (400-1000nm)	#84-458	S\$452.20 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	VIS-NIR (400-1000nm)	#24-318	S\$452.20 Volume Pricing	1 In Stock
50.00	-	6.00	VIS-NIR (400-1000nm)	#36-956	S\$452.20 Volume Pricing	13 In Stock
50.80	-	5.00	VIS-NIR (400-1000nm)	#15-416	S\$452.20 Volume Pricing	4 In Stock
75.00	-	3.00	VIS-NIR (400-1000nm)	#36-961	S\$777.00 Volume Pricing	5 In Stock
75.00	-	5.00	VIS-NIR (400-1000nm)	#36-966	S\$777.00 Volume Pricing	13 In Stock
100.00	-	5.00	VIS-NIR (400-1000nm)	#22-070	S\$1,288.00 Volume Pricing	1 In Stock
125.00	-	6.00	VIS-NIR (400-1000nm)	#22-071	S\$1,659.00 Volume Pricing	15 In Stock
150.00	-	8.00	VIS-NIR (400-1000nm)	#22-072	S\$2,198.00 Volume Pricing	7 In Stock
5.00	-	1.00	VIS 0° (425-675nm)	#47-837	S\$236.60 Volume Pricing	20+ In Stock

10.00	-	1.25	VIS 0° (425-675nm)	#47-196	S\$228.20 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	VIS 0° (425-675nm)	#24-298	S\$232.40 Volume Pricing	1 In Stock
12.50	-	1.50	VIS 0° (425-675nm)	#47-197	S\$232.40 Volume Pricing	20+ In Stock
12.50	-	2.00	VIS 0° (425-675nm)	#68-489	S\$232.40 Volume Pricing	10 In Stock
12.70	-	1.50	VIS 0° (425-675nm)	#15-411	S\$232.40 Volume Pricing	4 In Stock
15.00	-	2.00	VIS 0° (425-675nm)	#47-198	S\$240.80 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS 0° (425-675nm)	#63-205	S\$254.80 Volume Pricing	4 In Stock
25.00	-	1.00	VIS 0° (425-675nm)	#11-885	S\$267.40 Volume Pricing	1 In Stock
25.00	-	2.00	VIS 0° (425-675nm)	#11-886	S\$267.40 Volume Pricing	17 In Stock
25.00	-	3.00	VIS 0° (425-675nm)	#47-199	S\$267.40 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	VIS 0° (425-675nm)	#24-306	S\$267.40 Volume Pricing	4 In Stock
25.00	-	5.00	VIS 0° (425-675nm)	#11-887	S\$267.40 Volume Pricing	11 In Stock
25.40	-	3.00	VIS 0° (425-675nm)	#15-412	S\$267.40 Volume Pricing	20+ In Stock
30.00	-	4.00	VIS 0° (425-675nm)	#47-838	S\$336.00 Volume Pricing	8 In Stock
40.00	-	4.00	VIS 0° (425-675nm)	#47-839	S\$373.80 Volume Pricing	13 In Stock
50.00	-	1.00	VIS 0° (425-675nm)	#36-940	S\$443.80 Volume Pricing	10 In Stock
50.00	-	2.00	VIS 0° (425-675nm)	#36-945	S\$443.80 Volume Pricing	14 In Stock
50.00	-	3.00	VIS 0° (425-675nm)	#36-950	S\$443.80 Volume Pricing	7 In Stock
50.00	-	5.00	VIS 0° (425-675nm)	#47-840	S\$443.80 Volume Pricing	20+ In Stock

-	50.00 x 50.00	5.00	VIS 0° (425-675nm)	#24-314	S\$443.80 Volume Pricing	2 In Stock
50.00	-	6.00	VIS 0° (425-675nm)	#36-955	S\$443.80 Volume Pricing	9 In Stock
50.80	-	5.00	VIS 0° (425-675nm)	#15-413	S\$443.80 Volume Pricing	4 In Stock
75.00	-	3.00	VIS 0° (425-675nm)	#36-960	S\$756.00 Volume Pricing	2 In Stock
75.00	-	5.00	VIS 0° (425-675nm)	#36-965	S\$756.00 Volume Pricing	Contact Us
100.00	-	5.00	VIS 0° (425-675nm)	#22-067	S\$1,267.00 Volume Pricing	10 In Stock
125.00	-	6.00	VIS 0° (425-675nm)	#22-068	S\$1,610.00 Volume Pricing	4 In Stock
150.00	-	8.00	VIS 0° (425-675nm)	#22-069	S\$2,156.00 Volume Pricing	3 In Stock
5.00	-	1.00	YAG-BBAR (500-1100nm)	#13-347	S\$245.00 Volume Pricing	15 In Stock
10.00	-	1.25	YAG-BBAR (500-1100nm)	#13-348	S\$236.60 Volume Pricing	13 In Stock
-	12.50 x 12.50	1.50	YAG-BBAR (500-1100nm)	#24-303	S\$240.80 Volume Pricing	8 In Stock
12.50	-	1.50	YAG-BBAR (500-1100nm)	#13-349	S\$240.80 Volume Pricing	1 In Stock
12.50	-	2.00	YAG-BBAR (500-1100nm)	#13-350	S\$240.80 Volume Pricing	9 In Stock
12.70	-	1.50	YAG-BBAR (500-1100nm)	#15-784	S\$240.80 Volume Pricing	4 In Stock
15.00	-	2.00	YAG-BBAR (500-1100nm)	#13-351	S\$249.20 Volume Pricing	1 In Stock
20.00	-	2.00	YAG-BBAR (500-1100nm)	#13-352	S\$263.20 Volume Pricing	9 In Stock

25.00	-	1.00	YAG-BBAR (500-1100nm)	#13-353	S\$275.80 Volume Pricing	Contact Us
25.00	-	2.00	YAG-BBAR (500-1100nm)	#13-354	S\$275.80 Volume Pricing	6 In Stock
-	25.00 x 25.00	3.00	YAG-BBAR (500-1100nm)	#24-311	S\$275.80 Volume Pricing	3 In Stock
25.00	-	3.00	YAG-BBAR (500-1100nm)	#13-355	S\$275.80 Volume Pricing	3 In Stock
25.00	-	5.00	YAG-BBAR (500-1100nm)	#13-356	S\$275.80 Volume Pricing	3 In Stock
25.40	-	3.00	YAG-BBAR (500-1100nm)	#15-785	S\$275.80 Volume Pricing	6 In Stock
30.00	-	4.00	YAG-BBAR (500-1100nm)	#13-357	S\$344.40 Volume Pricing	8 In Stock
40.00	-	4.00	YAG-BBAR (500-1100nm)	#13-358	S\$383.60 Volume Pricing	15 In Stock
50.00	-	1.00	YAG-BBAR (500-1100nm)	#13-359	S\$452.20 Volume Pricing	1 In Stock
50.00	-	2.00	YAG-BBAR (500-1100nm)	#13-360	S\$452.20 Volume Pricing	Contact Us
50.00	-	3.00	YAG-BBAR (500-1100nm)	#13-361	S\$452.20 Volume Pricing	12 In Stock
50.00	-	5.00	YAG-BBAR (500-1100nm)	#13-362	S\$452.20 Volume Pricing	14 In Stock
-	50.00 x 50.00	5.00	YAG-BBAR (500-1100nm)	#24-319	S\$452.20 Volume Pricing	5 In Stock
50.00	-	6.00	YAG-BBAR (500-1100nm)	#13-363	S\$452.20 Volume Pricing	12 In Stock

50.80	-	5.00	YAG-BBAR (500-1100nm)	#15-786	S\$452.20 Volume Pricing	4 In Stock
75.00	-	3.00	YAG-BBAR (500-1100nm)	#15-801	S\$777.00 Volume Pricing	2 In Stock
75.00	-	5.00	YAG-BBAR (500-1100nm)	#15-802	S\$777.00 Volume Pricing	20+ In Stock
5.00	-	1.00	NIR I (600-1050nm)	#84-459	S\$236.60 Volume Pricing	8 In Stock
10.00	-	1.25	NIR I (600-1050nm)	#84-460	S\$228.20 Volume Pricing	20+ In Stock
12.50	-	1.50	NIR I (600-1050nm)	#84-461	S\$232.40 Volume Pricing	7 In Stock
-	12.50 x 12.50	1.50	NIR I (600-1050nm)	#24-299	S\$232.40 Volume Pricing	5 In Stock
12.50	-	2.00	NIR I (600-1050nm)	#84-462	S\$232.40 Volume Pricing	20+ In Stock
12.70	-	1.50	NIR I (600-1050nm)	#15-417	S\$232.40 Volume Pricing	2 In Stock
15.00	-	2.00	NIR I (600-1050nm)	#84-463	S\$240.80 Volume Pricing	20+ In Stock
20.00	-	2.00	NIR I (600-1050nm)	#84-464	S\$254.80 Volume Pricing	20+ In Stock
25.00	-	1.00	NIR I (600-1050nm)	#11-891	S\$267.40 Volume Pricing	15 In Stock
25.00	-	2.00	NIR I (600-1050nm)	#11-892	S\$267.40 Volume Pricing	2 In Stock
25.00	-	3.00	NIR I (600-1050nm)	#84-465	S\$267.40 Volume Pricing	5 In Stock
25.00	-	5.00	NIR I (600-1050nm)	#11-893	S\$267.40 Volume Pricing	1 In Stock
25.40	-	3.00	NIR I (600-1050nm)	#15-418	S\$267.40 Volume Pricing	3 In Stock
-	25.00 x 25.00	3.00	NIR I (600-1050nm)	#24-307	S\$267.40 Volume Pricing	Contact Us
30.00	-	4.00	NIR I (600-1050nm)	#84-466	S\$336.00 Volume Pricing	10 In Stock

40.00	-	4.00	NIR I (600-1050nm)	#84-467	S\$373.80 Volume Pricing	4 In Stock
50.00	-	1.00	NIR I (600-1050nm)	#36-937	S\$443.80 Volume Pricing	5 In Stock
50.00	-	2.00	NIR I (600-1050nm)	#36-942	S\$443.80 Volume Pricing	14 In Stock
50.00	-	3.00	NIR I (600-1050nm)	#36-947	S\$443.80 Volume Pricing	5 In Stock
50.00	-	5.00	NIR I (600-1050nm)	#84-468	S\$443.80 Volume Pricing	Contact Us
-	50.00 x 50.00	5.00	NIR I (600-1050nm)	#24-315	S\$443.80 Volume Pricing	2 In Stock
50.00	-	6.00	NIR I (600-1050nm)	#36-952	S\$443.80 Volume Pricing	20+ In Stock
50.80	-	5.00	NIR I (600-1050nm)	#15-419	S\$443.80 Volume Pricing	2 In Stock
75.00	-	3.00	NIR I (600-1050nm)	#36-957	S\$756.00 Volume Pricing	Contact Us
75.00	-	5.00	NIR I (600-1050nm)	#36-962	S\$756.00 Volume Pricing	Contact Us
5.00	-	1.00	NIR II (750-1550nm)	#11-894	S\$236.60 Volume Pricing	Contact Us
10.00	-	1.25	NIR II (750-1550nm)	#11-895	S\$228.20 Volume Pricing	5 In Stock
12.50	-	1.50	NIR II (750-1550nm)	#11-896	S\$232.40 Volume Pricing	Contact Us
-	12.50 x 12.50	1.50	NIR II (750-1550nm)	#24-300	S\$232.40 Volume Pricing	2 In Stock
12.50	-	2.00	NIR II (750-1550nm)	#11-897	S\$232.40 Volume Pricing	2 In Stock
12.70	-	1.50	NIR II (750-1550nm)	#15-420	S\$232.40 Volume Pricing	1 In Stock
15.00	-	2.00	NIR II (750-1550nm)	#11-898	S\$240.80 Volume Pricing	11 In Stock
20.00	-	2.00	NIR II (750-1550nm)	#11-899	S\$254.80 Volume Pricing	12 In Stock

25.00	-	1.00	NIR II (750-1550nm)	#11-900	S\$267.40 Volume Pricing	17 In Stock
25.00	-	2.00	NIR II (750-1550nm)	#11-901	S\$267.40 Volume Pricing	13 In Stock
-	25.00 x 25.00	3.00	NIR II (750-1550nm)	#24-308	S\$267.40 Volume Pricing	5 In Stock
25.00	-	3.00	NIR II (750-1550nm)	#11-902	S\$267.40 Volume Pricing	16 In Stock
25.00	-	5.00	NIR II (750-1550nm)	#11-903	S\$267.40 Volume Pricing	8 In Stock
25.40	-	3.00	NIR II (750-1550nm)	#15-421	S\$267.40 Volume Pricing	5 In Stock
30.00	-	4.00	NIR II (750-1550nm)	#11-904	S\$336.00 Volume Pricing	5 In Stock
40.00	-	4.00	NIR II (750-1550nm)	#11-905	S\$373.80 Volume Pricing	4 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#11-906	S\$443.80 Volume Pricing	7 In Stock
50.00	-	2.00	NIR II (750-1550nm)	#11-907	S\$443.80 Volume Pricing	12 In Stock
50.00	-	3.00	NIR II (750-1550nm)	#11-908	S\$443.80 Volume Pricing	13 In Stock
50.00	-	5.00	NIR II (750-1550nm)	#11-909	S\$443.80 Volume Pricing	4 In Stock
-	50.00 x 50.00	5.00	NIR II (750-1550nm)	#24-316	S\$443.80 Volume Pricing	6 In Stock
50.00	-	6.00	NIR II (750-1550nm)	#11-910	S\$443.80 Volume Pricing	12 In Stock
50.80	-	5.00	NIR II (750-1550nm)	#15-422	S\$443.80 Volume Pricing	5 In Stock
75.00	-	3.00	NIR II (750-1550nm)	#11-911	S\$756.00 Volume Pricing	20+ In Stock
75.00	-	5.00	NIR II (750-1550nm)	#11-912	S\$756.00 Volume Pricing	10 In Stock
100.00	-	5.00	UV-AR (250-425nm)	#29-604	S\$1,288.00 Volume Pricing	Contact Us
100.00	-	5.00	VIS-EXT (350-700nm)	#29-607	S\$1,288.00 Volume Pricing	5 In Stock

100.00	-	5.00	NIR I (600-1050nm)	#29-605	S\$1,267.00 Volume Pricing	1 In Stock
100.00	-	5.00	NIR II (750-1550nm)	#29-606	S\$1,267.00 Volume Pricing	16 In Stock
100.00	-	5.00	YAG-BBAR (500-1100nm)	#29-608	S\$1,288.00 Volume Pricing	Contact Us
100.00	-	10.00	Uncoated	#29-508	S\$1,001.00 Volume Pricing	20+ In Stock
125.00	-	6.00	UV-AR (250-425nm)	#29-609	S\$1,659.00 Volume Pricing	2 In Stock
125.00	-	6.00	VIS-EXT (350-700nm)	#29-612	S\$1,659.00 Volume Pricing	Contact Us
125.00	-	6.00	NIR I (600-1050nm)	#29-610	S\$1,610.00 Volume Pricing	1 In Stock
125.00	-	6.00	NIR II (750-1550nm)	#29-611	S\$1,610.00 Volume Pricing	5 In Stock
125.00	-	6.00	YAG-BBAR (500-1100nm)	#29-613	S\$1,659.00 Volume Pricing	2 In Stock
125.00	-	12.50	Uncoated	#29-509	S\$1,288.00 Volume Pricing	4 In Stock
150.00	-	8.00	UV-AR (250-425nm)	#29-614	S\$2,198.00 Volume Pricing	1 In Stock
150.00	-	8.00	VIS-EXT (350-700nm)	#29-617	S\$2,198.00 Volume Pricing	1 In Stock
150.00	-	8.00	NIR I (600-1050nm)	#29-615	S\$2,156.00 Volume Pricing	2 In Stock
150.00	-	8.00	NIR II (750-1550nm)	#29-616	S\$2,156.00 Volume Pricing	3 In Stock
150.00	-	8.00	YAG-BBAR (500-1100nm)	#29-618	S\$2,198.00 Volume Pricing	1 In Stock
150.00	-	15.00	Uncoated	#29-510	S\$2,037.00 Volume Pricing	5 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com