

[All Products](#) / [Optics](#) / [Fiber Optics](#)

Multimode Buffered Fiber Optics



UV/VIS Optical Fibers

- High OH Content
- Fused Silica Core
- Stepped Index
- Multimode Fiber

VIS/NIR Optical Fibers

- Low OH Content
- Ideal for Use with NIR Diode Lasers
- Fused Silica Core
- Stepped Multimode Fiber

Common Specifications

General

Note:

Fiber ends are not polished.

Optical Properties

Acceptance Angle (°): 25.4

Substrate: Fused Silica

Numerical Aperture NA: 0.22

Index of Refraction (n_d)
- Core: 1.457

Numerical Aperture (NA)
Tolerance: ± 0.02


Material Properties

Buffer Material: Polyimide



Environmental & Durability Factors

Operating Temperature (°C): -190 to +390

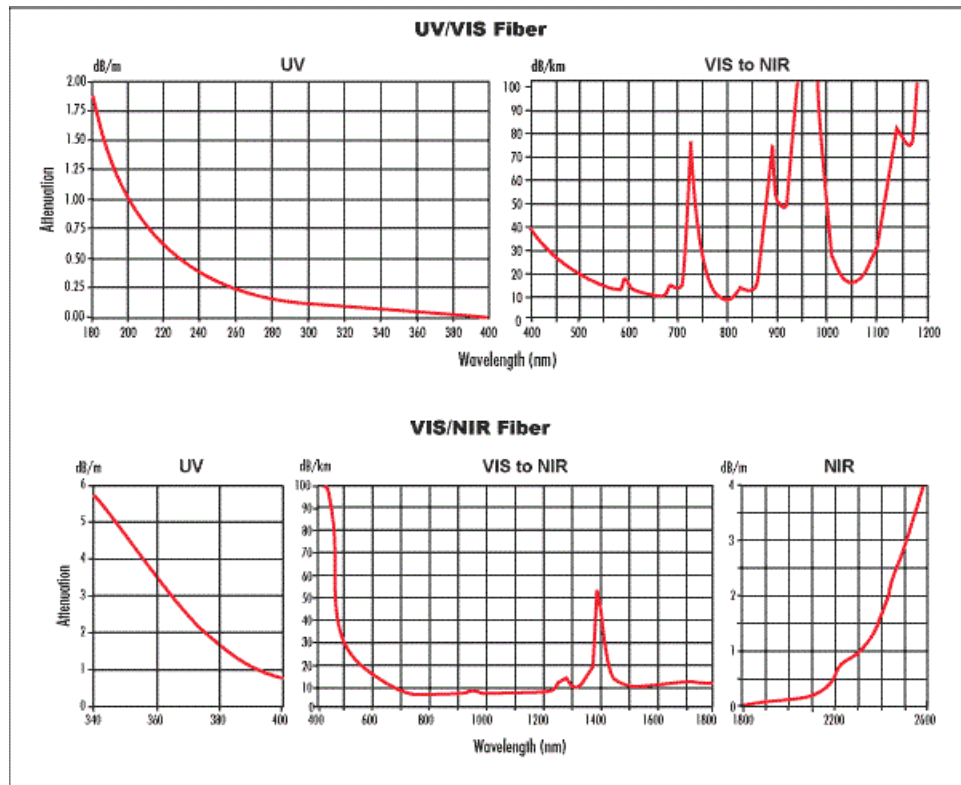

Technical Information

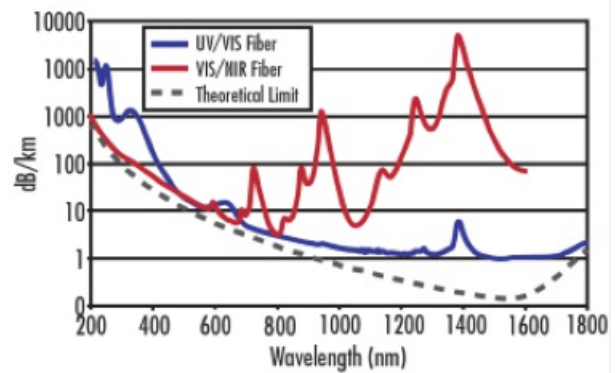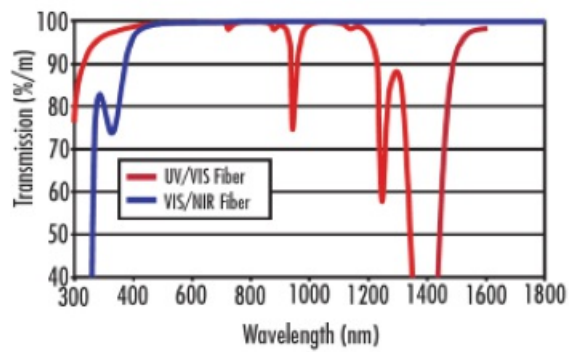

UV/VIS vs. VIS/NIR



Products

Title	Stock Number	Price	Buy
#57-066 Clearance			
50µm 0.22 NA UV/VIS Fiber, 10m Length			
	Clearance	S\$84.10 Volume Pricing	3 In Stock
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.			
<hr/>			
50µm 0.22 NA UV/VIS Fiber, 25m Length	#57-072	S\$210.25 Volume Pricing	1 In Stock
<hr/>			
#57-067 Clearance			
100µm 0.22 NA UV/VIS Fiber, 10m Length			
	Clearance	S\$69.60 Volume Pricing	2 In Stock
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.			
<hr/>			
100µm 0.22 NA UV/VIS Fiber, 25m Length	#57-073	S\$150.80 Volume Pricing	4 In Stock
<hr/>			

[#57-068 Clearance](#)



200µm 0.22
NA UV/VIS
Fiber, 10m
Length

Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

S\$116.00
[Volume Pricing](#)

9 In Stock

[#57-069 Clearance](#)



400µm 0.22
NA UV/VIS
Fiber, 10m
Length

Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

S\$320.45
[Volume Pricing](#)

Contact Us

400µm 0.22
NA UV/VIS
Fiber, 25m
Length

[#57-075](#)

S\$797.50
[Volume Pricing](#)

2 In Stock

[#57-070 Clearance](#)



600µm 0.22
NA UV/VIS
Fiber, 10m
Length

Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

S\$655.40
[Volume Pricing](#)

5 In Stock

50µm 0.22 NA
VIS/NIR Fiber,
25m Length

[#57-090](#)

S\$216.05
[Volume Pricing](#)

3 In Stock

[#57-085 Clearance](#)



100µm 0.22
NA VIS/NIR
Fiber, 10m
Length

Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

S\$71.05
[Volume Pricing](#)

Contact Us

100µm 0.22
NA VIS/NIR
Fiber, 25m
Length

[#57-091](#)

S\$155.15
[Volume Pricing](#)

2 In Stock

[#57-086 Clearance](#)



200µm 0.22
NA VIS/NIR
Fiber, 10m
Length

Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

S\$121.80
[Volume Pricing](#)

1 In Stock

200µm 0.22
NA VIS/NIR
Fiber, 25m
Length

[#57-092](#)

S\$303.05
[Volume Pricing](#)

1 In Stock

[#57-087 Clearance](#)



400µm 0.22
NA VIS/NIR
Fiber, 10m
Length

Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

S\$327.70
[Volume Pricing](#)

4 In Stock

400µm 0.22
NA VIS/NIR
Fiber, 25m
Length

[#57-093](#)

S\$820.70
[Volume Pricing](#)

1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com