

[All Products](#) / [Microscopy](#) / [Infinity Corrected Objectives](#)

Nikon CFI60 Infinity Corrected Brightfield Objectives [See More by Nikon](#)



- Excellent Color Reproduction
- Long Working Distance and High NA
- High Contrast with Minimal Flare
- Strain Free

Common Specifications

General

Compatible Tube Lens
Focal Length (mm):

Focal Length: 200mm

Manufacturer:

Nikon

Optical Properties

Field Number (mm): 22

Parfocal Length (mm): 60

Immersion Liquid: N/A

Sensor

Maximum Sensor Format:


2/3"

Threading & Mounting


Mounting Threads:

M25 x 0.75

Technical Information

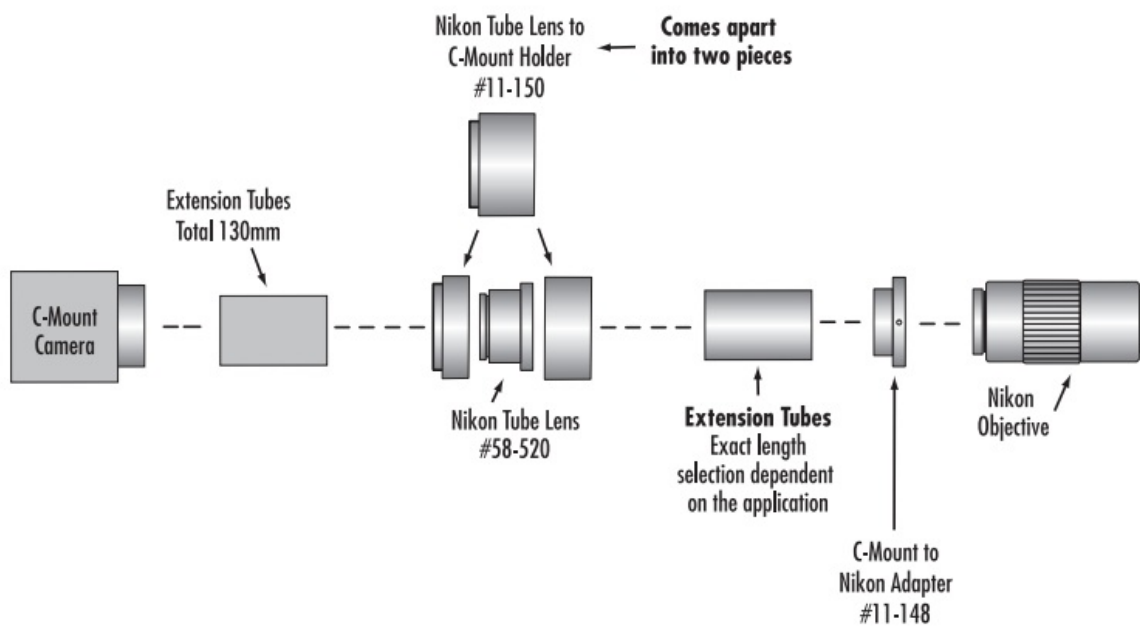

Nikon CF160 Infinity-Corrected Brightfield Objectives

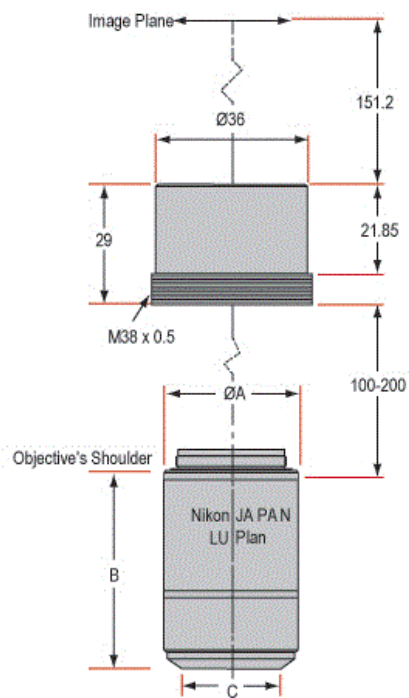

Units: mm

Products

Magnification	NA	Field Number (mm)	FL (mm)	Model Number	WD (mm)	Stock Number	Price	Buy
5X	0.15	22	40.00	MUE12050	23.5	#58-515	S\$1,491.00	3 In Stock
10X	0.30	22	20.00	MUE12100	17.5	#58-516	S\$1,974.00	5 In Stock
20X	0.40	22	10.00	MUE21200	19.00	#58-517	S\$3,724.00	5 In Stock
50X	0.60	22	4.00	MUE21500	11.00	#58-518	S\$4,459.00	8 In Stock
100X	0.80	22	2.00	MUE21900	4.5	#58-519	S\$9,604.00	4 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com