

[All Products](#) / [Imaging Lenses](#) / [Zoom & Variable Magnification Lenses](#) / [High Magnification Long Working Distance Zoom Lenses](#)

InfiniProbe™ Microscopes

See More by [Infinity Photo-Optical Company](#)



- Available in Standard and Right Angle Versions
- Focuses From Infinity to 32, 28, and 18mm Respectively
- Max. Sensor Format 2/3"
- Magnification From 2.5X to 8.0X
- Direct Video C-Mount Coupling

Common Specifications



Sensor



Maximum Sensor Format:	2/3"
------------------------	------

Threading & Mounting


Mount:	C-Mount
--------	---------

Technical Information

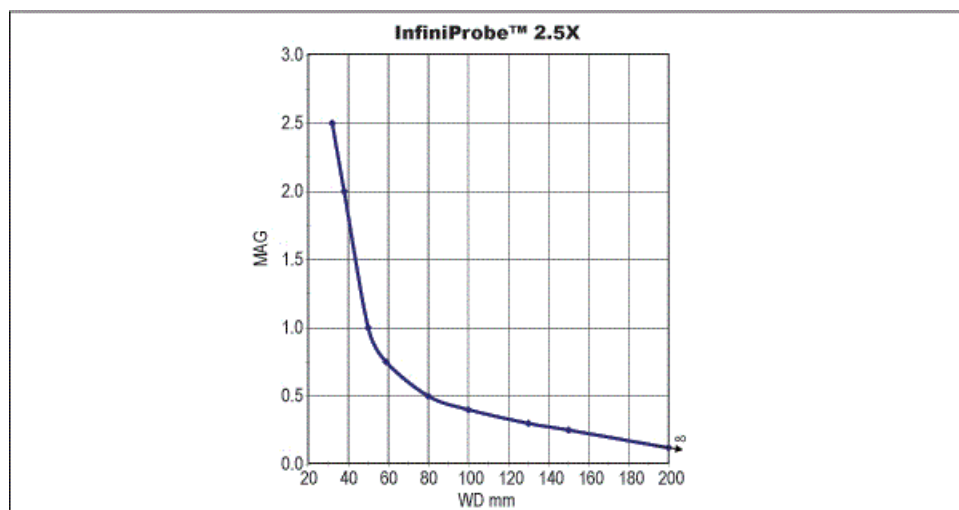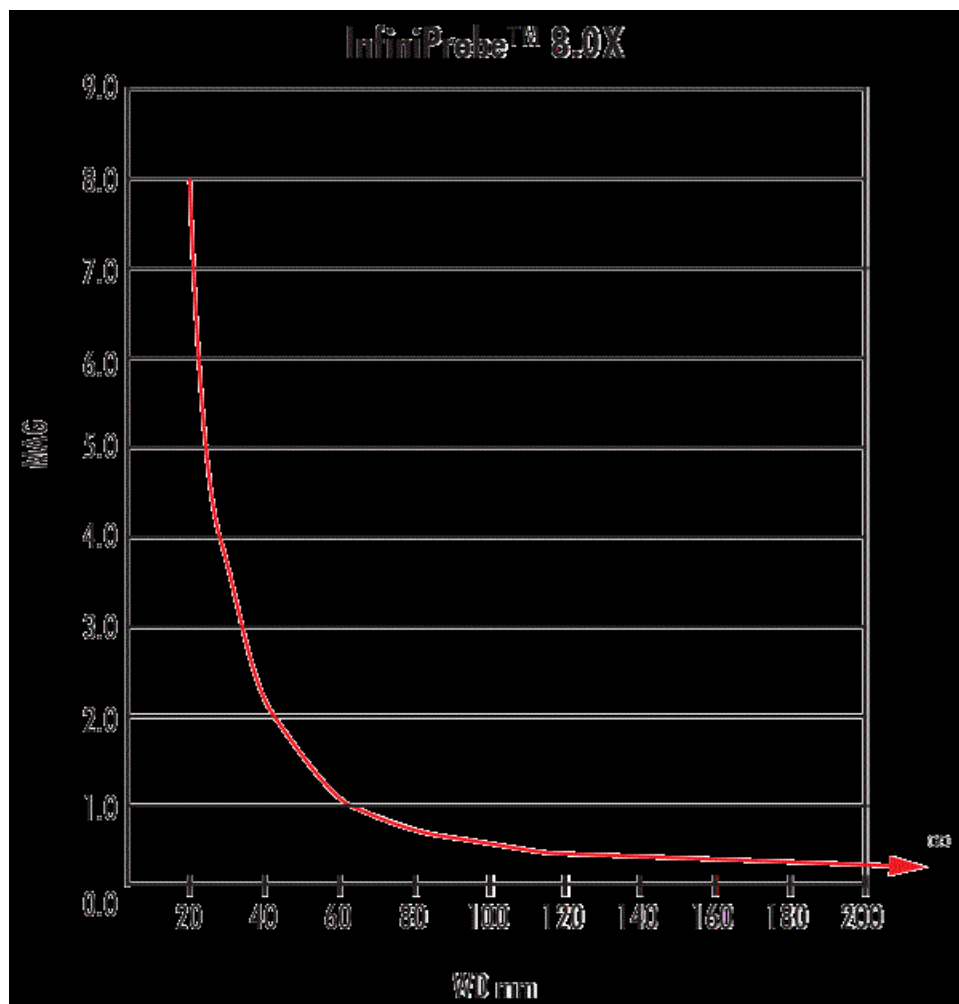

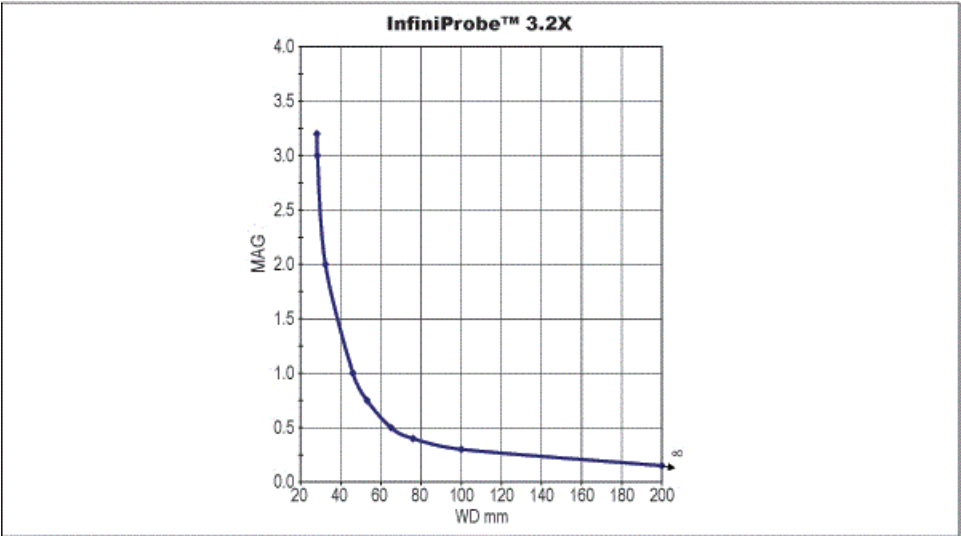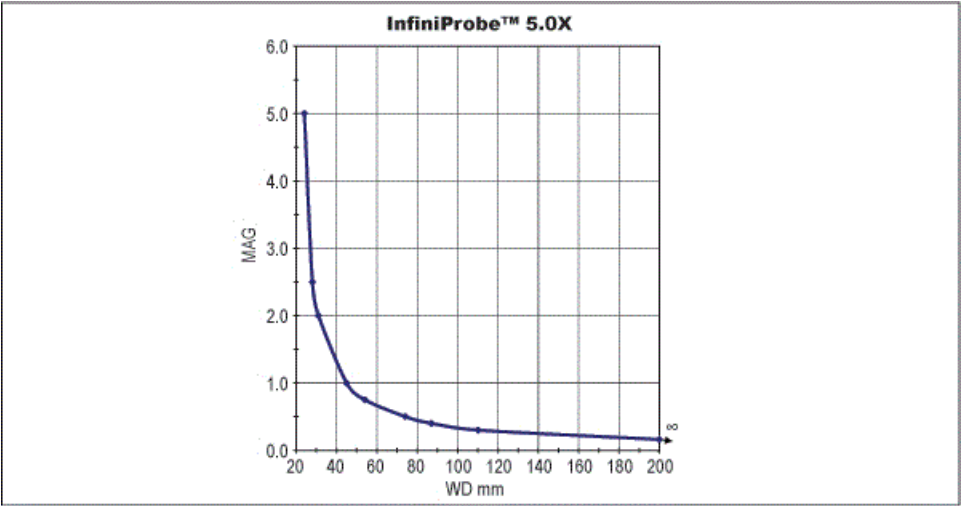

InfiniProbe™ PMAG vs WD Curves

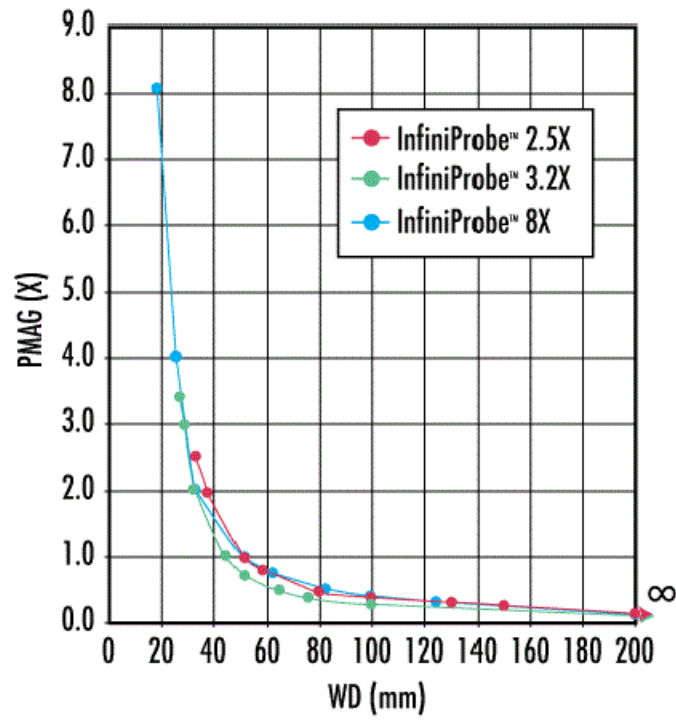

Products

Title	Stock Number	Price	Buy
InfiniProbe S-25 Video Microscope (0-2.5X)	#58-806	S\$3,227.00	Contact Us
InfiniProbe S-32 Video Microscope (0-3.2X)	#58-807	S\$3,612.00	Contact Us
InfiniProbe S-80 Video Microscope (0-8.0X)	#58-809	S\$4,802.00	1 In Stock
InfiniProbe S-25 Right Angle Video Microscope (0-2.5X)	#58-810	S\$4,039.00	Contact Us
InfiniProbe S-32 Right Angle Video Microscope (0-3.2X)	#58-811	S\$4,431.00	2 In Stock
InfiniProbe S-80 Right Angle Video Microscope (0-8.0X)	#58-813	S\$5,579.00	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com