

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

## TECHSPEC® MgF<sub>2</sub> Coated Plano-Convex (PCX) Lenses



- AR Coated to Provide <1.75% Reflectance per Surface for 400 - 700nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), [VIS-EXT](#), and [YAG-BBAR](#)
- Also Available [Pre-Mounted in Engraved C-Mount Housings](#)

### Common Specifications

#### Physical & Mechanical Properties



|        |                      |
|--------|----------------------|
| Bevel: | Protective as needed |
|--------|----------------------|

#### Optical Properties

|                             |    |
|-----------------------------|----|
| Focal Length Tolerance (%): | ±1 |
|-----------------------------|----|

|                        |           |
|------------------------|-----------|
| Wavelength Range (nm): | 400 - 700 |
|------------------------|-----------|

Technical Information

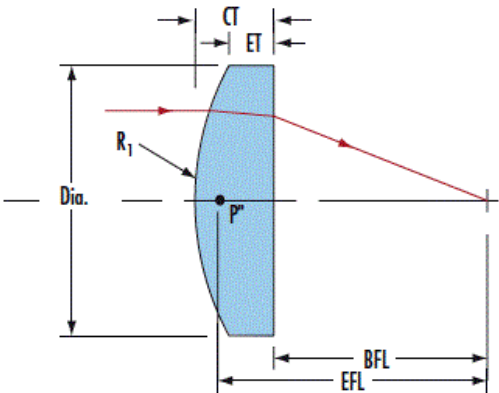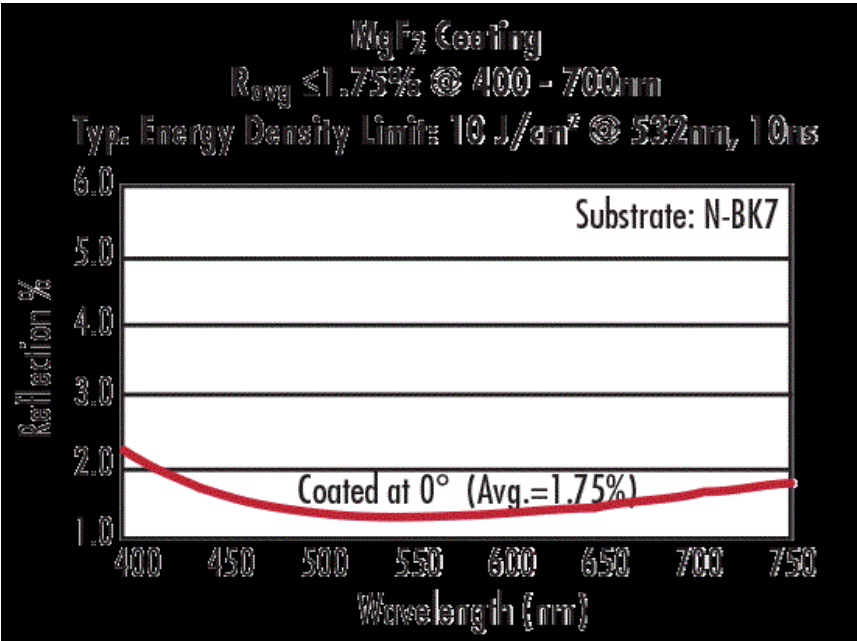

## Products

| Dia.<br>(mm) | EFL<br>(mm) | BFL<br>(mm) | Coating                         | Substrate               | Stock Number            | Price                                       | Buy          |
|--------------|-------------|-------------|---------------------------------|-------------------------|-------------------------|---------------------------------------------|--------------|
| 1.00         | 0.60        | 0.17        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-257</a> | S\$112.70<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 1.00         | 1.00        | 0.57        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-258</a> | S\$112.70<br><a href="#">Volume Pricing</a> | 16 In Stock  |
| 1.00         | 1.50        | 1.07        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-259</a> | S\$112.70<br><a href="#">Volume Pricing</a> | Contact Us   |
| 1.00         | 2.00        | 1.57        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-260</a> | S\$112.70<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 1.50         | 1.00        | 0.57        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-261</a> | S\$112.70<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 1.50         | 1.50        | 1.07        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-262</a> | S\$112.70<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 1.50         | 2.00        | 1.57        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-263</a> | S\$112.70<br><a href="#">Volume Pricing</a> | Contact Us   |
| 2.00         | 1.50        | 1.07        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-264</a> | S\$111.30<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 2.00         | 2.00        | 1.57        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-265</a> | S\$111.30<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 2.00         | 3.00        | 2.57        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-266</a> | S\$111.30<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 2.00         | 4.00        | 3.57        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-267</a> | S\$111.30<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 2.50         | 2.00        | 1.57        | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a> | <a href="#">#65-268</a> | S\$111.30<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|      |       |       |                                 |                          |                         |                                             |              |
|------|-------|-------|---------------------------------|--------------------------|-------------------------|---------------------------------------------|--------------|
| 2.50 | 2.50  | 2.05  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a>  | <a href="#">#65-269</a> | S\$111.30<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 2.50 | 3.00  | 2.57  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a>  | <a href="#">#65-270</a> | S\$111.30<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 2.50 | 4.00  | 3.57  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a>  | <a href="#">#65-271</a> | S\$111.30<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 2.50 | 5.00  | 4.57  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF9</a>  | <a href="#">#65-272</a> | S\$111.30<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 3.00 | 3.00  | 1.88  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a>   | <a href="#">#45-118</a> | S\$91.70<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| 3.00 | 4.50  | 3.50  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF44</a> | <a href="#">#45-142</a> | S\$91.70<br><a href="#">Volume Pricing</a>  | 15 In Stock  |
| 3.00 | 6.00  | 4.81  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#32-953</a> | S\$84.00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| 3.00 | 7.50  | 6.51  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#48-910</a> | S\$84.00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| 3.00 | 9.00  | 8.01  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#32-955</a> | S\$84.00<br><a href="#">Volume Pricing</a>  | 10 In Stock  |
| 3.00 | 12.00 | 11.29 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#45-273</a> | S\$84.00<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 3.00 | 15.00 | 14.17 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#45-426</a> | S\$84.00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| 4.00 | 4.00  | 3.06  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF44</a> | <a href="#">#45-224</a> | S\$84.00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| 4.00 | 6.00  | 4.51  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#45-428</a> | S\$84.00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| 4.00 | 8.00  | 7.17  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BAF10</a>  | <a href="#">#45-226</a> | S\$77.00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |

|      |       |       |                                 |                          |                         |                                            |              |
|------|-------|-------|---------------------------------|--------------------------|-------------------------|--------------------------------------------|--------------|
| 4.00 | 10.00 | 8.92  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#45-430</a> | S\$77.00<br><a href="#">Volume Pricing</a> | Contact Us   |
| 4.00 | 12.00 | 11.00 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#45-432</a> | S\$77.00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 4.50 | 4.50  | 3.05  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF44</a> | <a href="#">#45-144</a> | S\$84.00<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 4.50 | 9.00  | 7.41  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#45-148</a> | S\$77.00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 5.00 | 5.00  | 3.96  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-LASF44</a> | <a href="#">#45-228</a> | S\$67.20<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 5.00 | 7.50  | 6.43  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a>   | <a href="#">#48-655</a> | S\$66.50<br><a href="#">Volume Pricing</a> | 15 In Stock  |
| 5.00 | 10.00 | 8.91  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#45-230</a> | S\$66.50<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 5.00 | 12.00 | 10.83 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#45-434</a> | S\$66.50<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 5.00 | 15.00 | 13.94 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#45-355</a> | S\$66.50<br><a href="#">Volume Pricing</a> | 12 In Stock  |
| 5.00 | 20.00 | 19.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#49-883</a> | S\$66.50<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 5.00 | 25.00 | 23.95 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#87-913</a> | S\$66.50<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 5.00 | 30.00 | 28.95 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>    | <a href="#">#87-914</a> | S\$66.50<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.00 | 6.00  | 4.60  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a>   | <a href="#">#45-078</a> | S\$54.25<br><a href="#">Volume Pricing</a> | Contact Us   |
| 6.00 | 7.50  | 6.10  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a>   | <a href="#">#49-884</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|      |       |       |                                 |                       |                         |                                            |              |
|------|-------|-------|---------------------------------|-----------------------|-------------------------|--------------------------------------------|--------------|
| 6.00 | 9.00  | 7.95  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF5</a> | <a href="#">#32-470</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.00 | 10.00 | 8.82  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#38-215</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 6.00 | 12.00 | 10.94 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-472</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.00 | 15.00 | 13.68 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-080</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.00 | 18.00 | 17.07 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-474</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.00 | 20.00 | 19.04 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#38-216</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 6.00 | 21.00 | 20.06 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-232</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.00 | 24.00 | 23.01 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-957</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.00 | 25.00 | 24.04 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#38-217</a> | S\$51.80<br><a href="#">Volume Pricing</a> | Contact Us   |
| 6.00 | 30.00 | 29.14 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-120</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 6.00 | 36.00 | 34.95 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-849</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 14 In Stock  |
| 6.00 | 48.00 | 46.95 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-234</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 6.00 | 60.00 | 58.95 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#67-154</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 6.00 | 72.00 | 70.97 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-851</a> | S\$51.80<br><a href="#">Volume Pricing</a> | 15 In Stock  |

|      |       |       |                                 |                        |                         |                                            |              |
|------|-------|-------|---------------------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 7.00 | 7.00  | 5.50  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#71-293</a> | S\$54.25<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 7.00 | 10.00 | 8.10  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#71-300</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 7.00 | 12.00 | 10.30 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#71-307</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 8.00 | 8.00  | 6.40  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#71-314</a> | S\$54.25<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 8.00 | 10.00 | 7.60  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#71-321</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 8.00 | 12.00 | 10.00 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#71-328</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 9.00 | 9.00  | 7.32  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#45-082</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 9.00 | 10.00 | 8.49  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#38-218</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 9.00 | 12.00 | 10.60 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#49-885</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 9.00 | 13.50 | 11.94 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF5</a>  | <a href="#">#32-010</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 9.00 | 15.00 | 13.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-886</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 9.00 | 18.00 | 16.41 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#31-854</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 9.00 | 20.00 | 18.55 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-219</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 9.00 | 22.00 | 20.73 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-236</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 2 In Stock   |

|       |       |       |                                 |                        |                         |                                            |              |
|-------|-------|-------|---------------------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 9.00  | 25.00 | 23.68 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-220</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 9.00  | 27.00 | 25.35 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#32-959</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 9.00  | 36.00 | 34.48 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-122</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 9.00  | 45.00 | 43.98 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-357</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 9.00  | 54.00 | 52.69 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#67-155</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 9.00  | 72.00 | 70.68 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#67-156</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 9.00  | 90.00 | 88.68 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#67-157</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 10.00 | 10.00 | 8.18  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#63-484</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 10.00 | 12.50 | 10.99 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#38-223</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 10.00 | 15.00 | 13.32 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#63-485</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 10.00 | 17.50 | 15.66 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-224</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 10.00 | 20.00 | 18.03 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#63-486</a> | S\$53.55<br><a href="#">Volume Pricing</a> | Contact Us   |
| 10.00 | 25.00 | 23.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#63-487</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 10.00 | 30.00 | 28.01 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#63-488</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|       |        |       |                                 |                        |                         |                                            |              |
|-------|--------|-------|---------------------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 10.00 | 40.00  | 38.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#63-489</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 10.00 | 50.00  | 48.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#63-490</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 10.00 | 75.00  | 73.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#63-491</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 16 In Stock  |
| 10.00 | 100.00 | 98.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#63-492</a> | S\$53.55<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.00 | 12.00  | 9.76  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#45-084</a> | S\$58.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 15.00  | 12.03 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-303</a> | S\$58.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 18.00  | 16.22 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF5</a>  | <a href="#">#32-007</a> | S\$58.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 20.00  | 17.69 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-887</a> | S\$58.10<br><a href="#">Volume Pricing</a> | Contact Us   |
| 12.00 | 24.00  | 22.15 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#31-855</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 25.00  | 23.22 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-226</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.00 | 30.00  | 28.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-086</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 36.00  | 34.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#33-353</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 42.00  | 40.22 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-124</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 48.00  | 46.36 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#32-853</a> | S\$56.70<br><a href="#">Volume Pricing</a> | Contact Us   |

|       |        |       |                                 |                        |                         |                                            |              |
|-------|--------|-------|---------------------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 12.00 | 50.00  | 48.75 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-230</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 12.00 | 54.00  | 52.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-305</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 60.00  | 58.37 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#32-855</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 72.00  | 70.42 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-126</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 12.00 | 84.00  | 82.39 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#32-857</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 100.00 | 98.35 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-275</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.50 | 12.50  | 10.40 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#38-231</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 12.50 | 15.00  | 13.26 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#38-232</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 12.50 | 17.50  | 15.00 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-233</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 20.00  | 17.69 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-234</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 12.50 | 25.00  | 22.96 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-235</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | 30.00  | 28.22 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-237</a> | S\$54.95<br><a href="#">Volume Pricing</a> | Contact Us   |
| 12.50 | 35.00  | 33.42 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-238</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 12.50 | 40.00  | 38.55 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-239</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 4 In Stock   |

|       |        |       |                                 |                        |                         |                                            |              |
|-------|--------|-------|---------------------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 12.50 | 45.00  | 43.68 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-240</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.50 | 50.00  | 48.68 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-241</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 12.50 | 75.00  | 73.88 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-242</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 12.50 | 100.00 | 98.95 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-243</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 12.70 | 12.70  | 10.46 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#49-854</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 12.70 | 15.00  | 11.53 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-855</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.70 | 19.10  | 16.46 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-856</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 12.70 | 20.00  | 17.49 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-244</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 12.70 | 25.40  | 23.43 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-857</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.70 | 30.00  | 28.22 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-245</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 12.70 | 31.80  | 29.81 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-858</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.70 | 38.10  | 36.12 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-859</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.70 | 40.00  | 38.48 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-246</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 12.70 | 44.50  | 42.69 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-860</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|       |        |       |                                 |                       |                         |                                            |              |
|-------|--------|-------|---------------------------------|-----------------------|-------------------------|--------------------------------------------|--------------|
| 12.70 | 50.80  | 49.15 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#49-861</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.70 | 100.00 | 98.88 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#38-247</a> | S\$54.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 15.00 | 15.00  | 11.71 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF5</a> | <a href="#">#45-094</a> | S\$58.10<br><a href="#">Volume Pricing</a> | 12 In Stock  |
| 15.00 | 18.00  | 15.61 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF5</a> | <a href="#">#49-888</a> | S\$58.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 15.00 | 20.00  | 17.74 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF5</a> | <a href="#">#63-493</a> | S\$58.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 15.00 | 22.50  | 20.50 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF5</a> | <a href="#">#32-005</a> | S\$58.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 15.00 | 25.00  | 22.50 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#38-248</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 15.00 | 30.00  | 27.90 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#31-856</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 15.00 | 40.00  | 38.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-096</a> | S\$56.70<br><a href="#">Volume Pricing</a> | Contact Us   |
| 15.00 | 45.00  | 43.35 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#49-889</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 14 In Stock  |
| 15.00 | 50.00  | 48.35 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#38-249</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 15.00 | 60.00  | 58.65 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-436</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 15.00 | 75.00  | 73.79 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-359</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 15.00 | 100.00 | 98.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-260</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 5 In Stock   |

|                                                                                                                                                                                                                                                    |        |        |                                 |                        |                         |                                            |              |
|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------|--------|---------------------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 15.00                                                                                                                                                                                                                                              | 200.00 | 197.89 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#14-375</a> | S\$56.70<br><a href="#">Volume Pricing</a> | Contact Us   |
| 15.00                                                                                                                                                                                                                                              | 250.00 | 248.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#14-383</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| <a href="#">#45-438 Clearance</a>                                                                                                                                                                                                                  |        |        |                                 |                        |                         |                                            |              |
|  <p>Clearance</p> <p>Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.</p> |        |        |                                 |                        |                         |                                            |              |
| 18.00                                                                                                                                                                                                                                              | 18.00  | 11.20  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  |                         | S\$34.30                                   | 20+ In Stock |
| 18.00                                                                                                                                                                                                                                              | 18.00  | 15.20  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#48-424</a> | S\$58.80<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 18.00                                                                                                                                                                                                                                              | 20.00  | 17.59  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#38-250</a> | S\$58.10<br><a href="#">Volume Pricing</a> | Contact Us   |
| 18.00                                                                                                                                                                                                                                              | 22.50  | 20.26  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#49-890</a> | S\$58.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 18.00                                                                                                                                                                                                                                              | 25.00  | 21.51  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-251</a> | S\$58.10<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 18.00                                                                                                                                                                                                                                              | 27.00  | 24.73  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF5</a>  | <a href="#">#32-002</a> | S\$58.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 18.00                                                                                                                                                                                                                                              | 30.00  | 27.10  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-252</a> | S\$55.65<br><a href="#">Volume Pricing</a> | 5 In Stock   |

|       |        |       |                                 |                         |                         |                                            |              |
|-------|--------|-------|---------------------------------|-------------------------|-------------------------|--------------------------------------------|--------------|
| 18.00 | 36.00  | 33.65 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#31-857</a> | S\$55.65<br><a href="#">Volume Pricing</a> | Contact Us   |
| 18.00 | 50.00  | 48.09 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#38-253</a> | S\$55.65<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 18.00 | 54.00  | 52.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#45-307</a> | S\$55.65<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 18.00 | 72.00  | 70.05 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#32-860</a> | S\$55.65<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 20.00 | 20.00  | 17.42 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a>  | <a href="#">#45-238</a> | S\$59.85<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 20.00 | 25.00  | 22.76 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a>  | <a href="#">#49-891</a> | S\$58.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 20.00 | 30.00  | 27.30 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BAF10</a> | <a href="#">#45-240</a> | S\$58.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 20.00 | 35.00  | 32.04 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#49-892</a> | S\$58.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 20.00 | 40.00  | 36.77 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#32-961</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 20.00 | 50.00  | 47.87 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#45-361</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 20.00 | 60.00  | 57.03 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#32-963</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 20.00 | 70.00  | 68.03 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#32-937</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 20.00 | 80.00  | 78.45 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#45-440</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 20.00 | 100.00 | 97.13 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>   | <a href="#">#32-476</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|       |        |        |                                 |                       |                         |                                            |              |
|-------|--------|--------|---------------------------------|-----------------------|-------------------------|--------------------------------------------|--------------|
| 20.00 | 150.00 | 148.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-277</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00 | 25.00  | 20.22  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF5</a> | <a href="#">#45-098</a> | S\$59.85<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 30.00  | 24.69  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-363</a> | S\$59.85<br><a href="#">Volume Pricing</a> | Contact Us   |
| 25.00 | 35.00  | 30.42  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-146</a> | S\$59.85<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 40.00  | 36.31  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-279</a> | S\$59.85<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 50.00  | 46.75  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-478</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 60.00  | 56.90  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-128</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 25.00 | 75.00  | 72.00  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-480</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 85.00  | 82.17  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#45-365</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 100.00 | 97.17  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-482</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 125.00 | 122.70 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-862</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 17 In Stock  |
| 25.00 | 150.00 | 147.81 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-864</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 25.00 | 175.00 | 172.85 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#32-866</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 25.00 | 200.00 | 197.89 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#33-359</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 14 In Stock  |

|       |        |        |                                 |                        |                         |                                            |              |
|-------|--------|--------|---------------------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 25.00 | 250.00 | 248.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#67-158</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.00 | 300.00 | 298.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#67-159</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 17 In Stock  |
| 25.00 | 400.00 | 397.89 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#33-365</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 25.00 | 500.00 | 497.89 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-281</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | 750.00 | 747.89 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-283</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 25.40 | 25.40  | 21.48  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#49-862</a> | S\$59.85<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.40 | 35.00  | 30.46  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-254</a> | S\$59.85<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 25.40 | 38.10  | 33.48  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-863</a> | S\$59.85<br><a href="#">Volume Pricing</a> | 14 In Stock  |
| 25.40 | 40.00  | 36.11  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-255</a> | S\$59.85<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.40 | 50.80  | 47.50  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-864</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.40 | 63.50  | 60.37  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-865</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.40 | 75.00  | 72.69  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-262</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.40 | 76.20  | 73.56  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-866</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.40 | 88.90  | 86.26  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-867</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|       |        |        |                                 |                        |                         |                                            |              |
|-------|--------|--------|---------------------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 25.40 | 100.00 | 98.02  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-264</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 25.40 | 101.60 | 98.97  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#49-868</a> | S\$56.70<br><a href="#">Volume Pricing</a> | Contact Us   |
| 25.40 | 125.00 | 123.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-265</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.40 | 150.00 | 148.02 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-266</a> | S\$56.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 30.00 | 30.00  | 26.13  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#48-656</a> | S\$77.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 30.00 | 40.00  | 37.20  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#67-160</a> | S\$75.60<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 30.00 | 50.00  | 46.17  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF5</a>  | <a href="#">#32-484</a> | S\$75.60<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 30.00 | 60.00  | 56.03  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-242</a> | S\$73.50<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 30.00 | 75.00  | 70.95  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#32-486</a> | S\$73.50<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 30.00 | 100.00 | 96.01  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#32-488</a> | S\$73.50<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 30.00 | 120.00 | 116.04 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-244</a> | S\$73.50<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 35.00 | 35.00  | 30.52  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#38-267</a> | S\$80.50<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 35.00 | 50.00  | 44.40  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-268</a> | S\$77.70<br><a href="#">Volume Pricing</a> | Contact Us   |
| 35.00 | 70.00  | 66.04  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-269</a> | S\$77.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|       |        |        |                                 |                        |                         |                                            |              |
|-------|--------|--------|---------------------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 35.00 | 100.00 | 97.03  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#38-270</a> | S\$77.70<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 40.00 | 40.00  | 35.13  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#48-657</a> | S\$84.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 40.00 | 60.00  | 53.90  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-150</a> | S\$84.70<br><a href="#">Volume Pricing</a> | 11 In Stock  |
| 40.00 | 80.00  | 74.73  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#33-383</a> | S\$82.60<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 40.00 | 100.00 | 95.39  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#33-371</a> | S\$82.60<br><a href="#">Volume Pricing</a> | Contact Us   |
| 40.00 | 200.00 | 196.7  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#33-377</a> | S\$82.60<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 40.00 | 300.00 | 296.70 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-285</a> | S\$82.60<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 40.00 | 400.00 | 396.70 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-287</a> | S\$82.60<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 50.00 | 50.00  | 43.28  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#32-971</a> | S\$93.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 75.00  | 67.75  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-246</a> | S\$90.30<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 100.00 | 93.41  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#32-973</a> | S\$86.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 125.00 | 118.39 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-248</a> | S\$86.10<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 50.00 | 150.00 | 144.07 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#32-975</a> | S\$86.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.00 | 175.00 | 169.05 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-250</a> | S\$86.10<br><a href="#">Volume Pricing</a> | 12 In Stock  |

|       |        |        |                                 |                        |                         |                                             |              |
|-------|--------|--------|---------------------------------|------------------------|-------------------------|---------------------------------------------|--------------|
| 50.00 | 200.00 | 196.66 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-152</a> | S\$86.10<br><a href="#">Volume Pricing</a>  | 3 In Stock   |
| 50.00 | 250.00 | 246.74 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-154</a> | S\$86.10<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| 50.00 | 500.00 | 496.70 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-289</a> | S\$86.10<br><a href="#">Volume Pricing</a>  | 17 In Stock  |
| 50.80 | 50.81  | 44.08  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-SF11</a> | <a href="#">#71-335</a> | S\$93.10<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| 50.80 | 76.20  | 68.95  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#71-342</a> | S\$90.30<br><a href="#">Volume Pricing</a>  | 2 In Stock   |
| 75.00 | 75.00  | 53.49  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-368</a> | S\$155.40<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 75.00 | 100.00 | 87.57  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#71-840</a> | S\$152.60<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 75.00 | 125.00 | 115.99 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#71-841</a> | S\$152.60<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 75.00 | 150.00 | 142.45 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-370</a> | S\$152.60<br><a href="#">Volume Pricing</a> | 11 In Stock  |
| 75.00 | 175.00 | 168.68 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#71-842</a> | S\$152.60<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 75.00 | 200.00 | 194.24 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#45-372</a> | S\$152.60<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 75.00 | 250.00 | 244.73 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#63-495</a> | S\$152.60<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 75.00 | 300.00 | 294.4  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#71-843</a> | S\$152.60<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 75.00 | 400.00 | 394.4  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a>  | <a href="#">#71-844</a> | S\$152.60<br><a href="#">Volume Pricing</a> | 2 In Stock   |

|        |        |        |                                 |                       |                         |                                               |              |
|--------|--------|--------|---------------------------------|-----------------------|-------------------------|-----------------------------------------------|--------------|
| 75.00  | 500.00 | 494.73 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#63-496</a> | S\$152.60<br><a href="#">Volume Pricing</a>   | 20+ In Stock |
| 75.00  | 750.00 | 745.35 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#71-845</a> | S\$152.60<br><a href="#">Volume Pricing</a>   | 5 In Stock   |
| 100.00 | 200.00 | 190.77 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#17-900</a> | S\$483.00<br><a href="#">Volume Pricing</a>   | Contact Us   |
| 150.00 | 300.00 | 285.50 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#17-916</a> | S\$896.00<br><a href="#">Volume Pricing</a>   | 2 In Stock   |
| 200.00 | 400.00 | 381.54 | MgF <sub>2</sub><br>(400-700nm) | <a href="#">N-BK7</a> | <a href="#">#17-932</a> | S\$1,666.00<br><a href="#">Volume Pricing</a> | 5 In Stock   |



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)