

[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Optical Diffusers](#)

UV Fused Silica Ground Glass Diffusers



- Even, Diffuse Surface
- Ideal for Applications Utilizing UV Wavelengths
- Low Scatter Loss
- [Float Glass Substrates](#) Also Available

Common Specifications

Physical & Mechanical Properties

Grit: 220


Thickness (mm): 1.60

Optical Properties

Substrate: [Fused Silica](#) (Corning 7980)

Wavelength Range (nm): 200 - 2200

Technical Information

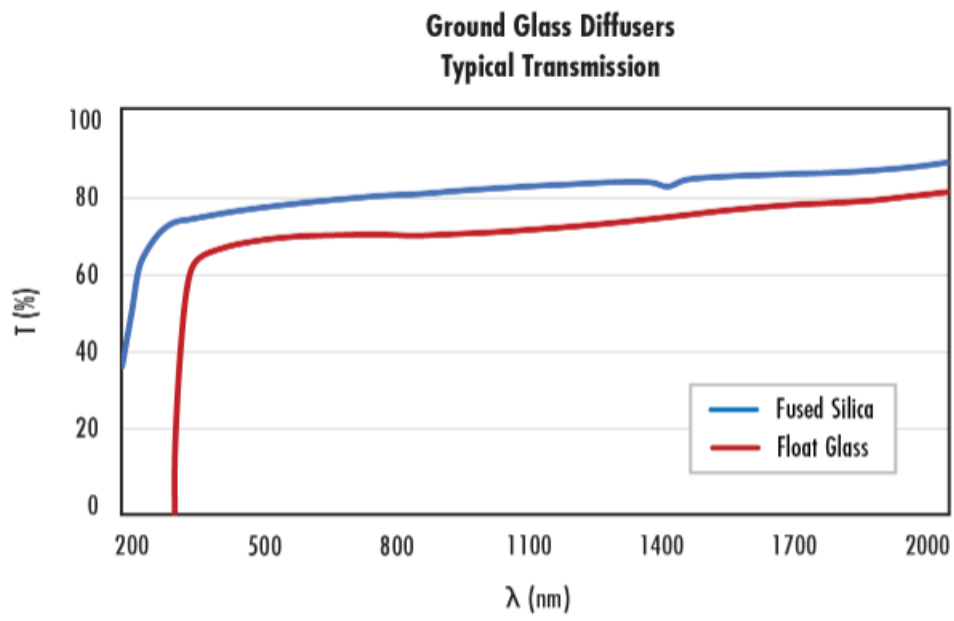

Products

Dia. (mm)	Dimensions (mm)	Grit	Thickness (mm)	Stock Number	Price	Buy
5.00	-	220	1.60	#63-222	S\$79.16 Volume Pricing	20+ In Stock
6.00	-	220	1.60	#65-891	S\$79.16 Volume Pricing	16 In Stock
-	10.00 x 10.00	220	1.60	#63-223	S\$79.16 Volume Pricing	20+ In Stock
10.00	-	220	1.60	#49-155	S\$79.16 Volume Pricing	20+ In Stock
12.50	-	220	1.60	#63-224	S\$79.16 Volume Pricing	20+ In Stock
-	12.50 x 12.50	220	1.60	#63-225	S\$79.16 Volume Pricing	20+ In Stock
15.00	-	220	1.60	#49-156	S\$82.88 Volume Pricing	20+ In Stock
20.00	-	220	1.60	#63-226	S\$82.88 Volume Pricing	12 In Stock
25.00	-	220	1.60	#49-157	S\$87.37 Volume Pricing	20+ In Stock
-	25.00 x 25.00	220	1.60	#49-158	S\$87.37 Volume Pricing	20+ In Stock
50.00	-	220	1.60	#49-237	S\$156.82 Volume Pricing	20+ In Stock
-	50.00 x 50.00	220	1.60	#49-159	S\$156.82 Volume Pricing	20+ In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com