

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Neutral Density \(ND\) Filters](#)

Non-Reflective Neutral Density (ND) Filters



- Prevent Unwanted Reflection Towards the Light Source
- Spectrally Flat
- VIS and NIR Ranges Available

Common Specifications


Physical & Mechanical Properties

Thickness (mm):	1.50 ±0.1	Parallelism (arcmin):	<5
Clear Aperture (%):	90.00		

Optical Properties

Substrate:	B270		
Coating:	Non-Reflective ND	Surface Quality:	60-40
Surface Accuracy:	2λ		

Technical Information

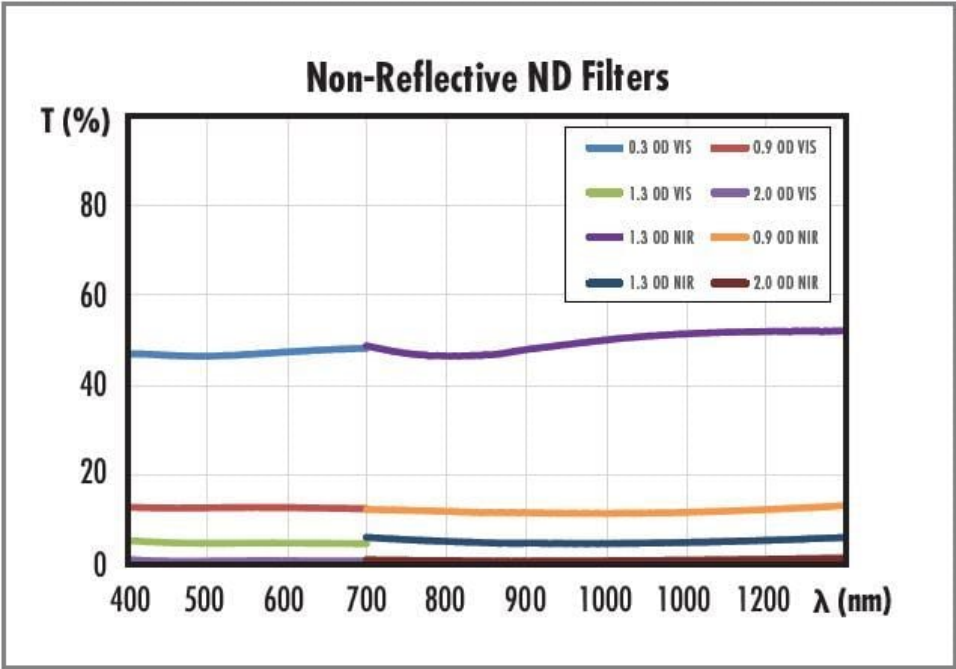

Products

Dia. (mm)	Optical Density OD (Average)	Thickness (mm)	Transmission (%)	Wavelength Range (nm)	Stock Number	Price	Buy
12.50	0.3	1.50	50.00	700 - 1200	#63-396	S\$179.20 Volume Pricing	Contact Us
25.00	0.3	1.50	50.00	700 - 1200	#63-406	S\$231.00 Volume Pricing	20+ In Stock
12.50	0.3	1.50	50.00	400 - 700	#63-376	S\$179.20 Volume Pricing	Contact Us
25.00	0.3	1.50	50.00	400 - 700	#63-386	S\$231.00 Volume Pricing	20+ In Stock
12.50	0.5	1.50	32.00	700 - 1200	#63-397	S\$179.20 Volume Pricing	20+ In Stock
25.00	0.5	1.50	32.00	700 - 1200	#63-407	S\$231.00 Volume Pricing	20+ In Stock
12.50	0.5	1.50	32.00	400 - 700	#63-377	S\$179.20 Volume Pricing	Contact Us
25.00	0.5	1.50	32.00	400 - 700	#63-387	S\$231.00 Volume Pricing	20+ In Stock
12.50	0.6	1.50	25.00	700 - 1200	#63-398	S\$179.20 Volume Pricing	Contact Us
25.00	0.6	1.50	25.00	700 - 1200	#63-408	S\$231.00 Volume Pricing	17 In Stock
12.50	0.6	1.50	25.00	400 - 700	#63-378	S\$179.20 Volume Pricing	Contact Us
25.00	0.6	1.50	25.00	400 - 700	#63-388	S\$231.00 Volume Pricing	16 In Stock
12.50	0.9	1.50	12.50	700 - 1200	#63-399	S\$179.20 Volume Pricing	Contact Us
25.00	0.9	1.50	12.50	700 - 1200	#63-409	S\$231.00 Volume Pricing	14 In Stock
12.50	0.9	1.50	12.50	400 - 700	#63-379	S\$179.20 Volume Pricing	20+ In Stock
25.00	0.9	1.50	12.50	400 - 700	#63-389	S\$231.00 Volume Pricing	15 In Stock
12.50	1.0	1.50	10.00	700 - 1200	#63-400	S\$179.20 Volume Pricing	20+ In Stock

25.00	1.0	1.50	10.00	700 - 1200	#63-410	S\$231.00 Volume Pricing	20+ In Stock
12.50	1.0	1.50	10.00	400 - 700	#63-380	S\$179.20 Volume Pricing	20+ In Stock
25.00	1.0	1.50	10.00	400 - 700	#63-390	S\$231.00 Volume Pricing	Contact Us
12.50	1.3	1.50	5.00	700 - 1200	#63-401	S\$179.20 Volume Pricing	10 In Stock
25.00	1.3	1.50	5.00	700 - 1200	#63-411	S\$231.00 Volume Pricing	20+ In Stock
12.50	1.3	1.50	5.00	400 - 700	#63-381	S\$179.20 Volume Pricing	3 In Stock
25.00	1.3	1.50	5.00	400 - 700	#63-391	S\$231.00 Volume Pricing	20+ In Stock
12.50	1.5	1.50	3.20	700 - 1200	#63-402	S\$179.20 Volume Pricing	Contact Us
25.00	1.5	1.50	3.20	700 - 1200	#63-412	S\$231.00 Volume Pricing	20+ In Stock
12.50	1.5	1.50	3.20	400 - 700	#63-382	S\$179.20 Volume Pricing	20+ In Stock
25.00	1.5	1.50	3.20	400 - 700	#63-392	S\$231.00 Volume Pricing	20+ In Stock
12.50	2.0	1.50	1.00	700 - 1200	#63-403	S\$179.20 Volume Pricing	Contact Us
25.00	2.0	1.50	1.00	700 - 1200	#63-413	S\$231.00 Volume Pricing	20+ In Stock
12.50	2.0	1.50	1.00	400 - 700	#63-383	S\$179.20 Volume Pricing	Contact Us
25.00	2.0	1.50	1.00	400 - 700	#63-393	S\$231.00 Volume Pricing	20+ In Stock
12.50	2.5	1.50	0.30	700 - 1200	#63-404	S\$179.20 Volume Pricing	20+ In Stock
25.00	2.5	1.50	0.30	700 - 1200	#63-414	S\$231.00 Volume Pricing	20+ In Stock
12.50	2.5	1.50	0.30	400 - 700	#63-384	S\$179.20 Volume Pricing	20+ In Stock
25.00	2.5	1.50	0.30	400 - 700	#63-394	S\$231.00 Volume Pricing	6 In Stock
12.50	3.0	1.50	0.10	700 - 1200	#63-405	S\$179.20 Volume Pricing	17 In Stock
25.00	3.0	1.50	0.10	700 - 1200	#63-415	S\$231.00 Volume Pricing	14 In Stock

12.50	3.0	1.50	0.10	400 - 700	#63-385	S\$179.20 Volume Pricing	20+ In Stock
25.00	3.0	1.50	0.10	400 - 700	#63-395	S\$231.00 Volume Pricing	20+ In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com