

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Focusing \(Concave\) Mirrors](#)

Precision Ellipsoidal Reflectors



- Precision Polished Substrate
- Protected Aluminum and Cold Mirror Coating Options
- Ideal for Solar and Condensing Applications
- [Precision Parabolic Reflectors](#) Also Available


Common Specifications

Optical Properties

Substrate: [BOROFLOAT®](#)

Coating Type: Metal

Technical Information

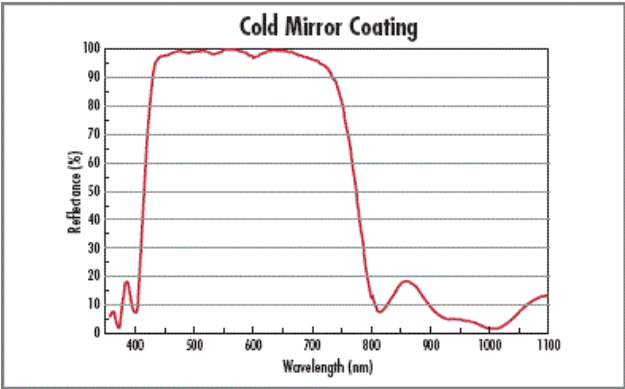

Products

Coating	Center Hole Diameter (mm)	Outer Diameter (mm)	Distance to Focal Point f_1 (mm)	Distance to Focal Point f_2 (mm)	Stock Number	Price	Buy
Protected Aluminum (400-700nm)	18.0	64.00	11	78	#90-968	S\$372.40 Volume Pricing	1 In Stock
Protected Aluminum (400-700nm)	20.0	86.00	14	134	#68-797	S\$555.80 Volume Pricing	2 In Stock
Protected Aluminum (400-700nm)	27.0	105.00	22	145	#90-969	S\$581.00 Volume Pricing	Contact Us
Protected Aluminum (400-700nm)	27.0	113.00	17	272	#68-798	S\$621.60 Volume Pricing	1 In Stock
Protected Aluminum (400-700nm)	31.0	128.00	17.8	294	#90-970	S\$742.00 Volume Pricing	3 In Stock
Protected Aluminum (400-700nm)	40.0	150.00	22.5	360	#90-971	S\$1,064.00 Volume Pricing	1 In Stock
Protected Aluminum (400-700nm)	60.0	220.00	40	440	#68-799	S\$1,330.00 Volume Pricing	Contact Us
Protected Aluminum (400-700nm)	80.0	300.00	45	790	#90-972	S\$1,960.00 Volume Pricing	2 In Stock
Cold Mirror, 0°	18.0	64.00	11	78	#90-973	S\$375.20 Volume Pricing	Contact Us
Cold Mirror, 0°	20.0	88.00	14	134	#68-800	S\$560.00 Volume Pricing	1 In Stock

Cold Mirror, 0°	27.0	105.00	22	145	#90-974	S\$585.20 Volume Pricing	2 In Stock
Cold Mirror, 0°	27.0	113.00	17	272	#68-801	S\$641.20 Volume Pricing	Contact Us
Cold Mirror, 0°	60.0	220.00	40	440	#68-803	S\$1,533.00 Volume Pricing	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com