

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Focusing \(Concave\) Mirrors](#)

Precision Parabolic Reflectors



- Precision Polished Substrate
- Protected Aluminum and Cold Mirror Coating Options
- Ideal for Highly Divergent Light Sources
- [Precision Ellipsoidal Reflectors](#) Also Available


Common Specifications

Optical Properties

Substrate: [BOROFLOAT®](#)

Coating Type: Metal

Technical Information

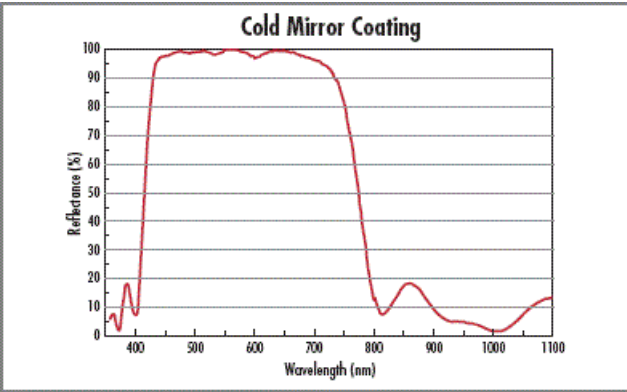

Products

Dia. (mm)	FL (mm)	Aperture (f/#)	Coating	Stock Number	Price	Buy
100.00	12.50	0.125	Protected Aluminum (400-700nm)	#90-964	S\$552.60 Volume Pricing	2 In Stock
100.00	19.00	0.190	Protected Aluminum (400-700nm)	#68-791	S\$552.60 Volume Pricing	3 In Stock
152.00	17.00	0.112	Protected Aluminum (400-700nm)	#68-792	S\$1,179.87 Volume Pricing	1 In Stock
152.00	30.00	0.197	Protected Aluminum (400-700nm)	#90-965	S\$1,045.45 Volume Pricing	Contact Us
220.00	100.00	0.455	Protected Aluminum (400-700nm)	#68-793	S\$1,299.35 Volume Pricing	2 In Stock
300.00	42.00	0.140	Protected Aluminum (400-700nm)	#90-966	S\$2,165.58 Volume Pricing	1 In Stock
100.00	12.50	0.125	Cold Mirror, 0°	#90-967	S\$754.22 Volume Pricing	Contact Us
100.00	19.00	0.190	Cold Mirror, 0°	#68-795	S\$754.22 Volume Pricing	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com