


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [UV Lenses](#)

TECHSPEC® Laser Grade Plano-Convex (PCX) Lenses

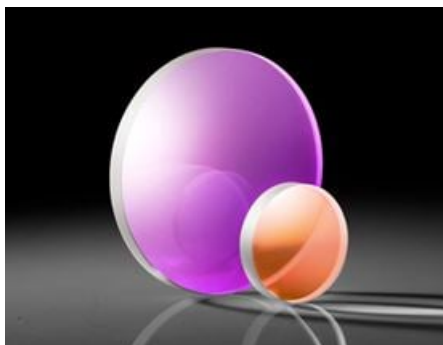

- Guaranteed Laser Damage Threshold
- 10-5 Surface Quality
- $\lambda/10$ Surface Accuracy

Common Specifications

Physical & Mechanical Properties




Bevel: Protective as needed

Optical Properties


Substrate: [Fused Silica](#) (Corning 7980)

Power (P-V) @ 632.8nm: λ

Technical Information

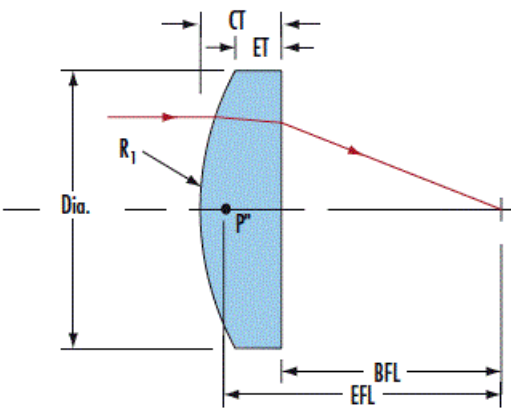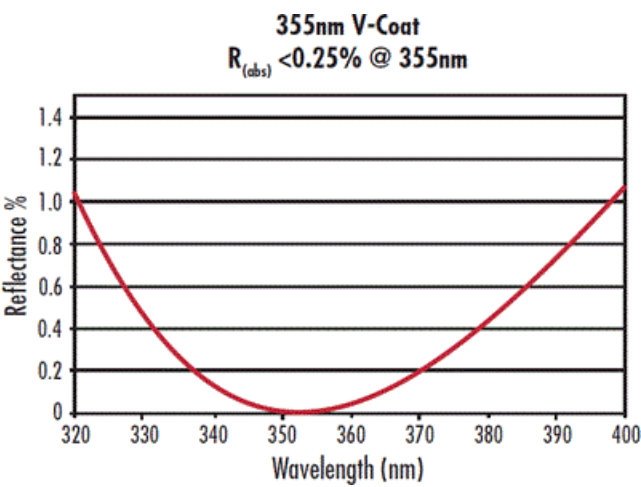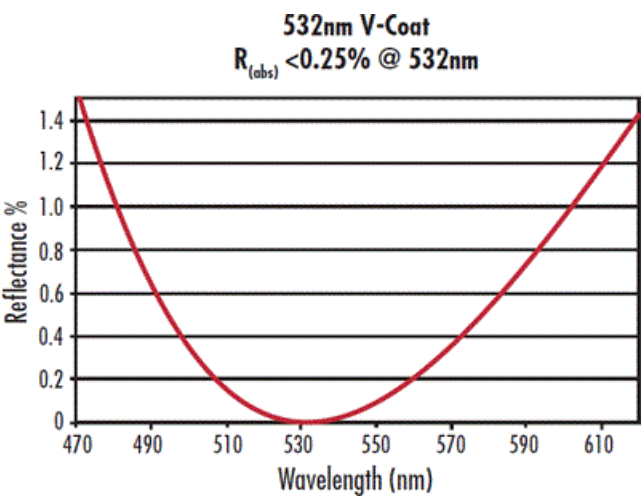

1064nm V-Coat
 $R_{(abs)} < 0.25\%$ @ 1064nm

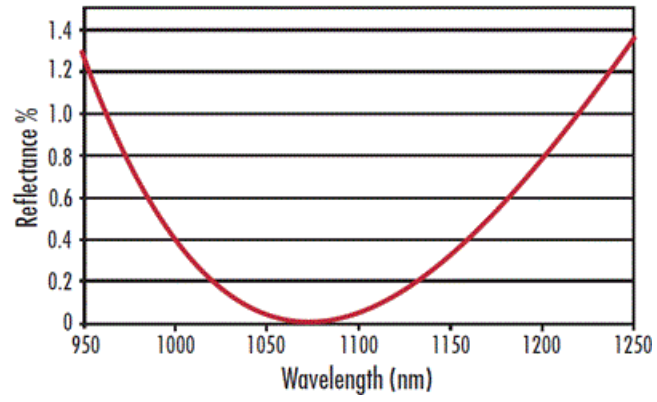

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
6.00	12.00	10.63	Uncoated	Fused Silica	#87-924	S\$211.40 Volume Pricing	20+ In Stock
6.00	12.00	10.63	Laser V-Coat (266nm)	Fused Silica	#87-928	S\$264.60 Volume Pricing	11 In Stock
6.00	12.00	10.63	Laser V-Coat (355nm)	Fused Silica	#87-932	S\$264.60 Volume Pricing	7 In Stock
6.00	12.00	10.63	Laser V-Coat (532nm)	Fused Silica	#87-936	S\$264.60 Volume Pricing	20+ In Stock
6.00	12.00	10.63	Laser V-Coat (1064nm)	Fused Silica	#87-940	S\$264.60 Volume Pricing	20+ In Stock
6.00	18.00	16.62	Uncoated	Fused Silica	#87-925	S\$211.40 Volume Pricing	20+ In Stock
6.00	18.00	16.62	Laser V-Coat (266nm)	Fused Silica	#87-929	S\$264.60 Volume Pricing	11 In Stock
6.00	18.00	16.62	Laser V-Coat (355nm)	Fused Silica	#87-933	S\$264.60 Volume Pricing	13 In Stock
6.00	18.00	16.62	Laser V-Coat (532nm)	Fused Silica	#87-937	S\$264.60 Volume Pricing	13 In Stock
6.00	18.00	16.62	Laser V-Coat (1064nm)	Fused Silica	#87-941	S\$264.60 Volume Pricing	5 In Stock
6.00	24.00	22.63	Uncoated	Fused Silica	#87-926	S\$211.40 Volume Pricing	20+ In Stock
6.00	24.00	22.63	Laser V-Coat (266nm)	Fused Silica	#87-930	S\$264.60 Volume Pricing	14 In Stock
6.00	24.00	22.63	Laser V-Coat (355nm)	Fused Silica	#87-934	S\$264.60 Volume Pricing	13 In Stock

6.00	24.00	22.63	Laser V-Coat (532nm)	Fused Silica	#87-938	S\$264.60 Volume Pricing	12 In Stock
6.00	24.00	22.63	Laser V-Coat (1064nm)	Fused Silica	#87-942	S\$264.60 Volume Pricing	5 In Stock
12.00	18.00	15.23	Uncoated	Fused Silica	#67-090	S\$226.80 Volume Pricing	5 In Stock
12.00	18.00	15.23	Laser V-Coat (266nm)	Fused Silica	#67-939	S\$291.20 Volume Pricing	6 In Stock
12.00	18.00	15.23	Laser V-Coat (355nm)	Fused Silica	#67-949	S\$291.20 Volume Pricing	7 In Stock
12.00	18.00	15.23	Laser V-Coat (532nm)	Fused Silica	#67-959	S\$291.20 Volume Pricing	7 In Stock
12.00	18.00	15.23	Laser V-Coat (1064nm)	Fused Silica	#67-969	S\$291.20 Volume Pricing	20+ In Stock
12.00	25.00	22.31	Uncoated	Fused Silica	#67-091	S\$226.80 Volume Pricing	10 In Stock
12.00	25.00	22.31	Laser V-Coat (266nm)	Fused Silica	#67-940	S\$291.20 Volume Pricing	3 In Stock
12.00	25.00	22.31	Laser V-Coat (355nm)	Fused Silica	#67-950	S\$291.20 Volume Pricing	4 In Stock
12.00	25.00	22.31	Laser V-Coat (532nm)	Fused Silica	#67-960	S\$291.20 Volume Pricing	Contact Us
12.00	25.00	22.31	Laser V-Coat (1064nm)	Fused Silica	#67-970	S\$291.20 Volume Pricing	8 In Stock
12.00	36.00	34.29	Uncoated	Fused Silica	#67-092	S\$226.80 Volume Pricing	20+ In Stock
12.00	36.00	34.29	Laser V-Coat (266nm)	Fused Silica	#67-941	S\$291.20 Volume Pricing	8 In Stock
12.00	36.00	34.29	Laser V-Coat (355nm)	Fused Silica	#67-951	S\$291.20 Volume Pricing	1 In Stock

12.00	36.00	34.29	Laser V-Coat (532nm)	Fused Silica	#67-961	S\$291.20 Volume Pricing	3 In Stock
12.00	36.00	34.29	Laser V-Coat (1064nm)	Fused Silica	#67-971	S\$291.20 Volume Pricing	1 In Stock
12.00	50.00	48.01	Uncoated	Fused Silica	#67-093	S\$226.80 Volume Pricing	20+ In Stock
12.00	50.00	48.01	Laser V-Coat (266nm)	Fused Silica	#67-942	S\$291.20 Volume Pricing	9 In Stock
12.00	50.00	48.01	Laser V-Coat (355nm)	Fused Silica	#67-952	S\$291.20 Volume Pricing	3 In Stock
12.00	50.00	48.01	Laser V-Coat (532nm)	Fused Silica	#67-962	S\$291.20 Volume Pricing	8 In Stock
12.00	50.00	48.01	Laser V-Coat (1064nm)	Fused Silica	#67-972	S\$291.20 Volume Pricing	2 In Stock
12.70	25.00	21.62	Uncoated	Fused Silica	#38-634	S\$226.80 Volume Pricing	20+ In Stock
12.70	25.00	21.62	Laser V-Coat (266nm)	Fused Silica	#38-656	S\$291.20 Volume Pricing	6 In Stock
12.70	25.00	21.62	Laser V-Coat (355nm)	Fused Silica	#38-681	S\$291.20 Volume Pricing	6 In Stock
12.70	25.00	21.62	Laser V-Coat (532nm)	Fused Silica	#38-707	S\$291.20 Volume Pricing	3 In Stock
12.70	25.00	21.62	Laser V-Coat (1064nm)	Fused Silica	#38-733	S\$291.20 Volume Pricing	6 In Stock
12.70	35.00	32.30	Uncoated	Fused Silica	#38-635	S\$226.80 Volume Pricing	4 In Stock
12.70	35.00	32.30	Laser V-Coat (266nm)	Fused Silica	#38-658	S\$291.20 Volume Pricing	7 In Stock
12.70	35.00	32.30	Laser V-Coat (355nm)	Fused Silica	#38-684	S\$291.20 Volume Pricing	5 In Stock

12.70	35.00	32.30	Laser V-Coat (532nm)	Fused Silica	#38-708	S\$291.20 Volume Pricing	13 In Stock
12.70	35.00	32.30	Laser V-Coat (1064nm)	Fused Silica	#38-734	S\$291.20 Volume Pricing	2 In Stock
12.70	50.00	47.30	Uncoated	Fused Silica	#38-636	S\$226.80 Volume Pricing	20+ In Stock
12.70	50.00	47.30	Laser V-Coat (266nm)	Fused Silica	#38-660	S\$291.20 Volume Pricing	5 In Stock
12.70	50.00	47.30	Laser V-Coat (355nm)	Fused Silica	#38-685	S\$291.20 Volume Pricing	3 In Stock
12.70	50.00	47.30	Laser V-Coat (532nm)	Fused Silica	#38-709	S\$291.20 Volume Pricing	20+ In Stock
12.70	50.00	47.30	Laser V-Coat (1064nm)	Fused Silica	#38-735	S\$291.20 Volume Pricing	2 In Stock
12.70	75.00	72.31	Uncoated	Fused Silica	#38-637	S\$226.80 Volume Pricing	17 In Stock
12.70	75.00	72.31	Laser V-Coat (266nm)	Fused Silica	#38-661	S\$291.20 Volume Pricing	4 In Stock
12.70	75.00	72.31	Laser V-Coat (355nm)	Fused Silica	#38-686	S\$291.20 Volume Pricing	1 In Stock
12.70	75.00	72.31	Laser V-Coat (532nm)	Fused Silica	#38-711	S\$291.20 Volume Pricing	2 In Stock
12.70	75.00	72.31	Laser V-Coat (1064nm)	Fused Silica	#38-736	S\$291.20 Volume Pricing	16 In Stock
12.70	100.00	97.32	Uncoated	Fused Silica	#38-638	S\$226.80 Volume Pricing	6 In Stock
12.70	100.00	97.32	Laser V-Coat (266nm)	Fused Silica	#38-662	S\$291.20 Volume Pricing	3 In Stock
12.70	100.00	97.32	Laser V-Coat (355nm)	Fused Silica	#38-687	S\$291.20 Volume Pricing	6 In Stock

12.70	100.00	97.32	Laser V-Coat (532nm)	Fused Silica	#38-712	S\$291.20 Volume Pricing	5 In Stock
12.70	100.00	97.32	Laser V-Coat (1064nm)	Fused Silica	#38-737	S\$291.20 Volume Pricing	5 In Stock
12.70	150.00	147.33	Uncoated	Fused Silica	#38-639	S\$226.80 Volume Pricing	20+ In Stock
12.70	150.00	147.33	Laser V-Coat (266nm)	Fused Silica	#38-665	S\$291.20 Volume Pricing	7 In Stock
12.70	150.00	147.33	Laser V-Coat (355nm)	Fused Silica	#38-688	S\$291.20 Volume Pricing	17 In Stock
12.70	150.00	147.33	Laser V-Coat (532nm)	Fused Silica	#38-715	S\$291.20 Volume Pricing	5 In Stock
12.70	150.00	147.33	Laser V-Coat (1064nm)	Fused Silica	#38-738	S\$291.20 Volume Pricing	3 In Stock
12.70	200.00	197.35	Uncoated	Fused Silica	#38-640	S\$226.80 Volume Pricing	20+ In Stock
12.70	200.00	197.35	Laser V-Coat (266nm)	Fused Silica	#38-666	S\$291.20 Volume Pricing	4 In Stock
12.70	200.00	197.35	Laser V-Coat (355nm)	Fused Silica	#38-689	S\$291.20 Volume Pricing	6 In Stock
12.70	200.00	197.35	Laser V-Coat (532nm)	Fused Silica	#38-716	S\$291.20 Volume Pricing	5 In Stock
12.70	200.00	197.35	Laser V-Coat (1064nm)	Fused Silica	#38-739	S\$291.20 Volume Pricing	11 In Stock
12.70	250.00	247.36	Uncoated	Fused Silica	#38-641	S\$226.80 Volume Pricing	10 In Stock
12.70	250.00	247.36	Laser V-Coat (266nm)	Fused Silica	#38-667	S\$291.20 Volume Pricing	3 In Stock
12.70	250.00	247.36	Laser V-Coat (355nm)	Fused Silica	#38-690	S\$291.20 Volume Pricing	5 In Stock

12.70	250.00	247.36	Laser V-Coat (532nm)	Fused Silica	#38-717	S\$291.20 Volume Pricing	4 In Stock
12.70	250.00	247.36	Laser V-Coat (1064nm)	Fused Silica	#38-740	S\$291.20 Volume Pricing	6 In Stock
12.70	300.00	297.38	Uncoated	Fused Silica	#38-643	S\$226.80 Volume Pricing	20+ In Stock
12.70	300.00	297.38	Laser V-Coat (266nm)	Fused Silica	#38-668	S\$291.20 Volume Pricing	3 In Stock
12.70	300.00	297.38	Laser V-Coat (355nm)	Fused Silica	#38-691	S\$291.20 Volume Pricing	7 In Stock
12.70	300.00	297.38	Laser V-Coat (532nm)	Fused Silica	#38-718	S\$291.20 Volume Pricing	4 In Stock
12.70	300.00	297.38	Laser V-Coat (1064nm)	Fused Silica	#38-741	S\$291.20 Volume Pricing	1 In Stock
12.70	500.00	497.44	Uncoated	Fused Silica	#38-644	S\$226.80 Volume Pricing	20+ In Stock
12.70	500.00	497.44	Laser V-Coat (266nm)	Fused Silica	#38-669	S\$291.20 Volume Pricing	3 In Stock
12.70	500.00	497.44	Laser V-Coat (355nm)	Fused Silica	#38-692	S\$291.20 Volume Pricing	9 In Stock
12.70	500.00	497.44	Laser V-Coat (532nm)	Fused Silica	#38-719	S\$291.20 Volume Pricing	14 In Stock
12.70	500.00	497.44	Laser V-Coat (1064nm)	Fused Silica	#38-742	S\$291.20 Volume Pricing	3 In Stock
12.70	1,000.00	997.59	Uncoated	Fused Silica	#38-645	S\$226.80 Volume Pricing	20+ In Stock
12.70	1,000.00	997.59	Laser V-Coat (266nm)	Fused Silica	#38-670	S\$291.20 Volume Pricing	1 In Stock
12.70	1,000.00	997.59	Laser V-Coat (355nm)	Fused Silica	#38-693	S\$291.20 Volume Pricing	3 In Stock

12.70	1,000.00	997.59	Laser V-Coat (532nm)	Fused Silica	#38-720	S\$291.20 Volume Pricing	8 In Stock
12.70	1,000.00	997.59	Laser V-Coat (1064nm)	Fused Silica	#38-743	S\$291.20 Volume Pricing	5 In Stock
25.00	38.00	33.03	Uncoated	Fused Silica	#67-094	S\$282.80 Volume Pricing	20+ In Stock
25.00	38.00	33.03	Laser V-Coat (266nm)	Fused Silica	#67-943	S\$323.40 Volume Pricing	17 In Stock
25.00	38.00	33.03	Laser V-Coat (355nm)	Fused Silica	#67-953	S\$323.40 Volume Pricing	8 In Stock
25.00	38.00	33.03	Laser V-Coat (532nm)	Fused Silica	#67-963	S\$323.40 Volume Pricing	5 In Stock
25.00	38.00	33.03	Laser V-Coat (1064nm)	Fused Silica	#67-973	S\$323.40 Volume Pricing	2 In Stock
25.00	50.00	46.00	Uncoated	Fused Silica	#67-095	S\$282.80 Volume Pricing	7 In Stock
25.00	50.00	46.00	Laser V-Coat (266nm)	Fused Silica	#67-944	S\$323.40 Volume Pricing	7 In Stock
25.00	50.00	46.00	Laser V-Coat (355nm)	Fused Silica	#67-954	S\$323.40 Volume Pricing	5 In Stock
25.00	50.00	46.00	Laser V-Coat (532nm)	Fused Silica	#67-964	S\$323.40 Volume Pricing	9 In Stock
25.00	50.00	46.00	Laser V-Coat (1064nm)	Fused Silica	#67-974	S\$323.40 Volume Pricing	6 In Stock
25.00	75.00	71.96	Uncoated	Fused Silica	#67-096	S\$282.80 Volume Pricing	13 In Stock
25.00	75.00	71.96	Laser V-Coat (266nm)	Fused Silica	#67-945	S\$323.40 Volume Pricing	Contact Us
25.00	75.00	71.96	Laser V-Coat (355nm)	Fused Silica	#67-955	S\$323.40 Volume Pricing	5 In Stock

25.00	75.00	71.96	Laser V-Coat (532nm)	Fused Silica	#67-965	S\$323.40 Volume Pricing	20+ In Stock
25.00	75.00	71.96	Laser V-Coat (1064nm)	Fused Silica	#67-975	S\$323.40 Volume Pricing	7 In Stock
25.00	100.00	97.40	Uncoated	Fused Silica	#67-097	S\$282.80 Volume Pricing	2 In Stock
25.00	100.00	97.4	Laser V-Coat (266nm)	Fused Silica	#67-946	S\$323.40 Volume Pricing	17 In Stock
25.00	100.00	97.40	Laser V-Coat (355nm)	Fused Silica	#67-956	S\$323.40 Volume Pricing	5 In Stock
25.00	100.00	97.40	Laser V-Coat (532nm)	Fused Silica	#67-966	S\$323.40 Volume Pricing	10 In Stock
25.00	100.00	97.40	Laser V-Coat (1064nm)	Fused Silica	#67-976	S\$323.40 Volume Pricing	9 In Stock
25.00	150.00	147.82	Uncoated	Fused Silica	#67-098	S\$282.80 Volume Pricing	14 In Stock
25.00	150.00	147.86	Laser V-Coat (266nm)	Fused Silica	#67-947	S\$323.40 Volume Pricing	3 In Stock
25.00	150.00	147.82	Laser V-Coat (355nm)	Fused Silica	#67-957	S\$323.40 Volume Pricing	20+ In Stock
25.00	150.00	147.82	Laser V-Coat (532nm)	Fused Silica	#67-967	S\$323.40 Volume Pricing	Contact Us
25.00	150.00	147.82	Laser V-Coat (1064nm)	Fused Silica	#67-977	S\$323.40 Volume Pricing	Contact Us
25.00	250.00	248.14	Uncoated	Fused Silica	#67-099	S\$282.80 Volume Pricing	1 In Stock
25.00	250.00	248.14	Laser V-Coat (266nm)	Fused Silica	#67-948	S\$323.40 Volume Pricing	15 In Stock
25.00	250.00	248.14	Laser V-Coat (355nm)	Fused Silica	#67-958	S\$323.40 Volume Pricing	6 In Stock

25.00	250.00	248.14	Laser V-Coat (532nm)	Fused Silica	#67-968	S\$323.40 Volume Pricing	5 In Stock
25.00	250.00	248.14	Laser V-Coat (1064nm)	Fused Silica	#67-978	S\$323.40 Volume Pricing	6 In Stock
25.40	35.00	28.55	Uncoated	Fused Silica	#38-624	S\$282.80 Volume Pricing	9 In Stock
25.40	35.00	28.55	Laser V-Coat (266nm)	Fused Silica	#38-646	S\$323.40 Volume Pricing	7 In Stock
25.40	35.00	28.55	Laser V-Coat (355nm)	Fused Silica	#38-671	S\$323.40 Volume Pricing	16 In Stock
25.40	35.00	28.55	Laser V-Coat (532nm)	Fused Silica	#38-694	S\$323.40 Volume Pricing	1 In Stock
25.40	35.00	28.55	Laser V-Coat (1064nm)	Fused Silica	#38-721	S\$323.40 Volume Pricing	2 In Stock
25.40	50.00	45.71	Uncoated	Fused Silica	#38-625	S\$282.80 Volume Pricing	12 In Stock
25.40	50.00	45.71	Laser V-Coat (266nm)	Fused Silica	#38-647	S\$323.40 Volume Pricing	3 In Stock
25.40	50.00	45.71	Laser V-Coat (355nm)	Fused Silica	#38-672	S\$323.40 Volume Pricing	5 In Stock
25.40	50.00	45.71	Laser V-Coat (532nm)	Fused Silica	#38-695	S\$323.40 Volume Pricing	7 In Stock
25.40	50.00	45.71	Laser V-Coat (1064nm)	Fused Silica	#38-722	S\$323.40 Volume Pricing	Contact Us
25.40	75.00	71.63	Uncoated	Fused Silica	#38-626	S\$282.80 Volume Pricing	15 In Stock
25.40	75.00	71.63	Laser V-Coat (266nm)	Fused Silica	#38-648	S\$323.40 Volume Pricing	5 In Stock
25.40	75.00	71.63	Laser V-Coat (355nm)	Fused Silica	#38-673	S\$323.40 Volume Pricing	4 In Stock

25.40	75.00	71.63	Laser V-Coat (532nm)	Fused Silica	#38-699	S\$323.40 Volume Pricing	4 In Stock
25.40	75.00	71.63	Laser V-Coat (1064nm)	Fused Silica	#38-723	S\$323.40 Volume Pricing	2 In Stock
25.40	100.00	97.32	Uncoated	Fused Silica	#38-627	S\$282.80 Volume Pricing	20+ In Stock
25.40	100.00	97.32	Laser V-Coat (266nm)	Fused Silica	#38-649	S\$323.40 Volume Pricing	5 In Stock
25.40	100.00	97.32	Laser V-Coat (355nm)	Fused Silica	#38-674	S\$323.40 Volume Pricing	10 In Stock
25.40	100.00	97.32	Laser V-Coat (532nm)	Fused Silica	#38-700	S\$323.40 Volume Pricing	2 In Stock
25.40	100.00	97.32	Laser V-Coat (1064nm)	Fused Silica	#38-724	S\$323.40 Volume Pricing	13 In Stock
25.40	150.00	147.33	Uncoated	Fused Silica	#38-628	S\$282.80 Volume Pricing	16 In Stock
25.40	150.00	147.33	Laser V-Coat (266nm)	Fused Silica	#38-650	S\$323.40 Volume Pricing	3 In Stock
25.40	150.00	147.33	Laser V-Coat (355nm)	Fused Silica	#38-675	S\$323.40 Volume Pricing	11 In Stock
25.40	150.00	147.33	Laser V-Coat (532nm)	Fused Silica	#38-701	S\$323.40 Volume Pricing	3 In Stock
25.40	150.00	147.33	Laser V-Coat (1064nm)	Fused Silica	#38-725	S\$323.40 Volume Pricing	4 In Stock
25.40	200.00	197.35	Uncoated	Fused Silica	#38-629	S\$282.80 Volume Pricing	20+ In Stock
25.40	200.00	197.35	Laser V-Coat (266nm)	Fused Silica	#38-651	S\$323.40 Volume Pricing	4 In Stock
25.40	200.00	197.35	Laser V-Coat (355nm)	Fused Silica	#38-676	S\$323.40 Volume Pricing	8 In Stock

25.40	200.00	197.35	Laser V-Coat (532nm)	Fused Silica	#38-702	S\$323.40 Volume Pricing	10 In Stock
25.40	200.00	197.35	Laser V-Coat (1064nm)	Fused Silica	#38-726	S\$323.40 Volume Pricing	Contact Us
25.40	250.00	247.36	Uncoated	Fused Silica	#38-630	S\$282.80 Volume Pricing	20+ In Stock
25.40	250.00	247.36	Laser V-Coat (266nm)	Fused Silica	#38-652	S\$323.40 Volume Pricing	8 In Stock
25.40	250.00	247.36	Laser V-Coat (355nm)	Fused Silica	#38-677	S\$323.40 Volume Pricing	7 In Stock
25.40	250.00	247.36	Laser V-Coat (532nm)	Fused Silica	#38-703	S\$323.40 Volume Pricing	7 In Stock
25.40	250.00	247.36	Laser V-Coat (1064nm)	Fused Silica	#38-727	S\$323.40 Volume Pricing	Contact Us
25.40	300.00	297.38	Uncoated	Fused Silica	#38-631	S\$282.80 Volume Pricing	20+ In Stock
25.40	300.00	297.38	Laser V-Coat (266nm)	Fused Silica	#38-653	S\$323.40 Volume Pricing	10 In Stock
25.40	300.00	297.38	Laser V-Coat (355nm)	Fused Silica	#38-678	S\$323.40 Volume Pricing	4 In Stock
25.40	300.00	297.38	Laser V-Coat (532nm)	Fused Silica	#38-704	S\$323.40 Volume Pricing	5 In Stock
25.40	300.00	297.38	Laser V-Coat (1064nm)	Fused Silica	#38-729	S\$323.40 Volume Pricing	4 In Stock
25.40	500.00	497.44	Uncoated	Fused Silica	#38-632	S\$282.80 Volume Pricing	13 In Stock
25.40	500.00	497.44	Laser V-Coat (266nm)	Fused Silica	#38-654	S\$323.40 Volume Pricing	6 In Stock
25.40	500.00	497.44	Laser V-Coat (355nm)	Fused Silica	#38-679	S\$323.40 Volume Pricing	Contact Us

25.40	500.00	497.44	Laser V-Coat (532nm)	Fused Silica	#38-705	S\$323.40 Volume Pricing	1 In Stock
25.40	500.00	497.44	Laser V-Coat (1064nm)	Fused Silica	#38-731	S\$323.40 Volume Pricing	5 In Stock
25.40	1,000.00	997.59	Uncoated	Fused Silica	#38-633	S\$282.80 Volume Pricing	20+ In Stock
25.40	1,000.00	997.59	Laser V-Coat (266nm)	Fused Silica	#38-655	S\$323.40 Volume Pricing	2 In Stock
25.40	1,000.00	997.59	Laser V-Coat (355nm)	Fused Silica	#38-680	S\$323.40 Volume Pricing	3 In Stock
25.40	1,000.00	997.59	Laser V-Coat (532nm)	Fused Silica	#38-706	S\$323.40 Volume Pricing	11 In Stock
25.40	1,000.00	997.59	Laser V-Coat (1064nm)	Fused Silica	#38-732	S\$323.40 Volume Pricing	7 In Stock
50.80	100.00	91.773	Uncoated	Fused Silica	#70-003	S\$567.00 Volume Pricing	20+ In Stock
50.80	150.00	143.144	Uncoated	Fused Silica	#70-004	S\$569.80 Volume Pricing	20+ In Stock
50.80	200.00	194.515	Uncoated	Fused Silica	#70-005	S\$569.80 Volume Pricing	2 In Stock
50.80	250.00	244.514	Uncoated	Fused Silica	#70-006	S\$569.80 Volume Pricing	20+ In Stock
50.80	300.00	294.516	Uncoated	Fused Silica	#70-007	S\$569.80 Volume Pricing	15 In Stock
50.80	100.00	91.773	Laser V-Coat (266nm)	Fused Silica	#70-013	S\$613.20 Volume Pricing	4 In Stock
50.80	150.00	143.144	Laser V-Coat (266nm)	Fused Silica	#70-014	S\$613.20 Volume Pricing	4 In Stock
50.80	250.00	244.514	Laser V-Coat (266nm)	Fused Silica	#70-016	S\$613.20 Volume Pricing	5 In Stock

50.80	300.00	294.516	Laser V-Coat (266nm)	Fused Silica	#70-017	S\$613.20 Volume Pricing	9 In Stock
50.80	100.00	91.773	Laser V-Coat (355nm)	Fused Silica	#70-023	S\$613.20 Volume Pricing	5 In Stock
50.80	150.00	143.144	Laser V-Coat (355nm)	Fused Silica	#70-024	S\$613.20 Volume Pricing	5 In Stock
50.80	200.00	194.515	Laser V-Coat (355nm)	Fused Silica	#70-025	S\$613.20 Volume Pricing	5 In Stock
50.80	250.00	244.514	Laser V-Coat (355nm)	Fused Silica	#70-026	S\$613.20 Volume Pricing	5 In Stock
50.80	300.00	294.516	Laser V-Coat (355nm)	Fused Silica	#70-027	S\$613.20 Volume Pricing	5 In Stock
50.80	100.00	91.773	Laser V-Coat (532nm)	Fused Silica	#70-033	S\$613.20 Volume Pricing	2 In Stock
50.80	150.00	143.144	Laser V-Coat (532nm)	Fused Silica	#70-034	S\$613.20 Volume Pricing	1 In Stock
50.80	200.00	194.515	Laser V-Coat (532nm)	Fused Silica	#70-035	S\$613.20 Volume Pricing	13 In Stock
50.80	250.00	244.514	Laser V-Coat (532nm)	Fused Silica	#70-036	S\$613.20 Volume Pricing	1 In Stock
50.80	300.00	294.516	Laser V-Coat (532nm)	Fused Silica	#70-037	S\$613.20 Volume Pricing	7 In Stock
50.80	100.00	91.773	Laser V-Coat (1064nm)	Fused Silica	#70-043	S\$613.20 Volume Pricing	2 In Stock
50.80	150.00	143.144	Laser V-Coat (1064nm)	Fused Silica	#70-044	S\$613.20 Volume Pricing	7 In Stock
50.80	200.00	194.515	Laser V-Coat (1064nm)	Fused Silica	#70-045	S\$613.20 Volume Pricing	1 In Stock

50.80	250.00	244.514	Laser V-Coat (1064nm)	Fused Silica	#70-046	S\$613.20 Volume Pricing	5 In Stock
50.80	300.00	294.516	Laser V-Coat (1064nm)	Fused Silica	#70-047	S\$613.20 Volume Pricing	5 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com