


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)

TECHSPEC® Zinc Sulfide Multispectral Windows

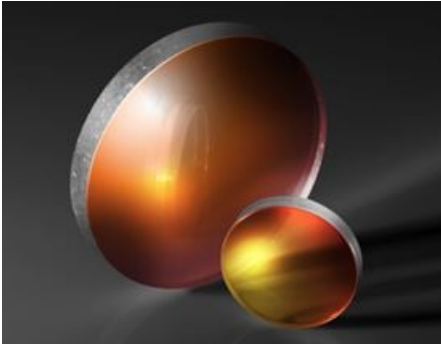


- Multispectral Grade Zinc Sulfide Substrate
- Low Absorption and Low Scatter from 0.4 - 12μm
- Available Uncoated or 3 - 12μm Broadband AR Coated Option



Common Specifications

Physical & Mechanical Properties			
Bevel:	Protective as needed	Clear Aperture (%):	90.00
Edges:	Fine Ground	Knoop Hardness (kg/mm ²):	210.00
Parallelism (arcmin):	<1	Poisson's Ratio:	0.27
Young's Modulus (GPa):	74.5		
Optical Properties			
Index of Refraction (n _d):	2.371		
Substrate:	Zinc Sulfide Multispectral	Surface Flatness (P-V):	λ/10 @ 10.6μm
Surface Quality:	60-40		
Material Properties			
Coefficient of Thermal Expansion CTE (10 ⁻⁶ /°C):		6.8	
Density (g/cm ³):		4.08	

Technical Information

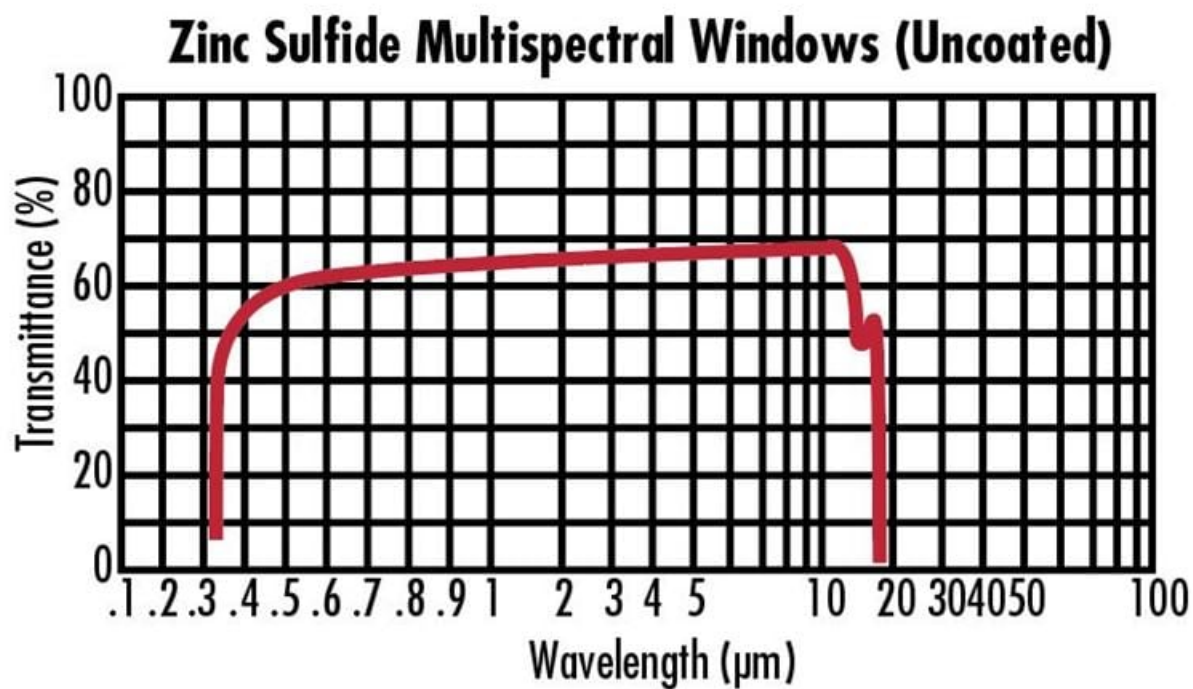

Products

Dia. (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
12.50	2.00	BBAR (3000-12000nm)	#64-144	S\$449.54 Volume Pricing	3 In Stock
25.00	3.00	BBAR (3000-12000nm)	#64-145	S\$637.72 Volume Pricing	20+ In Stock
40.00	4.00	BBAR (3000-12000nm)	#64-146	S\$978.24 Volume Pricing	Contact Us
50.00	3.00	BBAR (3000-12000nm)	#64-147	S\$1,276.94 Volume Pricing	Contact Us
12.50	2.00	Uncoated	#66-200	S\$295.71 Volume Pricing	17 In Stock
25.00	3.00	Uncoated	#66-201	S\$430.13 Volume Pricing	Contact Us
25.40	3.00	Uncoated	#19-653	S\$430.13 Volume Pricing	Contact Us
40.00	4.00	Uncoated	#66-202	S\$734.80 Volume Pricing	Contact Us
50.00	3.00	Uncoated	#66-203	S\$978.24 Volume Pricing	12 In Stock
50.80	3.00	Uncoated	#19-655	S\$978.24 Volume Pricing	10 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com