

[All Products](#) / [Laser Optics](#) / [Laser Lenses](#) / [Plano-Convex \(PCX\) Laser Lenses](#)

**TECHSPEC®**

## 785nm Laser Line Coated Plano-Convex (PCX) Lenses



- <0.25% Reflection at 785nm
- BBAR Coating Options Also Available: [uncoated](#), [MgF<sub>2</sub>](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#)
- [405nm](#), [532nm](#), [633nm](#), 785nm, [980nm](#), [1064nm](#), and [1550nm](#) V-Coated Options Offered

### Common Specifications

#### Physical & Mechanical Properties


Bevel: Protective as needed

#### Optical Properties

Coating: Laser V-Coat (785nm)

|                               |       |                              |                                   |
|-------------------------------|-------|------------------------------|-----------------------------------|
| Surface Quality:              | 40-20 | Power (P-V) @ 632.8nm:       | 1.5λ                              |
| Irregularity (P-V) @ 632.8nm: | λ/4   | Focal Length Tolerance (%):  | ±1                                |
| Design Wavelength DWL (nm):   | 785   | Damage Threshold, By Design: | 5 J/cm <sup>2</sup> @ 785nm, 10ns |

Technical Information

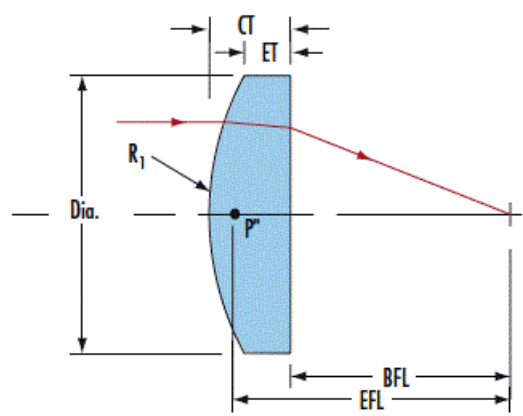

## Products

| Dia.<br>(mm) | EFL<br>(mm) | BFL<br>(mm) | Coating                 | Substrate              | Stock<br>Number         | Price                                      | Buy         |
|--------------|-------------|-------------|-------------------------|------------------------|-------------------------|--------------------------------------------|-------------|
| 5.00         | 7.50        | 6.43        | Laser V-Coat<br>(785nm) | <a href="#">N-SF11</a> | <a href="#">#89-014</a> | S\$81.39<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 5.00         | 10.00       | 8.92        | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-015</a> | S\$81.39<br><a href="#">Volume Pricing</a> | Contact Us  |
| 5.00         | 12.00       | 10.83       | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-016</a> | S\$81.39<br><a href="#">Volume Pricing</a> | 5 In Stock  |
| 5.00         | 15.00       | 13.94       | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-017</a> | S\$81.39<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 5.00         | 20.00       | 19.02       | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-018</a> | S\$81.39<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 5.00         | 25.00       | 23.95       | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-019</a> | S\$81.39<br><a href="#">Volume Pricing</a> | 7 In Stock  |
| 5.00         | 30.00       | 28.95       | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-020</a> | S\$81.39<br><a href="#">Volume Pricing</a> | 8 In Stock  |
| 6.00         | 6.00        | 4.60        | Laser V-Coat<br>(785nm) | <a href="#">N-SF11</a> | <a href="#">#65-509</a> | S\$70.19<br><a href="#">Volume Pricing</a> | 5 In Stock  |
| 6.00         | 7.50        | 6.1         | Laser V-Coat<br>(785nm) | <a href="#">N-SF11</a> | <a href="#">#69-465</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 5 In Stock  |
| 6.00         | 9.00        | 7.95        | Laser V-Coat<br>(785nm) | <a href="#">N-SF5</a>  | <a href="#">#66-263</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 8 In Stock  |
| 6.00         | 12.00       | 10.94       | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-510</a> | S\$67.21<br><a href="#">Volume Pricing</a> | 9 In Stock  |
| 6.00         | 15.00       | 13.68       | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-466</a> | S\$67.21<br><a href="#">Volume Pricing</a> | 17 In Stock |

|      |       |       |                      |                        |                         |                                            |              |
|------|-------|-------|----------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 6.00 | 18.00 | 17.07 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-511</a> | S\$67.95<br><a href="#">Volume Pricing</a> | 14 In Stock  |
| 6.00 | 21.00 | 20.06 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-467</a> | S\$67.95<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 6.00 | 24.00 | 23.01 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-512</a> | S\$67.95<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 6.00 | 30.00 | 29.14 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-513</a> | S\$67.21<br><a href="#">Volume Pricing</a> | 17 In Stock  |
| 6.00 | 36.00 | 34.95 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-468</a> | S\$67.95<br><a href="#">Volume Pricing</a> | Contact Us   |
| 6.00 | 48.00 | 46.96 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-469</a> | S\$67.95<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 6.00 | 60.00 | 58.96 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-470</a> | S\$67.95<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 6.00 | 72.00 | 70.97 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-471</a> | S\$67.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 9.00 | 9.00  | 7.32  | Laser V-Coat (785nm) | <a href="#">N-SF11</a> | <a href="#">#65-514</a> | S\$70.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 9.00 | 13.50 | 11.94 | Laser V-Coat (785nm) | <a href="#">N-SF5</a>  | <a href="#">#66-264</a> | S\$70.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 9.00 | 12.00 | 10.60 | Laser V-Coat (785nm) | <a href="#">N-SF11</a> | <a href="#">#69-472</a> | S\$70.95<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 9.00 | 15.00 | 13.02 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-473</a> | S\$70.95<br><a href="#">Volume Pricing</a> | 12 In Stock  |
| 9.00 | 18.00 | 16.41 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-515</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 9.00 | 22.00 | 20.73 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-474</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 11 In Stock  |

|       |       |       |                      |                        |                         |                                            |              |
|-------|-------|-------|----------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 9.00  | 27.00 | 25.34 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-516</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 9.00  | 36.00 | 34.48 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-517</a> | S\$69.44<br><a href="#">Volume Pricing</a> | Contact Us   |
| 9.00  | 45.00 | 43.98 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-518</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 9.00  | 54.00 | 52.69 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-475</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 11 In Stock  |
| 9.00  | 72.00 | 70.68 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-476</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 9.00  | 90.00 | 88.68 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-477</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 10.00 | 10.00 | 8.18  | Laser V-Coat (785nm) | <a href="#">N-SF11</a> | <a href="#">#69-478</a> | S\$70.95<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 10.00 | 15.00 | 13.32 | Laser V-Coat (785nm) | <a href="#">N-SF11</a> | <a href="#">#69-479</a> | S\$70.95<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 10.00 | 20.00 | 18.03 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-480</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 14 In Stock  |
| 10.00 | 25.00 | 23.02 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-481</a> | S\$69.44<br><a href="#">Volume Pricing</a> | Contact Us   |
| 10.00 | 30.00 | 28.01 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-482</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 10.00 | 40.00 | 38.02 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-483</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 14 In Stock  |
| 10.00 | 50.00 | 48.02 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-484</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 14 In Stock  |
| 10.00 | 75.00 | 73.02 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-485</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 5 In Stock   |

|       |        |       |                      |                        |                         |                                            |              |
|-------|--------|-------|----------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 10.00 | 100.00 | 98.02 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-486</a> | S\$69.44<br><a href="#">Volume Pricing</a> | 15 In Stock  |
| 12.00 | 12.00  | 9.76  | Laser V-Coat (785nm) | <a href="#">N-SF11</a> | <a href="#">#65-519</a> | S\$73.92<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 12.00 | 15.00  | 12.03 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-487</a> | S\$73.92<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 18.00  | 16.22 | Laser V-Coat (785nm) | <a href="#">N-SF5</a>  | <a href="#">#66-265</a> | S\$73.92<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 12.00 | 20.00  | 17.69 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-488</a> | S\$73.92<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.00 | 24.00  | 22.15 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-520</a> | S\$72.44<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 30.00  | 28.02 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-489</a> | S\$72.44<br><a href="#">Volume Pricing</a> | Contact Us   |
| 12.00 | 42.00  | 40.22 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-490</a> | S\$72.44<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 12.00 | 48.00  | 46.36 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-522</a> | S\$72.44<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.00 | 60.00  | 58.37 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#65-523</a> | S\$72.44<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 12.00 | 54.00  | 52.02 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-491</a> | S\$72.44<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 12.00 | 72.00  | 70.42 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-492</a> | S\$72.44<br><a href="#">Volume Pricing</a> | Contact Us   |
| 12.00 | 84.00  | 82.39 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-493</a> | S\$72.44<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 12.00 | 100.00 | 98.25 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-494</a> | S\$72.44<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|       |        |        |                         |                        |                         |                                            |              |
|-------|--------|--------|-------------------------|------------------------|-------------------------|--------------------------------------------|--------------|
| 15.00 | 15.00  | 11.71  | Laser V-Coat<br>(785nm) | <a href="#">N-SF5</a>  | <a href="#">#87-609</a> | S\$76.17<br><a href="#">Volume Pricing</a> | 17 In Stock  |
| 15.00 | 18.00  | 15.61  | Laser V-Coat<br>(785nm) | <a href="#">N-SF5</a>  | <a href="#">#87-610</a> | S\$76.17<br><a href="#">Volume Pricing</a> | 16 In Stock  |
| 15.00 | 20.00  | 17.74  | Laser V-Coat<br>(785nm) | <a href="#">N-SF5</a>  | <a href="#">#87-611</a> | S\$76.17<br><a href="#">Volume Pricing</a> | 16 In Stock  |
| 15.00 | 22.50  | 20.50  | Laser V-Coat<br>(785nm) | <a href="#">N-SF5</a>  | <a href="#">#87-612</a> | S\$76.17<br><a href="#">Volume Pricing</a> | 12 In Stock  |
| 20.00 | 20.00  | 17.42  | Laser V-Coat<br>(785nm) | <a href="#">N-SF11</a> | <a href="#">#89-021</a> | S\$83.64<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 20.00 | 25.00  | 22.76  | Laser V-Coat<br>(785nm) | <a href="#">N-SF11</a> | <a href="#">#89-022</a> | S\$82.88<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 20.00 | 35.00  | 32.04  | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-023</a> | S\$82.88<br><a href="#">Volume Pricing</a> | 14 In Stock  |
| 20.00 | 40.00  | 36.77  | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-024</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 20.00 | 50.00  | 47.87  | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-025</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 20.00 | 60.00  | 57.03  | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-026</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 20.00 | 70.00  | 68.03  | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-027</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 20.00 | 80.00  | 78.45  | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-028</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 20.00 | 100.00 | 97.13  | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-029</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 20.00 | 150.00 | 148.02 | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a>  | <a href="#">#89-030</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|       |        |        |                      |                       |                         |                                            |             |
|-------|--------|--------|----------------------|-----------------------|-------------------------|--------------------------------------------|-------------|
| 25.00 | 25.00  | 20.22  | Laser V-Coat (785nm) | <a href="#">N-SF5</a> | <a href="#">#65-524</a> | S\$83.64<br><a href="#">Volume Pricing</a> | 17 In Stock |
| 25.00 | 30.00  | 24.69  | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#69-495</a> | S\$83.64<br><a href="#">Volume Pricing</a> | 5 In Stock  |
| 25.00 | 35.00  | 30.42  | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#69-496</a> | S\$83.64<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 25.00 | 40.00  | 36.31  | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#69-497</a> | S\$83.64<br><a href="#">Volume Pricing</a> | 6 In Stock  |
| 25.00 | 50.00  | 46.75  | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#65-525</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 11 In Stock |
| 25.00 | 60.00  | 56.90  | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#69-498</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 5 In Stock  |
| 25.00 | 75.00  | 72.00  | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#65-526</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 12 In Stock |
| 25.00 | 85.00  | 82.17  | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#69-499</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 14 In Stock |
| 25.00 | 100.00 | 97.17  | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#65-527</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 16 In Stock |
| 25.00 | 125.00 | 122.70 | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#65-528</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 1 In Stock  |
| 25.00 | 150.00 | 147.81 | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#69-500</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 25.00 | 175.00 | 172.85 | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#69-501</a> | S\$80.65<br><a href="#">Volume Pricing</a> | Contact Us  |
| 25.00 | 250.00 | 248.02 | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#69-502</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 2 In Stock  |
| 25.00 | 300.00 | 298.02 | Laser V-Coat (785nm) | <a href="#">N-BK7</a> | <a href="#">#69-503</a> | S\$80.65<br><a href="#">Volume Pricing</a> | 12 In Stock |

|       |        |        |                      |                        |                         |                                             |            |
|-------|--------|--------|----------------------|------------------------|-------------------------|---------------------------------------------|------------|
| 25.00 | 500.00 | 497.89 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-504</a> | S\$80.65<br><a href="#">Volume Pricing</a>  | Contact Us |
| 25.00 | 750.00 | 747.89 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-505</a> | S\$80.65<br><a href="#">Volume Pricing</a>  | 2 In Stock |
| 30.00 | 30.00  | 26.13  | Laser V-Coat (785nm) | <a href="#">N-SF11</a> | <a href="#">#26-150</a> | S\$94.84<br><a href="#">Volume Pricing</a>  | 8 In Stock |
| 30.00 | 40.00  | 37.20  | Laser V-Coat (785nm) | <a href="#">N-SF11</a> | <a href="#">#26-151</a> | S\$92.60<br><a href="#">Volume Pricing</a>  | 9 In Stock |
| 30.00 | 50.00  | 46.17  | Laser V-Coat (785nm) | <a href="#">N-SF5</a>  | <a href="#">#26-152</a> | S\$92.60<br><a href="#">Volume Pricing</a>  | 9 In Stock |
| 30.00 | 100.00 | 96.01  | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#26-153</a> | S\$90.35<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 30.00 | 120.00 | 116.04 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#26-154</a> | S\$90.35<br><a href="#">Volume Pricing</a>  | 5 In Stock |
| 40.00 | 40.00  | 35.13  | Laser V-Coat (785nm) | <a href="#">N-SF11</a> | <a href="#">#26-155</a> | S\$102.31<br><a href="#">Volume Pricing</a> | 9 In Stock |
| 40.00 | 60.00  | 53.90  | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#26-156</a> | S\$102.31<br><a href="#">Volume Pricing</a> | 5 In Stock |
| 40.00 | 300.00 | 296.70 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#26-157</a> | S\$100.82<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 40.00 | 400.00 | 396.70 | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#26-158</a> | S\$100.82<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 50.00 | 50.00  | 43.28  | Laser V-Coat (785nm) | <a href="#">N-SF11</a> | <a href="#">#69-506</a> | S\$109.78<br><a href="#">Volume Pricing</a> | 8 In Stock |
| 50.00 | 75.00  | 67.70  | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-507</a> | S\$106.78<br><a href="#">Volume Pricing</a> | 6 In Stock |
| 50.00 | 100.00 | 93.41  | Laser V-Coat (785nm) | <a href="#">N-BK7</a>  | <a href="#">#69-508</a> | S\$103.05<br><a href="#">Volume Pricing</a> | 1 In Stock |

|       |        |        |                         |                       |                         |                                             |            |
|-------|--------|--------|-------------------------|-----------------------|-------------------------|---------------------------------------------|------------|
| 50.00 | 125.00 | 118.39 | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a> | <a href="#">#69-509</a> | S\$103.05<br><a href="#">Volume Pricing</a> | 6 In Stock |
| 50.00 | 150.00 | 144.07 | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a> | <a href="#">#69-510</a> | S\$103.05<br><a href="#">Volume Pricing</a> | 3 In Stock |
| 50.00 | 175.00 | 169.05 | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a> | <a href="#">#69-511</a> | S\$103.05<br><a href="#">Volume Pricing</a> | Contact Us |
| 50.00 | 200.00 | 196.66 | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a> | <a href="#">#69-512</a> | S\$103.05<br><a href="#">Volume Pricing</a> | 1 In Stock |
| 50.00 | 250.00 | 246.74 | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a> | <a href="#">#69-513</a> | S\$103.05<br><a href="#">Volume Pricing</a> | 6 In Stock |
| 50.00 | 500.00 | 496.70 | Laser V-Coat<br>(785nm) | <a href="#">N-BK7</a> | <a href="#">#69-514</a> | S\$103.05<br><a href="#">Volume Pricing</a> | 9 In Stock |



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)