

[All Products](#) / [Imaging Lenses](#) / [Fixed Focal Length Lenses](#)

TECHSPEC® LF Series Fixed Focal Length Lenses




- Full Frame (35mm), F-Mount Lens
- 29 MegaPixels, 5µm Pixel Size Sensors
- F-Mount Large Format (LF) Lens for Factory Automation
- 28mm to 100mm Focal Length

Common Specifications


General			
Series: LF Series		Imaging Lens Type: Lens for Large Format Sensors	
Physical & Mechanical Properties			
Iris Option: Variable			
Optical Properties			
Maximum Image Circle (mm): 43.30			
Coating: λ/4 MgF2		Coating Specification: λ/4 MgF2	
Sensor			
Maximum Sensor Format: 35mm (43.3mm Image Circle)		Pixel Size (μm): 5.00	
Threading & Mounting			
Mount: F-Mount			
Environmental & Durability Factors			
Storage Temperature (°C):		-20 to +60	

Technical Information

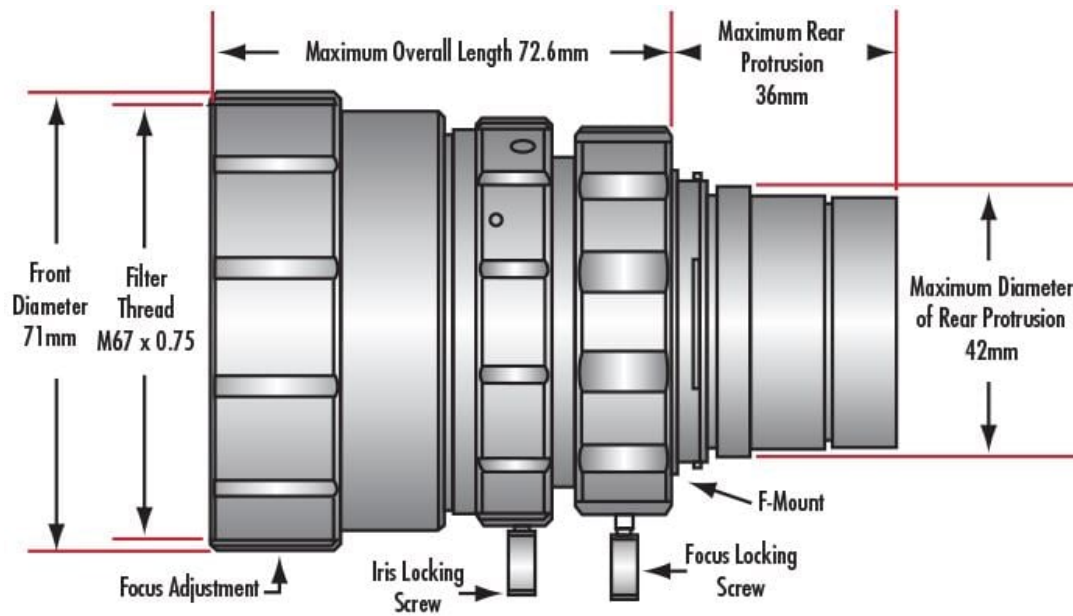


28mm Focal Length

50mm Focal Length Large Format Lens

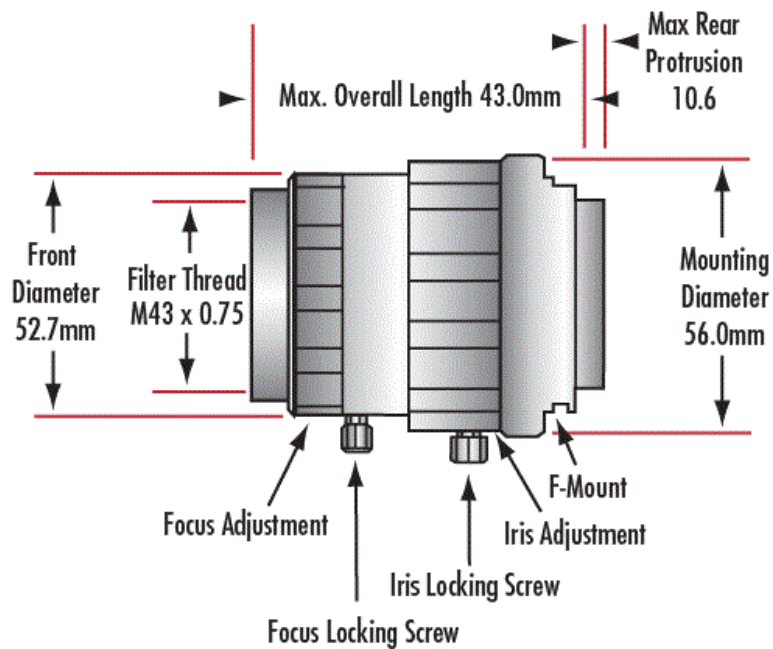

100mm Focal Length Large Format Lens

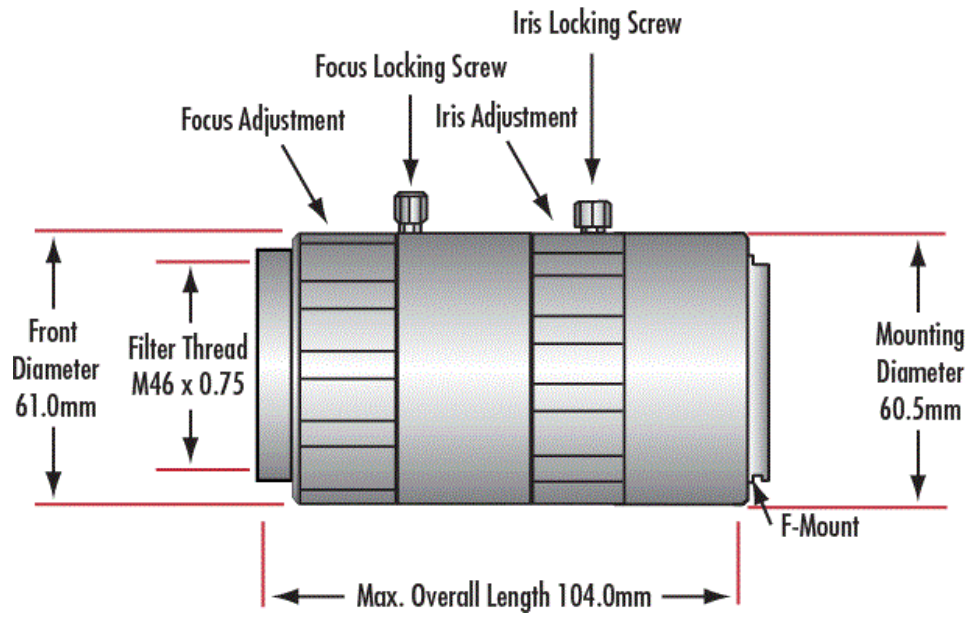

Products

FL (mm)	Max. Sensor Format	Aperture (f/#)	WD (mm)	Optimized Working Distance (mm)	Mount	Stock Number	Price	Buy
28.00	35mm (43.3mm Image Circle)	f/2.8 - f/22	400 - ∞	400 - 700	F- Mount	#85-199	S\$2,672.40	20+ In Stock
28.00	35mm (43.3mm Image Circle)	f/2.8 - f/22	700 - ∞	-	F- Mount	#85-200	S\$2,672.40	7 In Stock
50.00	35mm (43.3mm Image Circle)	f/2 - f/22	500 - ∞	-	F- Mount	#85-203	S\$1,414.20	16 In Stock
100.00	35mm (43.3mm Image Circle)	f/2.8 - f/22	500 - ∞	-	F- Mount	#85-204	S\$2,080.80	13 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com