

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Aspheric Lenses](#) / [Glass Molded](#)

LightPath® Geltech™ Molded Aspheric Lenses See More by [Lightpath®](#)



- Eliminate Spherical Aberration
- Multiple Coating Options Available
- Range of Numerical Apertures


Common Specifications

Optical Properties

Focal Length Tolerance (%):

±1

Technical Information

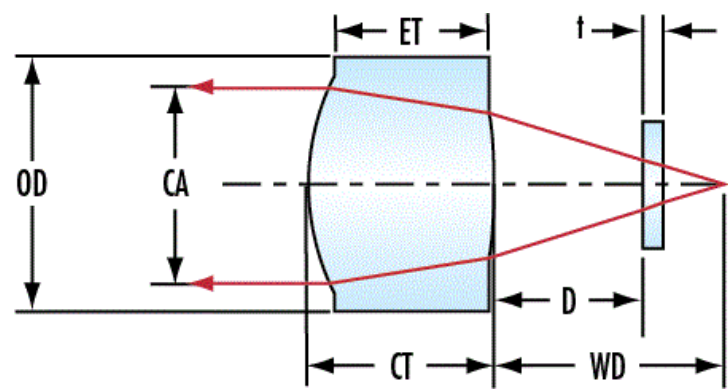

Products

Dia. (mm)	Dimensions (mm)	EFL (mm)	NA	Coating	Stock Number	Price	Buy
4.00	-	6.20	0.30	BBAR (350-700nm)	#71-004	S\$162.79 Volume Pricing	20+ In Stock
4.00	-	2.50	0.70	BBAR (350-700nm)	#71-003	S\$147.86 Volume Pricing	20+ In Stock
6.33	-	22.00	0.13	BBAR (350-700nm)	#83-543	S\$136.65 Volume Pricing	20+ In Stock
6.33	-	22.00	0.13	BBAR (600-1050nm)	#83-544	S\$136.65 Volume Pricing	20+ In Stock
2.00	-	5.00	0.15	BBAR (600-1050nm)	#48-145	S\$136.65 Volume Pricing	20+ In Stock
4.99	-	15.04	0.15	BBAR (350-700nm)	#16-689	S\$139.64 Volume Pricing	20+ In Stock
6.50	-	18.40	0.15	BBAR (350-700nm)	#87-113	S\$147.86 Volume Pricing	13 In Stock
6.50	-	18.40	0.15	BBAR (600-1050nm)	#87-114	S\$132.17 Volume Pricing	20+ In Stock
6.50	-	15.29	0.16	BBAR (350-700nm)	#37-098	S\$120.97 Volume Pricing	12 In Stock
6.50	-	15.29	0.16	BBAR (600-1050nm)	#37-099	S\$116.49 Volume Pricing	14 In Stock
6.50	-	15.29	0.16	BBAR (1050-1600nm)	#37-100	S\$116.49 Volume Pricing	20+ In Stock
6.33	-	13.86	0.18	BBAR (600-1050nm)	#46-372	S\$123.96 Volume Pricing	20+ In Stock

6.33	-	13.90	0.18	BBAR (350-700nm)	#83-556	S\$136.65 Volume Pricing	20+ In Stock
6.00	-	11.00	0.24	BBAR (1050-1600nm)	#37-111	S\$116.49 Volume Pricing	5 In Stock
7.20	-	11.00	0.25	VIS	#47-142	S\$147.86 Volume Pricing	20+ In Stock
7.20	-	11.00	0.25	BBAR (350-700nm)	#87-117	S\$136.65 Volume Pricing	20+ In Stock
#87-118 Clearance							
 Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
7.20	-	11.00	0.25	BBAR (600-1050nm)		S\$22.33	20+ In Stock
7.20	-	11.00	0.25	BBAR (1050-1600nm)	#87-119	S\$123.96 Volume Pricing	20+ In Stock
6.51	-	7.50	0.3	BBAR (350-700nm)	#87-129	S\$100.82 Volume Pricing	20+ In Stock
6.51	-	7.50	0.3	BBAR (600-1050nm)	#87-130	S\$100.82 Volume Pricing	20+ In Stock
6.51	-	7.50	0.3	BBAR (1050-1600nm)	#87-131	S\$100.82 Volume Pricing	20+ In Stock

7.20	-	11.00	0.3	BBAR (350-700nm)	#87-121	S\$100.82 Volume Pricing	20+ In Stock
7.20	-	11.00	0.3	BBAR (600-1050nm)	#87-122	S\$100.82 Volume Pricing	5 In Stock
3.00	-	3.52	0.4	BBAR (350-700nm)	#16-684	S\$139.64 Volume Pricing	Contact Us
7.20	-	6.24	0.4	BBAR (350-700nm)	#87-125	S\$147.86 Volume Pricing	9 In Stock
7.20	-	6.24	0.4	BBAR (600-1050nm)	#87-126	S\$139.64 Volume Pricing	20+ In Stock
7.20	-	6.24	0.4	BBAR (1050-1600nm)	#87-127	S\$139.64 Volume Pricing	16 In Stock
4.70	-	4.50	0.43	BBAR (350-700nm)	#83-578	S\$100.82 Volume Pricing	20+ In Stock
4.70	-	4.50	0.43	BBAR (600-1050nm)	#83-579	S\$100.82 Volume Pricing	20+ In Stock
4.70	-	4.50	0.43	BBAR (1050-1600nm)	#83-580	S\$100.82 Volume Pricing	20+ In Stock
6.65	-	6.70	0.44	BBAR (350-700nm)	#19-701	S\$120.97 Volume Pricing	20+ In Stock
6.65	-	6.70	0.44	BBAR (600-1050nm)	#19-702	S\$120.97 Volume Pricing	20+ In Stock

[#16-687 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

5.42	-	4.47	0.47	BBAR (350-700nm)		S\$59.67	8 In Stock
------	---	------	------	------------------	--	----------	------------

6.00	-	4.60	0.55	BBAR (1050-1600nm)	#87-159	S\$100.82 Volume Pricing	20+ In Stock
------	---	------	------	--------------------	-------------------------	---	--------------

[#37-112 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

-	1.0 x 1.0	0.55	0.5	BBAR (350-700nm)		S\$68.63	20+ In Stock
---	-----------	------	-----	------------------	--	----------	--------------

[#37-113 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

-	1.0 x 1.0	0.55	0.5	BBAR (600-1050nm)		S\$68.63	8 In Stock
---	-----------	------	-----	-------------------	--	----------	------------

-	1.0 x 1.0	0.55	0.5	BBAR (1050-1600nm)	#37-114	S\$136.65 Volume Pricing	20+ In Stock
1.40	-	1.05	0.5	BBAR (1050-1600nm)	#16-704	S\$139.64 Volume Pricing	13 In Stock
9.94	-	8.00	0.5	BBAR (350-700nm)	#37-102	S\$147.86 Volume Pricing	20+ In Stock
9.94	-	8.00	0.5	BBAR (600-1050nm)	#37-103	S\$139.64 Volume Pricing	11 In Stock
9.94	-	8.00	0.5	BBAR (1050-1600nm)	#37-104	S\$139.64 Volume Pricing	20+ In Stock
11.00	-	10.00	0.5	BBAR (350-700nm)	#33-425	S\$219.54 Volume Pricing	20+ In Stock
11.00	-	10.00	0.5	BBAR (600-1050nm)	#33-426	S\$219.54 Volume Pricing	20+ In Stock
9.20	-	6.75	0.54	BBAR (350-700nm)	#16-691	S\$139.64 Volume Pricing	20+ In Stock

6.00	-	4.60	0.55	BBAR (350-700nm)	#87-157	S\$100.82 Volume Pricing	20+ In Stock
6.00	-	4.60	0.55	BBAR (600-1050nm)	#87-158	S\$100.82 Volume Pricing	20+ In Stock
#47-144 Clearance							
 Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
9.94	-	8.00	0.50	BBAR (350-700nm)		S\$55.19	20+ In Stock
3.00	-	2.00	0.50	BBAR (350-700nm)	#83-582	S\$100.82 Volume Pricing	Contact Us
3.00	-	2.00	0.50	BBAR (600-1050nm)	#83-583	S\$100.82 Volume Pricing	20+ In Stock
4.70	-	2.76	0.5	BBAR (350-700nm)	#87-133	S\$123.96 Volume Pricing	17 In Stock

[#87-134 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

4.70	-	2.76	0.5	BBAR (600-1050nm)		S\$65.34	17 In Stock
------	---	------	-----	-------------------	--	----------	-------------

4.00	-	2.73	0.55	BBAR (350-700nm)	#83-605	S\$100.82 Volume Pricing	Contact Us
------	---	------	------	------------------	-------------------------	---	------------

4.00	-	2.73	0.55	BBAR (600-1050nm)	#83-606	S\$100.82 Volume Pricing	14 In Stock
------	---	------	------	-------------------	-------------------------	---	-------------

4.50	-	2.75	0.55	BBAR (350-700nm)	#83-616	S\$100.82 Volume Pricing	7 In Stock
------	---	------	------	------------------	-------------------------	---	------------

4.50	-	2.75	0.55	BBAR (600-1050nm)	#66-926	S\$100.82 Volume Pricing	20+ In Stock
------	---	------	------	-------------------	-------------------------	---	--------------

4.50	-	2.75	0.55	BBAR (1050-1600nm)	#66-927	S\$100.82 Volume Pricing	20+ In Stock
------	---	------	------	--------------------	-------------------------	---	--------------

5.59	-	4.13	0.55	BBAR (1050-1600nm)	#16-701	S\$139.64 Volume Pricing	20+ In Stock
------	---	------	------	--------------------	-------------------------	---	--------------

6.33	-	4.51	0.55	BBAR (350-700nm)	#87-153	S\$136.65 Volume Pricing	20+ In Stock
------	---	------	------	------------------	-------------------------	---	--------------

6.33	-	4.51	0.55	BBAR (600-1050nm)	#87-154	S\$132.17 Volume Pricing	20+ In Stock
------	---	------	------	-------------------	-------------------------	---	--------------

6.33	-	4.51	0.55	BBAR (1050-1600nm)	#87-155	S\$132.17 Volume Pricing	20+ In Stock
2.40	-	1.45	0.58	BBAR (350-700nm)	#83-613	S\$100.82 Volume Pricing	20+ In Stock
2.40	-	1.45	0.58	BBAR (600-1050nm)	#83-614	S\$100.82 Volume Pricing	5 In Stock
2.40	-	1.45	0.58	BBAR (1050-1600nm)	#83-615	S\$100.82 Volume Pricing	20+ In Stock
7.20	-	5.50	0.56	BBAR (350-700nm)	#87-145	S\$147.86 Volume Pricing	10 In Stock
7.20	-	5.50	0.60	BBAR (600-1050nm)	#87-146	S\$147.86 Volume Pricing	20+ In Stock
7.20	-	5.50	0.56	BBAR (1050-1600nm)	#87-147	S\$139.64 Volume Pricing	10 In Stock
15.00	-	10.00	0.6	BBAR (350-700nm)	#37-105	S\$120.97 Volume Pricing	Contact Us
15.00	-	10.00	0.6	BBAR (600-1050nm)	#37-106	S\$120.97 Volume Pricing	20+ In Stock
15.00	-	10.00	0.6	BBAR (1050-1600nm)	#37-107	S\$120.97 Volume Pricing	20+ In Stock
4.00	-	2.75	0.60	BBAR (350-700nm)	#83-626	S\$100.82 Volume Pricing	20+ In Stock
4.00	-	2.75	0.60	BBAR (600-1050nm)	#83-627	S\$100.82 Volume Pricing	20+ In Stock
6.33	-	4.03	0.64	BBAR (350-700nm)	#87-161	S\$132.17 Volume Pricing	20+ In Stock
6.33	-	4.03	0.64	BBAR (600-1050nm)	#87-162	S\$136.65 Volume Pricing	20+ In Stock

6.33	-	4.03	0.64	BBAR (1050-1600nm)	#87-163	S\$139.64 Volume Pricing	20+ In Stock
6.33	-	3.10	0.68	BBAR (350-700nm)	#87-165	S\$136.65 Volume Pricing	20+ In Stock
6.33	-	3.10	0.68	BBAR (600-1050nm)	#87-166	S\$132.17 Volume Pricing	20+ In Stock
6.33	-	3.10	0.77	BBAR (600- ^m)	#83-674	S\$219.54 Volume Pricing	Contact Us



Edmund
optics | worldwide

Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com