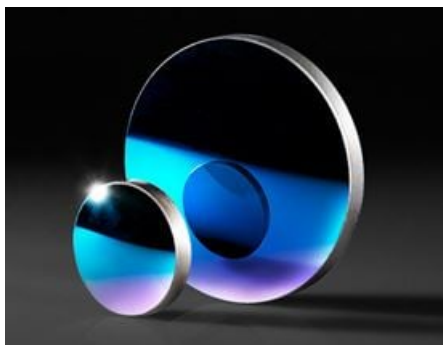


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Infrared \(IR\) Lenses](#)
TECHSPEC® Germanium Meniscus Lenses


- Wavelength Range of 2 - 16 μ m
- Durable Design for Demanding Applications
- Superior Spherical Correction
- Due to material supply chain disruptions with germanium, there may be increased lead times and price changes on our germanium products. For more information, please contact our [customer service team](#).
- Edmund Optics has limited remaining inventory of this part number and no raw material available to supply more once this is depleted. Please contact our Product Support Engineers to help with an alternate solution for your needs. Customer Service can provide you the latest price and availability.

Common Specifications

Physical & Mechanical Properties

Center Thickness Tolerance (mm):	± 0.10	Centering (arcmin):	<3
Clear Aperture (%):	90.00		

Optical Properties

Substrate:	Germanium (Ge)		
Focal Length Specification Wavelength (μ m):	10.6	Surface Quality:	60-40

Technical Information

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Stock Number	Price	Buy
25.00	25.00	23.34	Uncoated	#87-955	S\$913.50	20+ In Stock
25.00	25.00	23.34	BBAR (3000-5000nm)	#87-961	S\$2,131.50	9 In Stock
25.00	25.00	23.34	BBAR (8000-12000nm)	#87-967	S\$1,189.00	2 In Stock
25.00	30.00	28.31	Uncoated	#87-956	S\$913.50	20+ In Stock
25.00	30.00	28.31	BBAR (3000-5000nm)	#87-962	S\$1,189.00	7 In Stock
25.00	35.00	33.29	Uncoated	#87-957	S\$913.50	14 In Stock
50.00	50.00	46.69	Uncoated	#87-958	S\$2,131.50	1 In Stock
50.00	50.00	46.69	BBAR (3000-5000nm)	#87-964	S\$2,479.50	6 In Stock
50.00	100.00	96.49	Uncoated	#87-960	S\$2,131.50	9 In Stock
50.00	100.00	96.49	BBAR (8000-12000nm)	#87-972	S\$2,494.00	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com