


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Cylinder Lenses](#) / [Acyylinder Lenses](#)

TECHSPEC® Acylinder Lenses

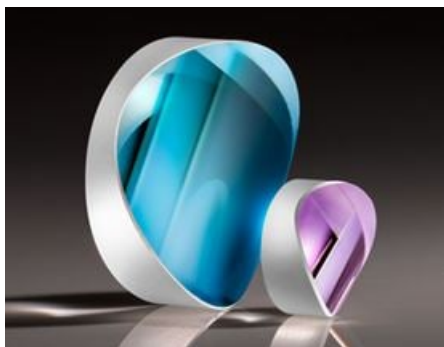

- Diffraction Limited Design
- Ideal for Creating Thin Line Profiles of Monochromatic Light Sources
- Focus Light in Single Dimension

Common Specifications

Physical & Mechanical Properties

Center Thickness Tolerance (mm): ± 0.1

Clear Aperture (%): 90.00

Optical Properties


Substrate: [N-SF5](#)

Focal Length Specification Wavelength (nm): 587.6

Surface Accuracy, RMS (μm): 1.0

Surface Quality: 60-40

Technical Information

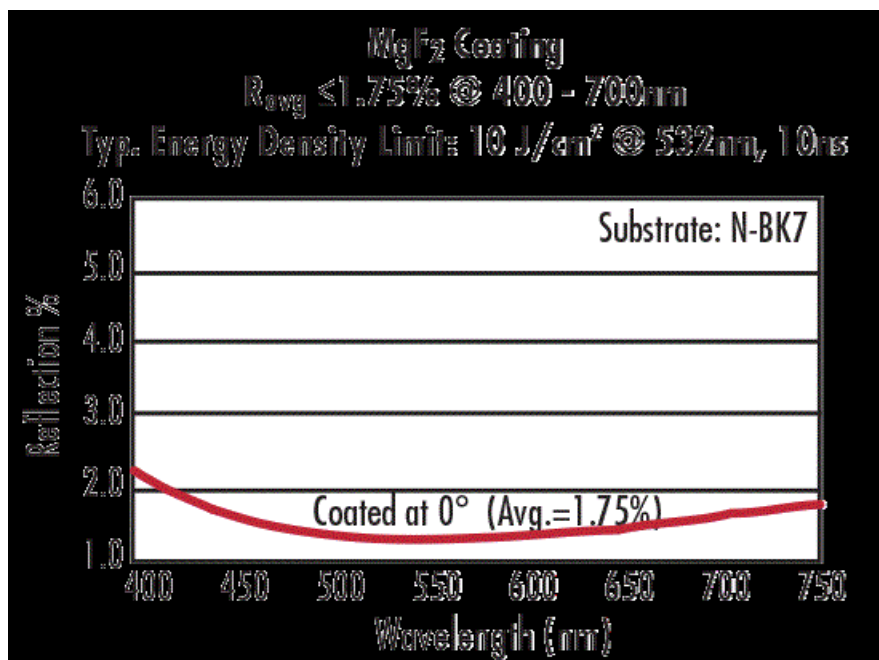

Products

Dia. (mm)	EFL (mm)	Substrate	Coating	Stock Number	Price	Buy
12.50	10.00	N-SF5	Uncoated	#86-030	S\$933.44 Volume Pricing	20+ In Stock
12.50	10.00	N-SF5	MgF ₂ (400-700nm)	#86-034	S\$970.78 Volume Pricing	3 In Stock
12.50	12.50	N-SF5	Uncoated	#86-031	S\$933.44 Volume Pricing	17 In Stock
12.50	12.50	N-SF5	MgF ₂ (400-700nm)	#86-035	S\$970.78 Volume Pricing	3 In Stock
25.00	20.00	N-SF5	Uncoated	#86-032	S\$1,284.41 Volume Pricing	Contact Us
25.00	20.00	N-SF5	MgF ₂ (400-700nm)	#86-036	S\$1,329.22 Volume Pricing	Contact Us
25.00	25.00	N-SF5	Uncoated	#86-033	S\$1,284.41 Volume Pricing	10 In Stock
25.00	25.00	N-SF5	MgF ₂ (400-700nm)	#86-037	S\$1,329.22 Volume Pricing	4 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com