

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Specialty Lenses](#)

Focusable Collimators



- Can Be Coupled to Standard 0.22 NA Fiber Optic Cables
- Options Available for UV-VIS or VIS-NIR
- Multiple Focal Length or Aperture Options

Common Specifications


Environmental & Durability Factors

Operating Temperature (°C):

-40 to 100


Technical Information

Fiber with 4mm Aperture Fiber Optic Collimator

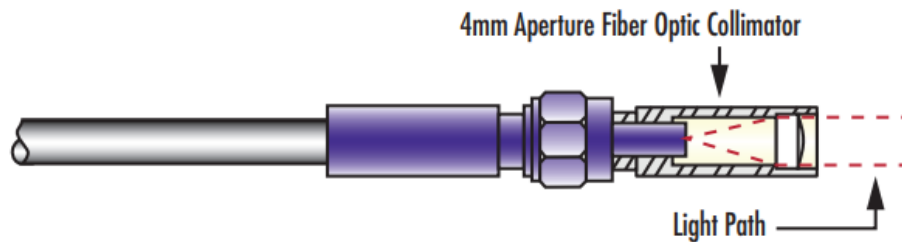


The 4mm Aperture Fiber Optic Collimator threads directly onto FC or SMA fiber.

Fiber with 10mm Aperture Fiber Optic Collimator

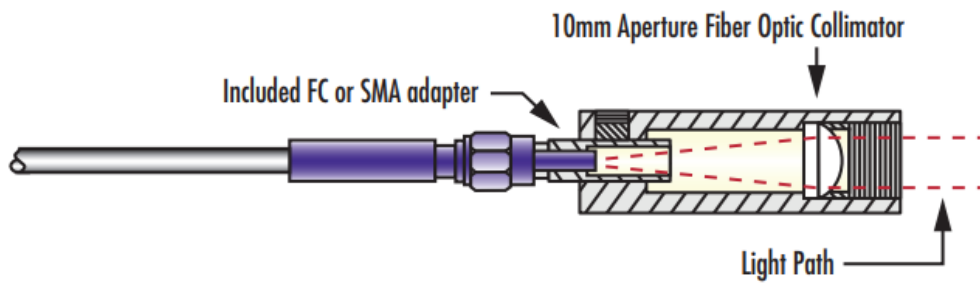

Each 10mm Aperture Fiber Optic Collimator includes an FC or SMA adapter that is inserted into the collimator and locked by a set screw.

Fiber with 10mm Aperture Fiber Optic Collimator and Refocusing Assembly

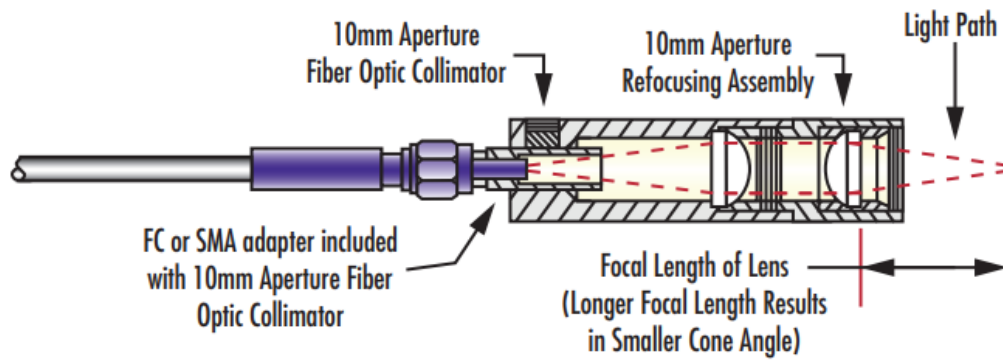

A 10mm Aperture Refocusing Assembly can then be directly threaded onto the 10mm Aperture Fiber Optic Collimator.

Products

Aperture Size	Connector	FL (mm)	Type	Wavelength Range (nm)	Stock Number	Price	Buy
4.0	FC	10.00	Fiber Collimator	190 - 1250	#88-189	S\$352.80 Volume Pricing	9 In Stock
4.0	SMA	10.00	Fiber Collimator	190 - 1250	#88-173	S\$352.80 Volume Pricing	5 In Stock
4.0	FC	10.00	Fiber Collimator	350 - 2200	#88-188	S\$288.40 Volume Pricing	2 In Stock
4.0	SMA	10.00	Fiber Collimator	350 - 2200	#88-172	S\$273.00 Volume Pricing	5 In Stock
10.0	FC	18.00	Fiber Collimator	190 - 1250	#88-191	S\$593.60 Volume Pricing	Contact Us
10.0	SMA	18.00	Fiber Collimator	190 - 1250	#88-181	S\$593.60 Volume Pricing	Contact Us
10.0	FC	18.00	Fiber Collimator	350 - 2200	#88-190	S\$352.80 Volume Pricing	3 In Stock
10.0	SMA	18.00	Fiber Collimator	350 - 2200	#88-180	S\$352.80 Volume Pricing	Contact Us
22.2	FC	38.00	Fiber Collimator	190 - 1250	#17-569	S\$816.20 Volume Pricing	5 In Stock
22.2	SMA	38.00	Fiber Collimator	190 - 1250	#17-567	S\$816.20 Volume Pricing	5 In Stock
10.0	-	18.00	Refocusing Assembly	190 - 1250	#88-185	S\$497.00 Volume Pricing	Contact Us
10.0	-	18.00	Refocusing Assembly	350 - 2200	#88-182	S\$273.00 Volume Pricing	Contact Us
10.0	-	25.00	Refocusing Assembly	190 - 1250	#88-186	S\$497.00 Volume Pricing	1 In Stock
10.0	-	25.00	Refocusing Assembly	350 - 2200	#88-183	S\$273.00 Volume Pricing	Contact Us
22.2	-	38.00	Refocusing Assembly	190 - 1250	#17-573	S\$985.60 Volume Pricing	1 In Stock
10.0	-	38.00	Refocusing Assembly	190 - 1250	#88-187	S\$497.00 Volume Pricing	1 In Stock
10.0	-	38.00	Refocusing Assembly	350 - 2200	#88-184	S\$273.00 Volume Pricing	4 In Stock

22.2	-	51.00	Refocusing Assembly	190 - 1250	#17-574	S\$985.60 Volume Pricing	7 In Stock
22.2	-	76.00	Refocusing Assembly	190 - 1250	#17-575	S\$985.60 Volume Pricing	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com