

[All Products](#) / [Microscopy](#) / [Infinity Corrected Objectives](#)

# Nikon CFI Super Fluor Objectives

See More by [Nikon](#)

- Superior UV Transmission
- High Numerical Aperture Designs
- Feature Low Auto-Fluorescence Materials



## Common Specifications

### General

Compatible Tube Lens			
Focal Length (mm):	Focal Length: 200mm	Manufacturer:	Nikon

### Optical Properties

Compatible Cover Glass			
Thickness (mm):	0.17	Field Number (mm):	22


### Sensor

Maximum Sensor Format:	2/3"
------------------------	------


### Threading & Mounting

Mounting Threads:	M25 x 0.75
-------------------	------------

Technical Information

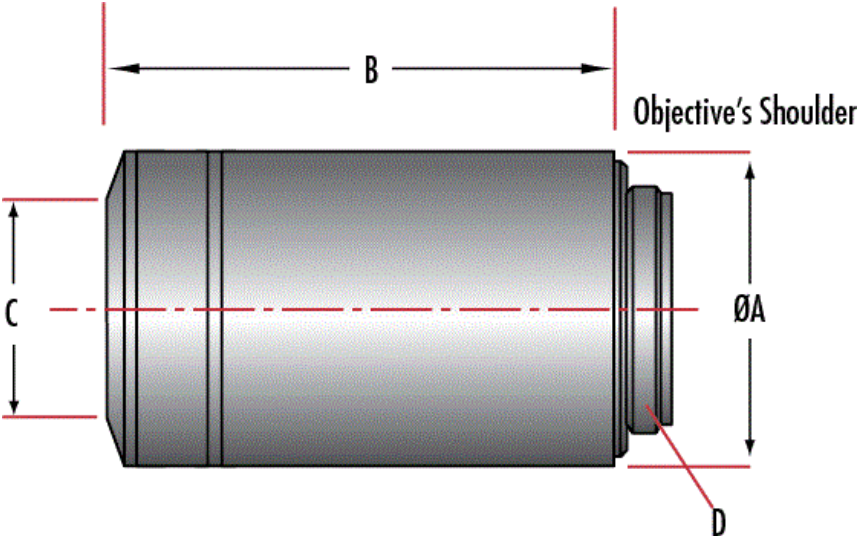

# Products

Magnification	NA	Field Number (mm)	Model Number	WD (mm)	Stock Number	Price	Buy
10X	0.50	22	MRF00101	1.2	<a href="#">#88-375</a>	S\$6,993.35	Contact Us
20X	0.75	22	MRF00201	1.0	<a href="#">#88-376</a>	S\$8,637.94	Contact Us
<a href="#">#75-346 New</a>							
							
New							
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
40X	1.3	22	MRF01401	0.19		S\$8,189.14	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100  
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)