


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® YAG-BBAR Coated Plano-Convex (PCX) Lenses

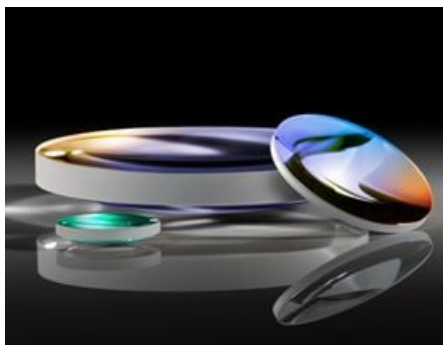

- Optimized for $R < 0.25\%$ @ Both 532nm and 1064nm
- AR Coated to Provide $< 1.0\%$ Reflectance per Surface for 500 - 1100nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), and [VIS-EXT](#)

Common Specifications

Physical & Mechanical Properties


Bevel:	Protective as needed
--------	----------------------

Optical Properties

Coating:	YAG-BBAR (500-1100nm)
----------	-----------------------

Focal Length Tolerance (%):	± 1
-----------------------------	---------

Technical Information

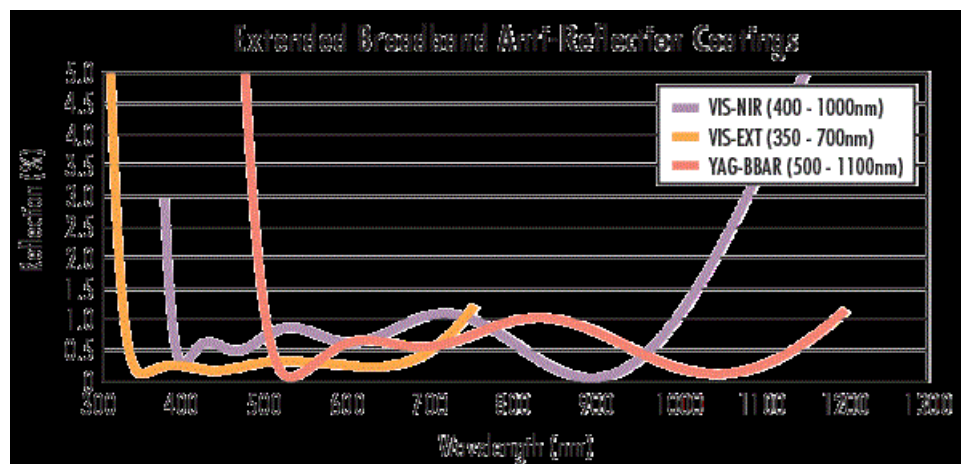

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	YAG-BBAR (500-1100nm)	N-LASF9	#35-710	S\$126.00 Volume Pricing	3 In Stock
1.00	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-711	S\$126.00 Volume Pricing	Contact Us
1.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-712	S\$126.00 Volume Pricing	11 In Stock
1.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-713	S\$126.00 Volume Pricing	5 In Stock
1.50	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-714	S\$126.00 Volume Pricing	9 In Stock
1.50	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-715	S\$126.00 Volume Pricing	4 In Stock
1.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-716	S\$126.00 Volume Pricing	5 In Stock
2.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-717	S\$124.60 Volume Pricing	4 In Stock
2.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-718	S\$124.60 Volume Pricing	3 In Stock
2.00	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-719	S\$124.60 Volume Pricing	3 In Stock
2.00	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-720	S\$124.60 Volume Pricing	10 In Stock
2.00	4.00	3.46	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-259	S\$184.80 Volume Pricing	5 In Stock

2.00	6.00	5.45	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-267	S\$177.80 Volume Pricing	4 In Stock
2.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-721	S\$124.60 Volume Pricing	5 In Stock
2.50	2.50	2.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-722	S\$124.60 Volume Pricing	20+ In Stock
2.50	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-723	S\$124.60 Volume Pricing	20+ In Stock
2.50	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-724	S\$124.60 Volume Pricing	10 In Stock
2.50	5.00	4.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-725	S\$124.60 Volume Pricing	3 In Stock
3.00	3.00	1.88	YAG-BBAR (500-1100nm)	N-SF11	#88-774	S\$107.10 Volume Pricing	16 In Stock
3.00	4.50	3.5	YAG-BBAR (500-1100nm)	N-LASF44	#88-775	S\$107.10 Volume Pricing	15 In Stock
3.00	6.00	4.81	YAG-BBAR (500-1100nm)	N-BK7	#88-776	S\$98.70 Volume Pricing	20+ In Stock
3.00	6.00	5.01	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-276	S\$184.80 Volume Pricing	5 In Stock
3.00	7.50	6.51	YAG-BBAR (500-1100nm)	N-BK7	#88-777	S\$98.70 Volume Pricing	20+ In Stock
3.00	9.00	8.01	YAG-BBAR (500-1100nm)	N-BK7	#88-778	S\$98.70 Volume Pricing	6 In Stock
3.00	9.00	8.11	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-284	S\$177.80 Volume Pricing	5 In Stock
3.00	12.00	11.29	YAG-BBAR (500-1100nm)	N-BK7	#88-779	S\$98.70 Volume Pricing	8 In Stock

3.00	15.00	14.22	YAG-BBAR (500-1100nm)	N-BK7	#88-780	S\$98.70 Volume Pricing	17 In Stock
4.00	4.00	3.06	YAG-BBAR (500-1100nm)	N-LASF44	#88-781	S\$106.40 Volume Pricing	20+ In Stock
4.00	6.00	4.51	YAG-BBAR (500-1100nm)	N-BK7	#88-782	S\$106.40 Volume Pricing	1 In Stock
4.00	8.00	6.91	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-292	S\$201.60 Volume Pricing	5 In Stock
4.00	10.00	8.92	YAG-BBAR (500-1100nm)	N-BK7	#88-784	S\$100.10 Volume Pricing	7 In Stock
4.00	12.00	11.00	YAG-BBAR (500-1100nm)	N-BK7	#88-785	S\$100.10 Volume Pricing	10 In Stock
4.00	12.00	11.04	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-300	S\$191.80 Volume Pricing	4 In Stock
4.50	4.50	3.05	YAG-BBAR (500-1100nm)	N-LASF44	#88-786	S\$106.40 Volume Pricing	7 In Stock
4.50	9.00	7.41	YAG-BBAR (500-1100nm)	N-BK7	#88-787	S\$100.10 Volume Pricing	3 In Stock
5.00	5.00	3.96	YAG-BBAR (500-1100nm)	N-LASF44	#88-788	S\$78.40 Volume Pricing	1 In Stock
5.00	7.50	6.43	YAG-BBAR (500-1100nm)	N-SF11	#88-789	S\$77.70 Volume Pricing	2 In Stock
5.00	10.00	8.91	YAG-BBAR (500-1100nm)	N-BK7	#88-790	S\$77.70 Volume Pricing	5 In Stock
5.00	12.00	10.83	YAG-BBAR (500-1100nm)	N-BK7	#88-791	S\$77.70 Volume Pricing	1 In Stock
5.00	15.00	13.94	YAG-BBAR (500-1100nm)	N-BK7	#88-792	S\$77.70 Volume Pricing	20+ In Stock

5.00	20.00	19.02	YAG-BBAR (500-1100nm)	N-BK7	#88-793	S\$77.70 Volume Pricing	5 In Stock
5.00	25.00	23.95	YAG-BBAR (500-1100nm)	N-BK7	#88-794	S\$77.70 Volume Pricing	10 In Stock
5.00	30.00	28.95	YAG-BBAR (500-1100nm)	N-BK7	#88-795	S\$77.70 Volume Pricing	12 In Stock
6.00	6.00	4.60	YAG-BBAR (500-1100nm)	N-SF11	#88-796	S\$65.45 Volume Pricing	14 In Stock
6.00	7.50	6.10	YAG-BBAR (500-1100nm)	N-SF11	#88-797	S\$64.75 Volume Pricing	11 In Stock
6.00	9.00	7.95	YAG-BBAR (500-1100nm)	N-SF5	#88-798	S\$64.75 Volume Pricing	Contact Us
6.00	10.00	8.82	YAG-BBAR (500-1100nm)	N-BK7	#38-568	S\$64.75 Volume Pricing	3 In Stock
6.00	12.00	10.94	YAG-BBAR (500-1100nm)	N-BK7	#88-799	S\$63.35 Volume Pricing	10 In Stock
6.00	15.00	13.68	YAG-BBAR (500-1100nm)	N-BK7	#88-800	S\$63.35 Volume Pricing	12 In Stock
6.00	18.00	17.07	YAG-BBAR (500-1100nm)	N-BK7	#88-801	S\$63.35 Volume Pricing	9 In Stock
6.00	20.00	19.04	YAG-BBAR (500-1100nm)	N-BK7	#38-569	S\$63.35 Volume Pricing	20+ In Stock
6.00	21.00	20.06	YAG-BBAR (500-1100nm)	N-BK7	#88-802	S\$63.35 Volume Pricing	1 In Stock
6.00	24.00	23.01	YAG-BBAR (500-1100nm)	N-BK7	#88-803	S\$63.35 Volume Pricing	Contact Us
6.00	25.00	24.04	YAG-BBAR (500-1100nm)	N-BK7	#38-570	S\$63.35 Volume Pricing	12 In Stock

6.00	30.00	29.14	YAG-BBAR (500-1100nm)	N-BK7	#88-804	S\$63.35 Volume Pricing	Contact Us
6.00	36.00	34.95	YAG-BBAR (500-1100nm)	N-BK7	#88-805	S\$63.35 Volume Pricing	1 In Stock
6.00	48.00	46.95	YAG-BBAR (500-1100nm)	N-BK7	#88-806	S\$63.35 Volume Pricing	5 In Stock
6.00	60.00	58.95	YAG-BBAR (500-1100nm)	N-BK7	#88-807	S\$63.35 Volume Pricing	3 In Stock
6.00	72.00	70.97	YAG-BBAR (500-1100nm)	N-BK7	#88-808	S\$63.35 Volume Pricing	5 In Stock
7.00	7.00	5.50	YAG-BBAR (500-1100nm)	N-LASF9	#71-299	S\$64.75 Volume Pricing	8 In Stock
7.00	10.00	8.10	YAG-BBAR (500-1100nm)	N-LASF9	#71-306	S\$64.05 Volume Pricing	5 In Stock
7.00	12.00	10.30	YAG-BBAR (500-1100nm)	N-LASF9	#71-313	S\$64.05 Volume Pricing	4 In Stock
8.00	8.00	6.40	YAG-BBAR (500-1100nm)	N-LASF9	#71-320	S\$64.75 Volume Pricing	8 In Stock
8.00	10.00	7.60	YAG-BBAR (500-1100nm)	N-LASF9	#71-327	S\$64.05 Volume Pricing	4 In Stock
8.00	12.00	10.00	YAG-BBAR (500-1100nm)	N-LASF9	#71-334	S\$64.05 Volume Pricing	9 In Stock
9.00	9.00	7.32	YAG-BBAR (500-1100nm)	N-SF11	#88-809	S\$66.50 Volume Pricing	Contact Us
9.00	10.00	8.49	YAG-BBAR (500-1100nm)	N-SF11	#38-571	S\$66.50 Volume Pricing	2 In Stock
9.00	12.00	10.60	YAG-BBAR (500-1100nm)	N-SF11	#88-810	S\$66.50 Volume Pricing	20+ In Stock

9.00	13.50	11.94	YAG-BBAR (500-1100nm)	N-SF5	#88-811	S\$66.50 Volume Pricing	8 In Stock
9.00	15.00	13.02	YAG-BBAR (500-1100nm)	N-BK7	#88-812	S\$66.50 Volume Pricing	1 In Stock
9.00	18.00	16.41	YAG-BBAR (500-1100nm)	N-BK7	#88-813	S\$64.75 Volume Pricing	8 In Stock
9.00	20.00	18.55	YAG-BBAR (500-1100nm)	N-BK7	#38-572	S\$64.75 Volume Pricing	5 In Stock
9.00	22.00	20.73	YAG-BBAR (500-1100nm)	N-BK7	#88-814	S\$64.75 Volume Pricing	Contact Us
9.00	25.00	23.68	YAG-BBAR (500-1100nm)	N-BK7	#38-573	S\$64.75 Volume Pricing	5 In Stock
9.00	27.00	25.34	YAG-BBAR (500-1100nm)	N-BK7	#88-815	S\$64.75 Volume Pricing	10 In Stock
9.00	36.00	34.48	YAG-BBAR (500-1100nm)	N-BK7	#88-816	S\$64.75 Volume Pricing	Contact Us
9.00	45.00	43.98	YAG-BBAR (500-1100nm)	N-BK7	#88-817	S\$64.75 Volume Pricing	14 In Stock
9.00	54.00	52.69	YAG-BBAR (500-1100nm)	N-BK7	#88-818	S\$64.75 Volume Pricing	5 In Stock
9.00	72.00	70.68	YAG-BBAR (500-1100nm)	N-BK7	#88-819	S\$64.75 Volume Pricing	11 In Stock
9.00	90.00	88.68	YAG-BBAR (500-1100nm)	N-BK7	#88-820	S\$64.75 Volume Pricing	5 In Stock
10.00	10.00	8.18	YAG-BBAR (500-1100nm)	N-SF11	#88-821	S\$66.50 Volume Pricing	20+ In Stock
10.00	12.50	10.99	YAG-BBAR (500-1100nm)	N-SF11	#38-574	S\$66.50 Volume Pricing	6 In Stock

10.00	15.00	13.32	YAG-BBAR (500-1100nm)	N-SF11	#88-822	S\$66.50 Volume Pricing	5 In Stock
10.00	17.50	15.66	YAG-BBAR (500-1100nm)	N-BK7	#38-575	S\$64.75 Volume Pricing	1 In Stock
10.00	20.00	18.03	YAG-BBAR (500-1100nm)	N-BK7	#88-823	S\$64.75 Volume Pricing	20+ In Stock
10.00	25.00	23.02	YAG-BBAR (500-1100nm)	N-BK7	#88-824	S\$64.75 Volume Pricing	5 In Stock
10.00	30.00	28.01	YAG-BBAR (500-1100nm)	N-BK7	#88-825	S\$64.75 Volume Pricing	17 In Stock
10.00	40.00	38.02	YAG-BBAR (500-1100nm)	N-BK7	#88-826	S\$64.75 Volume Pricing	2 In Stock
10.00	50.00	48.02	YAG-BBAR (500-1100nm)	N-BK7	#88-827	S\$64.75 Volume Pricing	11 In Stock
10.00	75.00	73.02	YAG-BBAR (500-1100nm)	N-BK7	#88-828	S\$64.75 Volume Pricing	Contact Us
10.00	100.00	98.02	YAG-BBAR (500-1100nm)	N-BK7	#88-829	S\$64.75 Volume Pricing	10 In Stock
12.00	12.00	9.76	YAG-BBAR (500-1100nm)	N-SF11	#88-830	S\$72.10 Volume Pricing	20+ In Stock
12.00	15.00	12.03	YAG-BBAR (500-1100nm)	N-BK7	#88-831	S\$72.10 Volume Pricing	12 In Stock
12.00	18.00	16.22	YAG-BBAR (500-1100nm)	N-SF5	#88-832	S\$72.10 Volume Pricing	Contact Us
12.00	20.00	17.69	YAG-BBAR (500-1100nm)	N-BK7	#88-833	S\$72.10 Volume Pricing	20+ In Stock
12.00	24.00	22.15	YAG-BBAR (500-1100nm)	N-BK7	#88-834	S\$70.00 Volume Pricing	20+ In Stock

12.00	25.00	23.22	YAG-BBAR (500-1100nm)	N-BK7	#38-576	S\$70.00 Volume Pricing	20+ In Stock
12.00	30.00	28.02	YAG-BBAR (500-1100nm)	N-BK7	#88-835	S\$70.00 Volume Pricing	2 In Stock
12.00	36.00	34.02	YAG-BBAR (500-1100nm)	N-BK7	#34-183	S\$70.00 Volume Pricing	3 In Stock
12.00	42.00	40.22	YAG-BBAR (500-1100nm)	N-BK7	#88-837	S\$70.00 Volume Pricing	16 In Stock
12.00	48.00	46.36	YAG-BBAR (500-1100nm)	N-BK7	#88-838	S\$70.00 Volume Pricing	5 In Stock
12.00	50.00	48.75	YAG-BBAR (500-1100nm)	N-BK7	#38-577	S\$70.00 Volume Pricing	4 In Stock
12.00	54.00	52.02	YAG-BBAR (500-1100nm)	N-BK7	#88-839	S\$70.00 Volume Pricing	5 In Stock
12.00	60.00	58.37	YAG-BBAR (500-1100nm)	N-BK7	#88-840	S\$70.00 Volume Pricing	Contact Us
12.00	72.00	70.42	YAG-BBAR (500-1100nm)	N-BK7	#88-841	S\$70.00 Volume Pricing	6 In Stock
12.00	84.00	82.39	YAG-BBAR (500-1100nm)	N-BK7	#88-842	S\$70.00 Volume Pricing	1 In Stock
12.00	100.00	98.35	YAG-BBAR (500-1100nm)	N-BK7	#88-843	S\$70.00 Volume Pricing	3 In Stock
12.50	12.50	10.40	YAG-BBAR (500-1100nm)	N-SF11	#38-578	S\$70.00 Volume Pricing	14 In Stock
12.50	15.00	13.26	YAG-BBAR (500-1100nm)	N-SF11	#38-579	S\$70.00 Volume Pricing	20+ In Stock
12.50	17.50	15.00	YAG-BBAR (500-1100nm)	N-BK7	#38-580	S\$70.00 Volume Pricing	Contact Us

12.50	20.00	17.69	YAG-BBAR (500-1100nm)	N-BK7	#38-581	S\$70.00 Volume Pricing	15 In Stock
12.50	25.00	22.96	YAG-BBAR (500-1100nm)	N-BK7	#38-584	S\$68.60 Volume Pricing	4 In Stock
12.50	30.00	28.22	YAG-BBAR (500-1100nm)	N-BK7	#38-585	S\$68.60 Volume Pricing	13 In Stock
12.50	35.00	33.42	YAG-BBAR (500-1100nm)	N-BK7	#38-586	S\$68.60 Volume Pricing	3 In Stock
12.50	40.00	38.55	YAG-BBAR (500-1100nm)	N-BK7	#38-587	S\$68.60 Volume Pricing	7 In Stock
12.50	45.00	43.68	YAG-BBAR (500-1100nm)	N-BK7	#38-588	S\$68.60 Volume Pricing	13 In Stock
12.50	50.00	48.68	YAG-BBAR (500-1100nm)	N-BK7	#38-589	S\$68.60 Volume Pricing	2 In Stock
12.50	75.00	73.88	YAG-BBAR (500-1100nm)	N-BK7	#38-591	S\$68.60 Volume Pricing	9 In Stock
12.50	100.00	98.95	YAG-BBAR (500-1100nm)	N-BK7	#38-593	S\$68.60 Volume Pricing	3 In Stock
12.70	12.70	10.46	YAG-BBAR (500-1100nm)	N-SF11	#88-844	S\$70.70 Volume Pricing	3 In Stock
12.70	15.00	11.53	YAG-BBAR (500-1100nm)	N-BK7	#88-845	S\$70.00 Volume Pricing	6 In Stock
12.70	19.10	16.46	YAG-BBAR (500-1100nm)	N-BK7	#88-846	S\$70.00 Volume Pricing	9 In Stock
12.70	20.00	17.49	YAG-BBAR (500-1100nm)	N-BK7	#38-594	S\$70.00 Volume Pricing	Contact Us
12.70	25.40	23.43	YAG-BBAR (500-1100nm)	N-BK7	#88-847	S\$68.60 Volume Pricing	6 In Stock

12.70	30.00	28.22	YAG-BBAR (500-1100nm)	N-BK7	#38-595	S\$68.60 Volume Pricing	Contact Us
12.70	31.80	29.81	YAG-BBAR (500-1100nm)	N-BK7	#88-848	S\$68.60 Volume Pricing	3 In Stock
12.70	38.10	36.12	YAG-BBAR (500-1100nm)	N-BK7	#88-849	S\$68.60 Volume Pricing	5 In Stock
12.70	40.00	38.48	YAG-BBAR (500-1100nm)	N-BK7	#38-596	S\$68.60 Volume Pricing	1 In Stock
12.70	44.50	42.69	YAG-BBAR (500-1100nm)	N-BK7	#88-850	S\$68.60 Volume Pricing	2 In Stock
12.70	50.80	49.15	YAG-BBAR (500-1100nm)	N-BK7	#88-851	S\$68.60 Volume Pricing	Contact Us
12.70	100.00	98.88	YAG-BBAR (500-1100nm)	N-BK7	#38-597	S\$68.60 Volume Pricing	1 In Stock
15.00	15.00	11.71	YAG-BBAR (500-1100nm)	N-SF5	#88-852	S\$72.10 Volume Pricing	10 In Stock
15.00	18.00	15.61	YAG-BBAR (500-1100nm)	N-SF5	#88-853	S\$72.10 Volume Pricing	4 In Stock
15.00	20.00	17.74	YAG-BBAR (500-1100nm)	N-SF5	#88-854	S\$72.10 Volume Pricing	20+ In Stock
15.00	22.50	20.50	YAG-BBAR (500-1100nm)	N-SF5	#88-855	S\$72.10 Volume Pricing	5 In Stock
15.00	25.00	22.50	YAG-BBAR (500-1100nm)	N-BK7	#38-598	S\$70.00 Volume Pricing	5 In Stock
15.00	30.00	27.90	YAG-BBAR (500-1100nm)	N-BK7	#88-856	S\$70.00 Volume Pricing	17 In Stock
15.00	40.00	38.02	YAG-BBAR (500-1100nm)	N-BK7	#88-857	S\$70.00 Volume Pricing	20+ In Stock

15.00	45.00	43.35	YAG-BBAR (500-1100nm)	N-BK7	#88-858	S\$70.00 Volume Pricing	8 In Stock
15.00	50.00	48.35	YAG-BBAR (500-1100nm)	N-BK7	#38-599	S\$70.00 Volume Pricing	14 In Stock
15.00	60.00	58.65	YAG-BBAR (500-1100nm)	N-BK7	#88-859	S\$70.00 Volume Pricing	7 In Stock
15.00	75.00	73.79	YAG-BBAR (500-1100nm)	N-BK7	#88-860	S\$70.00 Volume Pricing	5 In Stock
15.00	100.00	98.02	YAG-BBAR (500-1100nm)	N-BK7	#88-861	S\$70.00 Volume Pricing	14 In Stock
15.00	200.00	197.89	YAG-BBAR (500-1100nm)	N-BK7	#14-381	S\$70.00 Volume Pricing	6 In Stock
15.00	250.00	248.02	YAG-BBAR (500-1100nm)	N-BK7	#14-389	S\$70.00 Volume Pricing	Contact Us
18.00	18.00	15.20	YAG-BBAR (500-1100nm)	N-SF11	#88-862	S\$74.20 Volume Pricing	9 In Stock
18.00	20.00	17.59	YAG-BBAR (500-1100nm)	N-SF11	#38-600	S\$73.50 Volume Pricing	7 In Stock
18.00	22.50	20.26	YAG-BBAR (500-1100nm)	N-SF11	#88-863	S\$73.50 Volume Pricing	6 In Stock
18.00	25.00	21.51	YAG-BBAR (500-1100nm)	N-BK7	#38-601	S\$73.50 Volume Pricing	4 In Stock
18.00	27.00	24.73	YAG-BBAR (500-1100nm)	N-SF5	#88-864	S\$73.50 Volume Pricing	7 In Stock
18.00	30.00	27.10	YAG-BBAR (500-1100nm)	N-BK7	#38-602	S\$70.70 Volume Pricing	3 In Stock
18.00	36.00	33.65	YAG-BBAR (500-1100nm)	N-BK7	#88-865	S\$70.70 Volume Pricing	Contact Us

18.00	50.00	48.09	YAG-BBAR (500-1100nm)	N-BK7	#38-603	S\$70.70 Volume Pricing	20+ In Stock
18.00	54.00	52.02	YAG-BBAR (500-1100nm)	N-BK7	#88-866	S\$70.70 Volume Pricing	3 In Stock
18.00	72.00	70.05	YAG-BBAR (500-1100nm)	N-BK7	#88-867	S\$70.70 Volume Pricing	6 In Stock
20.00	20.00	17.42	YAG-BBAR (500-1100nm)	N-SF11	#88-868	S\$74.90 Volume Pricing	14 In Stock
20.00	25.00	22.76	YAG-BBAR (500-1100nm)	N-SF11	#88-869	S\$74.20 Volume Pricing	7 In Stock
20.00	35.00	32.04	YAG-BBAR (500-1100nm)	N-BK7	#88-871	S\$74.20 Volume Pricing	4 In Stock
20.00	40.00	36.77	YAG-BBAR (500-1100nm)	N-BK7	#88-872	S\$71.40 Volume Pricing	8 In Stock
20.00	50.00	47.87	YAG-BBAR (500-1100nm)	N-BK7	#88-873	S\$71.40 Volume Pricing	8 In Stock
20.00	60.00	57.03	YAG-BBAR (500-1100nm)	N-BK7	#88-874	S\$71.40 Volume Pricing	4 In Stock
20.00	70.00	68.03	YAG-BBAR (500-1100nm)	N-BK7	#88-875	S\$71.40 Volume Pricing	20+ In Stock
20.00	80.00	78.45	YAG-BBAR (500-1100nm)	N-BK7	#88-876	S\$71.40 Volume Pricing	20+ In Stock
20.00	100.00	97.13	YAG-BBAR (500-1100nm)	N-BK7	#88-877	S\$71.40 Volume Pricing	5 In Stock
20.00	150.00	148.02	YAG-BBAR (500-1100nm)	N-BK7	#88-878	S\$71.40 Volume Pricing	6 In Stock
25.00	25.00	20.22	YAG-BBAR (500-1100nm)	N-SF5	#88-879	S\$78.40 Volume Pricing	17 In Stock

25.00	30.00	24.69	YAG-BBAR (500-1100nm)	N-BK7	#88-880	S\$78.40 Volume Pricing	11 In Stock
25.00	35.00	30.42	YAG-BBAR (500-1100nm)	N-BK7	#88-881	S\$78.40 Volume Pricing	5 In Stock
25.00	40.00	36.31	YAG-BBAR (500-1100nm)	N-BK7	#88-882	S\$78.40 Volume Pricing	2 In Stock
25.00	50.00	46.75	YAG-BBAR (500-1100nm)	N-BK7	#88-883	S\$75.60 Volume Pricing	10 In Stock
25.00	60.00	56.90	YAG-BBAR (500-1100nm)	N-BK7	#88-884	S\$75.60 Volume Pricing	6 In Stock
25.00	75.00	72.00	YAG-BBAR (500-1100nm)	N-BK7	#88-885	S\$75.60 Volume Pricing	5 In Stock
25.00	85.00	82.17	YAG-BBAR (500-1100nm)	N-BK7	#88-886	S\$75.60 Volume Pricing	5 In Stock
25.00	100.00	97.17	YAG-BBAR (500-1100nm)	N-BK7	#88-887	S\$75.60 Volume Pricing	5 In Stock
25.00	125.00	122.70	YAG-BBAR (500-1100nm)	N-BK7	#88-888	S\$75.60 Volume Pricing	12 In Stock
25.00	150.00	147.81	YAG-BBAR (500-1100nm)	N-BK7	#88-889	S\$75.60 Volume Pricing	3 In Stock
25.00	175.00	172.85	YAG-BBAR (500-1100nm)	N-BK7	#88-890	S\$75.60 Volume Pricing	5 In Stock
25.00	200.00	197.89	YAG-BBAR (500-1100nm)	N-BK7	#34-184	S\$75.60 Volume Pricing	9 In Stock
25.00	250.00	248.02	YAG-BBAR (500-1100nm)	N-BK7	#88-892	S\$75.60 Volume Pricing	6 In Stock
25.00	300.00	298.02	YAG-BBAR (500-1100nm)	N-BK7	#88-893	S\$75.60 Volume Pricing	6 In Stock

25.00	400.00	397.89	YAG-BBAR (500-1100nm)	N-BK7	#34-185	S\$75.60 Volume Pricing	14 In Stock
25.00	500.00	497.89	YAG-BBAR (500-1100nm)	N-BK7	#88-895	S\$75.60 Volume Pricing	2 In Stock
25.00	750.00	747.89	YAG-BBAR (500-1100nm)	N-BK7	#88-896	S\$75.60 Volume Pricing	10 In Stock
25.40	25.40	21.48	YAG-BBAR (500-1100nm)	N-SF11	#88-897	S\$79.10 Volume Pricing	11 In Stock
25.40	35.00	30.46	YAG-BBAR (500-1100nm)	N-BK7	#38-604	S\$78.40 Volume Pricing	1 In Stock
25.40	38.10	33.48	YAG-BBAR (500-1100nm)	N-BK7	#88-898	S\$78.40 Volume Pricing	9 In Stock
25.40	40.00	36.11	YAG-BBAR (500-1100nm)	N-BK7	#38-605	S\$78.40 Volume Pricing	5 In Stock
25.40	50.80	47.50	YAG-BBAR (500-1100nm)	N-BK7	#88-899	S\$75.60 Volume Pricing	3 In Stock
25.40	63.50	60.37	YAG-BBAR (500-1100nm)	N-BK7	#88-900	S\$75.60 Volume Pricing	Contact Us
25.40	75.00	72.69	YAG-BBAR (500-1100nm)	N-BK7	#38-607	S\$75.60 Volume Pricing	5 In Stock
25.40	76.20	73.56	YAG-BBAR (500-1100nm)	N-BK7	#88-901	S\$75.60 Volume Pricing	10 In Stock
25.40	88.90	86.26	YAG-BBAR (500-1100nm)	N-BK7	#88-902	S\$75.60 Volume Pricing	Contact Us
25.40	100.00	98.02	YAG-BBAR (500-1100nm)	N-BK7	#38-608	S\$75.60 Volume Pricing	5 In Stock
25.40	101.60	98.97	YAG-BBAR (500-1100nm)	N-BK7	#88-903	S\$75.60 Volume Pricing	1 In Stock

25.40	125.00	123.02	YAG-BBAR (500-1100nm)	N-BK7	#38-609	S\$75.60 Volume Pricing	20+ In Stock
25.40	150.00	148.02	YAG-BBAR (500-1100nm)	N-BK7	#38-610	S\$75.60 Volume Pricing	13 In Stock
30.00	30.00	26.13	YAG-BBAR (500-1100nm)	N-SF11	#88-904	S\$89.60 Volume Pricing	7 In Stock
30.00	40.00	37.20	YAG-BBAR (500-1100nm)	N-SF11	#88-905	S\$86.80 Volume Pricing	Contact Us
30.00	50.00	46.17	YAG-BBAR (500-1100nm)	N-SF5	#88-906	S\$86.80 Volume Pricing	20+ In Stock
30.00	60.00	56.03	YAG-BBAR (500-1100nm)	N-BK7	#88-907	S\$84.00 Volume Pricing	14 In Stock
30.00	75.00	70.95	YAG-BBAR (500-1100nm)	N-BK7	#88-908	S\$84.00 Volume Pricing	Contact Us
30.00	100.00	96.01	YAG-BBAR (500-1100nm)	N-BK7	#88-909	S\$84.00 Volume Pricing	4 In Stock
30.00	120.00	116.04	YAG-BBAR (500-1100nm)	N-BK7	#88-910	S\$84.00 Volume Pricing	2 In Stock
35.00	35.00	30.52	YAG-BBAR (500-1100nm)	N-SF11	#38-611	S\$91.70 Volume Pricing	6 In Stock
35.00	50.00	44.40	YAG-BBAR (500-1100nm)	N-BK7	#38-612	S\$89.60 Volume Pricing	4 In Stock
35.00	70.00	66.04	YAG-BBAR (500-1100nm)	N-BK7	#38-613	S\$89.60 Volume Pricing	4 In Stock
35.00	100.00	97.03	YAG-BBAR (500-1100nm)	N-BK7	#38-614	S\$89.60 Volume Pricing	4 In Stock
40.00	40.00	35.13	YAG-BBAR (500-1100nm)	N-SF11	#88-911	S\$107.10 Volume Pricing	11 In Stock

40.00	60.00	53.90	YAG-BBAR (500-1100nm)	N-BK7	#88-912	S\$107.10 Volume Pricing	7 In Stock
40.00	80.00	74.73	YAG-BBAR (500-1100nm)	N-BK7	#34-186	S\$105.70 Volume Pricing	1 In Stock
40.00	100.00	95.39	YAG-BBAR (500-1100nm)	N-BK7	#34-187	S\$105.70 Volume Pricing	5 In Stock
40.00	200.00	196.70	YAG-BBAR (500-1100nm)	N-BK7	#34-188	S\$105.70 Volume Pricing	4 In Stock
40.00	300.00	296.70	YAG-BBAR (500-1100nm)	N-BK7	#88-916	S\$105.70 Volume Pricing	9 In Stock
40.00	400.00	396.70	YAG-BBAR (500-1100nm)	N-BK7	#88-917	S\$105.70 Volume Pricing	5 In Stock
50.00	50.00	43.28	YAG-BBAR (500-1100nm)	N-SF11	#88-918	S\$116.20 Volume Pricing	15 In Stock
50.00	75.00	67.75	YAG-BBAR (500-1100nm)	N-BK7	#88-919	S\$112.70 Volume Pricing	6 In Stock
50.00	100.00	93.41	YAG-BBAR (500-1100nm)	N-BK7	#88-920	S\$109.20 Volume Pricing	5 In Stock
50.00	125.00	118.39	YAG-BBAR (500-1100nm)	N-BK7	#88-921	S\$109.20 Volume Pricing	Contact Us
50.00	150.00	144.07	YAG-BBAR (500-1100nm)	N-BK7	#88-922	S\$109.20 Volume Pricing	6 In Stock
50.00	175.00	169.05	YAG-BBAR (500-1100nm)	N-BK7	#88-923	S\$109.20 Volume Pricing	7 In Stock
50.00	200.00	196.66	YAG-BBAR (500-1100nm)	N-BK7	#88-924	S\$109.20 Volume Pricing	2 In Stock
50.00	250.00	246.74	YAG-BBAR (500-1100nm)	N-BK7	#88-925	S\$109.20 Volume Pricing	3 In Stock

50.00	500.00	496.70	YAG-BBAR (500-1100nm)	N-BK7	#88-926	S\$109.20 Volume Pricing	8 In Stock
50.80	50.81	44.08	YAG-BBAR (500-1100nm)	N-SF11	#71-341	S\$116.20 Volume Pricing	7 In Stock
50.80	76.20	68.95	YAG-BBAR (500-1100nm)	N-BK7	#71-348	S\$112.70 Volume Pricing	4 In Stock
75.00	75.00	53.49	YAG-BBAR (500-1100nm)	N-BK7	#26-114	S\$225.40 Volume Pricing	Contact Us
75.00	100.00	85.61	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-308	S\$1,036.00 Volume Pricing	5 In Stock
75.00	125.00	112.66	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-316	S\$1,008.00 Volume Pricing	5 In Stock
75.00	150.00	142.45	YAG-BBAR (500-1100nm)	N-BK7	#26-115	S\$221.20 Volume Pricing	8 In Stock
75.00	150.00	136.31	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-324	S\$980.00 Volume Pricing	5 In Stock
75.00	200.00	194.24	YAG-BBAR (500-1100nm)	N-BK7	#26-116	S\$221.20 Volume Pricing	7 In Stock
75.00	200.00	187.18	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-332	S\$938.00 Volume Pricing	5 In Stock
75.00	250.00	244.73	YAG-BBAR (500-1100nm)	N-BK7	#26-117	S\$221.20 Volume Pricing	9 In Stock
75.00	500.00	494.73	YAG-BBAR (500-1100nm)	N-BK7	#26-118	S\$221.20 Volume Pricing	5 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com