

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Focus Tunable Lenses](#) / [Current-Driven Liquid Lenses](#)

Optotune Focus Tunable Lenses 16mm Clear Aperture Hirose Connector

See More by [Optotune](#)



- Multiple Imaging Lens Mounting Options
- Large Clear Aperture Ideal for Machine Vision Applications
- Industrial Hirose Connection with Temperature Sensing
- Integrated Temperature Control for Improved Thermal Effects
- [Optotune Focus Tunable Lenses 10mm Clear Aperture Hirose Connector](#) and [Lens Drivers](#) Also Available

Common Specifications

General

Driver:	#88-940	Lifecycles:	1,000,000,000
Response Time (ms):	5 (typical @ 30°C)	Settling Time (ms):	25 (typical @ 30°C)

Physical & Mechanical Properties

Clear Aperture CA (mm):	16.00	Dimensions (mm):	47.0 x 70.0
Thickness (mm):	17.60		

Optical Properties

Substrate:	Low Dispersion Polymer		
Abbe Number (v_d):	100.00	Index of Refraction (n_d):	1.3


Electrical

Current (mA):	-250 to 250	Power Consumption (W):	0 - 0.7
----------------------	-------------	-------------------------------	---------

Environmental & Durability Factors

Operating Temperature (°C):	-20 to +65
------------------------------------	------------

Technical Information

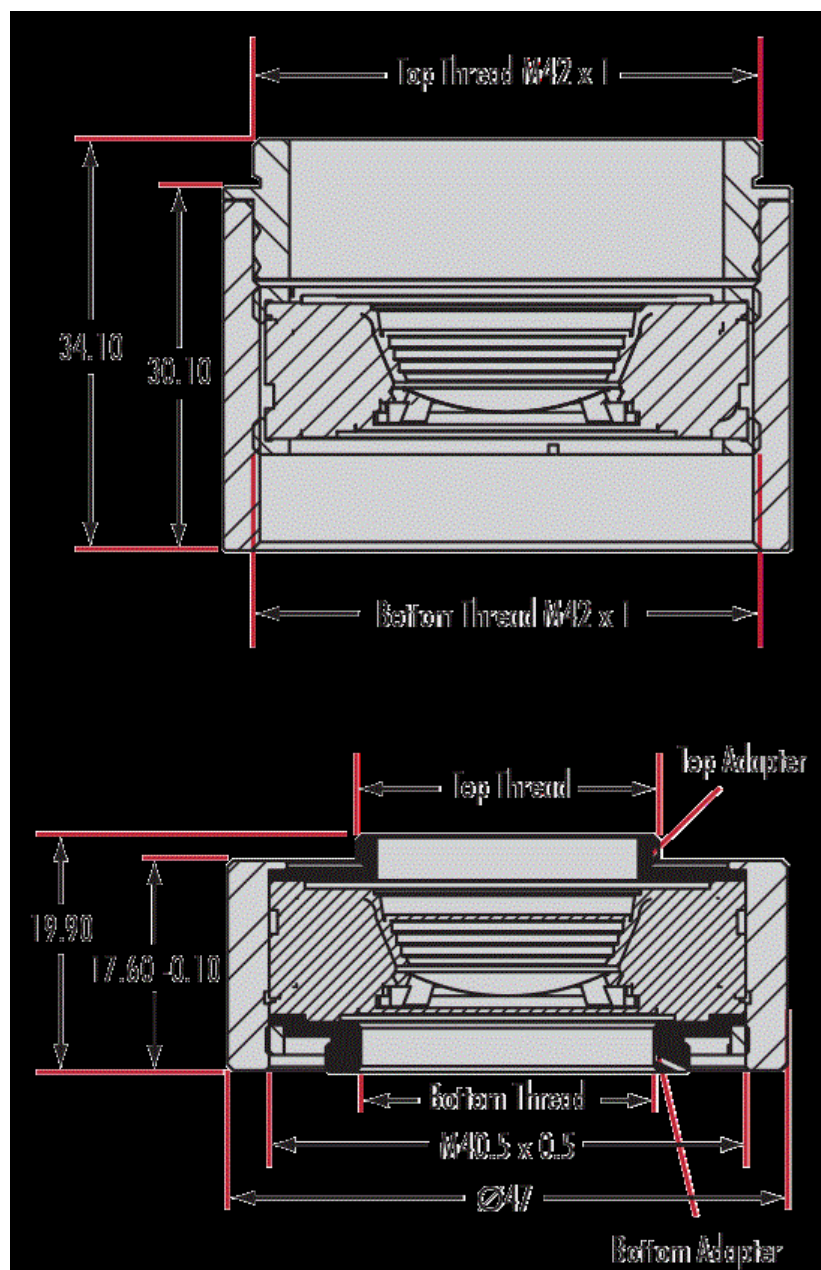

Products

CA (mm)	Coating	Focus Range (mm)	Transmitted Wavefront Error, RMS	Mounting Threads	Stock Number	Price	Buy
16.00	BBAR (420-950nm)	-2 to +3 diopter -500 to +333mm	Vertical: 0.25λ @ 525nm Horizontal: 0.50λ @ 525nm	M25.5 x 0.5 (Male) M40.5 x 0.5 (Female)	#33-491	S\$1,727.00	5 In Stock
16.00	BBAR (420-950nm)	-2 to +3 diopter -500 to +333mm	Vertical: 0.25λ @ 525nm Horizontal: 0.50λ @ 525nm	M27 x 0.5 (Male) M40.5 x 0.5 (Female)	#33-492	S\$1,727.00	3 In Stock
16.00	BBAR (420-950nm)	-2 to +3 diopter -500 to +333mm	Vertical: 0.25λ @ 525nm Horizontal: 0.50λ @ 525nm	M30.5 x 0.5 (Male) M40.5 x 0.5 (Female)	#33-493	S\$1,727.00	6 In Stock
16.00	BBAR (420-950nm)	-2 to +3 diopter -500 to +333mm	Vertical: 0.25λ @ 525nm Horizontal: 0.50λ @ 525nm	C-Mount (Male) C-Mount (Female)	#33-494	S\$1,727.00	16 In Stock
#78-517 New							
							
New							
16.00	BBAR (420-950nm)	-2 to +3 diopter -500 to +333mm	Vertical: 0.15λ @ 525nm Horizontal: 0.50λ @ 525nm	C-Mount (Male) C-Mount (Female)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	S\$2,565.00	1 In Stock

[#78-518 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

16.00	BBAR (850-1500nm)	-2 to +3 diopter -500 to +333mm	Vertical: 0.15λ @ 525nm Horizontal: 0.50λ @ 525nm	C-Mount (Male) C-Mount (Female)		S\$2,829.00	Contact Us
-------	----------------------	--	--	--	--	-------------	------------

16.00	BBAR (420-950nm)	-10 to +10 diopter -100 to +100mm	Vertical: 0.5λ @ 532nm Horizontal: 2.5λ @ 532nm	C-Mount (Male) C-Mount (Female)	#35-086	S\$3,283.00	Contact Us
-------	---------------------	---	---	--	-------------------------	-------------	------------



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com