


[All Products](#) / [Lights and Illumination](#) / [Machine Vision Lighting](#) / [Backlights](#)

Advanced Illumination EuroBrite™ Backlights [See More by Advanced Illumination](#)

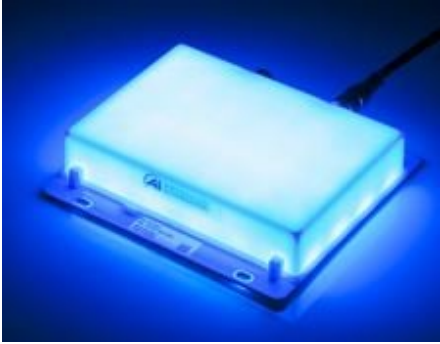

- Daisy Chain up to Four 100 x 150mm Units
- Requires No Heat Sink
- Available in White, Red, and Blue

Common Specifications

General			
Operating Lifetime (hours):	50,000	Type of Illumination:	LED Illuminator
Manufacturer:	Advanced Illumination	Geometry:	Backlight
Illumination Mode:	Strobed or Constant		
Electrical			
Maximum Input Current:	0.42 - 0.49A		
Analog Intensity Control:	10% @ 0.7V, 100% @ 10V	Trigger-to-Pulse Latency:	10µm
Hardware & Interface Connectivity			
Connector:	Flying Leads	Input Voltage (V):	24V nominal (min. 22 / max. 28)
Power Supply:	Power Supply Required and Sold Separately: USA: #66-855 Europe: #66-855 Japan: #89-513 Korea: #33-773 China: #66-855		
Environmental & Durability Factors			
Operating Temperature (°C):	0 - 60		

Technical Information

Products

Dimensions (mm)	Color	Wavelength (nm)	Stock Number	Price	Buy
75 x 89 x 30	White	-	#33-456	S\$362.50	1 In Stock
75 x 89 x 30	Red	625.00	#33-457	S\$297.25	Contact Us
75 x 89 x 30	Blue	470.00	#33-458	S\$362.50	Contact Us
150 x 139 x 30	White	-	#33-459	S\$645.25	1 In Stock
150 x 139 x 30	Red	625.00	#33-460	S\$645.25	1 In Stock
150 x 139 x 30	Blue	470.00	#33-461	S\$601.75	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com