

[All Products](#) / [Lights and Illumination](#) / [Machine Vision Lighting](#) / [Ring Lights](#)

## Effilux Adjustable LED Ring Lights



- Easy to Access Lens Array for Quick, Manual Adjustment of Illumination Emission Angles
- Included Interchangeable Windows Allows for Easy Adjustment of Light Diffusion
- Integrate Polarizer Accessory for Glare Elimination

# Common Specifications

## General

Type of Illumination:	LED Illuminator	Manufacturer:	Effilux
Geometry:	Ring Light	Illumination Mode:	Strobed or Constant

## Physical & Mechanical Properties

Inner Diameter (mm):	58.0	Dimensions (mm):	151.0 x 117.0 x 40.0
----------------------	------	------------------	----------------------

## Hardware & Interface Connectivity

Connector:	M12, 5 pins	Input Voltage (V):	24V DC
Power Supply:	<p>Power Supply Required and Sold Separately: USA: <a href="#">#15-874</a> Europe: <a href="#">#15-875</a> Japan: <a href="#">#73-409</a> Korea: <a href="#">#73-409</a> China: <a href="#">#15-874</a></p>		

## Threading & Mounting



Mount:	M4 (x4) and 3.5mm Thru (x4)
--------	-----------------------------

## Environmental & Durability Factors

Operating Temperature (°C):	-10 to 50	Environmental Rating:	IP65
-----------------------------	-----------	-----------------------	------

## Technical Information

### Effilux Adjustable LED Ring Lights

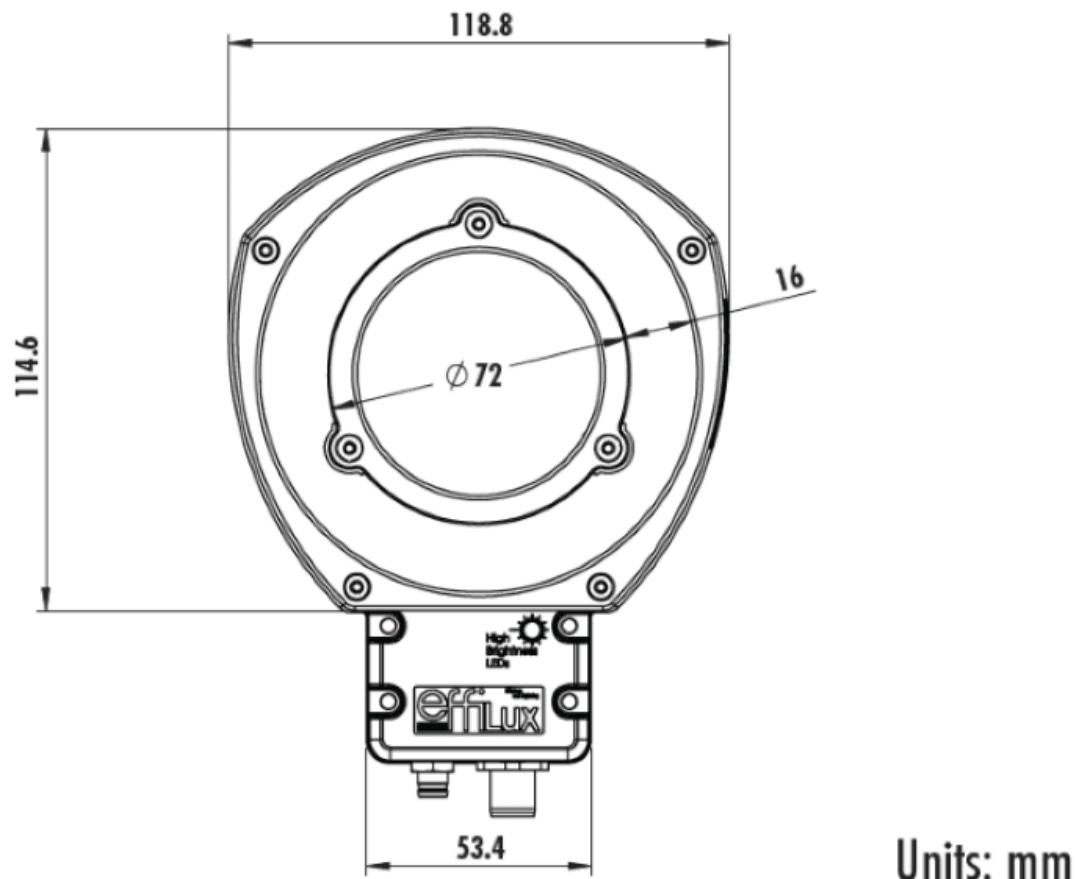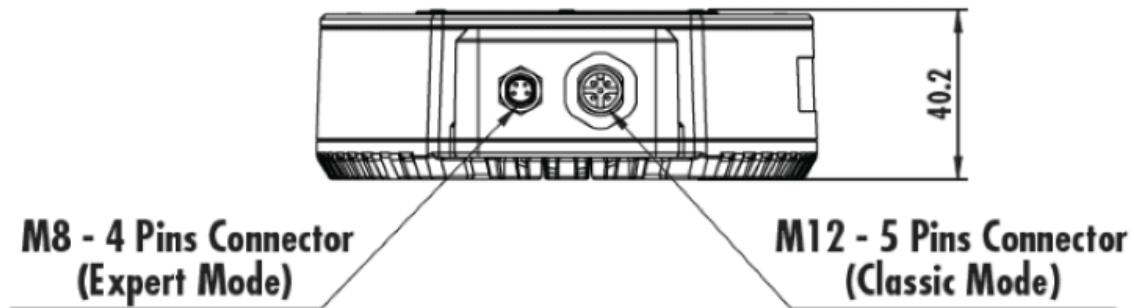

## Products

Color	Wavelength (nm)	Illumination Mode	Inner Diameter (mm)	Stock Number	Price	Buy
White	-	Strobed or Constant	58.0	<a href="#">#34-861</a>	S\$1,002.00	3 In Stock

[#75-583 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

Blue	465.00	Strobed or Constant	58.0		S\$1,084.00	Contact Us
------	--------	---------------------	------	--	-------------	------------

[#75-585 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

Green	525.00	Strobed or Constant	58.0		S\$1,084.00	Contact Us
-------	--------	---------------------	------	--	-------------	------------

Red	625.00	Strobed or Constant	58.0	<a href="#">#34-862</a>	S\$1,002.00	Contact Us
IR	850.00	Strobed or Constant	58.0	<a href="#">#34-863</a>	S\$1,090.00	2 In Stock
RGB	-	Strobed or Constant	58.0	<a href="#">#34-864</a>	S\$1,235.00	Contact Us

[#75-580 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

UV	405.00	Strobed or Constant	58.0	<a href="#">#34-862</a>	S\$2,420.00	Contact Us
----	--------	---------------------	------	-------------------------	-------------	------------

White, UV, IR	-	Strobed or Constant	58.0	<a href="#">#34-865</a>	S\$1,638.00	1 In Stock
------------------	---	---------------------	------	-------------------------	-------------	------------



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)