

[All Products](#) / [Lasers](#) / [Laser Sources](#) / [Life Science Lasers](#)

Low Cost Turnkey Lasers



- Multiple Colors and Wavelengths Available
- Ideal for Microscopy Applications
- TE Cooled



Common Specifications

General


Type of Laser: Diode

Laser Class - CDRH: IIIb

Electrical

Power Stability (%): <2% RMS over 4 hours

Technical Information

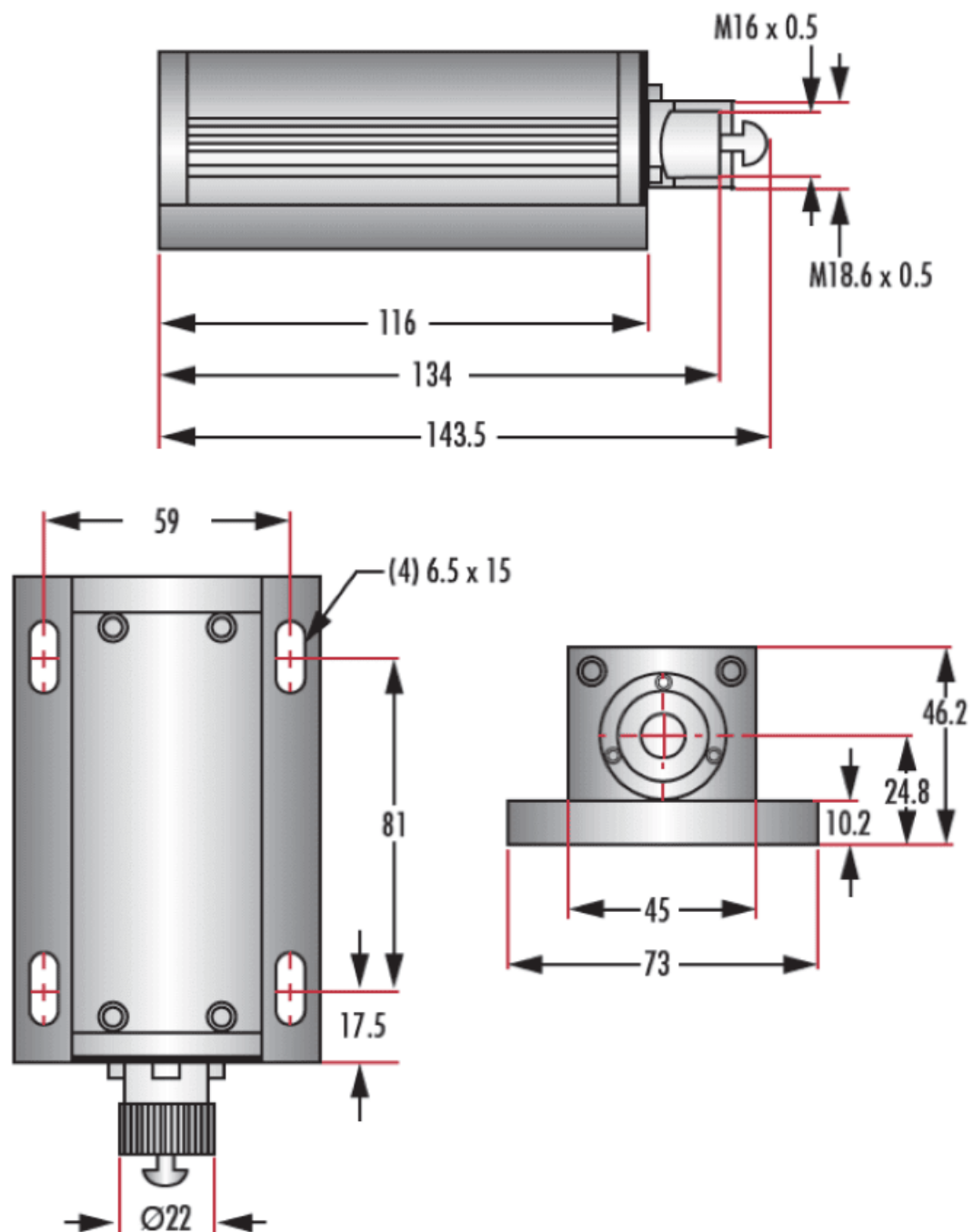

Products

Wavelength (nm)	Output Power (mW)	Output Type	Stock Number	Price	Buy
405.00	50	Free Space	#35-069	S\$4,690.75	2 In Stock
470.00	200	Fiber-Coupled	#19-504	S\$5,930.50	1 In Stock
473.00	50	Free Space	#35-070	S\$6,684.50	1 In Stock
488.00	50	Free Space	#37-091	S\$8,265.00	1 In Stock
532.00	50	Free Space	#35-072	S\$4,132.50	4 In Stock
532.00	50	Fiber-Coupled	#19-486	S\$4,995.25	1 In Stock
589.00	50	Free Space	#35-073	S\$9,570.00	1 In Stock
589.00	200	Fiber-Coupled	#19-506	S\$14,862.50	1 In Stock
640.00	50	Free Space	#35-074	S\$4,205.00	1 In Stock
785.00	50	Free Space	#19-488	S\$3,980.25	1 In Stock
808.00	50	Free Space	#19-489	S\$4,052.75	1 In Stock
980.00	50	Free Space	#19-490	S\$4,052.75	Contact Us
1,064.00	50	Free Space	#35-075	S\$3,458.25	4 In Stock
1,064.00	50	Fiber-Coupled	#19-487	S\$4,618.25	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com