

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Ball and Condenser Lenses](#)

Molded Aspheric Condenser Lenses



- Hardened for Improved Durability
- High Numerical Apertures
- Ideal for Illumination Applications

Common Specifications

Physical & Mechanical Properties

Bevel:


Protective as needed

Optical Properties

Conjugate Distance:

Infinite

Technical Information

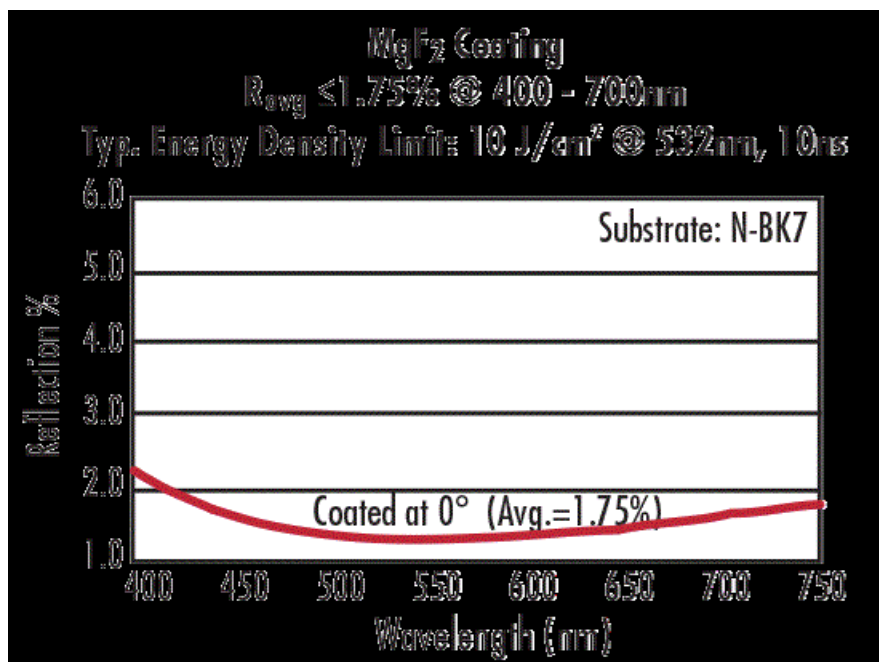

Products

Dia. (mm)	EFL (mm)	NA	Coating	Stock Number	Price	Buy
5.00	3.10	0.81	Uncoated	#15-172	S\$47.79 Volume Pricing	20+ In Stock
5.00	3.10	0.81	MgF ₂ (400-700nm)	#15-677	S\$64.22 Volume Pricing	20+ In Stock
5.00	3.70	0.68	Uncoated	#88-282	S\$47.79 Volume Pricing	20+ In Stock
5.00	3.70	0.68	MgF ₂ (400-700nm)	#35-031	S\$64.22 Volume Pricing	Contact Us
5.00	3.70	0.68	NIR I (600-1050nm)	#15-877	S\$85.13 Volume Pricing	Contact Us
5.00	3.70	0.68	VIS-EXT (350-700nm)	#71-481	S\$85.13 Volume Pricing	5 In Stock
6.30	9.00	0.35	Uncoated	#34-455	S\$47.79 Volume Pricing	20+ In Stock
6.30	9.00	0.35	MgF ₂ (400-700nm)	#35-033	S\$64.22 Volume Pricing	8 In Stock
6.30	9.00	0.35	NIR I (600-1050nm)	#15-878	S\$85.13 Volume Pricing	20+ In Stock
6.30	9.00	0.35	VIS-EXT (350-700nm)	#71-482	S\$85.13 Volume Pricing	5 In Stock
6.80	6.00	0.56	Uncoated	#34-456	S\$47.79 Volume Pricing	20+ In Stock
6.80	6.00	0.56	MgF ₂ (400-700nm)	#35-036	S\$64.22 Volume Pricing	9 In Stock
6.80	6.00	0.56	NIR I (600-1050nm)	#15-879	S\$85.13 Volume Pricing	9 In Stock

6.80	6.00	0.56	VIS-EXT (350-700nm)	#71-483	S\$85.13 Volume Pricing	Contact Us
8.50	7.40	0.57	Uncoated	#34-457	S\$47.79 Volume Pricing	20+ In Stock
8.50	7.40	0.57	MgF ₂ (400-700nm)	#35-037	S\$64.22 Volume Pricing	20+ In Stock
8.50	7.40	0.57	NIR I (600-1050nm)	#15-880	S\$85.13 Volume Pricing	5 In Stock
8.50	7.40	0.57	VIS-EXT (350-700nm)	#71-484	S\$85.13 Volume Pricing	5 In Stock
10.00	6.60	0.76	VIS-EXT (350-700nm)	#71-485	S\$85.13 Volume Pricing	3 In Stock
#88-283 Clearance						
 Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.						
10.00	6.60	0.76	Uncoated		S\$47.79 Volume Pricing	20+ In Stock
10.00	6.60	0.76	MgF ₂ (400-700nm)	#35-038	S\$64.22 Volume Pricing	20+ In Stock
10.00	6.60	0.76	NIR I (600-1050nm)	#15-881	S\$85.13 Volume Pricing	6 In Stock
12.00	7.50	0.8	Uncoated	#88-284	S\$47.79 Volume Pricing	20+ In Stock
12.00	7.50	0.8	MgF ₂ (400-700nm)	#35-039	S\$64.22 Volume Pricing	Contact Us

12.00	7.50	0.8	NIR I (600-1050nm)	#15-882	S\$85.13 Volume Pricing	11 In Stock
12.00	7.50	0.8	VIS-EXT (350-700nm)	#71-486	S\$85.13 Volume Pricing	6 In Stock
12.00	10.50	0.57	VIS-EXT (350-700nm)	#71-487	S\$85.13 Volume Pricing	4 In Stock
12.00	10.50	0.57	Uncoated	#88-285	S\$47.79 Volume Pricing	20+ In Stock
12.00	10.50	0.57	MgF ₂ (400-700nm)	#35-040	S\$64.22 Volume Pricing	12 In Stock
12.00	10.50	0.57	NIR I (600-1050nm)	#15-883	S\$85.13 Volume Pricing	6 In Stock
12.00	10.40	0.57	Uncoated	#88-286	S\$47.79 Volume Pricing	20+ In Stock
12.00	10.40	0.57	MgF ₂ (400-700nm)	#35-041	S\$64.22 Volume Pricing	7 In Stock
12.00	10.40	0.57	NIR I (600-1050nm)	#15-884	S\$85.13 Volume Pricing	5 In Stock
12.00	10.40	0.57	VIS-EXT (350-700nm)	#71-488	S\$85.13 Volume Pricing	5 In Stock
12.00	12.50	0.48	VIS-EXT (350-700nm)	#71-489	S\$85.13 Volume Pricing	5 In Stock
12.00	12.50	0.48	Uncoated	#88-287	S\$47.79 Volume Pricing	20+ In Stock
12.00	12.50	0.48	MgF ₂ (400-700nm)	#35-065	S\$64.22 Volume Pricing	20+ In Stock
12.00	12.50	0.48	NIR I (600-1050nm)	#15-885	S\$85.13 Volume Pricing	10 In Stock
13.00	7.70	0.85	VIS-EXT (350-700nm)	#71-490	S\$85.13 Volume Pricing	7 In Stock

13.00	7.70	0.85	Uncoated	#34-458	S\$47.79 Volume Pricing	Contact Us
13.00	7.70	0.85	MgF ₂ (400-700nm)	#35-044	S\$64.22 Volume Pricing	20+ In Stock
13.00	7.70	0.85	NIR I (600-1050nm)	#15-886	S\$85.13 Volume Pricing	20+ In Stock
15.00	8.25	0.91	Uncoated	#15-173	S\$47.79 Volume Pricing	20+ In Stock
15.00	8.25	0.91	MgF ₂ (400-700nm)	#15-678	S\$64.22 Volume Pricing	5 In Stock
15.00	8.25	0.91	NIR I (600-1050nm)	#15-887	S\$85.13 Volume Pricing	4 In Stock
15.00	8.25	0.91	VIS-EXT (350-700nm)	#71-491	S\$85.13 Volume Pricing	3 In Stock
16.00	10.80	0.74	Uncoated	#34-459	S\$47.79 Volume Pricing	20+ In Stock
16.00	10.80	0.74	MgF ₂ (400-700nm)	#35-047	S\$64.22 Volume Pricing	Contact Us
18.00	8.40	1.06	Uncoated	#34-460	S\$47.79 Volume Pricing	20+ In Stock
18.00	8.40	1.06	MgF ₂ (400-700nm)	#35-048	S\$64.22 Volume Pricing	Contact Us
18.00	13.50	0.67	Uncoated	#34-461	S\$47.79 Volume Pricing	20+ In Stock
18.00	13.50	0.67	MgF ₂ (400-700nm)	#35-049	S\$64.22 Volume Pricing	7 In Stock
18.00	13.50	0.67	NIR I (600-1050nm)	#15-888	S\$85.13 Volume Pricing	2 In Stock
18.00	13.50	0.67	VIS-EXT (350-700nm)	#71-492	S\$85.13 Volume Pricing	1 In Stock

20.00	11.00	0.89	VIS-EXT (350-700nm)	#71-493	S\$97.08 Volume Pricing	Contact Us
20.00	11.10	0.89	Uncoated	#88-288	S\$59.74 Volume Pricing	20+ In Stock
20.00	11.10	0.89	MgF ₂ (400-700nm)	#35-052	S\$76.17 Volume Pricing	20+ In Stock
20.00	11.10	0.89	NIR I (600-1050nm)	#15-889	S\$97.08 Volume Pricing	5 In Stock
20.00	16.00	0.63	Uncoated	#88-289	S\$59.74 Volume Pricing	Contact Us
20.00	16.00	0.63	MgF ₂ (400-700nm)	#35-062	S\$76.17 Volume Pricing	20+ In Stock
20.00	16.00	0.63	NIR I (600-1050nm)	#15-890	S\$97.08 Volume Pricing	4 In Stock
20.00	16.00	0.63	VIS-EXT (350-700nm)	#71-494	S\$97.08 Volume Pricing	2 In Stock
20.00	16.40	0.61	Uncoated	#15-174	S\$59.74 Volume Pricing	Contact Us
20.00	16.40	0.61	MgF ₂ (400-700nm)	#15-679	S\$76.17 Volume Pricing	Contact Us
20.00	16.40	0.61	NIR I (600-1050nm)	#15-892	S\$97.08 Volume Pricing	4 In Stock
20.00	17.50	0.57	Uncoated	#88-290	S\$59.74 Volume Pricing	20+ In Stock
20.00	17.50	0.57	MgF ₂ (400-700nm)	#35-063	S\$76.17 Volume Pricing	4 In Stock
20.00	17.50	0.57	NIR I (600-1050nm)	#15-891	S\$97.08 Volume Pricing	7 In Stock
20.00	17.50	0.57	VIS-EXT (350-700nm)	#71-495	S\$97.08 Volume Pricing	4 In Stock

24.00	16.40	0.61	VIS-EXT (350-700nm)	#71-496	S\$97.08 Volume Pricing	4 In Stock
24.00	15.40	0.78	Uncoated	#15-175	S\$64.22 Volume Pricing	20+ In Stock
24.00	15.40	0.78	MgF ₂ (400-700nm)	#15-680	S\$80.65 Volume Pricing	20+ In Stock
24.00	18.00	0.67	Uncoated	#15-176	S\$64.22 Volume Pricing	20+ In Stock
24.00	18.00	0.67	MgF ₂ (400-700nm)	#15-681	S\$80.65 Volume Pricing	12 In Stock
24.00	18.00	0.67	NIR I (600-1050nm)	#15-893	S\$97.08 Volume Pricing	13 In Stock
24.00	18.00	0.67	VIS-EXT (350-700nm)	#71-497	S\$97.08 Volume Pricing	5 In Stock
26.00	19.50	0.67	Uncoated	#34-462	S\$64.22 Volume Pricing	2 In Stock
26.00	19.50	0.67	MgF ₂ (400-700nm)	#35-064	S\$80.65 Volume Pricing	20+ In Stock
26.00	19.50	0.67	NIR I (600-1050nm)	#15-894	S\$97.08 Volume Pricing	7 In Stock
26.00	19.50	0.67	VIS-EXT (350-700nm)	#71-498	S\$97.08 Volume Pricing	8 In Stock
30.00	17.50	0.86	Uncoated	#88-291	S\$68.70 Volume Pricing	20+ In Stock
30.00	17.50	0.86	MgF ₂ (400-700nm)	#15-683	S\$83.64 Volume Pricing	20+ In Stock
30.00	17.50	0.86	NIR I (600-1050nm)	#15-895	S\$106.04 Volume Pricing	20+ In Stock
30.00	17.50	0.86	VIS-EXT (350-700nm)	#71-499	S\$106.04 Volume Pricing	4 In Stock

30.00	26.90	0.56	Uncoated	#15-177	S\$68.70 Volume Pricing	20+ In Stock
30.00	26.90	0.56	MgF ₂ (400-700nm)	#15-682	S\$83.64 Volume Pricing	3 In Stock
30.00	26.90	0.56	NIR I (600-1050nm)	#15-896	S\$106.04 Volume Pricing	11 In Stock
30.00	26.90	0.56	VIS-EXT (350-700nm)	#71-500	S\$106.04 Volume Pricing	3 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com