

[All Products](#) /
 [Laser Optics](#) /
 [Laser Mirrors](#) /
 [Laser Line Mirrors](#)

TECHSPEC® Concave Laser Line Mirrors



- Ideal for Focusing Laser Light
- >99.8% Reflectivity at Center Wavelength
- High Thermal Stability Fused Silica Substrates

Common Specifications

Physical & Mechanical Properties

Back Surface: Fine Grind

Clear Aperture (%): 90


Optical Properties

Substrate: [Fused Silica](#) (Corning 7980)


Surface Quality: 20-10

Technical Information

266nm and 355nm

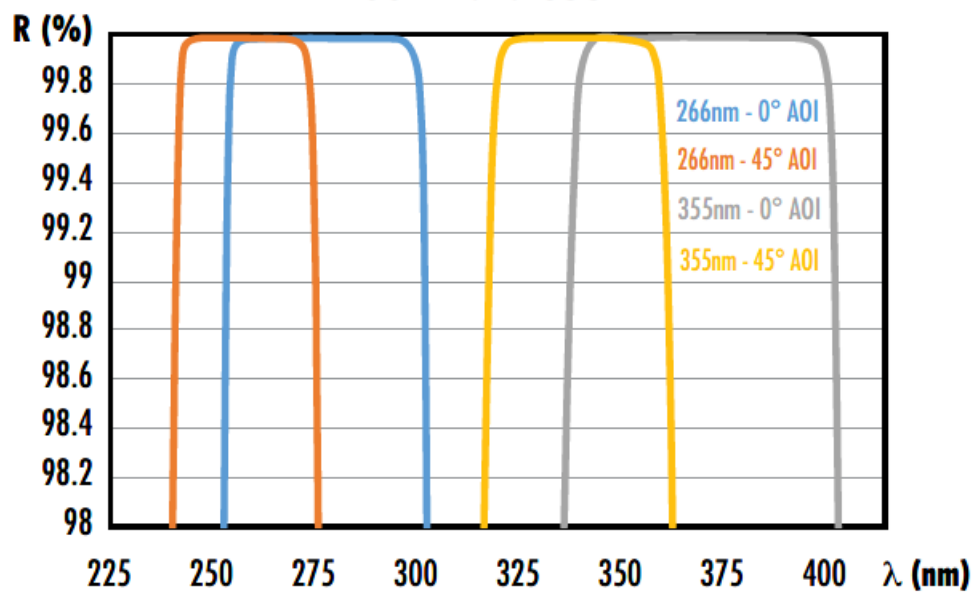

532nm and 1064nm

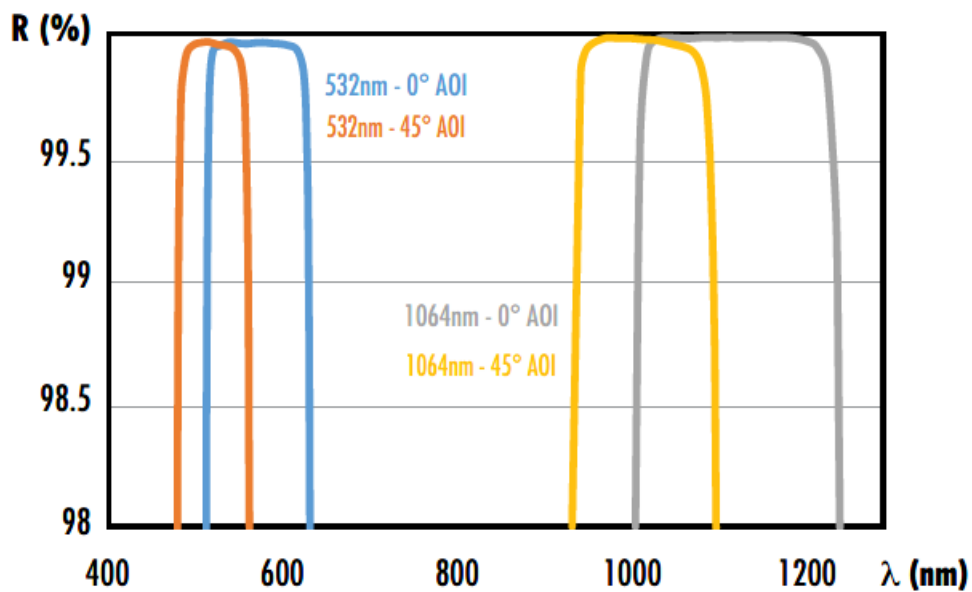

Products

DWL (nm)	Dia. (mm)	EFL (mm)	Coating	Stock Number	Price	Buy
266	25.40	25.00	Laser Mirror (266nm)	#39-947	S\$252.00 Volume Pricing	10 In Stock
266	25.40	50.00	Laser Mirror (266nm)	#39-948	S\$252.00 Volume Pricing	10 In Stock
266	25.40	75.00	Laser Mirror (266nm)	#39-949	S\$252.00 Volume Pricing	12 In Stock
266	25.40	100.00	Laser Mirror (266nm)	#39-950	S\$252.00 Volume Pricing	3 In Stock
266	25.40	200.00	Laser Mirror (266nm)	#39-951	S\$252.00 Volume Pricing	1 In Stock
266	25.40	500.00	Laser Mirror (266nm)	#39-952	S\$252.00 Volume Pricing	8 In Stock
355	25.40	25.00	Laser Mirror (355nm)	#39-954	S\$252.00 Volume Pricing	13 In Stock
355	25.40	50.00	Laser Mirror (355nm)	#39-955	S\$252.00 Volume Pricing	20+ In Stock
355	25.40	75.00	Laser Mirror (355nm)	#39-956	S\$252.00 Volume Pricing	17 In Stock
355	25.40	100.00	Laser Mirror (355nm)	#39-957	S\$252.00 Volume Pricing	14 In Stock
355	25.40	200.00	Laser Mirror (355nm)	#39-958	S\$252.00 Volume Pricing	20+ In Stock
355	25.40	500.00	Laser Mirror (355nm)	#39-959	S\$252.00 Volume Pricing	10 In Stock
532	25.40	25.00	Laser Mirror (532nm)	#39-960	S\$252.00 Volume Pricing	Contact Us
532	25.40	50.00	Laser Mirror (532nm)	#39-961	S\$252.00 Volume Pricing	4 In Stock
532	25.40	75.00	Laser Mirror (532nm)	#39-962	S\$252.00 Volume Pricing	3 In Stock
532	25.40	100.00	Laser Mirror (532nm)	#39-963	S\$252.00 Volume Pricing	5 In Stock

532	25.40	200.00	Laser Mirror (532nm)	#39-964	S\$252.00 Volume Pricing	3 In Stock
532	25.40	500.00	Laser Mirror (532nm)	#39-965	S\$252.00 Volume Pricing	3 In Stock
1064	25.40	25.00	Laser Mirror (1064nm)	#39-966	S\$252.00 Volume Pricing	11 In Stock
1064	25.40	50.00	Laser Mirror (1064nm)	#39-967	S\$252.00 Volume Pricing	4 In Stock
1064	25.40	75.00	Laser Mirror (1064nm)	#39-968	S\$252.00 Volume Pricing	10 In Stock
1064	25.40	100.00	Laser Mirror (1064nm)	#39-969	S\$252.00 Volume Pricing	Contact Us
1064	25.40	200.00	Laser Mirror (1064nm)	#39-970	S\$252.00 Volume Pricing	1 In Stock
1064	25.40	500.00	Laser Mirror (1064nm)	#39-971	S\$252.00 Volume Pricing	1 In Stock
266	50.80	50.00	Laser Mirror (266nm)	#11-327	S\$366.80 Volume Pricing	1 In Stock
266	50.80	100.00	Laser Mirror (266nm)	#11-328	S\$366.80 Volume Pricing	4 In Stock
266	50.80	150.00	Laser Mirror (266nm)	#11-329	S\$366.80 Volume Pricing	5 In Stock
266	50.80	250.00	Laser Mirror (266nm)	#11-330	S\$366.80 Volume Pricing	5 In Stock
266	50.80	500.00	Laser Mirror (266nm)	#11-331	S\$366.80 Volume Pricing	4 In Stock
355	50.80	50.00	Laser Mirror (355nm)	#11-332	S\$366.80 Volume Pricing	2 In Stock
355	50.80	100.00	Laser Mirror (355nm)	#11-333	S\$366.80 Volume Pricing	6 In Stock
355	50.80	150.00	Laser Mirror (355nm)	#11-334	S\$366.80 Volume Pricing	9 In Stock
355	50.80	250.00	Laser Mirror (355nm)	#11-335	S\$366.80 Volume Pricing	5 In Stock
355	50.80	500.00	Laser Mirror (355nm)	#11-336	S\$366.80 Volume Pricing	14 In Stock
532	50.80	50.00	Laser Mirror (532nm)	#11-337	S\$366.80 Volume Pricing	3 In Stock

532	50.80	100.00	Laser Mirror (532nm)	#11-338	S\$366.80 Volume Pricing	1 In Stock
532	50.80	150.00	Laser Mirror (532nm)	#11-339	S\$366.80 Volume Pricing	1 In Stock
532	50.80	250.00	Laser Mirror (532nm)	#11-340	S\$366.80 Volume Pricing	5 In Stock
532	50.80	500.00	Laser Mirror (532nm)	#11-341	S\$366.80 Volume Pricing	5 In Stock
1064	50.80	50.00	Laser Mirror (1064nm)	#11-342	S\$366.80 Volume Pricing	2 In Stock
1064	50.80	100.00	Laser Mirror (1064nm)	#11-343	S\$366.80 Volume Pricing	Contact Us
1064	50.80	150.00	Laser Mirror (1064nm)	#11-344	S\$366.80 Volume Pricing	6 In Stock
1064	50.80	250.00	Laser Mirror (1064nm)	#11-345	S\$366.80 Volume Pricing	4 In Stock
1064	50.80	500.00	Laser Mirror (1064nm)	#11-346	S\$366.80 Volume Pricing	2 In Stock
-	25.40	25.00	Uncoated	#39-973	S\$170.80 Volume Pricing	5 In Stock
-	25.40	50.00	Uncoated	#39-974	S\$170.80 Volume Pricing	16 In Stock
-	25.40	100.00	Uncoated	#39-977	S\$170.80 Volume Pricing	20+ In Stock
-	25.40	75.00	Uncoated	#39-975	S\$170.80 Volume Pricing	15 In Stock
-	25.40	200.00	Uncoated	#39-978	S\$170.80 Volume Pricing	20+ In Stock
-	25.40	500.00	Uncoated	#39-979	S\$170.80 Volume Pricing	20+ In Stock
-	50.80	50.00	Uncoated	#11-347	S\$316.40 Volume Pricing	20+ In Stock
-	50.80	100.00	Uncoated	#11-348	S\$313.60 Volume Pricing	7 In Stock
-	50.80	150.00	Uncoated	#11-349	S\$316.40 Volume Pricing	20+ In Stock
-	50.80	250.00	Uncoated	#11-350	S\$316.40 Volume Pricing	20+ In Stock

-	50.80	500.00	Uncoated	#11-352	S\$316.40 Volume Pricing	20+ In Stock
---	-------	--------	----------	-------------------------	---	--------------



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com