


[All Products](#) / [Optics](#) / [Ultrafast Optics](#) / [Nonlinear Crystals](#)

Nonlinear Crystals

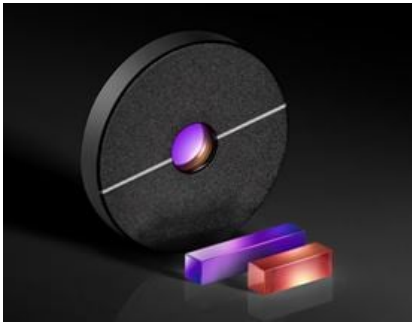

- BBO Crystals for Frequency Conversion of 800nm and 1030nm Lasers
- LBO Crystals for Frequency Conversion of 1030nm and 1064nm Lasers
- High Damage Thresholds Up to 10 J/cm² @ 1064nm, 10ns, 10Hz
- Broad Transparency Range from the UV to the IR

Common Specifications

Physical & Mechanical Properties

Perpendicularity (arcmin):	<5
----------------------------	----

Optical Properties

Coating:	AR Coating
Surface Quality:	20-10

Technical Information

Products

Crystal Type	Dimensions (mm)	Thickness (mm)	Mount	Typical Applications	Stock Number	Price	Buy
LBO	3.0 x 3.0	10.00	Unmounted	THG @ 1064nm, Type II	#11-174	S\$471.80 Volume Pricing	3 In Stock
LBO	3.0 x 3.0	10.00	Unmounted	SHG @ 1064 nm, Type I	#24-199	S\$456.40 Volume Pricing	5 In Stock
LBO	3.0 x 3.0	15.00	Unmounted	NCPM SHG @ 1064nm, T=150°C	#11-172	S\$623.00 Volume Pricing	5 In Stock
LBO	3.0 x 3.0	15.00	Unmounted	SHG @ 1064nm, Type I	#11-173	S\$623.00 Volume Pricing	3 In Stock
LBO	4.0 x 4.0	10.00	Unmounted	SHG @ 1064 nm, Type I	#24-200	S\$917.00 Volume Pricing	5 In Stock
BBO	6.0 x 6.0	0.20	Mounted	THG @ 800nm, Type I	#11-170	S\$1,029.00 Volume Pricing	3 In Stock
BBO	6.0 x 6.0	0.50	Mounted	THG @ 800nm, Type I	#11-168	S\$903.00 Volume Pricing	3 In Stock
BBO	6.0 x 6.0	0.10	Mounted	SHG @ 800nm, Type I	#23-340	S\$1,078.00 Volume Pricing	2 In Stock
BBO	6.0 x 6.0	0.20	Mounted	SHG @ 800nm, Type I	#23-341	S\$1,078.00 Volume Pricing	2 In Stock
BBO	6.0 x 6.0	0.20	Mounted	SHG @ 1030 nm, Type I	#24-196	S\$1,078.00 Volume Pricing	3 In Stock
BBO	6.0 x 6.0	0.50	Mounted	SHG @ 515 nm, Type I	#24-201	S\$1,029.00 Volume Pricing	5 In Stock
BBO	6.0 x 6.0	0.50	Mounted	SHG @ 800nm, Type I	#11-167	S\$903.00 Volume Pricing	9 In Stock
BBO	6.0 x 6.0	0.50	Mounted	SHG @ 1030nm, Type I	#11-169	S\$1,029.00 Volume Pricing	3 In Stock
LBO	6.0 x 6.0	0.90	Unmounted	SHG @ 1030nm, Type I	#11-171	S\$1,155.00 Volume Pricing	3 In Stock
BBO	6.0 x 6.0	1.00	Mounted	SHG @ 800nm, Type I	#15-277	S\$882.00 Volume Pricing	3 In Stock
BBO	6.0 x 6.0	1.00	Mounted	SHG @ 1030nm, Type I	#15-278	S\$938.00 Volume Pricing	5 In Stock

BBO	10.0 x 10.0	0.50	Mounted	SHG @ 800nm, Type I	#11-166	S\$1,547.00 Volume Pricing	3 In Stock
KDP	12.0 x 12.0	5.00	Unmounted	SHG @ 532 nm, Type I	#24-197	S\$903.00 Volume Pricing	5 In Stock
KDP	15.0 x 15.0	7.00	Unmounted	SHG @ 532 nm, Type I	#24-198	S\$1,078.00 Volume Pricing	5 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com