

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Off-Axis Mirrors](#)
TECHSPEC® Silver Off-Axis Parabolic Mirrors

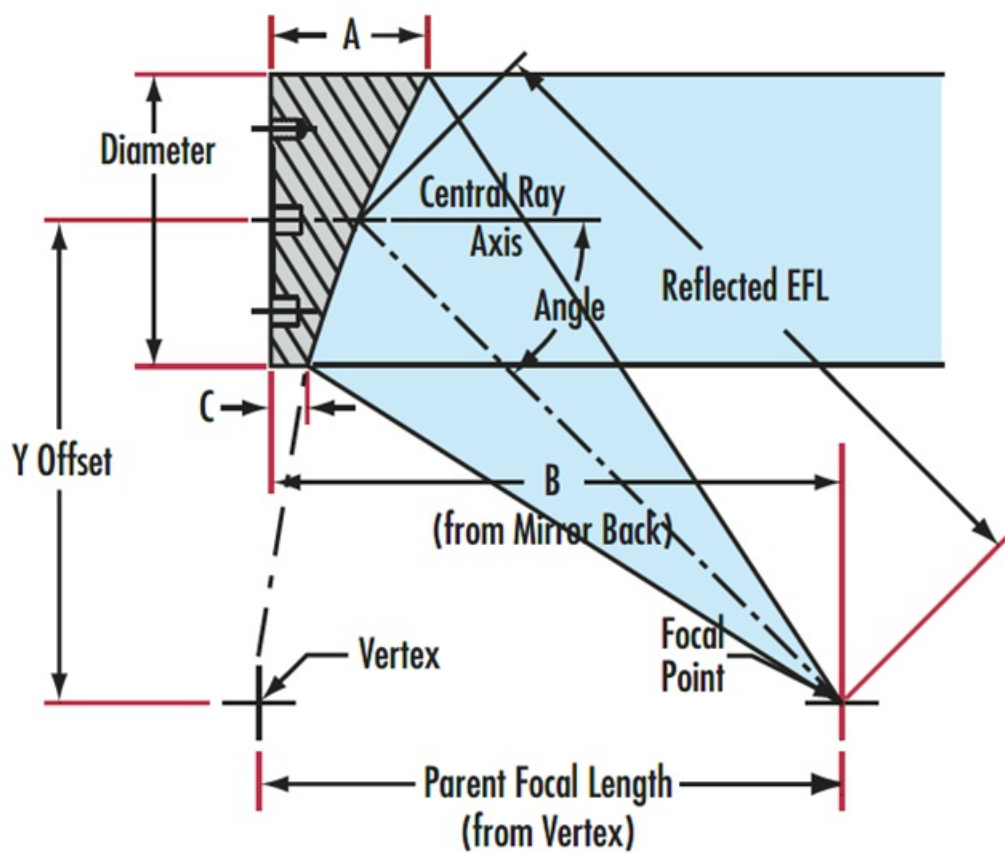

- Protected Silver Coating for Visible and IR Application
- 100Å Surface Roughness
- 90° Offset Angle
- Aluminum and Gold Coated Off-Axis Parabolic Mirrors Also Available

Common Specifications

Physical & Mechanical Properties

Surface Roughness (Å):	<100 RMS	Clear Aperture (%):	90
Optical Properties			
Focal Length Tolerance (%):	±1	Coating:	Protected Silver (450-12000nm)
Coating Type:	Metal	Coating Specification:	R _{avg} ≥98% @ 2,000 - 12,000nm, R _{avg} (typical) 96% @ 450 - 2,000nm
Off-Set Angle (°):	90	Wavelength Range (nm):	450 - 12000
Surface Quality:	80-50	Substrate:	Aluminum 6061-T6

Technical Information



Products

Dia. (mm)	EFL (mm)	Coating	Off- Set Angle (°)	Surface Roughness (Å)	Stock Number	Price	Buy
25.40	25.40	Protected Silver (450- 12000nm)	90	<100 RMS	#36-586	S\$600.60 Volume Pricing	1 In Stock
25.40	50.80	Protected Silver (450- 12000nm)	90	<100 RMS	#36-587	S\$600.60 Volume Pricing	3 In Stock
25.40	76.20	Protected Silver (450- 12000nm)	90	<100 RMS	#36-588	S\$600.60 Volume Pricing	Contact Us
25.40	101.60	Protected Silver (450- 12000nm)	90	<100 RMS	#36-589	S\$600.60 Volume Pricing	4 In Stock
25.40	127.00	Protected Silver (450- 12000nm)	90	<100 RMS	#36-590	S\$600.60 Volume Pricing	2 In Stock
25.40	152.40	Protected Silver (450- 12000nm)	90	<100 RMS	#36-591	S\$600.60 Volume Pricing	Contact Us
25.40	177.80	Protected Silver (450- 12000nm)	90	<100 RMS	#36-592	S\$740.60 Volume Pricing	2 In Stock
25.40	203.20	Protected Silver (450- 12000nm)	90	<100 RMS	#36-593	S\$600.60 Volume Pricing	3 In Stock
50.80	50.80	Protected Silver (450- 12000nm)	90	<100 RMS	#36-594	S\$810.60 Volume Pricing	Contact Us
50.80	76.20	Protected Silver (450- 12000nm)	90	<100 RMS	#36-595	S\$810.60 Volume Pricing	Contact Us
50.80	101.60	Protected Silver (450- 12000nm)	90	<100 RMS	#36-596	S\$810.60 Volume Pricing	2 In Stock
50.80	152.40	Protected Silver (450- 12000nm)	90	<100 RMS	#36-597	S\$810.60 Volume Pricing	3 In Stock

50.80	177.80	Protected Silver (450- 12000nm)	90	<100 RMS	#36-598	S\$810.60 Volume Pricing	4 In Stock
50.80	190.60	Protected Silver (450- 12000nm)	90	<100 RMS	#36-599	S\$810.60 Volume Pricing	5 In Stock
76.20	50.80	Protected Silver (450- 12000nm)	90	<100 RMS	#36-600	S\$1,076.60 Volume Pricing	3 In Stock
76.20	76.20	Protected Silver (450- 12000nm)	90	<100 RMS	#36-601	S\$1,076.60 Volume Pricing	1 In Stock
101.60	152.40	Protected Silver (450- 12000nm)	90	<100 RMS	#36-602	S\$1,538.60 Volume Pricing	5 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com