


[All Products](#) / [Laser Optics](#) / [Laser Optical Assemblies](#) / [Beam Shapers](#)

AdlOptica Focal- π Shaper Q Flat Top Beam Shapers [See More by AdlOptica](#)

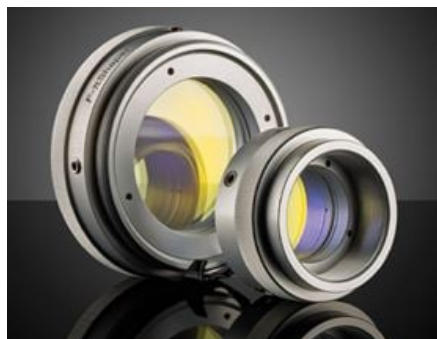


- Shapes Gaussian Beams to Airy Disk Profile
- Airy Disk is Focusable to Flat Top Spot
- Near 100% Efficiency
- [AdlOptica \$\pi\$ Shaper Flat Top Beam Shapers](#) Also Available

Common Specifications

Optical Properties

Transmission (%):	>99	Input Beam Mode:	TEM ₀₀
Typical Input Beam Mode Quality, M ² :	<1.5	Input Beam Divergence (mrad):	±20

Technical Information

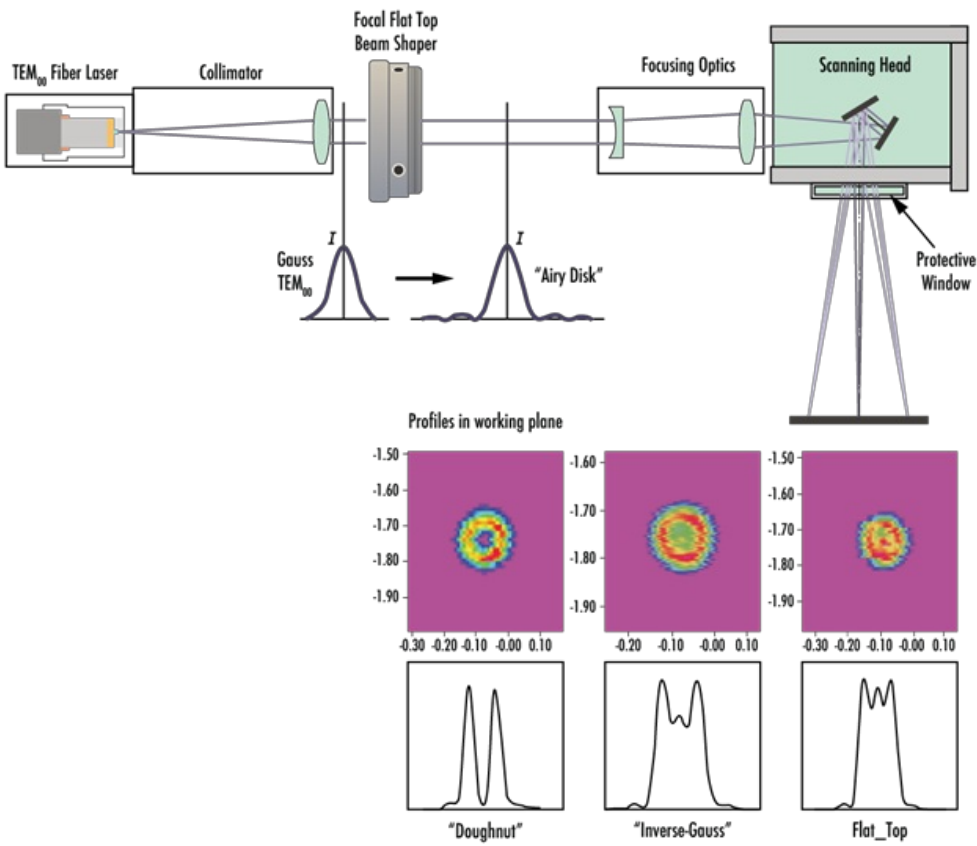

Products

DWL (nm)	Wavelength Range (nm)	CA (mm)	Dia. (mm)	Length (mm)	Input Beam Diameter, $1/e^2$ (mm)	Stock Number	Price	Buy
266	250 - 275	20	42.00	29.00	4 - 6	#25-842	S\$4,744.00 Volume Pricing	1 In Stock
266	250 - 275	20	42.00	29.00	6 - 9	#25-843	S\$4,744.00 Volume Pricing	Contact Us
266	250 - 275	20	42.00	29.00	8 - 12	#25-844	S\$4,744.00 Volume Pricing	Contact Us
355, 532	355 - 532	20	42.00	29.00	2.5 - 4	#25-847	S\$4,883.00 Volume Pricing	Contact Us
355, 532	355 - 532	20	42.00	29.00	3 - 5	#25-848	S\$4,883.00 Volume Pricing	1 In Stock
355, 532	335 - 560	20	42.00	29.00	4 - 6	#12-238	S\$4,883.00 Volume Pricing	Contact Us
355, 532	335 - 560	20	42.00	29.00	6 - 9	#12-239	S\$4,883.00 Volume Pricing	Contact Us
355, 532	335 - 560	20	42.00	29.00	8 - 12	#12-240	S\$4,883.00 Volume Pricing	1 In Stock
750, 900	750 - 900	20	42.00	29.00	8 - 12	#25-927	S\$4,423.00 Volume Pricing	Contact Us
750, 900	750 - 900	20	42.00	29.00	2.5 - 4	#25-849	S\$4,423.00 Volume Pricing	Contact Us
750, 900	750 - 900	20	42.00	29.00	4 - 6	#25-850	S\$4,423.00 Volume Pricing	Contact Us
750, 900	750 - 900	20	42.00	29.00	6 - 9	#25-851	S\$4,423.00 Volume Pricing	Contact Us
1064	1020 - 1100	20	42.00	29.00	2.5 - 4	#25-845	S\$4,423.00 Volume Pricing	Contact Us
1064	1020 - 1100	20	42.00	29.00	3 - 5	#12-230	S\$4,423.00 Volume Pricing	Contact Us
1064	1020 - 1100	20	42.00	29.00	4 - 6	#12-231	S\$4,423.00 Volume Pricing	1 In Stock

1064	1020 - 1100	20	42.00	29.00	6 - 9	#12-232	S\$4,423.00 Volume Pricing	1 In Stock
1064	1020 - 1100	20	42.00	29.00	8 - 12	#12-233	S\$4,423.00 Volume Pricing	1 In Stock
1064	1020 - 1100	20	42.00	29.00	11 - 17	#25-846	S\$4,423.00 Volume Pricing	Contact Us
1064	1020 - 1100	38	64.00	21.00	15 - 20	#12-236	S\$4,423.00 Volume Pricing	Contact Us
1064	1020 - 1100	38	64.00	21.00	18 - 23	#12-237	S\$4,423.00 Volume Pricing	1 In Stock
1070	1020 - 1100	10	42.00	29.00	8 - 12	#17-593	S\$5,948.00 Volume Pricing	1 In Stock
1070	1020 - 1100	38	64.00	21.00	18 - 23	#17-594	S\$6,111.00 Volume Pricing	Contact Us
1550, 2000	1550 - 2000	20	42.00	29.00	4 - 6	#25-852	S\$4,883.00 Volume Pricing	Contact Us
1550, 2000	1550 - 2000	20	42.00	29.00	6 - 9	#25-853	S\$4,883.00 Volume Pricing	Contact Us
1550, 2000	1550 - 2000	20	42.00	29.00	8 - 12	#25-854	S\$4,883.00 Volume Pricing	Contact Us
10600	9000 - 11000	20	42.00	29.00	8 - 12	#17-592	S\$6,502.00 Volume Pricing	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com