


[All Products](#) / [Optics](#) / [SCHOTT Optical Components](#)

SCHOTT NG Absorptive Neutral Density (ND) Filters

See More by [SCHOTT Optical Components](#)

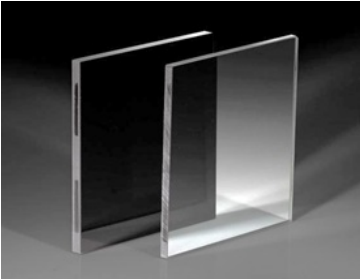



- Tightly Controlled Transmission Specifications
- NG4, NG9, or NG11 Glass Types
- Specified Optical Densities from 0.15 to 5.0
- Provide Even Light Attenuation in the Visible Spectrum
- [SCHOTT NG Gray Glass](#) Also Available

Common Specifications


Optical Properties

Coating:	Uncoated	Wavelength Range (nm):	400 - 700
----------	----------	------------------------	-----------

Technical Information

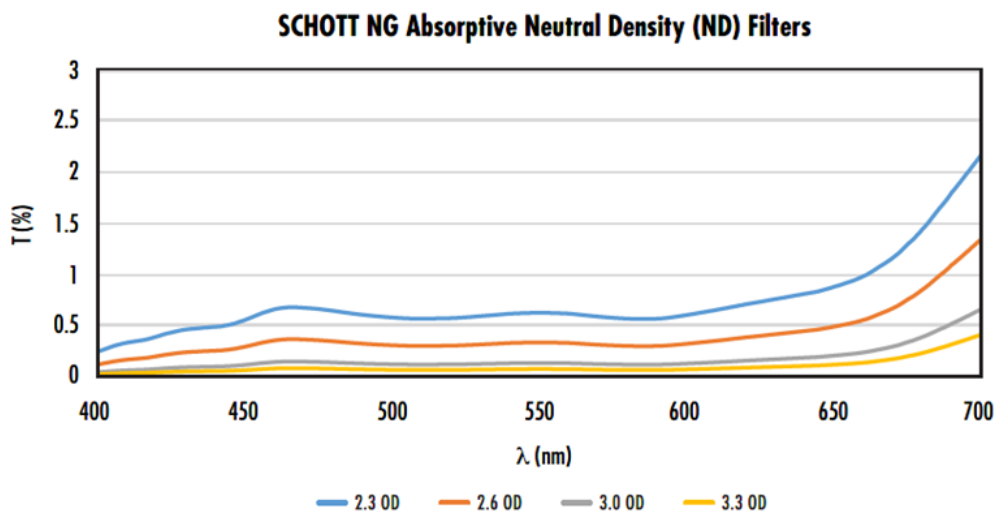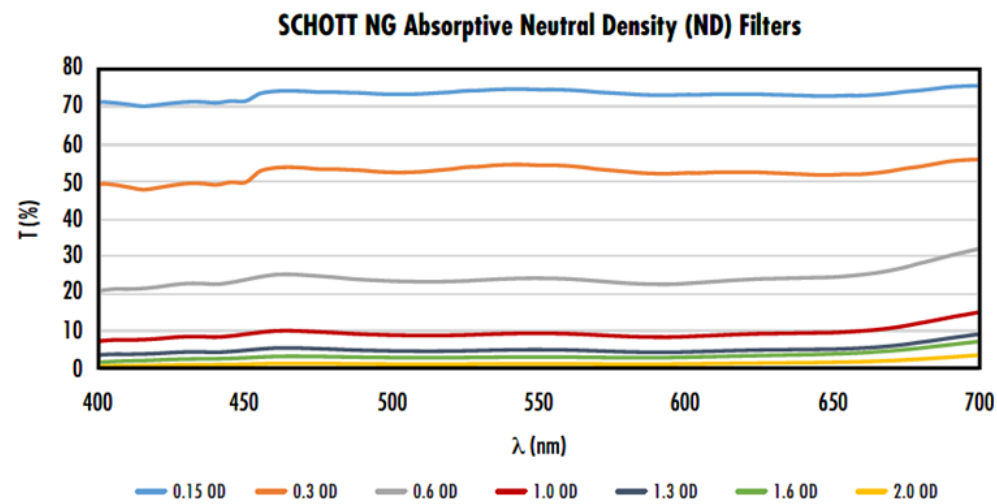

SCHOTT NG Absorptive Neutral Density (ND) Filters

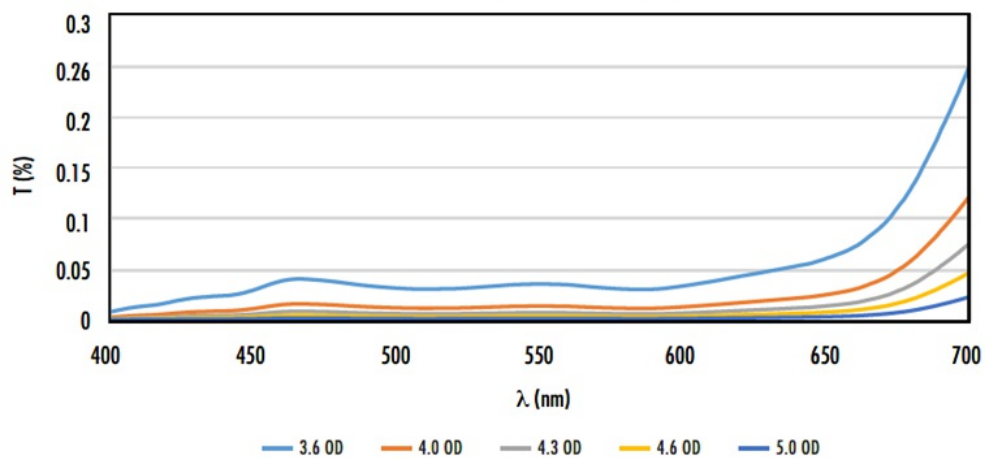

Products

Dia. (mm)	Dimensions (mm)	Glass/Filter Number	Optical Density OD (Average)	Thickness (mm)	Transmission (%)	Stock Number	Price	Buy
25.00	-	SCHOTT NG11	0.1	0.60	79.43	#16-718	S\$61.60 Volume Pricing	12 In Stock
12.50	-	SCHOTT NG11	0.1	0.60	79.43	#16-717	S\$37.80 Volume Pricing	20+ In Stock
-	50.0 x 50.0	SCHOTT NG11	0.1	0.60	79.43	#16-719	S\$136.50 Volume Pricing	16 In Stock
12.50	-	SCHOTT NG11	0.15	1.20	70.79	#16-645	S\$37.80 Volume Pricing	14 In Stock
25.00	-	SCHOTT NG11	0.15	1.20	70.79	#16-661	S\$61.60 Volume Pricing	5 In Stock
-	50.0 x 50.0	SCHOTT NG11	0.15	1.20	70.79	#14-042	S\$136.50 Volume Pricing	9 In Stock
12.50	-	SCHOTT NG11	0.2	1.60	63.10	#16-720	S\$37.80 Volume Pricing	20+ In Stock
25.00	-	SCHOTT NG11	0.2	1.60	63.10	#16-721	S\$61.60 Volume Pricing	5 In Stock
-	50.0 x 50.0	SCHOTT NG11	0.2	1.60	63.10	#16-722	S\$136.50 Volume Pricing	20+ In Stock
12.50	-	SCHOTT NG11	0.3	2.50	50.12	#16-646	S\$37.80 Volume Pricing	20+ In Stock
25.00	-	SCHOTT NG11	0.3	2.50	50.12	#16-662	S\$61.60 Volume Pricing	12 In Stock
-	50.0 x 50.0	SCHOTT NG11	0.3	2.50	50.12	#14-044	S\$136.50 Volume Pricing	12 In Stock
12.50	-	SCHOTT NG4	0.4	0.70	39.81	#16-723	S\$37.80 Volume Pricing	20+ In Stock
25.00	-	SCHOTT NG4	0.4	0.70	39.81	#16-724	S\$61.60 Volume Pricing	20+ In Stock
-	50.0 x 50.0	SCHOTT NG4	0.4	0.70	39.81	#16-725	S\$136.50 Volume Pricing	20+ In Stock
12.50	-	SCHOTT NG4	0.5	0.90	31.62	#16-726	S\$37.80 Volume Pricing	14 In Stock
25.00	-	SCHOTT NG4	0.5	0.90	31.62	#16-727	S\$61.60 Volume Pricing	20+ In Stock
-	50.0 x 50.0	SCHOTT NG4	0.5	0.90	31.62	#16-728	S\$136.50 Volume Pricing	20+ In Stock
12.50	-	SCHOTT NG4	0.6	1.20	25.12	#16-647	S\$37.80 Volume Pricing	20+ In Stock
25.00	-	SCHOTT NG4	0.6	1.20	25.12	#16-663	S\$61.60 Volume Pricing	16 In Stock

-	50.0 x 50.0	SCHOTT NG4	0.6	1.20	25.12	#14-046	S\$136.50 Volume Pricing	8 In Stock
12.50	-	SCHOTT NG4	0.9	1.70	12.59	#16-729	S\$37.80 Volume Pricing	7 In Stock
25.00	-	SCHOTT NG4	0.9	1.70	12.59	#16-730	S\$61.60 Volume Pricing	5 In Stock
-	50.0 x 50.0	SCHOTT NG4	0.9	1.70	12.59	#16-731	S\$136.50 Volume Pricing	4 In Stock
12.50	-	SCHOTT NG4	1.0	1.90	10.00	#16-648	S\$37.80 Volume Pricing	17 In Stock
25.00	-	SCHOTT NG4	1.0	1.90	10.00	#16-664	S\$61.60 Volume Pricing	14 In Stock
-	50.0 x 50.0	SCHOTT NG4	1.0	1.90	10.00	#14-048	S\$136.50 Volume Pricing	9 In Stock
12.50	-	SCHOTT NG4	1.3	2.50	5.01	#16-649	S\$37.80 Volume Pricing	1 In Stock
25.00	-	SCHOTT NG4	1.3	2.50	5.01	#16-665	S\$61.60 Volume Pricing	10 In Stock
-	50.0 x 50.0	SCHOTT NG4	1.3	2.50	5.01	#14-050	S\$136.50 Volume Pricing	8 In Stock
12.50	-	SCHOTT NG9	1.6	1.10	2.51	#16-650	S\$37.80 Volume Pricing	20+ In Stock

[#16-666 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

25.00	-	SCHOTT NG9	1.6	1.10	2.51		S\$39.20	6 In Stock
-	50.0 x 50.0	SCHOTT NG9	1.6	1.10	2.51	#14-052	S\$136.50 Volume Pricing	8 In Stock
12.50	-	SCHOTT NG9	2.0	1.40	1.00	#16-651	S\$37.80 Volume Pricing	14 In Stock
25.00	-	SCHOTT NG9	2.0	1.40	1.00	#16-667	S\$61.60 Volume Pricing	14 In Stock
-	50.0 x 50.0	SCHOTT NG9	2.0	1.40	1.00	#14-054	S\$136.50 Volume Pricing	10 In Stock

12.50	-	SCHOTT NG9	2.3	1.60	0.500	#16-652	S\$37.80 Volume Pricing	8 In Stock
25.00	-	SCHOTT NG9	2.3	1.60	0.500	#16-668	S\$61.60 Volume Pricing	20+ In Stock
-	50.0 x 50.0	SCHOTT NG9	2.3	1.60	0.500	#14-056	S\$136.50 Volume Pricing	5 In Stock
12.50	-	SCHOTT NG9	2.6	1.90	0.250	#16-653	S\$37.80 Volume Pricing	20+ In Stock
25.00	-	SCHOTT NG9	2.6	1.90	0.250	#16-669	S\$61.60 Volume Pricing	20+ In Stock
-	50.0 x 50.0	SCHOTT NG9	2.6	1.90	0.250	#14-058	S\$136.50 Volume Pricing	8 In Stock
12.50	-	SCHOTT NG9	3.0	2.10	0.100	#16-654	S\$37.80 Volume Pricing	20+ In Stock
25.00	-	SCHOTT NG9	3.0	2.10	0.100	#16-670	S\$61.60 Volume Pricing	20+ In Stock
-	50.0 x 50.0	SCHOTT NG9	3.0	2.10	0.100	#14-060	S\$136.50 Volume Pricing	8 In Stock
12.50	-	SCHOTT NG9	3.3	2.40	0.050	#16-655	S\$37.80 Volume Pricing	14 In Stock
25.00	-	SCHOTT NG9	3.3	2.40	0.050	#16-671	S\$61.60 Volume Pricing	5 In Stock
-	50.0 x 50.0	SCHOTT NG9	3.3	2.40	0.050	#14-062	S\$136.50 Volume Pricing	5 In Stock
12.50	-	SCHOTT NG9	3.6	2.60	0.025	#16-656	S\$37.80 Volume Pricing	11 In Stock
25.00	-	SCHOTT NG9	3.6	2.60	0.025	#16-672	S\$61.60 Volume Pricing	20+ In Stock
-	50.0 x 50.0	SCHOTT NG9	3.6	2.60	0.025	#14-064	S\$136.50 Volume Pricing	5 In Stock
12.50	-	SCHOTT NG9	4.0	2.90	0.010	#16-657	S\$37.80 Volume Pricing	20+ In Stock
25.00	-	SCHOTT NG9	4.0	2.90	0.010	#16-673	S\$61.60 Volume Pricing	20+ In Stock
12.50	-	SCHOTT NG9	4.3	3.10	0.005	#16-658	S\$37.80 Volume Pricing	9 In Stock
25.00	-	SCHOTT NG9	4.3	3.10	0.005	#16-674	S\$61.60 Volume Pricing	13 In Stock
-	50.0 x 50.0	SCHOTT NG9	4.3	3.10	0.005	#14-068	S\$136.50 Volume Pricing	7 In Stock
12.50	-	SCHOTT NG9	4.6	3.30	0.003	#16-659	S\$37.80 Volume Pricing	20+ In Stock
25.00	-	SCHOTT NG9	4.6	3.30	0.003	#16-675	S\$61.60 Volume Pricing	Contact Us
-	50.0 x 50.0	SCHOTT NG9	4.6	3.30	0.003	#14-070	S\$136.50 Volume Pricing	8 In Stock

12.50	-	SCHOTT NG9	5.0	3.60	0.001	#16-660	S\$37.80 Volume Pricing	9 In Stock
25.00	-	SCHOTT NG9	5.0	3.60	0.001	#16-676	S\$61.60 Volume Pricing	3 In Stock
-	50.0 x 50.0	SCHOTT NG9	5.0	3.60	0.001	#14-072	S\$136.50 Volume Pricing	20+ In Stock
-	50.0 x 50.0	SCHOTT NG9	4.0	2.90	0.010	#14-066	S\$136.50 Volume Pricing	8 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com