


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)

TECHSPEC® $\lambda/4$ UV Fused Silica Windows

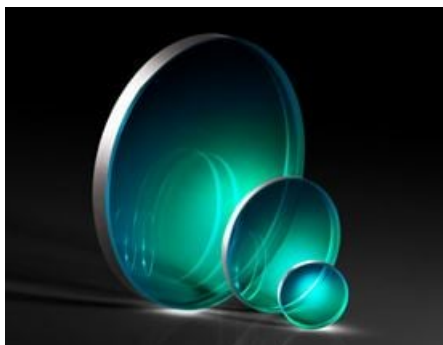

- Available Uncoated or BBAR Coated for UV, Visible, and NIR
- Ideal for Imaging Applications
- Circular and Rectangular Sizes from 5 to 200mm
- [1 \$\lambda\$](#) or [\$\lambda/10\$](#) UV Fused Silica Windows Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	90
Edges:	Fine Ground	Knoop Hardness (kg/mm²):	522.00
Parallelism (arcmin):	<1	Poisson's Ratio:	0.16
Young's Modulus (GPa):	73		


Optical Properties

Abbe Number (v_d):	67.8		
Index of Refraction (n_d):	1.458	Surface Quality:	40-20


Material Properties

Density (g/cm³):	2.20
------------------------------------	------


Technical Information

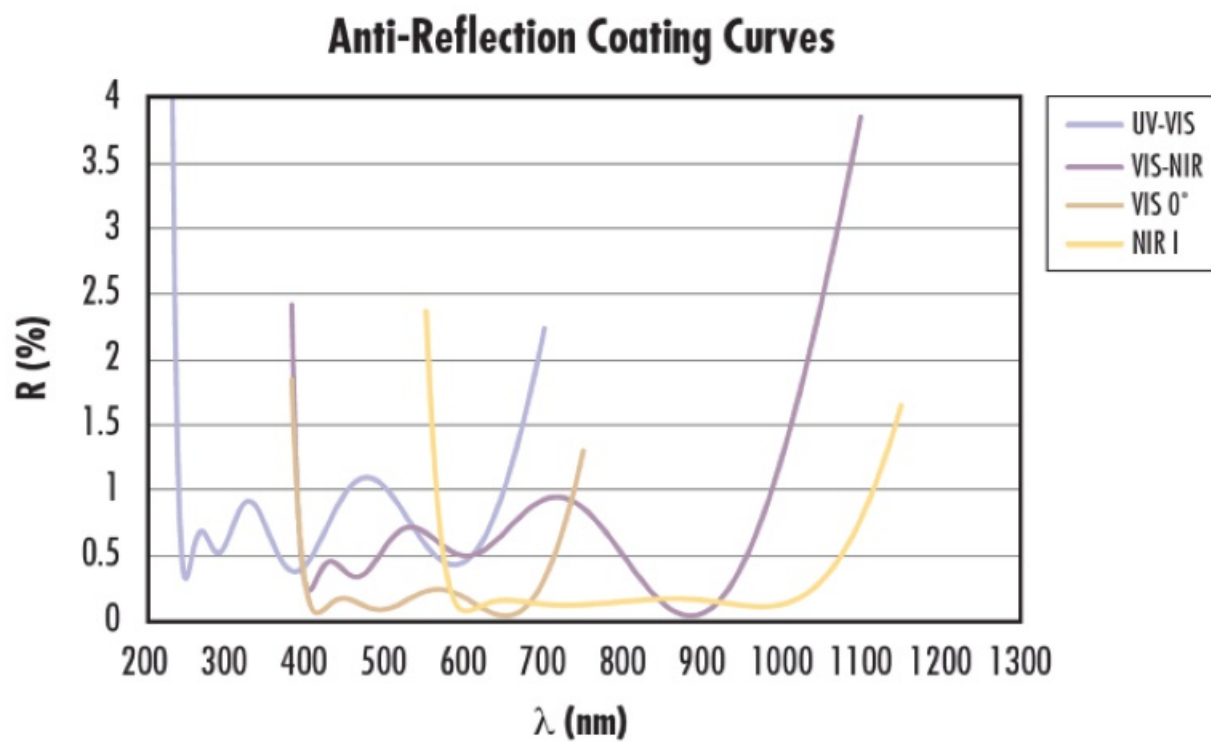

Standard Visible Anti-Reflection Coatings

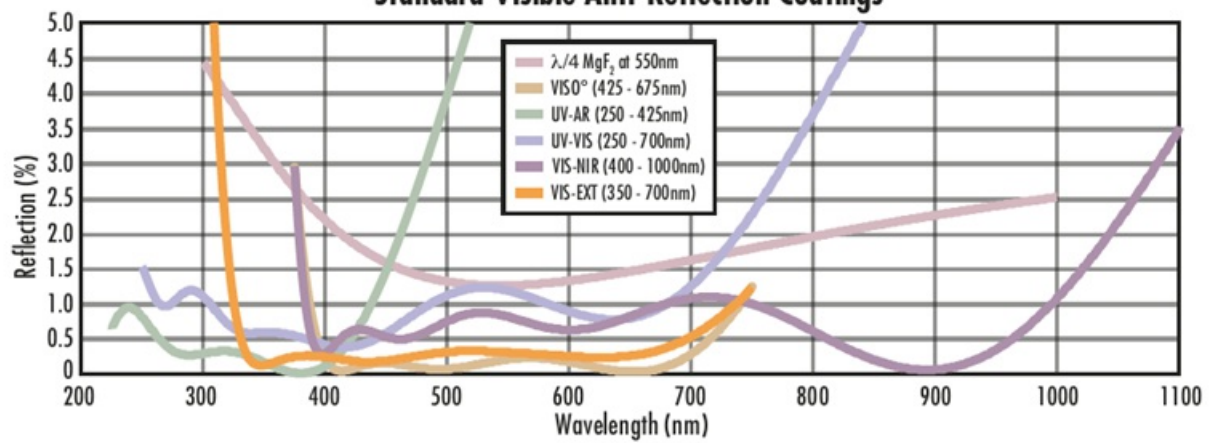

Standard Near Infrared Anti-Reflection Coatings

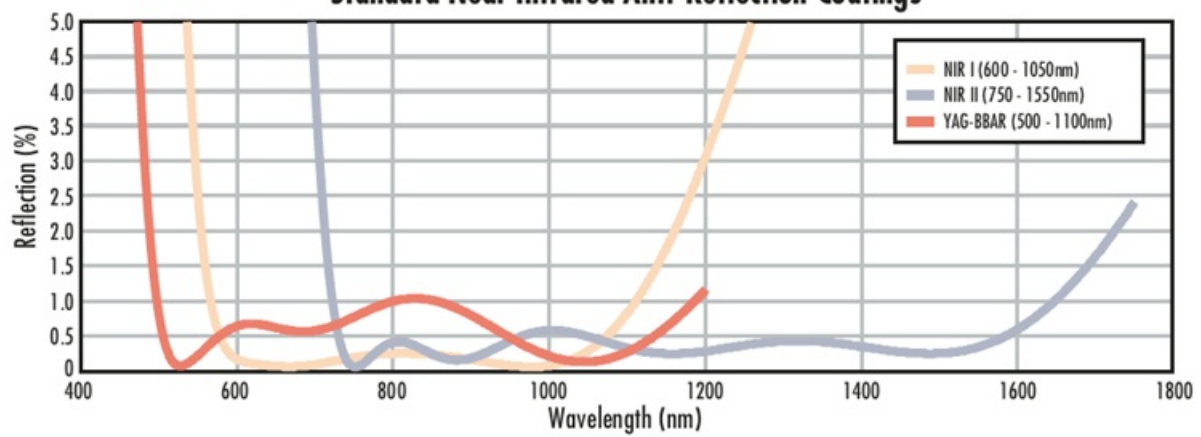

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
5.00	-	1.00	Uncoated	#14-955	S\$144.20 Volume Pricing	9 In Stock
5.00	-	1.00	UV-AR (250-425nm)	#25-633	S\$186.20 Volume Pricing	3 In Stock
5.00	-	1.00	UV-VIS (250-700nm)	#14-968	S\$186.20 Volume Pricing	10 In Stock
5.00	-	1.00	VIS-NIR (400-1000nm)	#14-981	S\$190.40 Volume Pricing	2 In Stock
5.00	-	1.00	VIS 0° (425-675nm)	#18-320	S\$180.60 Volume Pricing	9 In Stock
5.00	-	1.00	NIR I (600-1050nm)	#18-333	S\$180.60 Volume Pricing	4 In Stock
5.00	-	1.00	NIR II (750-1550nm)	#25-650	S\$180.60 Volume Pricing	5 In Stock
-	6.00 x 6.00	2.00	Uncoated	#29-297	S\$148.40 Volume Pricing	20+ In Stock
10.00	-	1.00	Uncoated	#14-956	S\$152.60 Volume Pricing	20+ In Stock
10.00	-	1.00	UV-AR (250-425nm)	#25-634	S\$193.20 Volume Pricing	3 In Stock
10.00	-	1.00	UV-VIS (250-700nm)	#14-969	S\$193.20 Volume Pricing	6 In Stock
10.00	-	1.00	VIS-NIR (400-1000nm)	#14-982	S\$198.80 Volume Pricing	8 In Stock
10.00	-	1.00	VIS 0° (425-675nm)	#18-321	S\$190.40 Volume Pricing	20+ In Stock
10.00	-	1.00	NIR I (600-1050nm)	#18-334	S\$190.40 Volume Pricing	4 In Stock

10.00	-	1.00	NIR II (750-1550nm)	#25-651	S\$190.40 Volume Pricing	8 In Stock
10.00	-	2.00	Uncoated	#14-957	S\$152.60 Volume Pricing	20+ In Stock
10.00	-	2.00	UV-AR (250-425nm)	#25-635	S\$193.20 Volume Pricing	1 In Stock
10.00	-	2.00	UV-VIS (250-700nm)	#14-970	S\$193.20 Volume Pricing	1 In Stock
10.00	-	2.00	VIS-NIR (400-1000nm)	#14-983	S\$198.80 Volume Pricing	15 In Stock
10.00	-	2.00	VIS 0° (425-675nm)	#18-322	S\$190.40 Volume Pricing	5 In Stock
10.00	-	2.00	NIR I (600-1050nm)	#18-335	S\$190.40 Volume Pricing	20+ In Stock
10.00	-	2.00	NIR II (750-1550nm)	#25-652	S\$190.40 Volume Pricing	5 In Stock
10.00	-	3.00	Uncoated	#70-520	S\$152.60 Volume Pricing	5 In Stock
10.00	-	3.00	UV-AR (250-425nm)	#72-335	S\$193.20 Volume Pricing	5 In Stock
10.00	-	3.00	UV-VIS (250-700nm)	#72-336	S\$193.20 Volume Pricing	2 In Stock
10.00	-	3.00	VIS 0° (425-675nm)	#72-337	S\$190.40 Volume Pricing	2 In Stock
10.00	-	3.00	NIR I (600-1050nm)	#72-338	S\$190.40 Volume Pricing	2 In Stock
10.00	-	3.00	NIR II (750-1550nm)	#72-339	S\$190.40 Volume Pricing	5 In Stock
10.00	-	3.00	VIS-NIR (400-1000nm)	#72-340	S\$198.80 Volume Pricing	5 In Stock
12.50	-	1.00	Uncoated	#70-521	S\$152.60 Volume Pricing	12 In Stock
12.50	-	1.00	UV-AR (250-425nm)	#72-341	S\$193.20 Volume Pricing	5 In Stock

12.50	-	1.00	UV-VIS (250-700nm)	#72-342	S\$193.20 Volume Pricing	7 In Stock
12.50	-	1.00	VIS 0° (425-675nm)	#72-343	S\$190.40 Volume Pricing	Contact Us
12.50	-	1.00	NIR I (600-1050nm)	#72-344	S\$190.40 Volume Pricing	3 In Stock
12.50	-	1.00	NIR II (750-1550nm)	#72-345	S\$190.40 Volume Pricing	4 In Stock
12.50	-	1.00	VIS-NIR (400-1000nm)	#72-346	S\$198.80 Volume Pricing	1 In Stock
12.50	-	2.00	Uncoated	#14-958	S\$152.60 Volume Pricing	20+ In Stock
12.50	-	2.00	UV-AR (250-425nm)	#25-636	S\$193.20 Volume Pricing	3 In Stock
12.50	-	2.00	UV-VIS (250-700nm)	#14-971	S\$193.20 Volume Pricing	5 In Stock
12.50	-	2.00	VIS-NIR (400-1000nm)	#14-984	S\$198.80 Volume Pricing	7 In Stock
12.50	-	2.00	VIS 0° (425-675nm)	#18-323	S\$190.40 Volume Pricing	5 In Stock
12.50	-	2.00	NIR I (600-1050nm)	#18-336	S\$190.40 Volume Pricing	1 In Stock
12.50	-	2.00	NIR II (750-1550nm)	#25-653	S\$190.40 Volume Pricing	6 In Stock
12.50	-	3.00	Uncoated	#14-959	S\$152.60 Volume Pricing	14 In Stock
12.50	-	3.00	UV-AR (250-425nm)	#25-638	S\$193.20 Volume Pricing	1 In Stock
12.50	-	3.00	UV-VIS (250-700nm)	#14-972	S\$193.20 Volume Pricing	7 In Stock
12.50	-	3.00	VIS-NIR (400-1000nm)	#14-985	S\$198.80 Volume Pricing	1 In Stock

12.50	-	3.00	VIS 0° (425-675nm)	#18-324	S\$190.40 Volume Pricing	Contact Us
12.50	-	3.00	NIR I (600-1050nm)	#18-337	S\$190.40 Volume Pricing	2 In Stock
12.50	-	3.00	NIR II (750-1550nm)	#25-654	S\$190.40 Volume Pricing	7 In Stock
15.00	-	2.00	Uncoated	#14-960	S\$159.60 Volume Pricing	20+ In Stock
15.00	-	2.00	UV-AR (250-425nm)	#25-639	S\$203.00 Volume Pricing	1 In Stock
15.00	-	2.00	UV-VIS (250-700nm)	#14-973	S\$203.00 Volume Pricing	1 In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#14-986	S\$205.80 Volume Pricing	6 In Stock
15.00	-	2.00	VIS 0° (425-675nm)	#18-325	S\$198.80 Volume Pricing	3 In Stock
15.00	-	2.00	NIR I (600-1050nm)	#18-338	S\$198.80 Volume Pricing	4 In Stock
15.00	-	2.00	NIR II (750-1550nm)	#25-655	S\$198.80 Volume Pricing	20+ In Stock
20.00	-	1.00	Uncoated	#70-522	S\$169.40 Volume Pricing	5 In Stock
20.00	-	1.00	UV-AR (250-425nm)	#72-347	S\$211.40 Volume Pricing	3 In Stock
20.00	-	1.00	UV-VIS (250-700nm)	#72-348	S\$211.40 Volume Pricing	5 In Stock
20.00	-	1.00	VIS 0° (425-675nm)	#72-349	S\$205.80 Volume Pricing	1 In Stock
20.00	-	1.00	NIR I (600-1050nm)	#72-350	S\$205.80 Volume Pricing	4 In Stock
20.00	-	1.00	NIR II (750-1550nm)	#72-351	S\$205.80 Volume Pricing	5 In Stock
20.00	-	1.00	VIS-NIR (400-1000nm)	#72-352	S\$215.60 Volume Pricing	5 In Stock

20.00	-	2.00	Uncoated	#14-961	S\$169.40 Volume Pricing	20+ In Stock
20.00	-	2.00	UV-AR (250-425nm)	#25-640	S\$211.40 Volume Pricing	5 In Stock
20.00	-	2.00	UV-VIS (250-700nm)	#14-974	S\$211.40 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS-NIR (400-1000nm)	#14-987	S\$215.60 Volume Pricing	Contact Us
20.00	-	2.00	VIS 0° (425-675nm)	#18-326	S\$205.80 Volume Pricing	8 In Stock
20.00	-	2.00	NIR I (600-1050nm)	#18-339	S\$205.80 Volume Pricing	1 In Stock
20.00	-	2.00	NIR II (750-1550nm)	#25-656	S\$205.80 Volume Pricing	16 In Stock
20.00	-	3.00	Uncoated	#70-523	S\$169.40 Volume Pricing	13 In Stock
20.00	-	3.00	UV-AR (250-425nm)	#72-353	S\$211.40 Volume Pricing	4 In Stock
20.00	-	3.00	UV-VIS (250-700nm)	#72-354	S\$211.40 Volume Pricing	5 In Stock
20.00	-	3.00	VIS 0° (425-675nm)	#72-355	S\$205.80 Volume Pricing	1 In Stock
20.00	-	3.00	NIR I (600-1050nm)	#72-356	S\$205.80 Volume Pricing	3 In Stock
20.00	-	3.00	NIR II (750-1550nm)	#72-357	S\$205.80 Volume Pricing	8 In Stock
20.00	-	3.00	VIS-NIR (400-1000nm)	#72-358	S\$215.60 Volume Pricing	Contact Us
25.00	-	1.00	Uncoated	#70-524	S\$177.80 Volume Pricing	20+ In Stock
25.00	-	1.00	UV-AR (250-425nm)	#72-359	S\$219.80 Volume Pricing	1 In Stock

25.00	-	1.00	UV-VIS (250-700nm)	#72-360	S\$228.20 Volume Pricing	2 In Stock
25.00	-	1.00	VIS 0° (425-675nm)	#72-361	S\$215.60 Volume Pricing	1 In Stock
25.00	-	1.00	NIR I (600-1050nm)	#72-362	S\$215.60 Volume Pricing	4 In Stock
25.00	-	1.00	NIR II (750-1550nm)	#72-363	S\$215.60 Volume Pricing	4 In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#72-364	S\$224.00 Volume Pricing	7 In Stock
25.00	-	2.00	Uncoated	#14-962	S\$177.80 Volume Pricing	20+ In Stock
25.00	-	2.00	UV-AR (250-425nm)	#25-641	S\$219.80 Volume Pricing	5 In Stock
25.00	-	2.00	UV-VIS (250-700nm)	#14-975	S\$219.80 Volume Pricing	9 In Stock
25.00	-	2.00	VIS-NIR (400-1000nm)	#14-988	S\$224.00 Volume Pricing	9 In Stock
25.00	-	2.00	VIS 0° (425-675nm)	#18-327	S\$215.60 Volume Pricing	8 In Stock
25.00	-	2.00	NIR I (600-1050nm)	#18-340	S\$215.60 Volume Pricing	13 In Stock
25.00	-	2.00	NIR II (750-1550nm)	#25-657	S\$215.60 Volume Pricing	5 In Stock
25.00	-	3.00	Uncoated	#14-963	S\$177.80 Volume Pricing	3 In Stock
25.00	-	3.00	UV-AR (250-425nm)	#25-642	S\$219.80 Volume Pricing	3 In Stock
25.00	-	3.00	UV-VIS (250-700nm)	#14-976	S\$228.20 Volume Pricing	6 In Stock
25.00	-	3.00	VIS-NIR (400-1000nm)	#14-989	S\$224.00 Volume Pricing	11 In Stock

25.00	-	3.00	VIS 0° (425-675nm)	#18-328	S\$215.60 Volume Pricing	5 In Stock
25.00	-	3.00	NIR I (600-1050nm)	#18-341	S\$215.60 Volume Pricing	5 In Stock
25.00	-	3.00	NIR II (750-1550nm)	#25-658	S\$215.60 Volume Pricing	5 In Stock
25.00	-	4.00	Uncoated	#14-964	S\$177.80 Volume Pricing	16 In Stock
25.00	-	4.00	UV-AR (250-425nm)	#25-643	S\$219.80 Volume Pricing	1 In Stock
25.00	-	4.00	UV-VIS (250-700nm)	#14-977	S\$219.80 Volume Pricing	1 In Stock
25.00	-	4.00	VIS-NIR (400-1000nm)	#14-990	S\$224.00 Volume Pricing	5 In Stock
25.00	-	4.00	VIS 0° (425-675nm)	#18-329	S\$215.60 Volume Pricing	5 In Stock
25.00	-	4.00	NIR I (600-1050nm)	#18-342	S\$215.60 Volume Pricing	5 In Stock
25.00	-	4.00	NIR II (750-1550nm)	#25-659	S\$215.60 Volume Pricing	7 In Stock
25.00	-	5.00	Uncoated	#70-525	S\$177.80 Volume Pricing	20+ In Stock
25.00	-	5.00	UV-AR (250-425nm)	#72-365	S\$219.80 Volume Pricing	2 In Stock
25.00	-	5.00	UV-VIS (250-700nm)	#72-366	S\$219.80 Volume Pricing	5 In Stock
25.00	-	5.00	VIS 0° (425-675nm)	#72-367	S\$215.60 Volume Pricing	6 In Stock
25.00	-	5.00	NIR I (600-1050nm)	#72-368	S\$215.60 Volume Pricing	3 In Stock
25.00	-	5.00	NIR II (750-1550nm)	#72-369	S\$215.60 Volume Pricing	1 In Stock
25.00	-	5.00	VIS-NIR (400-1000nm)	#72-376	S\$224.00 Volume Pricing	8 In Stock

-	25.00 x 35.00	3.00	Uncoated	#29-298	S\$226.80 Volume Pricing	20+ In Stock
-	25.20 x 35.60	1.00	Uncoated	#29-299	S\$226.80 Volume Pricing	15 In Stock
25.40	-	3.00	Uncoated	#70-526	S\$177.80 Volume Pricing	20+ In Stock
25.40	-	3.00	UV-AR (250-425nm)	#72-377	S\$219.80 Volume Pricing	1 In Stock
25.40	-	3.00	UV-VIS (250-700nm)	#72-378	S\$219.80 Volume Pricing	6 In Stock
25.40	-	3.00	VIS 0° (425-675nm)	#72-379	S\$215.60 Volume Pricing	Contact Us
25.40	-	3.00	NIR I (600-1050nm)	#72-380	S\$215.60 Volume Pricing	4 In Stock
25.40	-	3.00	NIR II (750-1550nm)	#72-381	S\$215.60 Volume Pricing	5 In Stock
25.40	-	3.00	VIS-NIR (400-1000nm)	#72-382	S\$224.00 Volume Pricing	3 In Stock
30.00	-	3.00	Uncoated	#70-527	S\$193.20 Volume Pricing	14 In Stock
30.00	-	3.00	UV-AR (250-425nm)	#72-383	S\$239.40 Volume Pricing	4 In Stock
30.00	-	3.00	UV-VIS (250-700nm)	#72-384	S\$236.60 Volume Pricing	Contact Us
30.00	-	3.00	VIS 0° (425-675nm)	#72-385	S\$236.60 Volume Pricing	4 In Stock
30.00	-	3.00	NIR I (600-1050nm)	#72-386	S\$232.40 Volume Pricing	5 In Stock
30.00	-	3.00	NIR II (750-1550nm)	#72-387	S\$232.40 Volume Pricing	5 In Stock
30.00	-	3.00	VIS-NIR (400-1000nm)	#72-388	S\$232.40 Volume Pricing	5 In Stock
35.00	-	3.00	Uncoated	#70-528	S\$219.80 Volume Pricing	9 In Stock

35.00	-	3.00	UV-AR (250-425nm)	#72-389	S\$249.20 Volume Pricing	10 In Stock
35.00	-	3.00	UV-VIS (250-700nm)	#72-390	S\$245.00 Volume Pricing	4 In Stock
35.00	-	3.00	VIS 0° (425-675nm)	#72-391	S\$239.40 Volume Pricing	Contact Us
35.00	-	3.00	NIR I (600-1050nm)	#72-392	S\$239.40 Volume Pricing	1 In Stock
35.00	-	3.00	NIR II (750-1550nm)	#72-393	S\$239.40 Volume Pricing	3 In Stock
35.00	-	3.00	VIS-NIR (400-1000nm)	#72-394	S\$245.00 Volume Pricing	5 In Stock
40.00	-	2.00	Uncoated	#70-529	S\$249.20 Volume Pricing	20+ In Stock
40.00	-	2.00	UV-AR (250-425nm)	#72-395	S\$299.60 Volume Pricing	Contact Us
40.00	-	2.00	UV-VIS (250-700nm)	#72-396	S\$310.80 Volume Pricing	5 In Stock
40.00	-	2.00	VIS 0° (425-675nm)	#72-397	S\$296.80 Volume Pricing	4 In Stock
40.00	-	2.00	NIR I (600-1050nm)	#72-398	S\$296.80 Volume Pricing	6 In Stock
40.00	-	2.00	NIR II (750-1550nm)	#72-399	S\$296.80 Volume Pricing	4 In Stock
40.00	-	2.00	VIS-NIR (400-1000nm)	#72-400	S\$303.80 Volume Pricing	Contact Us
40.00	-	4.00	Uncoated	#14-965	S\$249.20 Volume Pricing	20+ In Stock
40.00	-	4.00	UV-AR (250-425nm)	#25-644	S\$299.60 Volume Pricing	5 In Stock
40.00	-	4.00	UV-VIS (250-700nm)	#14-978	S\$299.60 Volume Pricing	1 In Stock

40.00	-	4.00	VIS-NIR (400-1000nm)	#14-991	S\$303.80 Volume Pricing	3 In Stock
40.00	-	4.00	VIS 0° (425-675nm)	#18-330	S\$296.80 Volume Pricing	15 In Stock
40.00	-	4.00	NIR I (600-1050nm)	#18-343	S\$296.80 Volume Pricing	1 In Stock
40.00	-	4.00	NIR II (750-1550nm)	#25-660	S\$296.80 Volume Pricing	Contact Us
50.00	-	1.00	Uncoated	#70-530	S\$282.80 Volume Pricing	20+ In Stock
50.00	-	1.00	UV-AR (250-425nm)	#72-401	S\$333.20 Volume Pricing	4 In Stock
50.00	-	1.00	UV-VIS (250-700nm)	#72-402	S\$333.20 Volume Pricing	5 In Stock
50.00	-	1.00	VIS 0° (425-675nm)	#72-403	S\$330.40 Volume Pricing	1 In Stock
50.00	-	1.00	NIR I (600-1050nm)	#72-404	S\$330.40 Volume Pricing	5 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#72-405	S\$330.40 Volume Pricing	3 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#72-406	S\$337.40 Volume Pricing	8 In Stock
50.00	-	2.00	Uncoated	#70-531	S\$282.80 Volume Pricing	20+ In Stock
50.00	-	2.00	UV-AR (250-425nm)	#72-407	S\$333.20 Volume Pricing	5 In Stock
50.00	-	2.00	UV-VIS (250-700nm)	#72-408	S\$333.20 Volume Pricing	7 In Stock
50.00	-	2.00	VIS 0° (425-675nm)	#72-409	S\$330.40 Volume Pricing	3 In Stock
50.00	-	2.00	NIR I (600-1050nm)	#72-410	S\$330.40 Volume Pricing	5 In Stock
50.00	-	2.00	NIR II (750-1550nm)	#72-412	S\$330.40 Volume Pricing	3 In Stock

50.00	-	2.00	VIS-NIR (400-1000nm)	#72-413	S\$337.40 Volume Pricing	5 In Stock
50.00	-	3.00	Uncoated	#70-532	S\$282.80 Volume Pricing	10 In Stock
50.00	-	3.00	UV-AR (250-425nm)	#72-414	S\$333.20 Volume Pricing	2 In Stock
50.00	-	3.00	UV-VIS (250-700nm)	#72-415	S\$333.20 Volume Pricing	5 In Stock
50.00	-	3.00	VIS 0° (425-675nm)	#72-416	S\$330.40 Volume Pricing	2 In Stock
50.00	-	3.00	NIR I (600-1050nm)	#72-417	S\$330.40 Volume Pricing	5 In Stock
50.00	-	3.00	NIR II (750-1550nm)	#72-418	S\$330.40 Volume Pricing	1 In Stock
50.00	-	3.00	VIS-NIR (400-1000nm)	#72-419	S\$337.40 Volume Pricing	5 In Stock
50.00	-	4.00	Uncoated	#14-966	S\$282.80 Volume Pricing	9 In Stock
50.00	-	4.00	UV-AR (250-425nm)	#25-645	S\$333.20 Volume Pricing	4 In Stock
50.00	-	4.00	UV-VIS (250-700nm)	#14-979	S\$333.20 Volume Pricing	2 In Stock
50.00	-	4.00	VIS-NIR (400-1000nm)	#14-992	S\$337.40 Volume Pricing	3 In Stock
50.00	-	4.00	VIS 0° (425-675nm)	#18-331	S\$330.40 Volume Pricing	8 In Stock
50.00	-	4.00	NIR I (600-1050nm)	#18-344	S\$330.40 Volume Pricing	7 In Stock
50.00	-	4.00	NIR II (750-1550nm)	#25-661	S\$330.40 Volume Pricing	6 In Stock
75.00	-	2.00	Uncoated	#70-533	S\$448.00 Volume Pricing	7 In Stock

75.00	-	2.00	UV-AR (250-425nm)	#72-420	S\$557.20 Volume Pricing	1 In Stock
75.00	-	2.00	UV-VIS (250-700nm)	#72-421	S\$557.20 Volume Pricing	6 In Stock
75.00	-	2.00	VIS 0° (425-675nm)	#72-422	S\$548.80 Volume Pricing	4 In Stock
75.00	-	2.00	NIR I (600-1050nm)	#72-423	S\$548.80 Volume Pricing	5 In Stock
75.00	-	2.00	NIR II (750-1550nm)	#72-424	S\$548.80 Volume Pricing	8 In Stock
75.00	-	2.00	VIS-NIR (400-1000nm)	#72-425	S\$565.60 Volume Pricing	1 In Stock
75.00	-	4.00	Uncoated	#14-967	S\$448.00 Volume Pricing	20+ In Stock
75.00	-	4.00	UV-AR (250-425nm)	#25-646	S\$557.20 Volume Pricing	1 In Stock
75.00	-	4.00	UV-VIS (250-700nm)	#14-980	S\$557.20 Volume Pricing	5 In Stock
75.00	-	4.00	VIS-NIR (400-1000nm)	#14-993	S\$565.60 Volume Pricing	11 In Stock
75.00	-	4.00	VIS 0° (425-675nm)	#18-332	S\$548.80 Volume Pricing	8 In Stock
75.00	-	4.00	NIR I (600-1050nm)	#18-345	S\$548.80 Volume Pricing	Contact Us
75.00	-	4.00	NIR II (750-1550nm)	#25-663	S\$548.80 Volume Pricing	11 In Stock
100.00	-	2.00	Uncoated	#20-159	S\$637.00 Volume Pricing	17 In Stock
100.00	-	2.00	UV-AR (250-425nm)	#29-619	S\$1,057.00 Volume Pricing	4 In Stock
100.00	-	2.00	UV-VIS (250-700nm)	#22-055	S\$1,057.00 Volume Pricing	5 In Stock

100.00	-	2.00	VIS-NIR (400-1000nm)	#22-061	S\$1,057.00 Volume Pricing	Contact Us
100.00	-	2.00	VIS 0° (425-675nm)	#22-058	S\$1,057.00 Volume Pricing	1 In Stock
100.00	-	2.00	NIR I (600-1050nm)	#29-620	S\$1,057.00 Volume Pricing	4 In Stock
100.00	-	2.00	NIR II (750-1550nm)	#29-621	S\$1,057.00 Volume Pricing	Contact Us
125.00	-	3.00	Uncoated	#20-161	S\$875.00 Volume Pricing	13 In Stock
125.00	-	3.00	UV-AR (250-425nm)	#29-622	S\$1,414.00 Volume Pricing	2 In Stock
125.00	-	3.00	UV-VIS (250-700nm)	#22-056	S\$1,414.00 Volume Pricing	1 In Stock
125.00	-	3.00	VIS-NIR (400-1000nm)	#22-062	S\$1,414.00 Volume Pricing	1 In Stock
125.00	-	3.00	VIS 0° (425-675nm)	#22-059	S\$1,414.00 Volume Pricing	2 In Stock
125.00	-	3.00	NIR I (600-1050nm)	#29-623	S\$1,414.00 Volume Pricing	2 In Stock
125.00	-	3.00	NIR II (750-1550nm)	#29-624	S\$1,414.00 Volume Pricing	Contact Us
150.00	-	3.00	Uncoated	#20-162	S\$1,085.00 Volume Pricing	8 In Stock
150.00	-	3.00	UV-AR (250-425nm)	#29-625	S\$1,764.00 Volume Pricing	3 In Stock
150.00	-	3.00	UV-VIS (250-700nm)	#22-057	S\$1,764.00 Volume Pricing	3 In Stock
150.00	-	3.00	VIS-NIR (400-1000nm)	#22-063	S\$1,764.00 Volume Pricing	2 In Stock
150.00	-	3.00	VIS 0° (425-675nm)	#22-060	S\$1,764.00 Volume Pricing	2 In Stock
150.00	-	3.00	NIR I (600-1050nm)	#29-626	S\$1,764.00 Volume Pricing	3 In Stock

150.00	-	3.00	NIR II (750-1550nm)	#29-627	S\$1,764.00 Volume Pricing	Contact Us
200.00	-	5.00	Uncoated	#26-476	S\$1,603.00 Volume Pricing	1 In Stock
200.00	-	5.00	VIS-NIR (400-1000nm)	#26-685	S\$2,282.00 Volume Pricing	2 In Stock
250.00	-	8.00	Uncoated	#29-938	S\$4,977.00 Volume Pricing	5 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com