


[All Products](#) / [Optics](#) / [Optical Filters](#) / [Shortpass Filters](#)

OD 2.0 Shortpass Filters


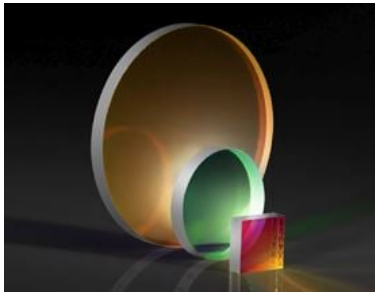


- Sharp Cut-Off Wavelength
- ≥85% Transmission and OD 2.0 Blocking
- 6mm Square or 12.5/25mm Diameter Sizes
- [TECHSPEC® OD 4.0 Shortpass Filters](#) Also Available

Common Specifications

Physical & Mechanical Properties			
Thickness (mm):	2.00 ±0.10	Clear Aperture (%):	90
Physical Durability:	MIL-C-48497A, Section 3.4.1		
Optical Properties			
Angle of Incidence (°):	0		
Optical Density OD (Average):	≥2.0	Substrate:	BOROFLOAT®
Coating:	Hard Coated	Surface Quality:	60-40
Transmission (%):	≥85		
Environmental & Durability Factors			
Environmental Durability:	MIL-STD-810F, Section 507.4		

Technical Information

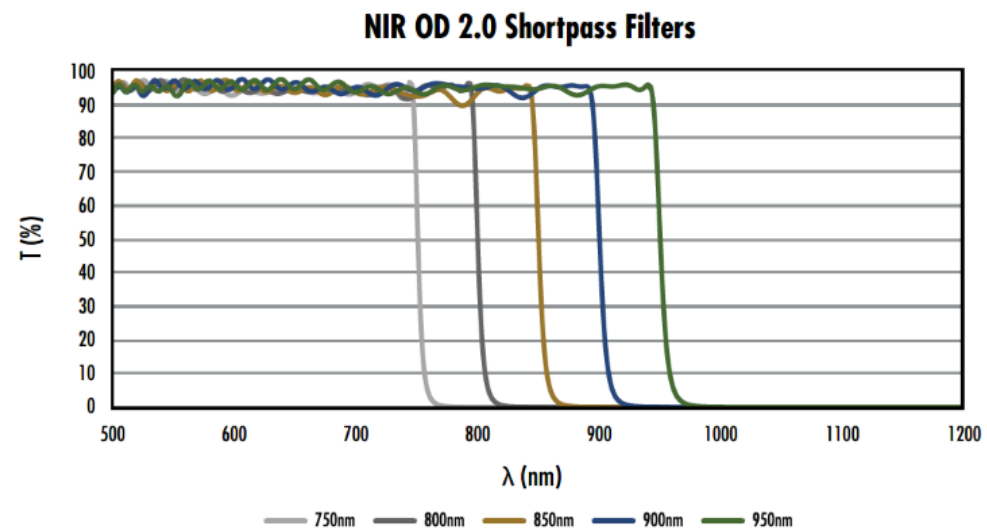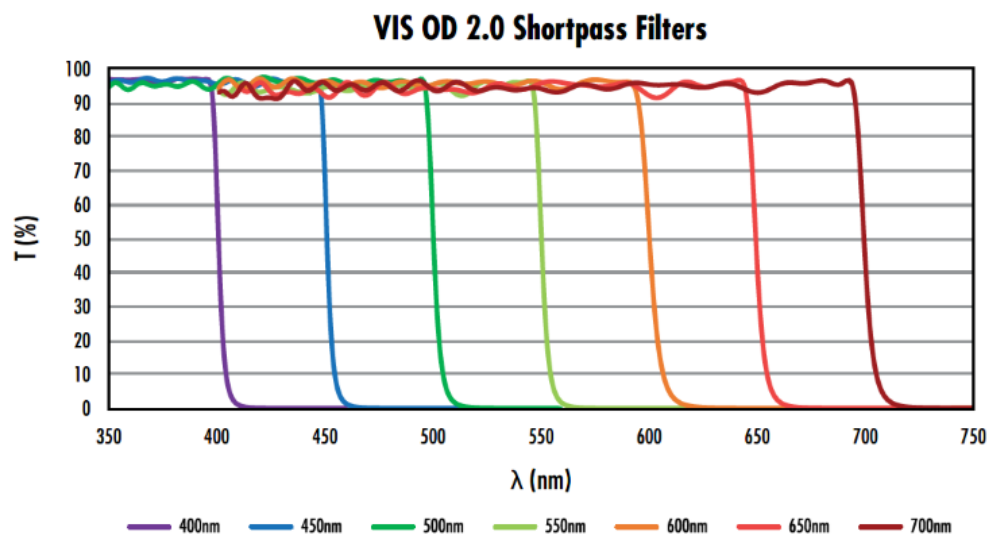

Products

Dimensions (mm)	Dia. (mm)	Cut-Off Wavelength (nm)	Rejection Wavelength (nm)	Transmission Wavelength (nm)	Wavelength Range (nm)	Stock Number	Price	Buy
6.00 x 6.00	-	400.00	420 - 505	325 - 385	325 - 505	#15-464	S\$70.00 Volume Pricing	8 In Stock
6.00 x 6.00	-	450.00	470 - 570	325 - 430	325 - 570	#15-234	S\$70.00 Volume Pricing	17 In Stock
6.00 x 6.00	-	500.00	520 - 610	325 - 480	325 - 610	#15-235	S\$70.00 Volume Pricing	20+ In Stock
6.00 x 6.00	-	550.00	575 - 710	375 - 530	375 - 710	#15-236	S\$70.00 Volume Pricing	1 In Stock
6.00 x 6.00	-	600.00	625 - 775	400 - 580	400 - 775	#15-237	S\$70.00 Volume Pricing	6 In Stock
6.00 x 6.00	-	650.00	675 - 850	400 - 630	400 - 850	#15-238	S\$70.00 Volume Pricing	14 In Stock
6.00 x 6.00	-	700.00	730 - 900	400 - 675	400 - 900	#15-239	S\$70.00 Volume Pricing	13 In Stock
6.00 x 6.00	-	750.00	780 - 990	400 - 720	400 - 990	#15-240	S\$70.00 Volume Pricing	20+ In Stock
6.00 x 6.00	-	800.00	850 - 1050	410 - 765	410 - 1050	#15-241	S\$70.00 Volume Pricing	20+ In Stock
6.00 x 6.00	-	850.00	900 - 1110	440 - 825	440 - 1100	#15-242	S\$70.00 Volume Pricing	20+ In Stock
6.00 x 6.00	-	900.00	950 - 1180	500 - 860	500 - 1180	#15-243	S\$70.00 Volume Pricing	20+ In Stock
6.00 x 6.00	-	950.00	1025 - 1250	500 - 900	500 - 1250	#15-244	S\$70.00 Volume Pricing	20+ In Stock
-	12.50	400.00	420 - 505	325 - 385	325 - 505	#15-465	S\$126.00 Volume Pricing	20+ In Stock
-	12.50	450.00	470 - 570	325 - 430	325 - 570	#15-245	S\$126.00 Volume Pricing	20+ In Stock
-	12.50	500.00	520 - 610	325 - 480	325 - 610	#15-246	S\$126.00 Volume Pricing	20+ In Stock
-	12.50	550.00	575 - 710	375 - 530	375 - 710	#15-247	S\$126.00 Volume Pricing	10 In Stock
-	12.50	600.00	625 - 775	400 - 580	400 - 775	#15-248	S\$126.00 Volume Pricing	8 In Stock
-	12.50	650.00	675 - 850	400 - 630	400 - 850	#15-249	S\$126.00 Volume Pricing	5 In Stock
-	12.50	700.00	730 - 900	400 - 675	400 - 900	#15-250	S\$126.00 Volume Pricing	20+ In Stock
-	12.50	750.00	780 - 990	400 - 720	400 - 990	#15-251	S\$126.00 Volume Pricing	15 In Stock
-	12.50	800.00	850 - 1050	410 - 765	410 - 1050	#15-252	S\$126.00 Volume Pricing	20+ In Stock

-	12.50	850.00	900 - 1110	440 - 825	440 - 1100	#15-253	S\$126.00 Volume Pricing	20+ In Stock
-	12.50	900.00	950 - 1180	500 - 860	500 - 1180	#15-254	S\$126.00 Volume Pricing	9 In Stock
-	12.50	950.00	1025 - 1250	500 - 900	500 - 1250	#15-255	S\$126.00 Volume Pricing	6 In Stock
-	25.00	400.00	420 - 505	325 - 385	325 - 505	#15-466	S\$161.00 Volume Pricing	5 In Stock
-	25.00	450.00	470 - 570	325 - 430	325 - 570	#15-256	S\$161.00 Volume Pricing	20+ In Stock
-	25.00	500.00	520 - 610	325 - 480	325 - 610	#15-257	S\$161.00 Volume Pricing	20+ In Stock
-	25.00	550.00	575 - 710	375 - 530	375 - 710	#15-258	S\$161.00 Volume Pricing	14 In Stock
-	25.00	600.00	625 - 775	400 - 580	400 - 775	#15-259	S\$161.00 Volume Pricing	3 In Stock
-	25.00	650.00	675 - 850	400 - 630	400 - 850	#15-260	S\$161.00 Volume Pricing	3 In Stock
-	25.00	700.00	730 - 900	400 - 675	400 - 900	#15-261	S\$161.00 Volume Pricing	20+ In Stock
-	25.00	750.00	780 - 990	400 - 720	400 - 990	#15-262	S\$161.00 Volume Pricing	20+ In Stock
-	25.00	800.00	850 - 1050	410 - 765	410 - 1050	#15-263	S\$161.00 Volume Pricing	20+ In Stock
-	25.00	850.00	900 - 1110	440 - 825	440 - 1100	#15-264	S\$161.00 Volume Pricing	11 In Stock
-	25.00	900.00	950 - 1180	500 - 860	500 - 1180	#15-265	S\$161.00 Volume Pricing	11 In Stock
-	25.00	950.00	1025 - 1250	500 - 900	500 - 1250	#15-266	S\$161.00 Volume Pricing	9 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com