

[All Products](#) / [Lights and Illumination](#) / [Microscopy Lighting](#) / [Microscopy Illumination Sources](#)

SCHOTT VisiLED UV Ringlights

See More by [SCHOTT Optical Components](#)




- Switch Between Bright-Field and UV Illumination
- Maximum UV Illuminance up to 160 W/m²
- Actively Controlled LED Temperature
- Five Segment Modes (Full, Semi, Quarter-Circle, Dual-Segment, Four-Segment)


Technical Information



SCHOTT VisiLED UV Ringlights feature 5 different segment modes to achieve optimal illumination for your application.

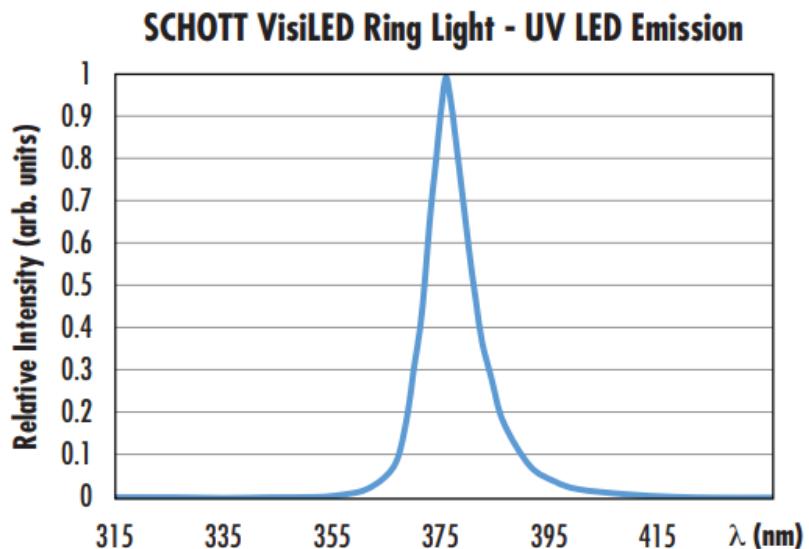

SCHOTT VisiLED Ring Light - White LED Emission

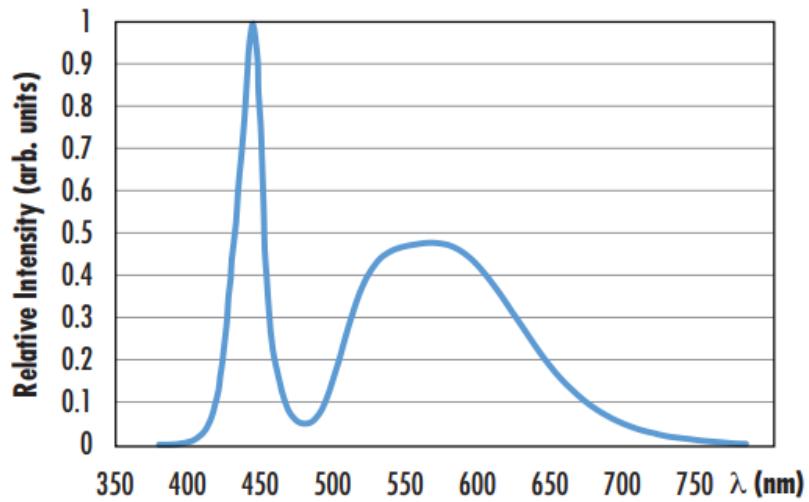

Products

Color	Illumination Mode	Inner Diameter (mm)	Outer Diameter (mm)	Irradiance	Stock Number	Price	Buy
UV	Variable	66	114	UV: 160 W/m ² White: 100 klx at 75mm	#16-789	S\$2,471.00	1 In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com