

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Aspheric Lenses](#) / [Glass Molded](#)
TECHSPEC® Precision Molded Aspheric Lenses


- Precision Glass Molded Lenses
- Ideal for High Volume Production Requirements
- Available in Convenient Packs of 10 for Volume Integration

Common Specifications


Physical & Mechanical Properties

Centering (arcmin):	≤5	Bevel:	Protective as needed
Shape of Back Surface:	Plano	Surface Roughness (Å):	22 (typical)

Optical Properties

Substrate:	L-BAL35	Asphere Figure Error, RMS @ 632.8nm:	1.2λ
Surface Quality:	60-40	Conjugate Distance:	Infinite

Technical Information

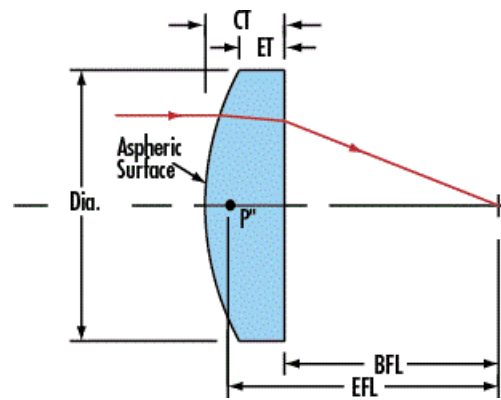

Products

Title	Stock Number	Price	Buy
25mm Dia., 0.50 Numerical Aperture, Uncoated, Precision Molded Aspheric Lens	#17-082	S\$365.40	20+ In Stock
25mm Dia., 0.50 Numerical Aperture, Uncoated, Precision Molded Aspheric Lens (Pack of 10)	#17-156	S\$2,545.20 Volume Pricing	1 In Stock
15mm Dia., 0.66 Numerical Aperture, Uncoated, Precision Molded Aspheric Lens	#29-506	S\$285.60	20+ In Stock
15mm Dia., 0.66 Numerical Aperture, VIS Coated, Precision Molded Aspheric Lens	#29-507	S\$317.80	20+ In Stock



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100

[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :

www.edmundoptics.com