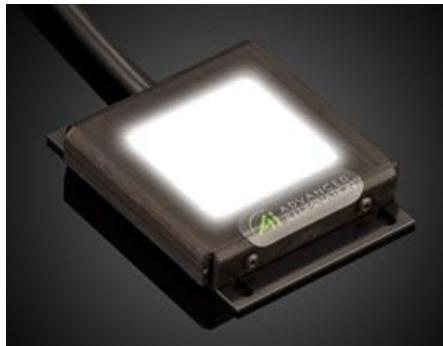


[All Products](#) / [Lights and Illumination](#) / [Machine Vision Lighting](#) / [Backlights](#)

Advanced Illumination MicroBrite High Intensity Edge-Lit Backlights

 See More by [Advanced Illumination](#)


- High Intensity Machine Vision Illuminator
- Edge-to-Edge Uniform, Low Heat Illumination
- Thin, Compact Form Factor
- Optional Manual Intensity Adjustments ([#86-887](#) and [#89-555](#)) Recommended

Common Specifications

General

LED Lifetime (hours):	50,000	Type of Illumination:	LED Illuminator
Note:	Optional Manual Intensity Adjustment #86-887 and #89-555 are Available	Manufacturer:	Advanced Illumination
Geometry:	Backlight	Illumination Mode:	Constant

Hardware & Interface Connectivity

Connector:	Flying Leads	Input Voltage (V):	24V
Environmental & Durability Factors			
Operating Temperature (°C):	0 - 60	Environmental Rating:	IP50

Technical Information

Products

Dimensions (mm)	Color	Wavelength (nm)	Stock Number	Price	Buy
70.3 x 54.71 x 11.33	White	-	#18-547	S\$1,225.00	1 In Stock
70.3 x 54.71 x 11.33	Blue	455	#18-549	S\$1,225.00	3 In Stock
70.3 x 54.71 x 11.33	Green	530	#18-550	S\$1,225.00	Contact Us
70.3 x 54.71 x 11.33	Red	625	#18-548	S\$1,225.00	1 In Stock
70.3 x 54.71 x 11.33	IR	850	#18-551	S\$1,225.00	1 In Stock
120.02 x 104.60 x 11.25	White	-	#18-552	S\$1,379.00	Contact Us
120.02 x 104.60 x 11.25	Blue	455	#18-554	S\$1,379.00	1 In Stock
120.02 x 104.60 x 11.25	Green	530	#18-555	S\$1,379.00	1 In Stock
120.02 x 104.60 x 11.25	Red	625	#18-553	S\$1,379.00	2 In Stock
120.02 x 104.60 x 11.25	IR	850	#18-556	S\$1,379.00	Contact Us



Copyright 2024, Edmund Optics Singapore Pte. Ltd, 18 Woodlands Loop #04-00, Singapore 738100
[PRIVACY POLICY](#) [COOKIE POLICY](#) [TERMS & CONDITIONS](#)

Phone: 1-800-363-1992 :
www.edmundoptics.com